



M8 3-poles, female straight connector

M8 3-poles, male straight connector

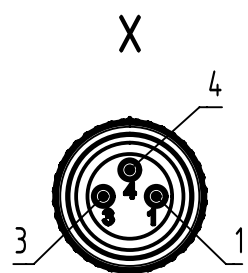


Loading-Plan:

- 1 — brown — 1
- 3 — blue — 3
- 4 — black — 4

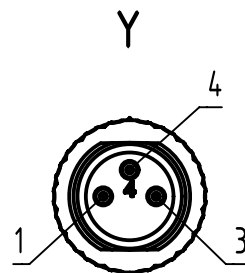

For Information Only
-won't be replaced when changed-

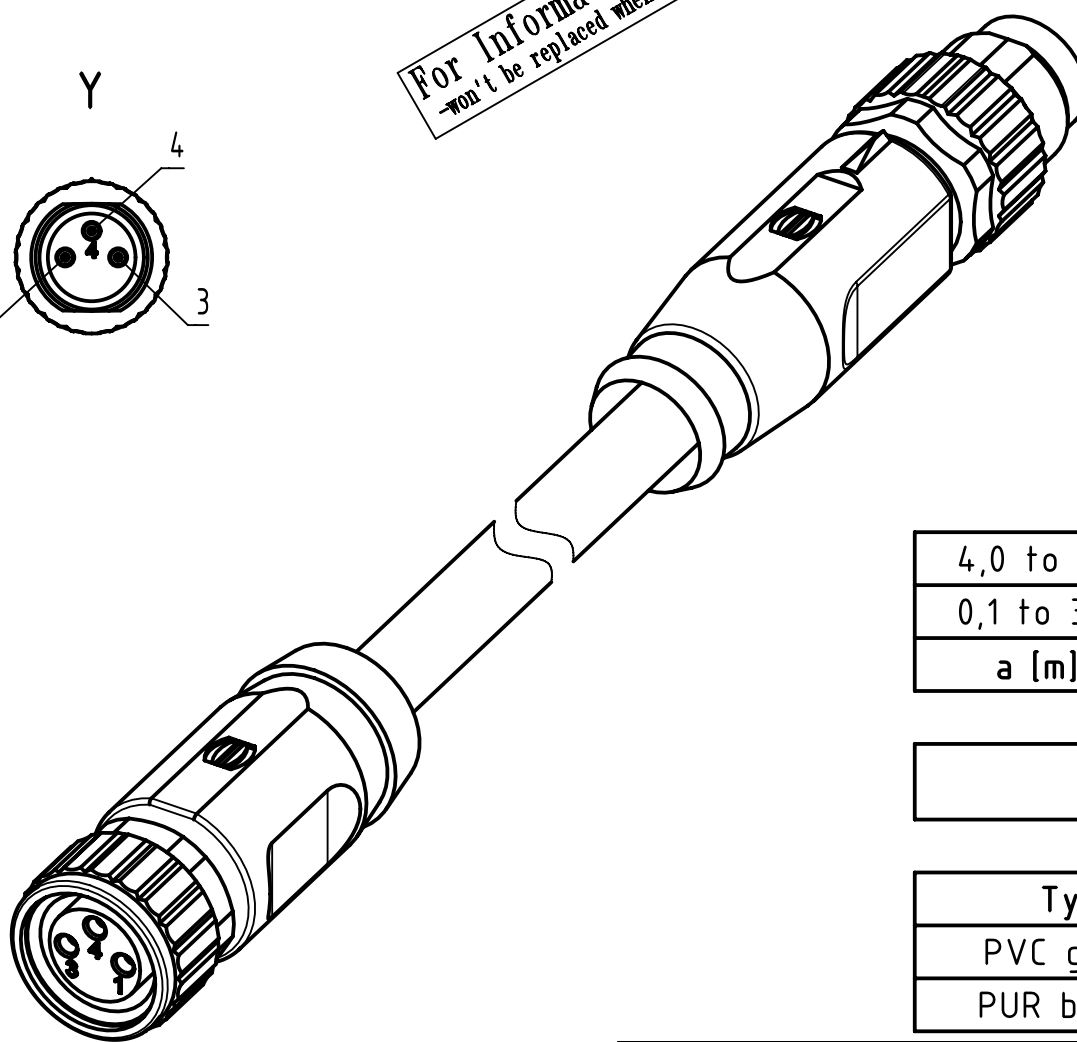

- Protection level: IP67
- Temperature range: -25°C ... +80°C

length in "1m" step	40	XXX=400
	39	XXX=390
	.	.
	12	XXX=120
length in "0,1m" step	11	XXX=110
	10	XXX=100
	9,9	XXX=099
	9,8	XXX=098
	.	.
	0,4	XXX=004
	0,3	XXX=003
	0,2	XXX=002
	0,1	XXX=001
Step	a [m]	XXX

4,0 to 40	+1%
0,1 to 3,9	+0,04
a [m]	Tolerance

Part no.	213480813XXXXXX
----------	-----------------

Type of cable	XX
PVC grey, 3x0,25mm ²	XX=80
PUR black, 3x0,25mm ²	XX=88

	All rights reserved		Scale 2:1		Free size tol.		Ref.	
	Department EC PD - RO		Created by TAMAS	Inspected by	Standardisation	Date 2014-05-20	State Checked Out	
HARTING Electronics GmbH		Title M8 Cable Assembly				Doc-Key / ECM-Nr. 100577987/UGD/009/A		Rev. A
D-32339 Espelkamp		Type TB	Number 213480813XXXXX				Page 1/1	