 



MARKING:

MARKING:



No	BOM ITEM	Q' TY	P/N
1	97606-1 TERMINAL	2 pcs	BBN97606
2	97607-1 TERMINAL	1 pcs	BBN97607
3	IS-018 INNER BODY(YM-C20)	1 pcs	MP020S12
4	PVC 45P (SA87, IS-018)	30 g	RPP04512
5	98739PS-0 BLADE	3 pcs	BBP98739
6	IS-16 INNER BODY(YM-C19)	1 set	M1016S12
7	PVC 45P (SA87, IS-16B)	30 g	RPP04512
8	PE TIE (BLACK · 6 inch)	1 pcs	KBB10006

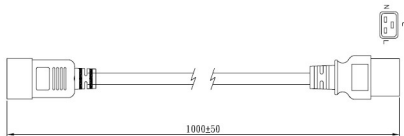

WIRING COLOR:

E: Yellow/Green

N: Blue

L: Brown

LENGTH ON CORD: (206-14)

▲VDE▲ KEMA-KEUR 60227 IEC 53 RVV 300/500V
 NF-USE 1346 IEMMEQU H05VV-F 3G 1.5mm² 60227 IEC 53 RVV 300/500V
 A003083 3ASL/150 4V-75 V-75 (75°C) 250/440V ORDINARY DUTY Q96257 -LF-CE

CABLE		H05VV-F 3G 1.5 DENT PRINT CT-12 (BLACK)			
PLUG		IS-018 + IS-16B	LENGTH	1000	UNITmm
CLIENT	NAME		N/W	0.221771	UNITkg
	P/N	P-C20C1PB1	SG DWG	SR-130859-1	VER. A

X8B 6E3016 12 100 00