



Datenblatt - Fiche technique - Data sheet


11.02.8970




ROLINE USB 3.0 Kabel, Typ A-A, 1,8m

ROLINE Câble USB 3.0 Type A-A, 1.8m

ROLINE USB 3.0 Cable, A - A, M/M, 1.8 m

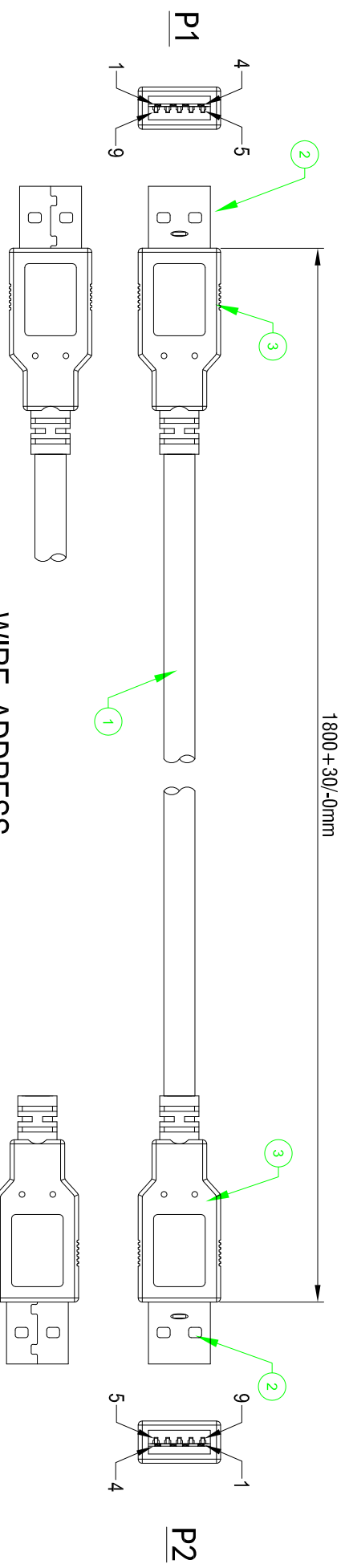

WIRE ADDRESS

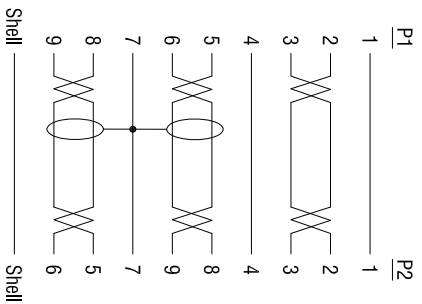

Electrical Test:
 1.100% TEST OPEN SHORT MIS-WIRE.
 2.CONTACT RESISTANCE:3Ω MAX.
 3.INSULATION RESISTANCE:5MΩ MIN.
 4.HI-POT:300V DC/10MS.

NUMBER	1	2	4	Quantity	Unit
3	45P PVC BLACK				6
2	USB 3.0 A MALE(Blue Insulator, Shell Nickel Plated, Pin Gold Plated 30U ^m)			2	PCS
1	UL2725 OR UL20276 (28AWG*1P+EAM)*2C+28AWG*1P+24AWG*2C+AEB, OD=5.5mm, BLACK PVC JACKET (BC Wire)			1	PCS
PRODUCT SPECIFICATIONS					

VER.A	REVISE	DATE
D		
C		
B		
item no. : 11.02.8970		
Draw	Sam	Date: 2014.11.28
Approval		
Duty	F16	
Sample NO.	Drawings of 1/1 (Proportion: 1/1) (mm) A4	

