



Datenblatt - Fiche technique - Data sheet




11.02.8310



ROLINE USB 2.0 Kabel, Typ A ST - Micro B ST, 0,15 m

ROLINE Câble USB 2.0, USB A mâle - Micro USB B mâle, 0,15 m

ROLINE USB 2.0 Cable, A - Micro B, M/M, 0.15 m

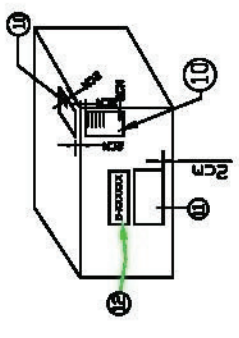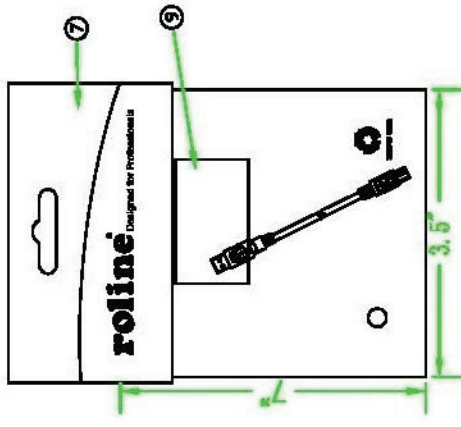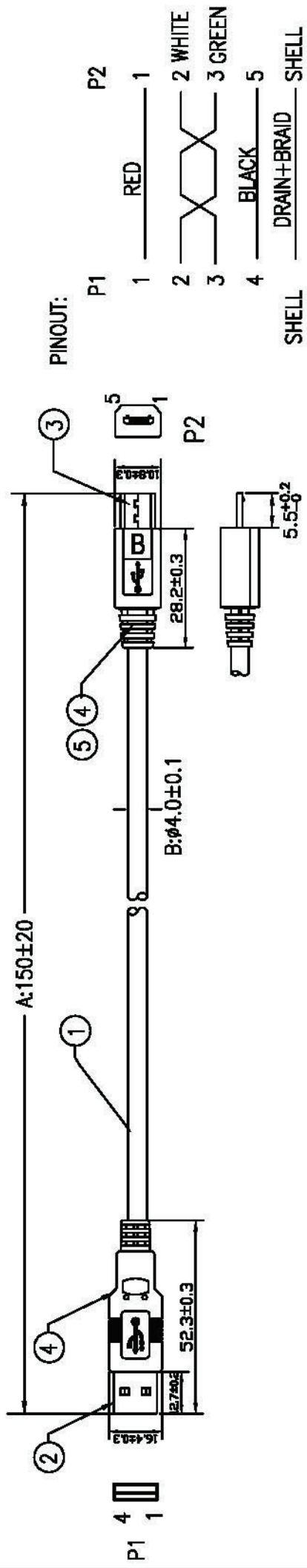

- NOTE:**
- 1) PRIMARY DIMENSION: A,B
 - 2) P1 USB A Male, P2 USB Micro B male
 - 3) ROHS & REACH COMPLIANT
 - 4) 28AWG x 1 PR + 28 AWG x 2C, gold plated pin 30U", 15cm, black color
 - 5) 1 PC/ PE BAG + ROLINE HEADER CARD

roline

ROLINE USB 2.0 CABLE, USB AM TO
USB MICRO BM, BLACK, 0.15M

DIMENSIONS	TOLERANCE	CONF.
0.00 TO 30.00mm	±0.10mm	CONF.
30.01 TO 80.00mm	±0.15mm	APPL.
80.01 TO 180.00mm	±0.15mm	
180.01mm	±0.20mm	
MATERIAL		
FINISH		

DR: **999**

PART NO. 11.02.8310

SCALE: 1/1 UNIT: MM SIZE: A4 REV: A

5	INNER JACKET:PE (RoHS)
4	OUTER JACKET PVC 45Pa BLACK(1101) (RoHS)
3	MicroUSB B PLUG BLACK TERMINAL PLATED GOLD 30U" SOLDER TYPE (RoHS)
2	USB A TYPE 4P MALE WHITE TERMINAL PLATED GOLD 30U" SOLDER TYPE (RoHS)
1	Micro USB2.0 UL2725(28#1P+AL)+28#2C+A+D+B(65%) OD:4.0mm BLACK(1101) 150MM (RoHS)