



Datenblatt - Fiche technique - Data sheet


11.02.8825



ROLINE GOLD USB 2.0 Kabel, USB A ST - USB Micro B ST, 0,8m

ROLINE GOLD Câble USB 2.0, USB A mâle - Micro USB B mâle, 0,8m

ROLINE GOLD USB 2.0 Cable, A - Micro B, M/M, 0.8 m

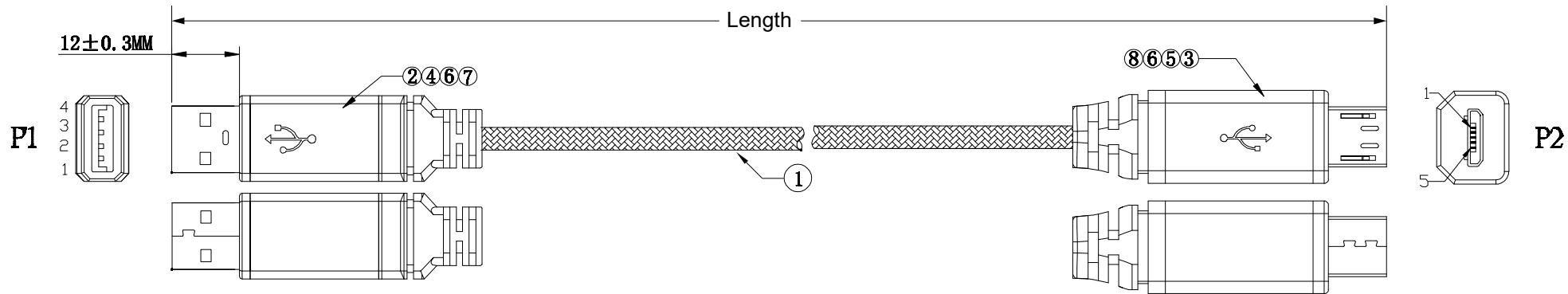

P1	PIN OUT	P2
1	Red	1
2	White	2
3	Green	3
4	Black	5
SHELL	Drain Wire	SHELL

Specification :

- 1 CA2-3701-001 USB Cable; UL2725
28AWG (7/0.127TC)*1P+24AWG (7/0.2TC)*2C+AEB(65%AL)
OD:4.5mm; Jacket: Black Color with Braid
- 2 C01-0025 USB 2.0 AM, Insulator: White, Pin Gold Plated 3u"
- 3 C01-0033 USB 2.0 Micro 5P; Insulator: Black Color; Pin Gold Plated 3u"
Shell: Gold Plated
- 4 H04-0046 USB 2.0 AM, Shell: Gold Plated
- 5 P01-0001 PE
- 6 P01-0000 PVC: 45P, Black
- 7 CM3-0061 USB 2.0 AM Case: Aluminum, Golden Color; L24.0*W15.8*H9.0 mm
- 8 CM3-0067 USB 2.0 Micro 5P Case: Aluminum, Golden Color; L17.8*W10.9*H8.345 mm

P./N.	Length
11.02.8825	800 ⁺²⁰ ₀ mm
11.02.8826	1800 ⁺⁵⁰ ₀ mm

REV.	DATE	CONTENTS OF CHANGE	DESIGNER	TOL ±								APPROVAL	CHECK	DRAWING	DESIGN	DRAWING NAME	ROLINE USB 2.0 AM to Micro 5P, 28AWG		
				RANGE	Pla	Met	Ins	Por	Cab	Pac	Gas						DIS	DATE	PART NO.
①				0~6	0.1	0.1	0.1	0.2	0.5	1	0.5	0.2	PHILIP	PHILIP	TREE	2016-02-17	11.02.8825 / 11.02.8826	ROO	
②				6~30	0.1	0.1	.15	.25	1	1	0.5	.25							
③				30~80	0.1	.15	0.2	0.3	2	1.5	1	0.3							
④				80~180	.15	.15	.25	0.3	2	2	1	.45							
⑤				180~315	.15	0.2	0.3	0.4	2.5	2	1	0.6							
				315~800	0.2	0.3	0.4	0.5	3	3	2	1.1	SCALE	1:1	UNIT	MM			

SECOMP