

5

4

3

2

1

DRAWING NO.

CPMC881-CUST

REVISIONS

OFFICIAL RELEASE

01

03-05-09

Z

G

B

Y

T

Thomas

Chow

Thomas

Chow

Description: Stright BNC Crimp Plug For RG58 Style Cable

Part No: CPMC881

Application: For Cable RG58 Style

Crimp Tool: 24-9958P

Impedance: 50 Ohms

Fequency Range: 0-4 GHz

Material: Body Zinc Nickel Plated

Contact Brass Gold Plated

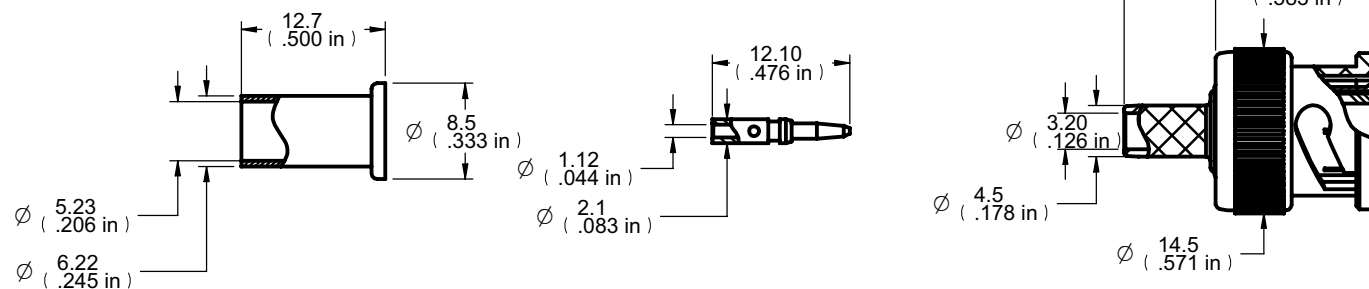
Insulator PTFE

Crimp Sleeve Brass Nickel Plated

Coupling Nut Zinc Nickel Plated

RoHS Compliance: Yes

Technical Detail: Refer to Emerson Document P/N 27-0000

**DIM OUTLINE**

CUSTOMER COPY

TOLERANCE UNLESS OTHERWISE SPECIFIED		DRAWN BY GARY.ZHG	DATE 03-05-09
DECIMALS	mm	CHECKED BY TERRY.W	DATE 03-05-09
X	\pm 0.5	APPROVED BY THOMAS	DATE 03-10-09
X.X	\pm 0.3	U/M	mm
X.XX	\pm 0.1		
ANGLES	\pm 0.5°		

 cinch CONNECTIVITY SOLUTIONS a bel group		TITLE	
		STRAIGHT BNC CRIMP PLUG FOR R58 STYLE CABLE	
SHEET	DRAWING NO.	SIZE	
1 OF 1	CPMC881-CUST	A	

受控 CONTROLLED DOCUMENT

编号 P/N	CPMC881-CUST	版本 Rev	01	日期 Rel'd Date	Apr29,09
-----------	--------------	-----------	----	------------------	----------

THIS DRAWING WAS PRODUCED BY COMPUTER, DO NOT SCALE DRAWING OR UPDATE MANUALLY.

5

4

3

2

1