



RoHS Compliant

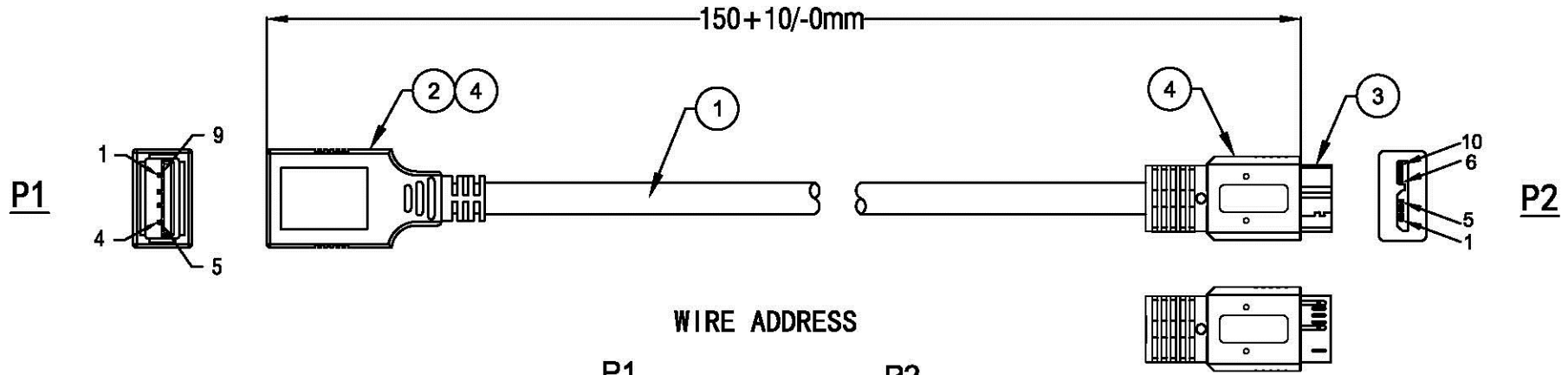

WIRE ADDRESS

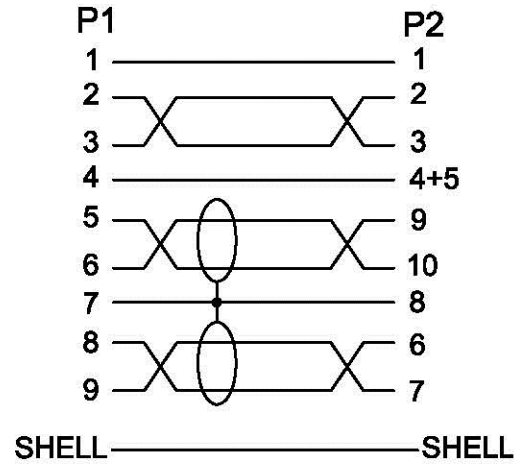

Electrical Test:

- 1.100% TEST OPEN SHORT MIS-WIRE
- 2.CONTACT RESISTANCE:3Ω MAX.
- 3.INSULATION RESISTANCE:5MΩ MIN.
- 4.HI-POT:300V DC/10MS

ROLINE USB3.0 Cable, A-Micro B, F/M, w. OTG

4	45P PVC WHITE		G
3	MICRO USB3.0 MALE (BLACK INSULATION NICKEL PLATED)	1	PCS
2	USB3.0 AF (BLUE INSULATION NICKEL PLATED)	1	PCS
1	USB3.0 UL2725(28AWG*1P+EAM)*2C+28AWG*1P+24AWG*2C+AEB OD=5.5mm,WHITE PVC JACKET	1	PCS
NUMBER	PRODUCT SPECIFICATIONS	Quantity	Unit

Item	11.02.8315	
ROLINE USB 3.0 Cable, A-Micro B, F/M, W/OTG		
Draw	Kobe	Date: 2015.12.29
Approval		
Duty	F16	

**SECOMP**