



Connector Location A

Connector Location B

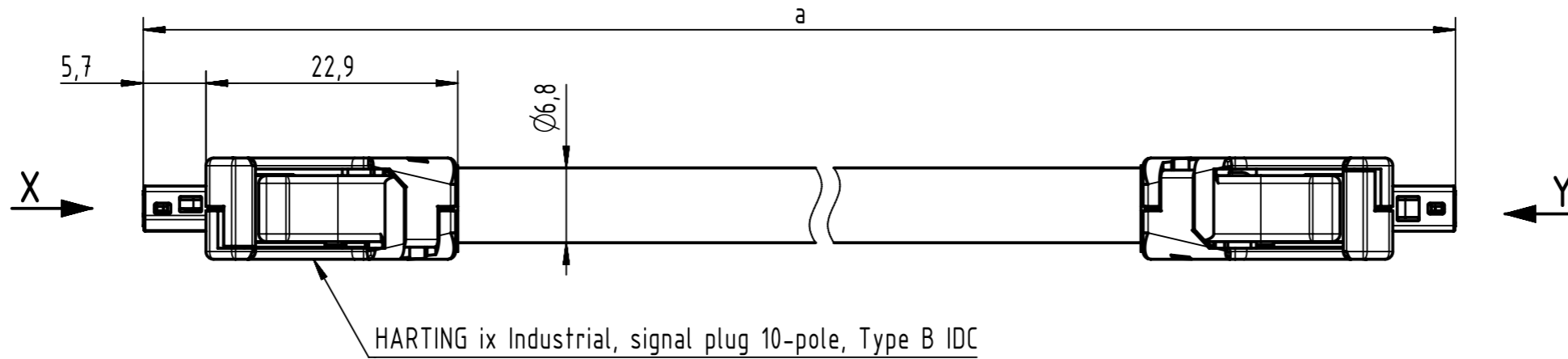

Loading-Plan acc. to DIN 47100

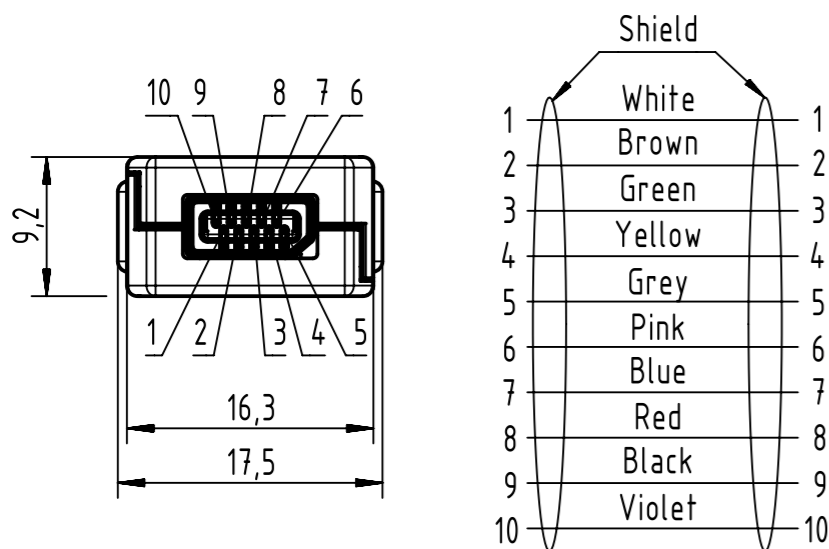

- Protection level: IP20
- Temperature range: -30°C...+80°C
- Contact material: copper alloy
- Contact area: Gold 0.2µm min.

length in "1m" step	100	XXX=000
	99	XXX=990
	.	.
	12	XXX=120
	11	XXX=110
length in "0.1m" step	10	XXX=100
	9.9	XXX=099
	9.8	XXX=098
	.	.
	0.5	XXX=005
	0.4	XXX=004
	0.3	XXX=003
	0.2	XXX=002
Step	a [m]	XXX

6.0 to 100	±1%
0.6 to 5.9	+0.04
0.2 to 0.5	+0.02
a [m]	Tolerance

HELU Signal PVC cable 5x2x0.14mm ² , grey	33481111A20XXX
Type of cable	Part no.

	All rights reserved		Created by STOCHECIC		Inspected by COSTEA		Standardisation AVRAM		Date 2018-01-12		State Final Release	
	Department HCS - RO		ix Industrial Type B PVC cable assembly									
HARTING Customised Solutions D-32339 Espelkamp		Type TB		Number 33481111A20XXX				Rev. A		Page 1/1		