


Connector Location A


Connector Location B

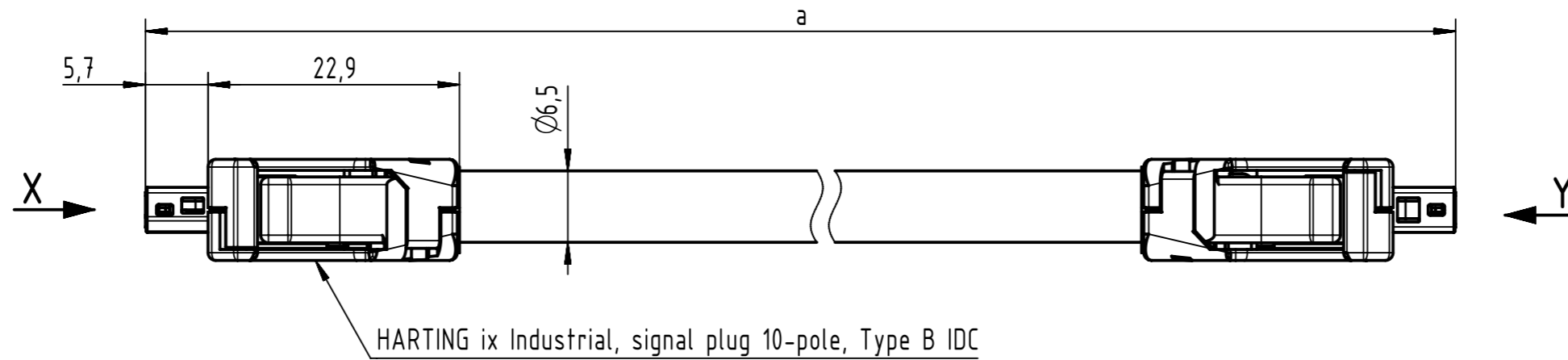



X

Loading-Plan
acc. to DIN 47100

Y

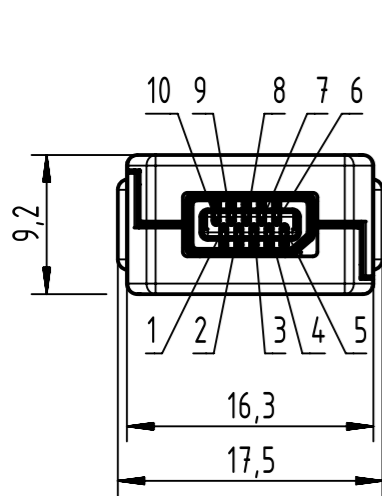

Shield	
1	White
2	Brown
3	Green
4	Yellow
5	Grey
6	Pink
7	Blue
8	Red
9	Black
10	Violet

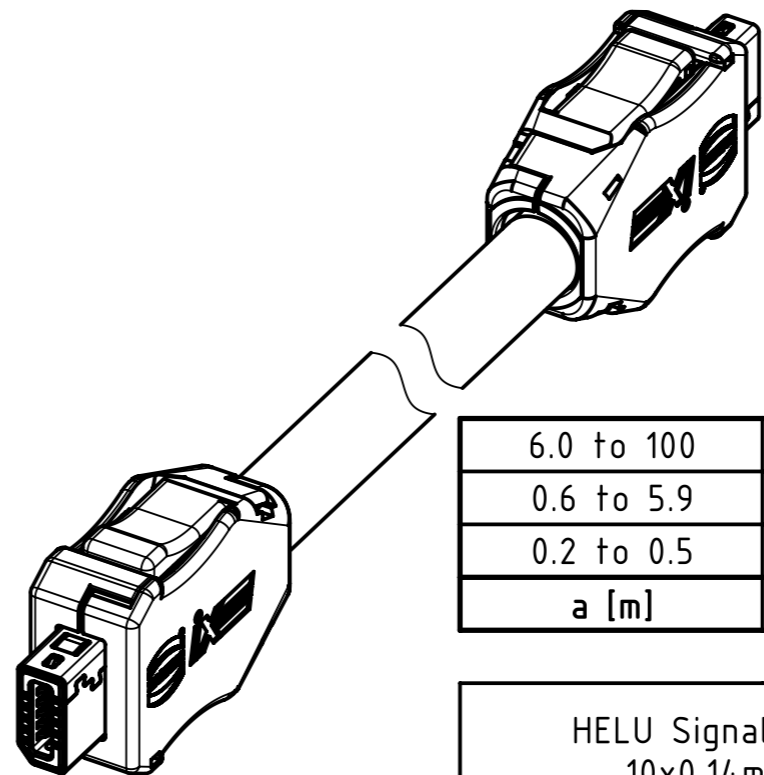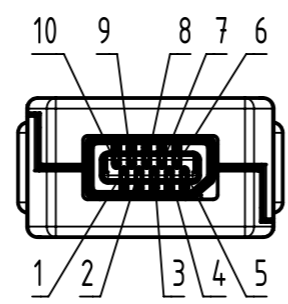

6.0 to 100	±1%
0.6 to 5.9	+0.04
0.2 to 0.5	+0.02
a [m]	Tolerance

length in "1m" step	100	XXX=000
	99	XXX=990
	.	.
	12	XXX=120
length in "0.1m" step	11	XXX=110
	10	XXX=100
	9.9	XXX=099
	9.8	XXX=098
	.	.
	0.5	XXX=005
	0.4	XXX=004
	0.3	XXX=003
	0.2	XXX=002
Step	a [m]	XXX

HELU Signal PUR cable
10x0.14mm², grey

Type of cable

33481111A21XXX

Part no.

- Protection level: IP20
- Temperature range: -40°C...+80°C
- Contact material: copper alloy
- Contact area: Gold 0.2µm min.

	All rights reserved		Created by STOCHECIC		Inspected by COSTEA		Standardisation AVRAM		Date 2018-01-12		State Final Release		
	Department HCS - RO		ix Industrial Type B PUR cable assembly										
HARTING Customised Solutions		D-32339 Espelkamp		Title		Type TB		Number 33481111A21XXX		Doc-Key / ECM-Nr. 100758988/UGD/000/A 500000129886		Rev. A	Page 1/1