
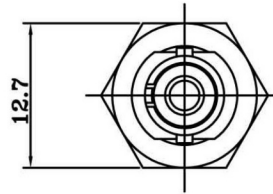
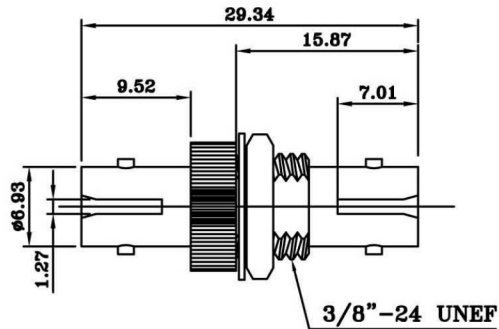



ROHS Compliant

Code: KOTMM, KOTSM

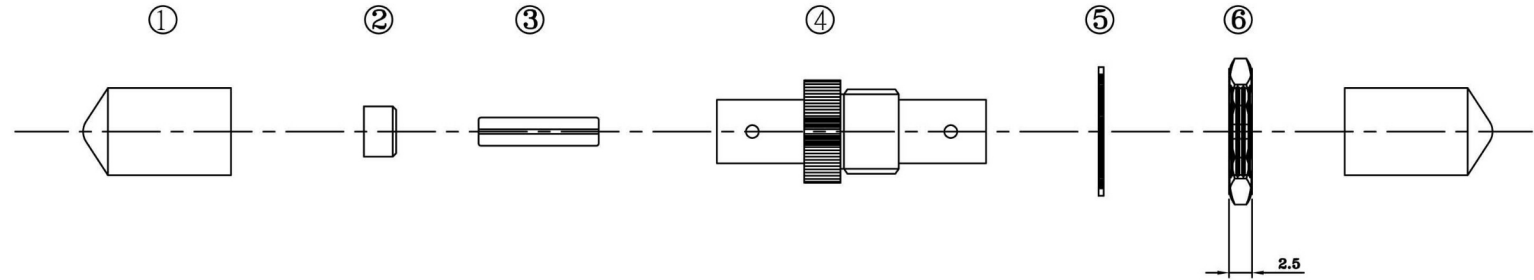

Connector specifications:

- a. Colour: KOTMM black dust cover, KOTSM yellow dust cover
 - b. Alignment Sleeve: KOTMM PhBr, KOTSM Zr02
 - c. Insertion Loss: 0.20dB MAX
 - d. Durability (500 MATINGS): 0.15dB MAX INCREASE
 - e. Retention Force: 200~600 Grams
 - f. Operating Temperature: -40°C~+80°C
 - g. Material: Zn-Alloy
- Keystone Adaptor Material: ABS UL94V-0, available in white or black

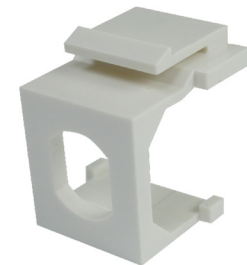

6	3/8"-24 UNEF	Cu-Ni	1	▽:Critical Dim ⊙:Major CAV Tolerances 0. ±0.50 0.0 ±0.20 Angle ±2°
5	Washer	Steel-Ni	1	
4	ST Adaptor Body Simplex	Zn-Alloy	1	
3	Sleeve	KOTMM PhBr, KOTSM Zr02	1	
2	Bush	Cu-Ni	1	
1	ST Adaptor Cap	PVC	2	⊕
NO	Descriptions	Material	Q'ty	