


ROHS Compliant

Code:KOCMM, KOCSM

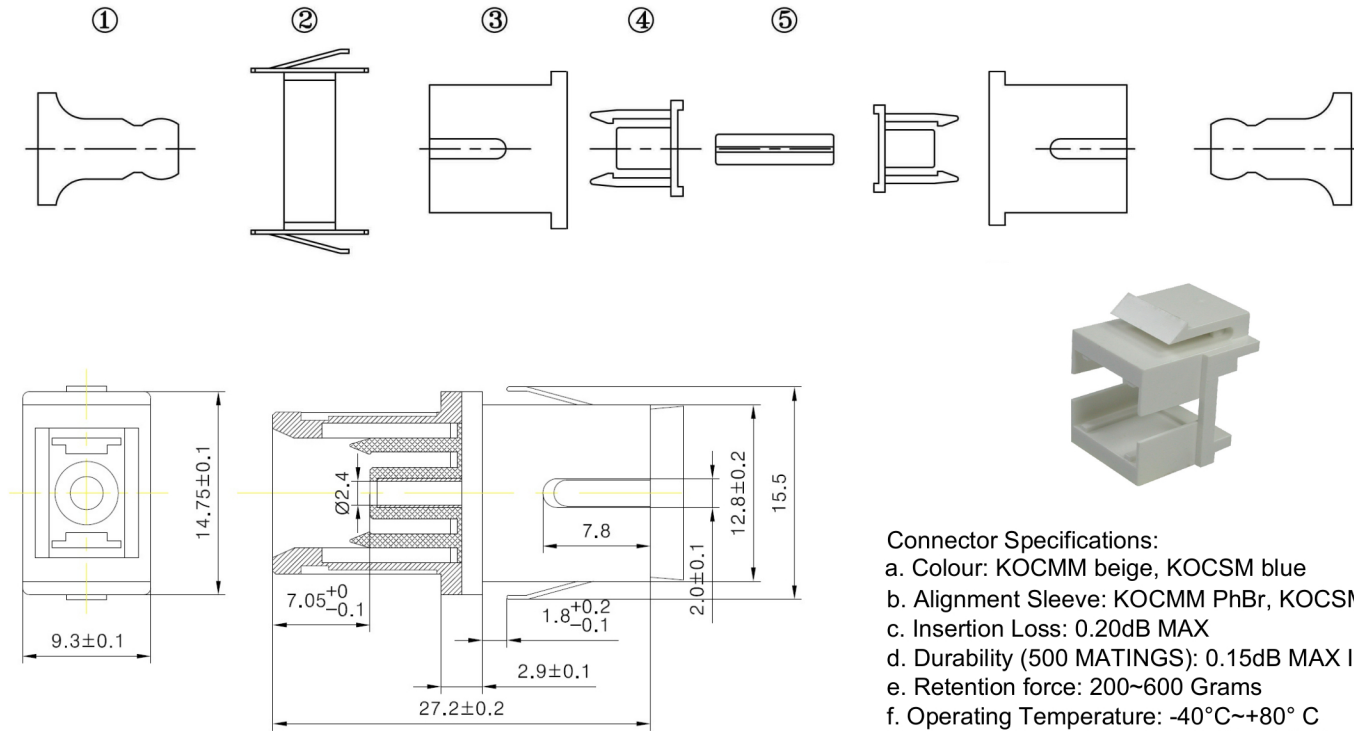

Connector Specifications:

- a. Colour: KOCMM beige, KOCSM blue
 - b. Alignment Sleeve: KOCMM PhBr, KOCSM Zr02
 - c. Insertion Loss: 0.20dB MAX
 - d. Durability (500 MATINGS): 0.15dB MAX INCREASE
 - e. Retention force: 200~600 Grams
 - f. Operating Temperature: -40°C~+80° C
- Keystone Adaptor Material: ABS UL94V-0,
available in white or black

5	Sleeve	KOCMM PhBr, KOCSM Zr02	1	▽:Critical Dim
4	SC Hook	PBT(GF 15%)	2	⊙:Major CAV
3	SC Adaptor Body Simplex	PBT(GF 30%)	2	Tolerances
2	Clip	Stainless	1	0. ±0.50
1	SC Adaptor Cap	ABS	2	0.0 ±0.20
NO	Descriptions	Material	Q'ty	Angle ±2°