
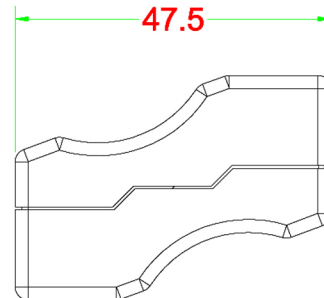
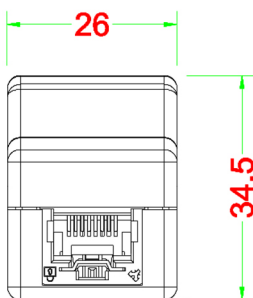


ROHS Compliant

Code: SACLJ

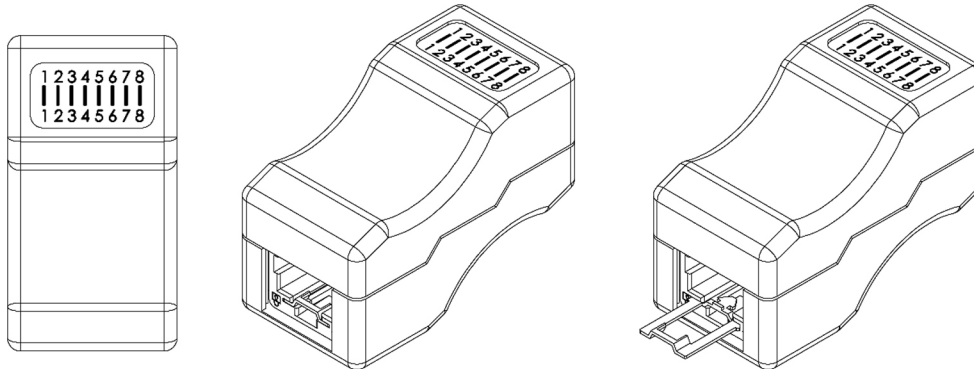

Performance:

Meets C6 EIA/TIA 568B Standard.

Materials:

Body : Fireproof ABS UL-94V0

Jack : 8P8C 50 μ "/1.27 μ m gold plating

PCB : FR-4 / UL-94V0

Locking bar: Cold Rolled Steel SPCC

Electrical Specifications:

Insulation Resistance : 500M ohms (min.)

Contact Resistance : 20m ohms (max.)

Current Rating : 1.5 Amps .

DC Resistance : 0.1 ohm (max.)

Withstanding Voltage : 1000 VAC RMS @ 60Hz / 1 min.

Mechanical Specifications:

Jack Insertion Cycle : Over 2000 Cycles (min.)

Lock Bar Tension : 15 kgs (min.)

Operation Temperature : -40 °C ~ +70 °C

TOLERANCE: X $\pm$ 1 • X $\pm$ 0.2 • XX $\pm$ 0.15