 

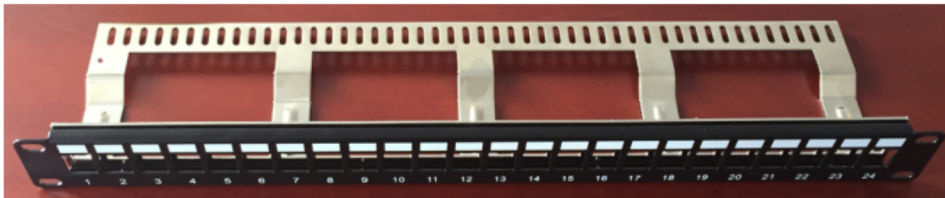


ROHS Compliant

Code: FFK24mtpt

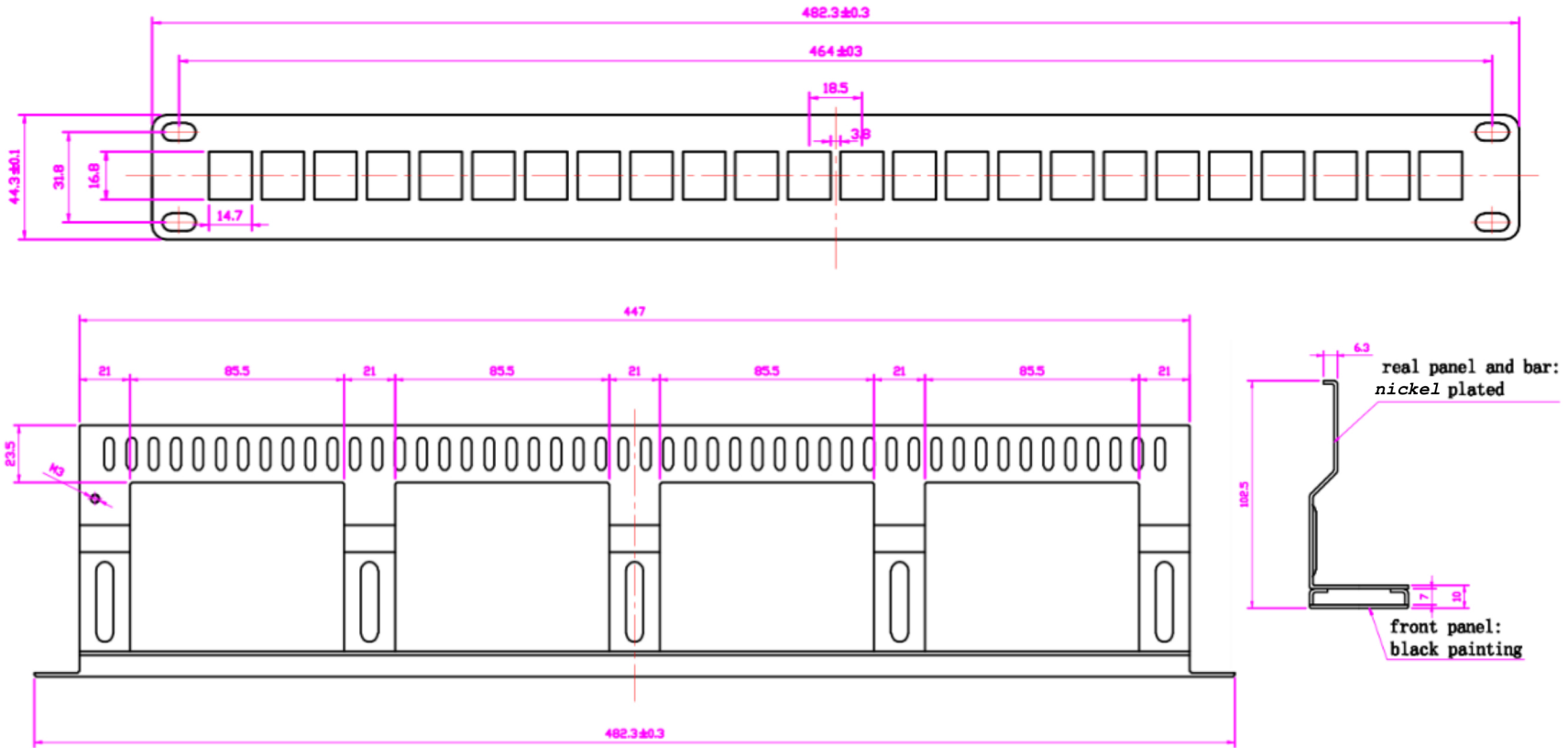







Accessories included:

4sets of M6 black cage nuts

1pc 25cm earth wire with 1set of M4 fixing parts

ROHS Compliant

Code: SGKSLJ

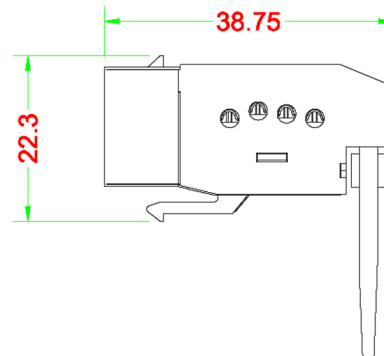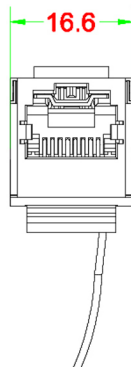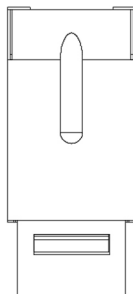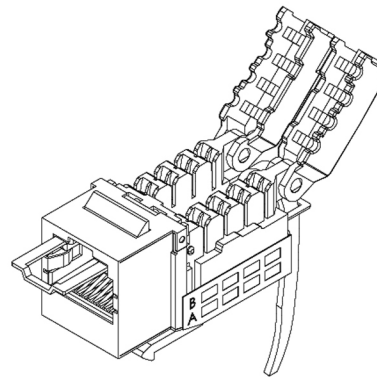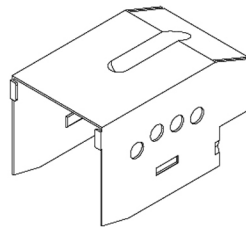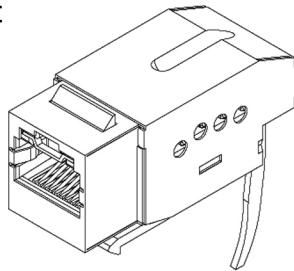

- Performance:
Meets C6A EIA/TIA 568C Standard.

- Materials:
Body : Fireproof ABS UL-94V0
Metallic Case : Metal
Jack : 8P8C 50 μ "/1.27 μ m gold plated
PCB : FR-4 / UL-94V0
IDC Cap : Fireproof PC
IDC Body: Fireproof ABS UL-94V0
IDS Pin : Phosphor Bronze & Tinned
Lock Bar : Metal (SPCC)
IDC Description : For 22-26 AWG / 0.404 - 0.643 mm
For 110 or Krone punch-down Tool
Toolless (when use IDC cap directly)

- Electrical Specifications:
Insulation Resistance: 500 M Ω (min.)
Contact Resistance: 20 m Ω (max.)
Current Rating: 1.5 Amps
DC Resistance: 0.1 Ω (max.)
Withstanding Voltage: 1000 VAC RMS @ 60Hz / 1 min.

- Mechanical Specification:
IDC Punch Down Cycle: Over 250 Cycles (min.)
Jack Insertion Cycle: Over 2000 Cycles (min.)

- Operation Temperature: -40 °C ~ +70 °C