

923 Receptacle

speedtec - ready

8-pin

**Earth-to-Housing Connection according to VDE 0627
rear mount /lock nut M25x1.5 fixed end stop**

Technical Data

number of pins	8
power	4 (3+PE)
signal	4
temperature range	-20 °C to 130 °C
protection type	when connected IP 66/67

Electrical Data

rated current	max. 30 A*	max. 7 A*
rated voltage	630V (AC/DC)	250 V (AC/DC)
rated insulation voltage (L-L)	6000 V	2500 V

mating cycles	500
---------------	-----

Data according to VDE 0110/EN61984, Paragraph 6.19.2.2

pollution degree	3
over voltage category	III
max. height for operation	2000 m

Material


housing	zinc diecast / nickel plated
insulation insert	PA 6.6 mod., UL 94/V0
seals	EKM

Contacts (not part of product contents)

Tools (not part of product contents)



Contact Arrangement
mating view

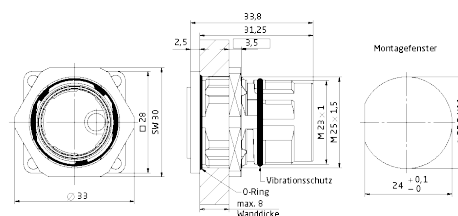

Main Dimensions

Receptacle

*for max. wire cross-section
pay attention to the
cross-section of used contacts