

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

2181121004

Status:


Active

Overview:

PicoBlade Connector System

Description:

PicoBlade Female-to-Pigtail Off-the-Shelf (OTS) Cable Assembly, Single Row, 425.00mm Length, 10 Circuits, Natural

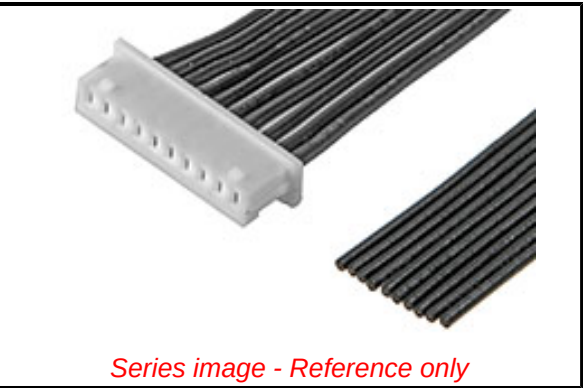

Documents:

Drawing (PDF)

RoHS Certificate of Compliance (PDF)

General	
Product Family	Cable Assemblies
Series	218112
Application	Signal, Wire-to-Board, Wire-to-Wire
Assembly Configuration	Single Ended Connector
Connector to Connector	PicoBlade-to-Pigtail
Overmolded	No
Overview	PicoBlade Connector System
Product Name	PicoBlade
Type	Discrete Wire Assembly
UPC	195842250925
Physical	
Cable Length	425.00mm
Circuits (Loaded)	10
Color - Resin	Natural
Gender	Female-Pigtail
Lock to Mating Part	Yes
Material - Metal	Phosphor Bronze
Material - Plating Mating	Tin
Material - Plating Termination	Tin
Material - Resin	Polyester
Net Weight	5.871/g
Number of Rows	1
Packaging Type	Bag
Pitch - Mating Interface	1.25mm
Plating min - Mating	0.889µm
Plating min - Termination	0.914µm
Single Ended	Yes
Termination Interface: Style	Crimp or Compression
Wire Insulation Diameter	0.50-1.00mm
Wire Size AWG	28
Wire/Cable Type	UL 1061
Material Info	
Reference - Drawing Numbers	
Sales Drawing	2181121000-000

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per - D(2020)9139-DC (19 Jan 2021)

Halogen-Free

Status

Not Low-Halogen

For more information, please visit [Contact US](#)

China RoHS

Green Image

ELV

Not Relevant

RoHS Phthalates

Not Contained

Search Parts in this Series

218112 Series

Mates With

PicoBlade Header [53261](#) , [53047](#) , [53398](#) , [53048](#) . PicoBlade Plug Housing [51047](#)

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION