


# SERPAC<sup>®</sup> RBF33X06Y28Y

Electronic Enclosures

2

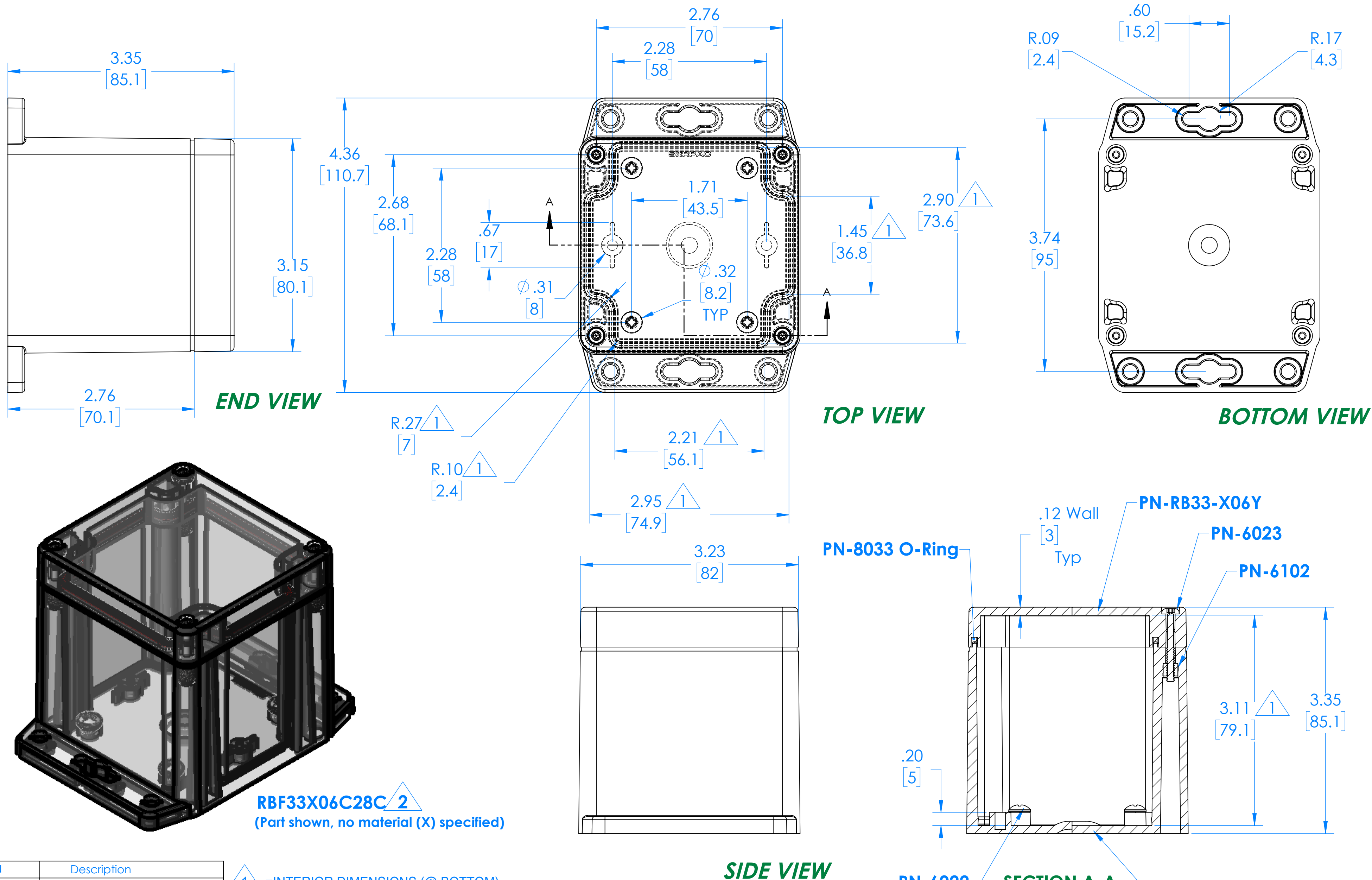

| PN        | Description                    |
|-----------|--------------------------------|
| RB33-X06Y | (1) RB33-X06Y, Top             |
| RBF33X28Y | (1) RBF33X28Y, Bottom          |
| 8033      | (1) RB33 O-Ring                |
| 6023      | (4) #4-40 Torx 10 Hd Screw     |
| 6022      | (4) #10 High/Low Pan Hd x 1/4" |
| 6102      | (4) #4-40 Threaded Insert      |


- 1 = INTERIOR DIMENSIONS (@ BOTTOM)
- 2 = STANDARD COLORS (Y) ARE: BLACK (B), CLEAR (C) AND GRAY (G)  
TOPS AND BOTTOMS ALL POSSIBLE COMBINATIONS AVAILABLE  
STANDARD MATERIALS (X) IS: POLYCARBONATE (P)

-Watertight enclosure meets or exceeds Nema 4 and or IP67.

DIMENSIONS in Inch [mm]

ALL DIMENSIONS ARE  $\pm .010"$  7/13/2021  
2009 Wright Ave., La Verne, Ca. 91750  
Ph. (626) 331-0517 Fx. (626) 331-8584 [serpac.com](http://serpac.com)

# RBF33 Circuit Board (Fits all Parts starting with RBF33)

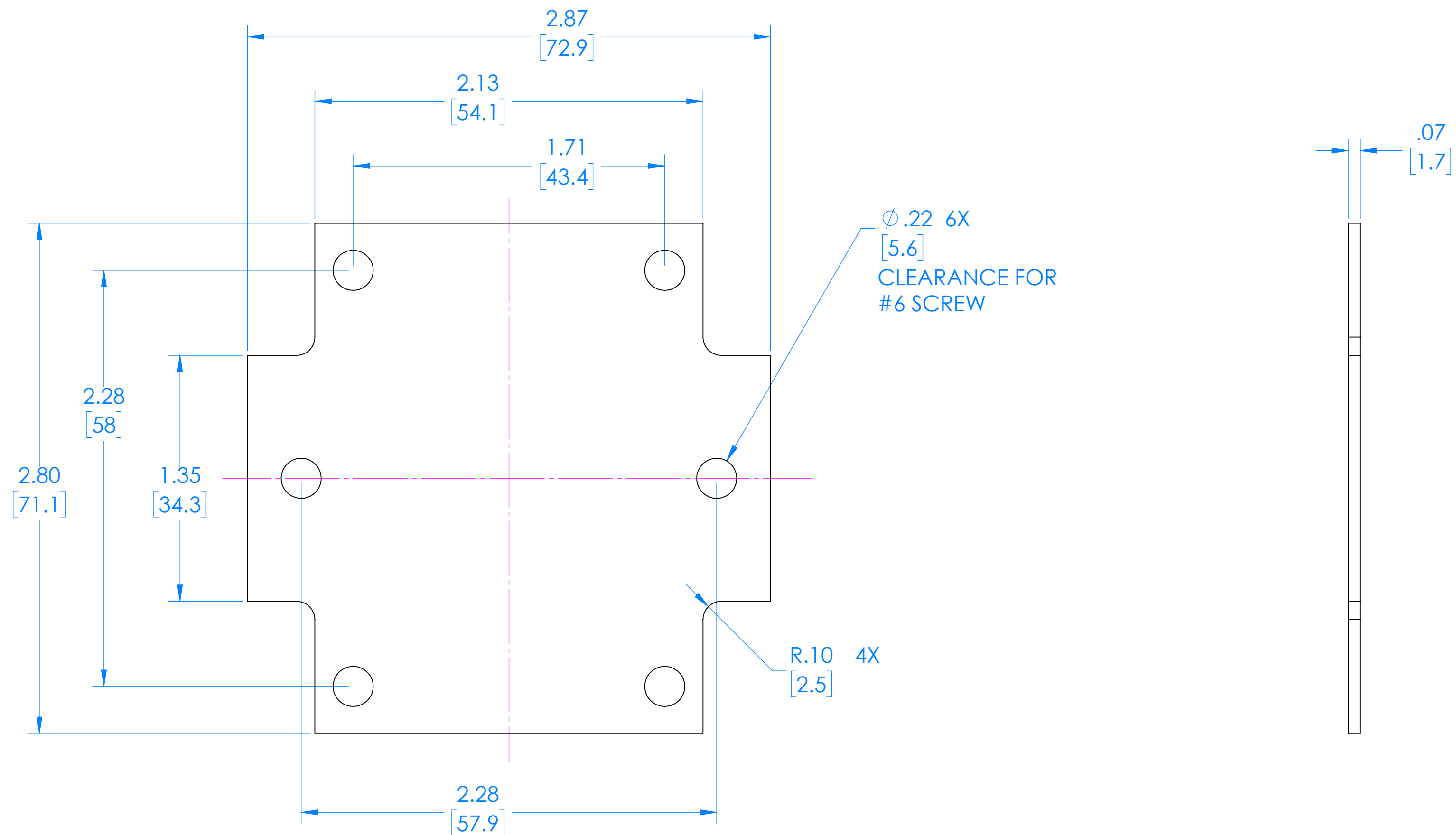

(REFERENCE ONLY)