


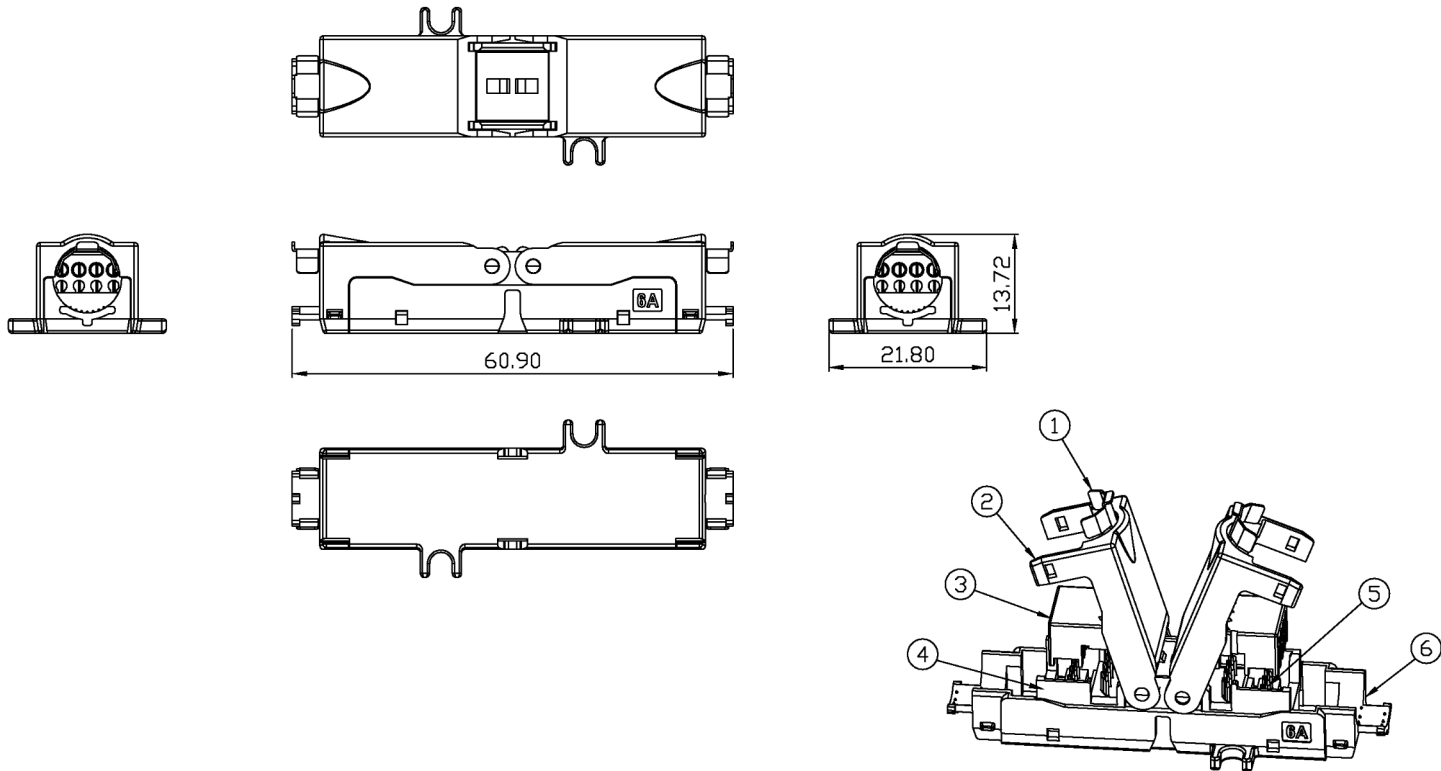

- Current rating : 1.5A
- Dielectric withstanding voltage: 1000V AC
- Insulation resistance : 500M Ω MIN
- Contact resistance : 20m Ω MAX
- Durability:100 mechanical cycles
- Wiring properties: 26 ~ 22 AWG
- Supporting cable diameter: 6 ~ 9mm

MATERIAL

- (1) Earth point:SUS304
- (2) Housing Lid: Zinc-alloy, Nickel Plated
- (3) IDC Housing cover: PC FR
- (4) IDC Housing: PC VO
- (5) IDC Terminals: Phosphor bronze, Tin Plated
- (6) Housing Base: Zinc-alloy, Nickel Plated