



ROHS Compliant

**Code: KCUAA3bk2**

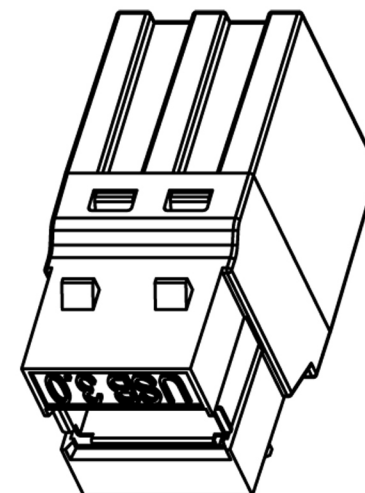

Connector Contact: 15U" Gold Plating  
 Contact Resistance: 30mΩ (max)  
 Insulation Resistance: 10MΩ (min)  
 Voltage Rating: 30 VDC (rms)  
 Insertion Force: 35N (max)  
 Extraction Force: 10N (min)  
 Durability Ratings: 1500 cycles (min)  
 Operating Temperature: -20 ~ 50°C  
 Storage Temperature: -40 ~ 70°C

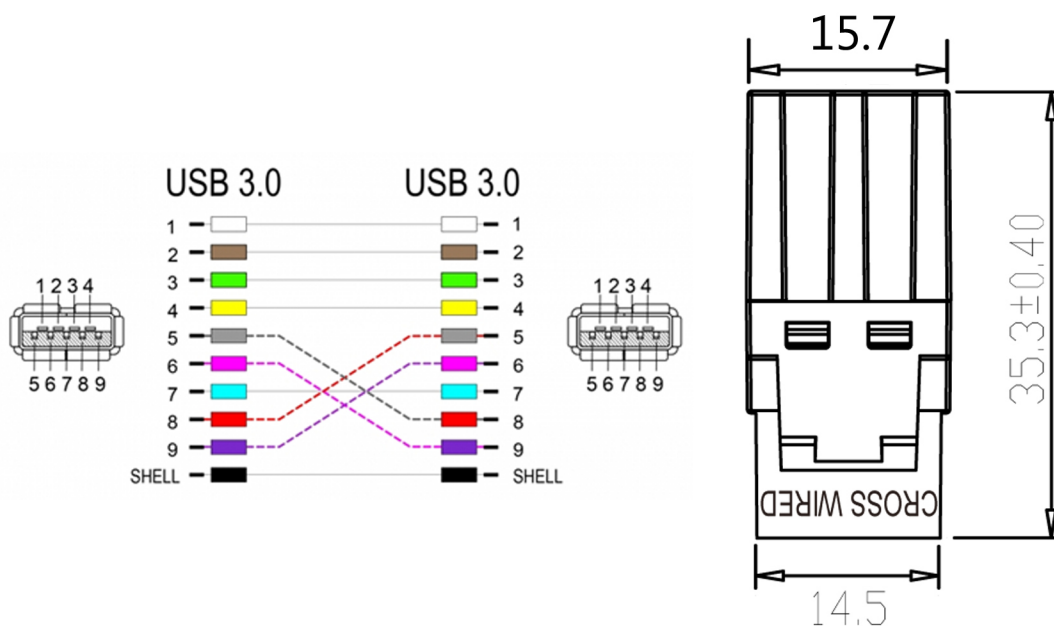