


ROHS Compliant

Code: SGACK902S

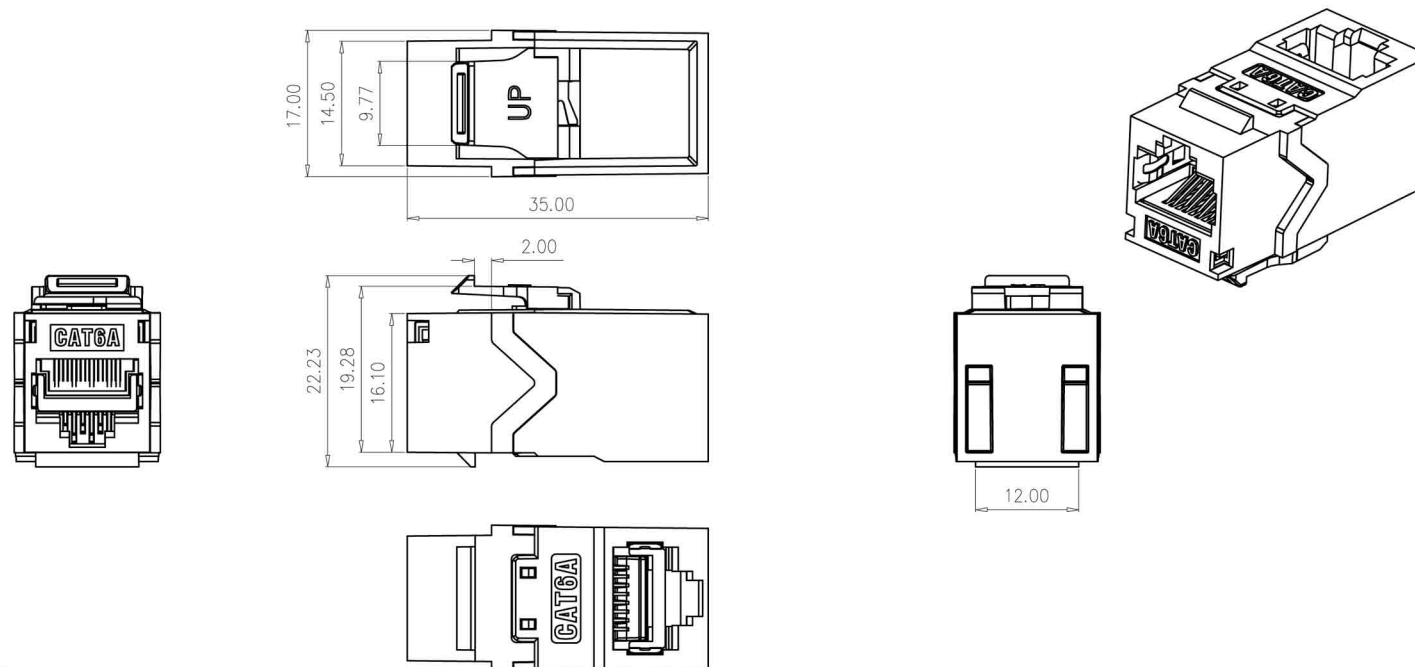

ELECTRICAL

CURRENT RATING: 1.5A.

DIELECTRIC WITHSTANDING VOLTAGE: 1000V AC 60Hz.

INSULATION RESISTANCE: 500M Ω MIN.

CONTACT RESISTANCE: 20m Ω MAX.

MECHANICAL

(1)Materials:Zinc Alloy

(2)RJ45 Jack Contact:Phosphor bronze,50U"/1.27 μ m Gold Plating