
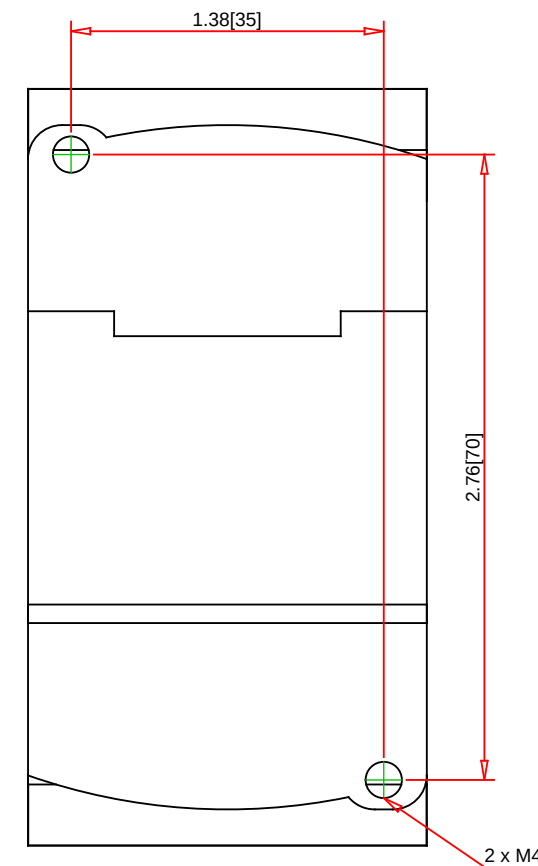


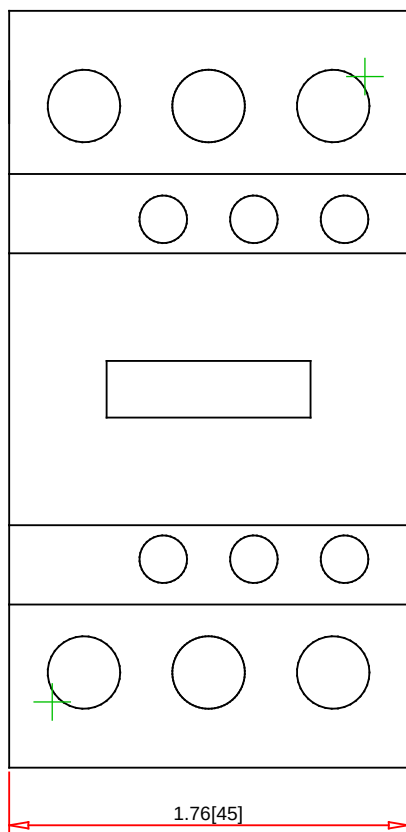

Note:
- Drawings Not To Scale
- Drawings Subject to Change Without Notice
- Dimensions are inches next to [Millimeters]

Part No.:
LC1D326GD

Schneider Electric
Schneider Electric United States
North American Division
Boston One Campus
800 Federal Street
Andover, MA 01810, USA
Phone: +1 8773425173
Email: CCC@us.schneider-electric.com

Technical Information:
Rating: 600V / 32A
UL File/CCN: E164862 / NLDX
CSA File: LR43364 3211 04
Meets Standards: IEC 60647-4
Weight: 0.83 lb (0.375 kg)
Termination Method: Ring Tongue
Wire Size: Power: Lug Size 0.32 in (8mm)
Control: Lug Size 0.32 in (8mm)
Terminal torque: Power: 15 lb-in (1.7 Nm)
Control: 15 lb-in (1.7 Nm)
Mounting Hwd.: 35mm DIN Rail, #8 screw

Specification:

Description	TeSys D IEC Contactor - 32A - Vdc Coil				
Type	TeSys D IEC Contactor - 32A - 125Vdc Coil				
Voltages Code:	GD at 120Vdc				
Coil Consumption:	Inrush 5.4 W Sealed 5.4 W				
Single Phase		Three Phase			
115V	230V	200V	230V	460V	575V
2 HP	5 HP	10 HP	10 HP	20 HP	30 HP