


DANS LE BUT CONSTANT D'AMELIORER SES PRODUITS, Amphenol Socapex SE RESERVE LE DROIT D'EN MODIFIER TOUTE COTE OU CARACTERISTIQUE.
IMP 037 A

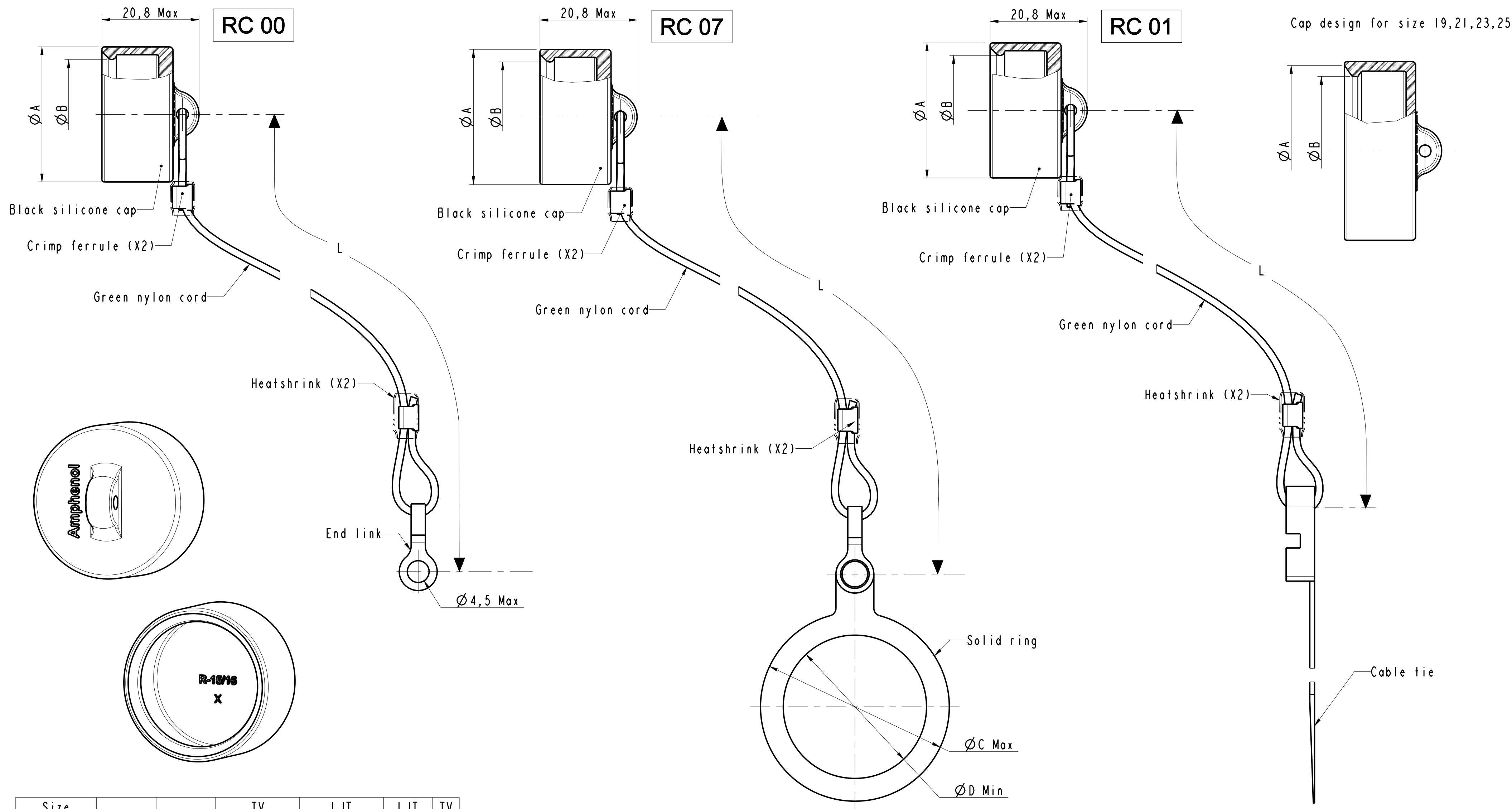

Size	Ø A Max	Ø B Max	TV		LJT		LJT	TV
TV/LJT			C Max	D Min	C Max	D Min	L ⁺¹³ ₋₇	
9	19,25	13,85	27	17,64	26,16	17,78	76,20	127
11	22,55	17,20	32	21,97	30,73	21,34		
13	25,95	20,60	37	25,12	35,56	25,65		
15	28,75	23,40	40	29,92	40,64	28,96	88,90	
17	32,75	27,40	44	32,00	43,18	32,00		
19	35,05	28,25	46	36,27	45,72	35,36		
21	37,95	31,60	49	38,25	48,77	38,35	101,60	
23	41,15	34,80	54	42,62	53,34	41,66		
25	44,30	37,70	56	44,45	55,88	44,70		

Note:

1. All attachments (Ferrule, End links & Solid ring) are stainless steel passivated.

Commercial designation
RC 00 N TV 9

Shell size: 9 to 25

Series: TV, LJT

N: For nylon cord

Shell Type

00: Square Flange Receptacle

07: Jamnut Receptacle

01: Line Receptacle

RC: Rubber Cap

Protective rubber cap for receptacle
(TV,LJT)

Size 15 represented

MODIFICATIONS	H	Updated drawing	ECHELLE	Amphenol Socapex		DESSIN: S. Holennavar LE: 03/02/16	
			1,75				
				BP 29 - 74311 THYEZ CEDEX		TECHNIQUE: R Reddy LE: 13/08/20	
						H	
						173-PLC-1385-00 1/1	