

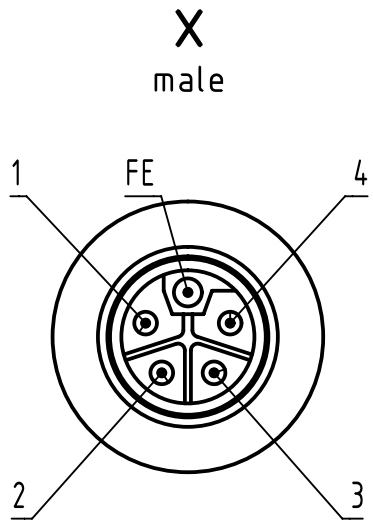


Connector Location A

Connector Location B

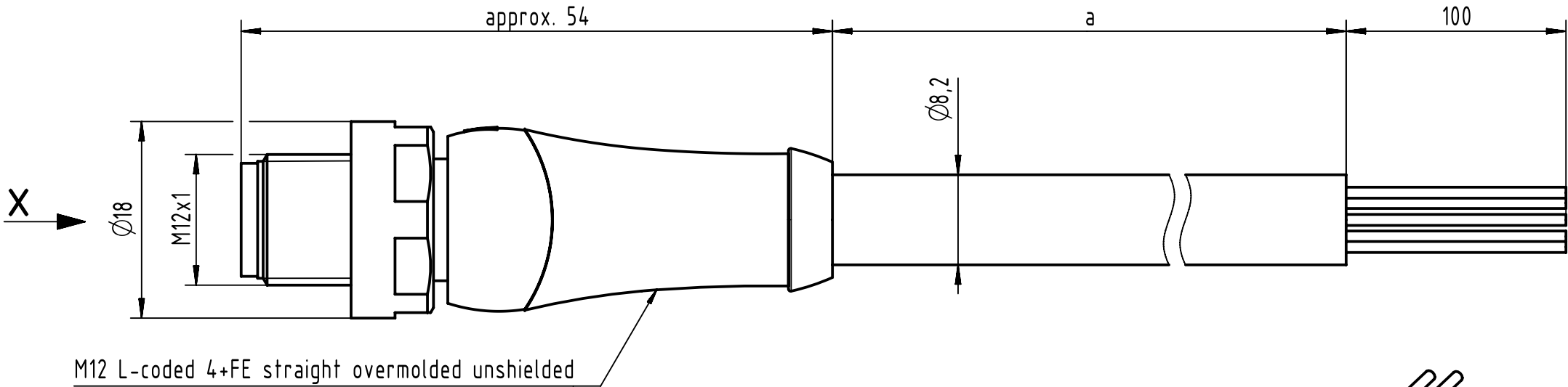

- Protection level: IP65/67
- Temperature range: -25°C ... +80°C

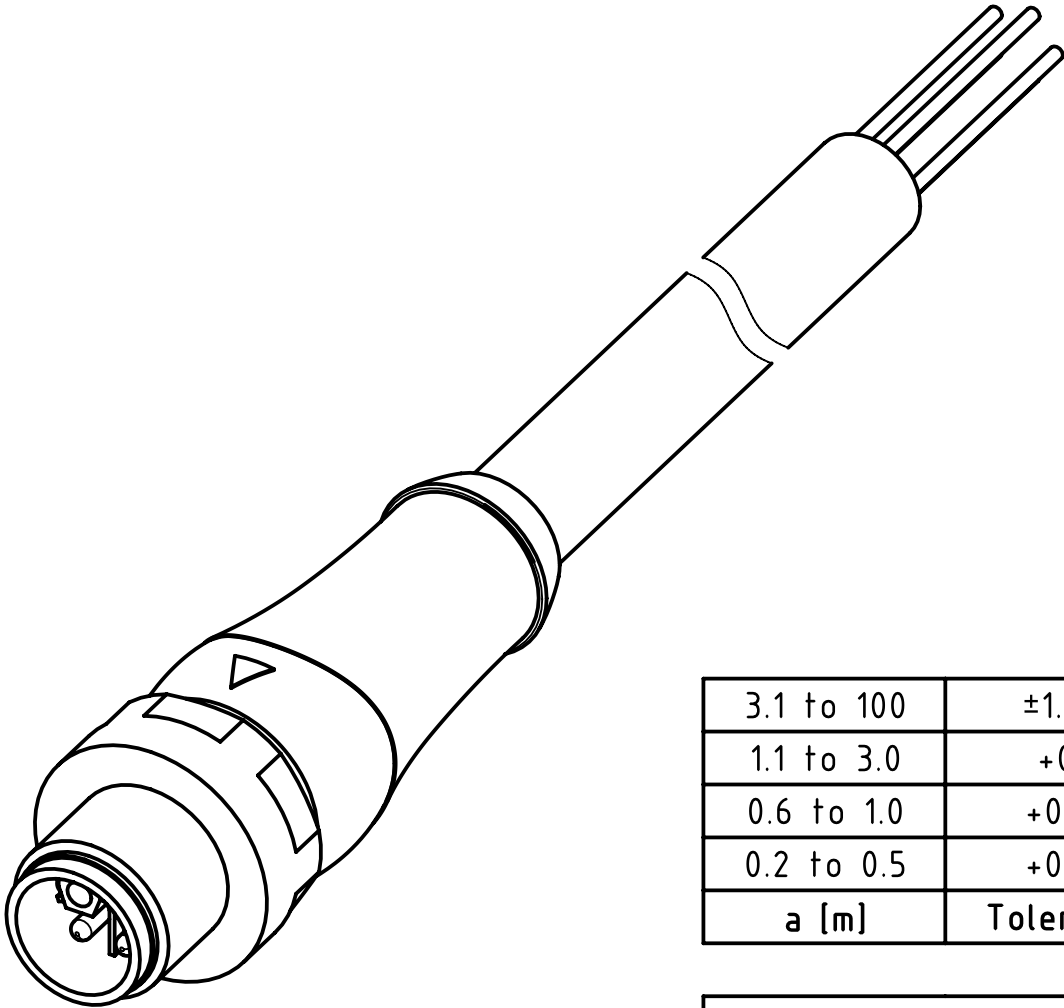

3.1 to 100	±1.5%
1.1 to 3.0	+0.1
0.6 to 1.0	+0.05
0.2 to 0.5	+0.03
a [m]	Tolerance

length in "1m" step	100	XXX=000
	99	XXX=990
	.	.
	12	XXX=120
	11	XXX=110
length in "0.1m" step	10	XXX=100
	9.9	XXX=099
	9.8	XXX=098
	.	.
	0.5	XXX=005
Step	0.4	XXX=004
	0.3	XXX=003
	0.2	XXX=002
Step	a [m]	XXX

PUR black 5x1.5mm ²	21343000543XXX
Type of cable	Part no.

All Dimensions in mm		Tech. Character.		Free size tol.		According to production drawing	
All rights reserved		Created by 407576		Inspected by COSTEA		Standardisation BANCUI	
Department HCS - RO		Stoica		Costea		Date 2023-11-08	
HARTING Customised Solutions		Title M12 L-cod 4+FE st/- m/- PUR		State Final Release		Doc-Key / ECM-Nr. 100955642/UGD/001/C 500000256959	
D-32339 Espelkamp		Type TB		Number 21343000543XXX		Rev. C	
						Page 1/1	