


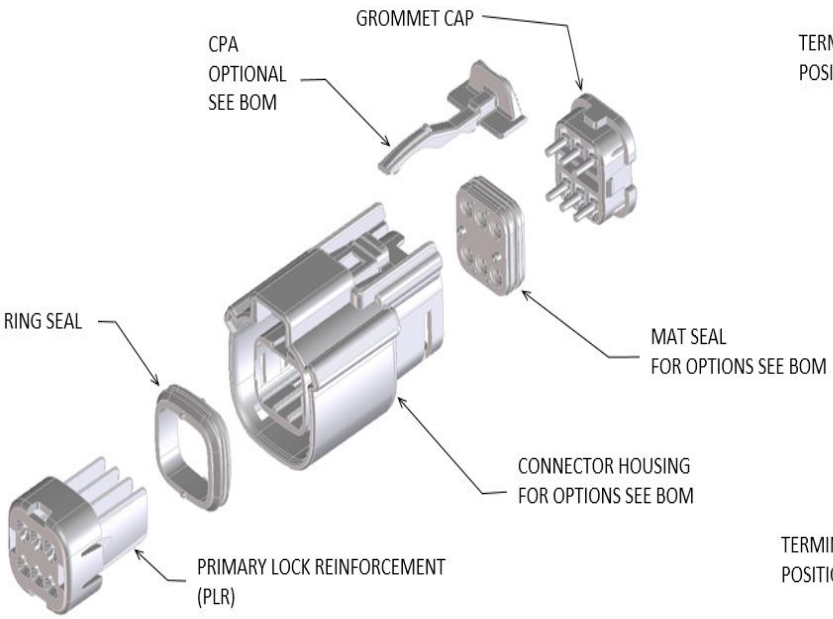

CPA  
OPTIONAL  
SEE BOM


GROMMET CAP

RING SEAL

MAT SEAL  
FOR OPTIONS SEE BOM

CONNECTOR HOUSING  
FOR OPTIONS SEE BOM

PRIMARY LOCK REINFORCEMENT  
(PLR)

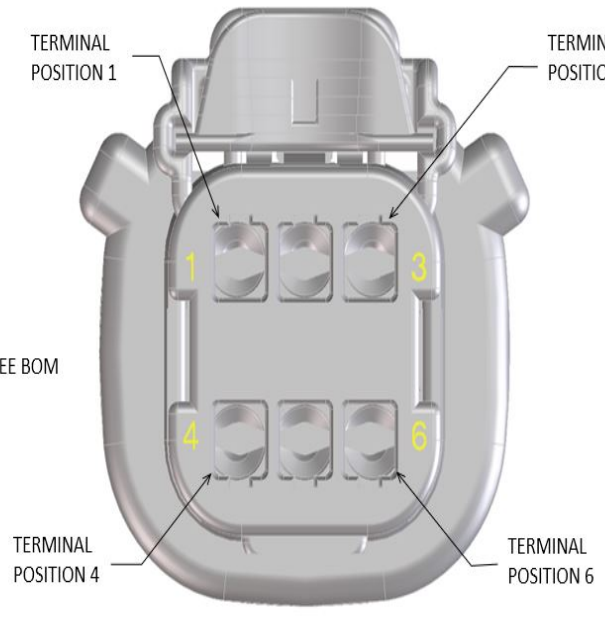

TERMINAL  
POSITION 1

TERMINAL  
POSITION 3

TERMINAL  
POSITION 4

TERMINAL  
POSITION 6

ABBREVIATION

DESCRIPTION

COLOR

MATERIAL

A-BLACK

HOUSING, KEYING OPTION A

BLACK

SPS/NYLON GF20

DESCRIPTION

COLOR

MATERIAL

B-LIGHT GRAY

LIGHT GRAY

SPS/NYLON GF20

DESCRIPTION

COLOR

MATERIAL

C-BROWN

BROWN

SPS/NYLON GF20

DESCRIPTION

COLOR

MATERIAL

D-GREEN

GREEN

SPS/NYLON GF20

DESCRIPTION

COLOR

MATERIAL

C-DARK GRAY

DARK GRAY

SPS/NYLON GF20

DESCRIPTION

COLOR

MATERIAL

D-STONE GRAY

STONE GRAY

SPS/NYLON GF20

DESCRIPTION

COLOR

MATERIAL

A-YELLOW

YELLOW

SPS/NYLON GF20

DESCRIPTION

COLOR

MATERIAL

A-LIGHT BLUE

LIGHT BLUE

SPS/NYLON GF20

DESCRIPTION

COLOR

MATERIAL

A-BLACK-CLIP

HOUSING, KEYING OPTION A WITH CLIPSLOT

BLACK

SPS/NYLON GF20

DESCRIPTION

COLOR

MATERIAL

B-LIGHT GRAY-CLIP

HOUSING, KEYING OPTION B WITH CLIPSLOT

LIGHT GRAY

SPS/NYLON GF20

DESCRIPTION

COLOR

MATERIAL

C-BROWN-CLIP

HOUSING, KEYING OPTION C WITH CLIPSLOT

BROWN

SPS/NYLON GF20

DESCRIPTION

COLOR

MATERIAL

D-GREEN-CLIP

HOUSING, KEYING OPTION D WITH CLIPSLOT

GREEN

SPS/NYLON GF20

DESCRIPTION

COLOR

MATERIAL

C-DARK GRAY-CLIP

HOUSING, KEYING OPTION C WITH CLIPSLOT

DARK GRAY

SPS/NYLON GF20

DESCRIPTION

COLOR

MATERIAL

D-STONE GRAY-CLIP

HOUSING, KEYING OPTION D WITH CLIPSLOT

STONE GRAY

SPS/NYLON GF20

DESCRIPTION

COLOR

MATERIAL

A-YELLOW-CLIP

HOUSING, KEYING OPTION A WITH CLIPSLOT

YELLOW

SPS/NYLON GF20

DESCRIPTION

COLOR

MATERIAL

A-LIGHT BLUE-CLIP

HOUSING, KEYING OPTION A WITH CLIPSLOT

LIGHT BLUE

SPS/NYLON GF20

DESCRIPTION

COLOR

MATERIAL

GCO

GROMMET CAP (OPEN)

BLACK

SPS/NYLON GF20

DESCRIPTION

COLOR

MATERIAL

GCP

GROMMET CAP (PLUGGED)

BLACK

SPS/NYLON GF20

DESCRIPTION

COLOR

MATERIAL

PLR

PLR

NATURAL

SPS/NYLON GF20

DESCRIPTION

COLOR

MATERIAL

CPA

CPA

RED

PBT GF30

DESCRIPTION

COLOR

MATERIAL

M

MAT SEAL

LIGHT BLUE

INHERENTLY LUBRICATED SILICONE

DESCRIPTION

COLOR

MATERIAL

R

RING SEAL

RUST RED

INHERENTLY LUBRICATED SILICONE

FOR ADDITIONAL INFORMATION SEE SD-33472-0001

| ASSEMBLY DESCRIPTION          | ASSEMBLY PART NUMBER | COMPONENT                                                                |             |     |     |          |           | BLOCKED TERMINALS                                                                                                    |   |   | STATUS          | COMMENT          | OPTIONAL ATTACHMENTS SOLD SEPARATELY |                        |
|-------------------------------|----------------------|--------------------------------------------------------------------------|-------------|-----|-----|----------|-----------|----------------------------------------------------------------------------------------------------------------------|---|---|-----------------|------------------|--------------------------------------|------------------------|
|                               |                      | THE PRESENCE OF AN ABBREVIATION INDICATES THE PRESENCE OF THAT COMPONENT |             |     |     |          |           | CAVITY WITH A NUMBER INDICATES BLOCKED TERMINAL POSITION<br>CAVITY WITHOUT A NUMBER INDICATES OPEN TERMINAL POSITION |   |   |                 |                  | BACKSHELL WITH RIBS                  | BACKSHELL WITHOUT RIBS |
|                               |                      | HOUSING KEY/COLOR                                                        | GROMMET CAP | PLR | CPA | MAT SEAL | RING SEAL |                                                                                                                      |   |   |                 |                  |                                      |                        |
| MX150 ASSY RCP 2X3 BK A/6     | 334720601            | A-BLACK                                                                  | GCO         | PLR |     | M        | R         | -                                                                                                                    | - | - | SALEABLE        |                  | 34951-0610                           | 34951-0620             |
|                               |                      |                                                                          |             |     |     |          |           | -                                                                                                                    | - | - |                 |                  |                                      |                        |
| MX150 ASSY RCP 2X3 LG B/6     | 334720602            | B-LIGHT GRAY                                                             | GCO         | PLR |     | M        | R         | -                                                                                                                    | - | - | SALEABLE        |                  | 34951-0610                           | 34951-0620             |
|                               |                      |                                                                          |             |     |     |          |           | -                                                                                                                    | - | - |                 |                  |                                      |                        |
| MX150 ASSY RCP 2X3 BR C/6     | 334720603            | C-BROWN                                                                  | GCO         | PLR |     | M        | R         | -                                                                                                                    | - | - | NOT RECOMMENDED | SEE PN 334720668 | 34951-0610                           | 34951-0620             |
|                               |                      |                                                                          |             |     |     |          |           | -                                                                                                                    | - | - |                 |                  |                                      |                        |
| MX150 ASSY RCP 2X3 GR D/6     | 334720604            | D-GREEN                                                                  | GCO         | PLR |     | M        | R         | -                                                                                                                    | - | - | NOT RECOMMENDED | SEE PN 334720669 | 34951-0610                           | 34951-0620             |
|                               |                      |                                                                          |             |     |     |          |           | -                                                                                                                    | - | - |                 |                  |                                      |                        |
| MX150 ASSY RCP 2X3 CPA BK A/6 | 334720606            | A-BLACK                                                                  | GCO         | PLR | CPA | M        | R         | -                                                                                                                    | - | - | SALEABLE        |                  | 34951-0610                           | 34951-0620             |
|                               |                      |                                                                          |             |     |     |          |           | -                                                                                                                    | - | - |                 |                  |                                      |                        |
| MX150 ASSY RCP 2X3 CPA LG B/6 | 334720607            | B-LIGHT GRAY                                                             | GCO         | PLR | CPA | M        | R         | -                                                                                                                    | - | - | SALEABLE        |                  | 34951-0610                           | 34951-0620             |
|                               |                      |                                                                          |             |     |     |          |           | -                                                                                                                    | - | - |                 |                  |                                      |                        |
| MX150 ASSY RCP 2X3 CPA BR C/6 | 334720608            | C-BROWN                                                                  | GCO         | PLR | CPA | M        | R         | -                                                                                                                    | - | - | NOT RECOMMENDED | SEE PN 334720670 | 34951-0610                           | 34951-0620             |
|                               |                      |                                                                          |             |     |     |          |           | -                                                                                                                    | - | - |                 |                  |                                      |                        |
| MX150 ASSY RCP 2X3 CPA GR D/6 | 334720609            | D-GREEN                                                                  | GCO         | PLR | CPA | M        | R         | -                                                                                                                    | - | - | NOT RECOMMENDED | SEE PN 334720671 | 34951-0610                           | 34951-0620             |
|                               |                      |                                                                          |             |     |     |          |           | -                                                                                                                    | - | - |                 |                  |                                      |                        |
| MX150 ASSY RCP 2X3 BK A/5     | 334720611            | A-BLACK                                                                  | GCP         | PLR |     | M        | R         | -                                                                                                                    | - | 3 | SALEABLE        |                  | 34951-0610                           | 34951-0620             |
|                               |                      |                                                                          |             |     |     |          |           | -                                                                                                                    | - | - |                 |                  |                                      |                        |
| MX150 ASSY RCP 2X3 LG B/5     | 334720612            | B-LIGHT GRAY                                                             | GCP         | PLR |     | M        | R         | -                                                                                                                    | - | 3 | SALEABLE        |                  | 34951-0610                           | 34951-0620             |
|                               |                      |                                                                          |             |     |     |          |           | -                                                                                                                    | - | - |                 |                  |                                      |                        |
| MX150 ASSY RCP 2X3 BR C/5     | 334720613            | C-BROWN                                                                  | GCP         | PLR |     | M        | R         | -                                                                                                                    | - | 3 | NOT RECOMMENDED |                  | 34951-0610                           | 34951-0620             |
|                               |                      |                                                                          |             |     |     |          |           | -                                                                                                                    | - | - |                 |                  |                                      |                        |
| MX150 ASSY RCP 2X3 GR D/5     | 334720614            | D-GREEN                                                                  | GCP         | PLR |     | M        | R         | -                                                                                                                    | - | 3 | NOT RECOMMENDED |                  | 34951-0610                           | 34951-0620             |
|                               |                      |                                                                          |             |     |     |          |           | -                                                                                                                    | - | - |                 |                  |                                      |                        |
| MX150 ASSY RCP 2X3 CPA BK A/5 | 334720616            | A-BLACK                                                                  | GCP         | PLR | CPA | M        | R         | -                                                                                                                    | - | 3 | SALEABLE        |                  | 34951-0610                           | 34951-0620             |
|                               |                      |                                                                          |             |     |     |          |           | -                                                                                                                    | - | - |                 |                  |                                      |                        |

ER NO

DATE

07/06/2026

DOCUMENT NO.

334720602

REVISION AO

Page 1 of 7



MX150 RECEPTACLE 2X3 SEALED ASSEMBLY MAT SEAL  
BOM AND PIN OUT SHEET

| ASSEMBLY DESCRIPTION          | ASSEMBLY PART NUMBER | COMPONENT                                                                |             |     |     |          |           | BLOCKED TERMINALS                                                                                                    |   |   | STATUS          | COMMENT          | OPTIONAL ATTACHMENTS SOLD SEPARATELY |                        |
|-------------------------------|----------------------|--------------------------------------------------------------------------|-------------|-----|-----|----------|-----------|----------------------------------------------------------------------------------------------------------------------|---|---|-----------------|------------------|--------------------------------------|------------------------|
|                               |                      | THE PRESENCE OF AN ABBREVIATION INDICATES THE PRESENCE OF THAT COMPONENT |             |     |     |          |           | CAVITY WITH A NUMBER INDICATES BLOCKED TERMINAL POSITION<br>CAVITY WITHOUT A NUMBER INDICATES OPEN TERMINAL POSITION |   |   |                 |                  | BACKSHELL WITH RIBS                  | BACKSHELL WITHOUT RIBS |
|                               |                      | HOUSING KEY/COLOR                                                        | GROMMET CAP | PLR | CPA | MAT SEAL | RING SEAL |                                                                                                                      |   |   |                 |                  |                                      |                        |
| MX150 ASSY RCP 2X3 CPA LG B/5 | 334720617            | B-LIGHT GRAY                                                             | GCP         | PLR | CPA | M        | R         | -                                                                                                                    | - | 3 | SALEABLE        |                  | 34951-0610                           | 34951-0620             |
|                               |                      |                                                                          |             |     |     |          |           | -                                                                                                                    | - | - |                 |                  |                                      |                        |
| MX150 ASSY RCP 2X3 CPA BR C/5 | 334720618            | C-BROWN                                                                  | GCP         | PLR | CPA | M        | R         | -                                                                                                                    | - | 3 | NOT RECOMMENDED |                  | 34951-0610                           | 34951-0620             |
|                               |                      |                                                                          |             |     |     |          |           | -                                                                                                                    | - | - |                 |                  |                                      |                        |
| MX150 ASSY RCP 2X3 CPA GR D/5 | 334720619            | D-GREEN                                                                  | GCP         | PLR | CPA | M        | R         | -                                                                                                                    | - | 3 | NOT RECOMMENDED |                  | 34951-0610                           | 34951-0620             |
|                               |                      |                                                                          |             |     |     |          |           | -                                                                                                                    | - | - |                 |                  |                                      |                        |
| MX150 ASSY RCP 2X3 BK A/4     | 334720621            | A-BLACK                                                                  | GCP         | PLR |     | M        | R         | -                                                                                                                    | - | 3 | SALEABLE        |                  | 34951-0610                           | 34951-0620             |
|                               |                      |                                                                          |             |     |     |          |           | 4                                                                                                                    | - | - |                 |                  |                                      |                        |
| MX150 ASSY RCP 2X3 LG B/4     | 334720622            | B-LIGHT GRAY                                                             | GCP         | PLR |     | M        | R         | -                                                                                                                    | - | 3 | SALEABLE        |                  | 34951-0610                           | 34951-0620             |
|                               |                      |                                                                          |             |     |     |          |           | 4                                                                                                                    | - | - |                 |                  |                                      |                        |
| MX150 ASSY RCP 2X3 BR C/4     | 334720623            | C-BROWN                                                                  | GCP         | PLR |     | M        | R         | -                                                                                                                    | - | 3 | NOT RECOMMENDED |                  | 34951-0610                           | 34951-0620             |
|                               |                      |                                                                          |             |     |     |          |           | 4                                                                                                                    | - | - |                 |                  |                                      |                        |
| MX150 ASSY RCP 2X3 GR D/4     | 334720624            | D-GREEN                                                                  | GCP         | PLR |     | M        | R         | -                                                                                                                    | - | 3 | NOT RECOMMENDED |                  | 34951-0610                           | 34951-0620             |
|                               |                      |                                                                          |             |     |     |          |           | 4                                                                                                                    | - | - |                 |                  |                                      |                        |
| MX150 ASSY RCP 2X3 CPA BK A/4 | 334720626            | A-BLACK                                                                  | GCP         | PLR | CPA | M        | R         | -                                                                                                                    | - | 3 | SALEABLE        |                  | 34951-0610                           | 34951-0620             |
|                               |                      |                                                                          |             |     |     |          |           | 4                                                                                                                    | - | - |                 |                  |                                      |                        |
| MX150 ASSY RCP 2X3 CPA LG B/4 | 334720627            | B-LIGHT GRAY                                                             | GCP         | PLR | CPA | M        | R         | -                                                                                                                    | - | 3 | SALEABLE        |                  | 34951-0610                           | 34951-0620             |
|                               |                      |                                                                          |             |     |     |          |           | 4                                                                                                                    | - | - |                 |                  |                                      |                        |
| MX150 ASSY RCP 2X3 CPA BR C/4 | 334720628            | C-BROWN                                                                  | GCP         | PLR | CPA | M        | R         | -                                                                                                                    | - | 3 | NOT RECOMMENDED |                  | 34951-0610                           | 34951-0620             |
|                               |                      |                                                                          |             |     |     |          |           | 4                                                                                                                    | - | - |                 |                  |                                      |                        |
| MX150 ASSY RCP 2X3 CPA GR D/4 | 334720629            | D-GREEN                                                                  | GCP         | PLR | CPA | M        | R         | -                                                                                                                    | - | 3 | NOT RECOMMENDED |                  | 34951-0610                           | 34951-0620             |
|                               |                      |                                                                          |             |     |     |          |           | 4                                                                                                                    | - | - |                 |                  |                                      |                        |
| MX150 ASSY RCP 2X3 BK A/0     | 334720636            | A-BLACK                                                                  | GCP         | PLR |     | M        | R         | 1                                                                                                                    | 2 | 3 | SALEABLE        |                  | 34951-0610                           | 34951-0620             |
|                               |                      |                                                                          |             |     |     |          |           | 4                                                                                                                    | 5 | 6 |                 |                  |                                      |                        |
| MX150 ASSY RCP 2X3 LG B/0     | 334720637            | B-LIGHT GRAY                                                             | GCP         | PLR |     | M        | R         | 1                                                                                                                    | 2 | 3 | SALEABLE        |                  | 34951-0610                           | 34951-0620             |
|                               |                      |                                                                          |             |     |     |          |           | 4                                                                                                                    | 5 | 6 |                 |                  |                                      |                        |
| MX150 ASSY RCP 2X3 BR C/0     | 334720638            | C-BROWN                                                                  | GCP         | PLR |     | M        | R         | 1                                                                                                                    | 2 | 3 | NOT RECOMMENDED | SEE PN 334720749 | 34951-0610                           | 34951-0620             |
|                               |                      |                                                                          |             |     |     |          |           | 4                                                                                                                    | 5 | 6 |                 |                  |                                      |                        |
| MX150 ASSY RCP 2X3 GR D/0     | 334720639            | D-GREEN                                                                  | GCP         | PLR |     | M        | R         | 1                                                                                                                    | 2 | 3 | NOT RECOMMENDED | SEE PN 334720750 | 34951-0610                           | 34951-0620             |
|                               |                      |                                                                          |             |     |     |          |           | 4                                                                                                                    | 5 | 6 |                 |                  |                                      |                        |
| MX150 ASSY RCP 2X3 BK A/2     | 334720641            | A-BLACK                                                                  | GCP         | PLR |     | M        | R         | -                                                                                                                    | 2 | 3 | SALEABLE        |                  | 34951-0610                           | 34951-0620             |
|                               |                      |                                                                          |             |     |     |          |           | 4                                                                                                                    | 5 | - |                 |                  |                                      |                        |
| MX150 ASSY RCP 2X3 BK A/5     | 334720642            | A-BLACK                                                                  | GCP         | PLR |     | M        | R         | -                                                                                                                    | - | - | SALEABLE        |                  | 34951-0610                           | 34951-0620             |
|                               |                      |                                                                          |             |     |     |          |           | 4                                                                                                                    | - | - |                 |                  |                                      |                        |
| MX150 ASSY RCP 2X3 CPA BK A/3 | 334720643            | A-BLACK                                                                  | GCP         | PLR | CPA | M        | R         | 1                                                                                                                    | - | 3 | SALEABLE        |                  | 34951-0610                           | 34951-0620             |
|                               |                      |                                                                          |             |     |     |          |           | 4                                                                                                                    | - | - |                 |                  |                                      |                        |
| MX150 ASSY RCP 2X3 CPA LG B/3 | 334720644            | B-LIGHT GRAY                                                             | GCP         | PLR | CPA | M        | R         | 1                                                                                                                    | - | 3 | SALEABLE        |                  | 34951-0610                           | 34951-0620             |
|                               |                      |                                                                          |             |     |     |          |           | 4                                                                                                                    | - | - |                 |                  |                                      |                        |
| MX150 ASSY RCP 2X3 CPA BR C/3 | 334720645            | C-BROWN                                                                  | GCP         | PLR | CPA | M        | R         | 1                                                                                                                    | - | 3 | NOT RECOMMENDED |                  | 34951-0610                           | 34951-0620             |
|                               |                      |                                                                          |             |     |     |          |           | 4                                                                                                                    | - | - |                 |                  |                                      |                        |
| MX150 ASSY RCP 2X3 CPA GR D/3 | 334720646            | D-GREEN                                                                  | GCP         | PLR | CPA | M        | R         | 1                                                                                                                    | - | 3 | NOT RECOMMENDED |                  | 34951-0610                           | 34951-0620             |
|                               |                      |                                                                          |             |     |     |          |           | 4                                                                                                                    | - | - |                 |                  |                                      |                        |
| MX150 ASSY RCP 2X3 BK A/2     | 334720648            | A-BLACK                                                                  | GCP         | PLR |     | M        | R         | 1                                                                                                                    | - | 3 | SALEABLE        |                  | 34951-0610                           | 34951-0620             |
|                               |                      |                                                                          |             |     |     |          |           | 4                                                                                                                    | - | 6 |                 |                  |                                      |                        |
| MX150 ASSY RCP 2X3 LG B/2     | 334720649            | B-LIGHT GRAY                                                             | GCP         | PLR |     | M        | R         | 1                                                                                                                    | - | 3 | SALEABLE        |                  | 34951-0610                           | 34951-0620             |
|                               |                      |                                                                          |             |     |     |          |           | 4                                                                                                                    | - | 6 |                 |                  |                                      |                        |
| MX150 ASSY RCP 2X3 BR C/2     | 334720650            | C-BROWN                                                                  | GCP         | PLR |     | M        | R         | 1                                                                                                                    | - | 3 | NOT RECOMMENDED |                  | 34951-0610                           | 34951-0620             |
|                               |                      |                                                                          |             |     |     |          |           | 4                                                                                                                    | - | 6 |                 |                  |                                      |                        |
| MX150 ASSY RCP 2X3 GR D/2     | 334720651            | D-GREEN                                                                  | GCP         | PLR |     | M        | R         | 1                                                                                                                    | - | 3 | NOT RECOMMENDED |                  | 34951-0610                           | 34951-0620             |
|                               |                      |                                                                          |             |     |     |          |           | 4                                                                                                                    | - | 6 |                 |                  |                                      |                        |
| MX150 ASSY RCP 2X3 CPA BK A/2 | 334720653            | A-BLACK                                                                  | GCP         | PLR | CPA | M        | R         | 1                                                                                                                    | - | 3 | SALEABLE        |                  | 34951-0610                           | 34951-0620             |
|                               |                      |                                                                          |             |     |     |          |           | 4                                                                                                                    | - | 6 |                 |                  |                                      |                        |
| MX150 ASSY RCP 2X3 CPA LG B/2 | 334720654            | B-LIGHT GRAY                                                             | GCP         | PLR | CPA | M        | R         | 1                                                                                                                    | - | 3 | SALEABLE        |                  | 34951-0610                           | 34951-0620             |
|                               |                      |                                                                          |             |     |     |          |           | 4                                                                                                                    | - | 6 |                 |                  |                                      |                        |



MX150 RECEPTACLE 2X3 SEALED ASSEMBLY MAT SEAL  
BOM AND PIN OUT SHEET

| ASSEMBLY DESCRIPTION          | ASSEMBLY PART NUMBER | COMPONENT                                                                |             |     |     |          |           | BLOCKED TERMINALS                                                                                                    |   |   | STATUS          | COMMENT | OPTIONAL ATTACHMENTS SOLD SEPARATELY |                        |
|-------------------------------|----------------------|--------------------------------------------------------------------------|-------------|-----|-----|----------|-----------|----------------------------------------------------------------------------------------------------------------------|---|---|-----------------|---------|--------------------------------------|------------------------|
|                               |                      | THE PRESENCE OF AN ABBREVIATION INDICATES THE PRESENCE OF THAT COMPONENT |             |     |     |          |           | CAVITY WITH A NUMBER INDICATES BLOCKED TERMINAL POSITION<br>CAVITY WITHOUT A NUMBER INDICATES OPEN TERMINAL POSITION |   |   |                 |         | BACKSHELL WITH RIBS                  | BACKSHELL WITHOUT RIBS |
|                               |                      | HOUSING KEY/COLOR                                                        | GROMMET CAP | PLR | CPA | MAT SEAL | RING SEAL |                                                                                                                      |   |   |                 |         |                                      |                        |
| MX150 ASSY RCP 2X3 CPA BR C/2 | 334720655            | C-BROWN                                                                  | GCP         | PLR | CPA | M        | R         | 1                                                                                                                    | - | 3 | NOT RECOMMENDED |         | 34951-0610                           | 34951-0620             |
|                               |                      |                                                                          |             |     |     |          |           | 4                                                                                                                    | - | 6 |                 |         |                                      |                        |
| MX150 ASSY RCP 2X3 CPA GR D/2 | 334720656            | D-GREEN                                                                  | GCP         | PLR | CPA | M        | R         | 1                                                                                                                    | - | 3 | NOT RECOMMENDED |         | 34951-0610                           | 34951-0620             |
|                               |                      |                                                                          |             |     |     |          |           | 4                                                                                                                    | - | 6 |                 |         |                                      |                        |
| MX150 ASSY RCP 2X3 BK A/5     | 334720658            | A-BLACK                                                                  | GCP         | PLR |     | M        | R         | -                                                                                                                    | - | 3 | SALEABLE        |         | 34951-0610                           | 34951-0620             |
|                               |                      |                                                                          |             |     |     |          |           | -                                                                                                                    | - | - |                 |         |                                      |                        |
| MX150 ASSY RCP 2X3 BK A/3     | 334720659            | A-BLACK                                                                  | GCP         | PLR |     | M        | R         | -                                                                                                                    | - | 3 | SALEABLE        |         | 34951-0610                           | 34951-0620             |
|                               |                      |                                                                          |             |     |     |          |           | -                                                                                                                    | 5 | 6 |                 |         |                                      |                        |
| MX150 ASSY RCP 2X3 CPA BK A/0 | 334720660            | A-BLACK                                                                  | GCP         | PLR | CPA | M        | R         | 1                                                                                                                    | 2 | 3 | SALEABLE        |         | 34951-0610                           | 34951-0620             |
|                               |                      |                                                                          |             |     |     |          |           | 4                                                                                                                    | 5 | 6 |                 |         |                                      |                        |
| MX150 ASSY RCP 2X3 BK A/5     | 334720661            | A-BLACK                                                                  | GCP         | PLR |     | M        | R         | -                                                                                                                    | 2 | - | SALEABLE        |         | 34951-0610                           | 34951-0620             |
|                               |                      |                                                                          |             |     |     |          |           | -                                                                                                                    | - | - |                 |         |                                      |                        |
| MX150 ASSY RCP 2X3 BK A/4     | 334720662            | A-BLACK                                                                  | GCP         | PLR |     | M        | R         | -                                                                                                                    | 2 | - | SALEABLE        |         | 34951-0610                           | 34951-0620             |
|                               |                      |                                                                          |             |     |     |          |           | -                                                                                                                    | 5 | - |                 |         |                                      |                        |
| MX150 ASSY RCP 2X3 BK A/4     | 334720663            | A-BLACK                                                                  | GCP         | PLR |     | M        | R         | -                                                                                                                    | - | - | SALEABLE        |         | 34951-0610                           | 34951-0620             |
|                               |                      |                                                                          |             |     |     |          |           | -                                                                                                                    | 5 | 6 |                 |         |                                      |                        |
| MX150 ASSY RCP 2X3 BK A/3     | 334720664            | A-BLACK                                                                  | GCP         | PLR |     | M        | R         | -                                                                                                                    | - | - | SALEABLE        |         | 34951-0610                           | 34951-0620             |
|                               |                      |                                                                          |             |     |     |          |           | 4                                                                                                                    | 5 | 6 |                 |         |                                      |                        |
| MX150 ASSY RCP 2X3 BK A/5     | 334720665            | A-BLACK                                                                  | GCP         | PLR |     | M        | R         | 1                                                                                                                    | - | - | SALEABLE        |         | 34951-0610                           | 34951-0620             |
|                               |                      |                                                                          |             |     |     |          |           | -                                                                                                                    | - | - |                 |         |                                      |                        |
| MX150 ASSY RCP 2X3 BK A/3     | 334720666            | A-BLACK                                                                  | GCP         | PLR |     | M        | R         | -                                                                                                                    | 2 | - | SALEABLE        |         | 34951-0610                           | 34951-0620             |
|                               |                      |                                                                          |             |     |     |          |           | -                                                                                                                    | 5 | 6 |                 |         |                                      |                        |
| MX150 ASSY RCP 2X3 BK A/2     | 334720667            | A-BLACK                                                                  | GCP         | PLR |     | M        | R         | 1                                                                                                                    | - | 3 | SALEABLE        |         | 34951-0610                           | 34951-0620             |
|                               |                      |                                                                          |             |     |     |          |           | -                                                                                                                    | 5 | 6 |                 |         |                                      |                        |
| MX150 ASSY RCP 2X3 DG C/6     | 334720668            | C-DARK GRAY                                                              | GCO         | PLR |     | M        | R         | -                                                                                                                    | - | - | SALEABLE        |         | 34951-0610                           | 34951-0620             |
|                               |                      |                                                                          |             |     |     |          |           | -                                                                                                                    | - | - |                 |         |                                      |                        |
| MX150 ASSY RCP 2X3 SG D/6     | 334720669            | D-STONE GRAY                                                             | GCO         | PLR |     | M        | R         | -                                                                                                                    | - | - | SALEABLE        |         | 34951-0610                           | 34951-0620             |
|                               |                      |                                                                          |             |     |     |          |           | -                                                                                                                    | - | - |                 |         |                                      |                        |
| MX150 ASSY RCP 2X3 CPA DG C/6 | 334720670            | C-DARK GRAY                                                              | GCO         | PLR | CPA | M        | R         | -                                                                                                                    | - | - | SALEABLE        |         | 34951-0610                           | 34951-0620             |
|                               |                      |                                                                          |             |     |     |          |           | -                                                                                                                    | - | - |                 |         |                                      |                        |
| MX150 ASSY RCP 2X3 CPA SG D/6 | 334720671            | D-STONE GRAY                                                             | GCO         | PLR | CPA | M        | R         | -                                                                                                                    | - | - | SALEABLE        |         | 34951-0610                           | 34951-0620             |
|                               |                      |                                                                          |             |     |     |          |           | -                                                                                                                    | - | - |                 |         |                                      |                        |
| MX150 ASSY RCP 2X3 LG B/5     | 334720672            | B-LIGHT GRAY                                                             | GCP         | PLR |     | M        | R         | -                                                                                                                    | - | - | SALEABLE        |         | 34951-0610                           | 34951-0620             |
|                               |                      |                                                                          |             |     |     |          |           | -                                                                                                                    | 5 | - |                 |         |                                      |                        |
| MX150 ASSY RCP 2X3 BK A/5     | 334720673            | A-BLACK                                                                  | GCP         | PLR |     | M        | R         | -                                                                                                                    | - | - | SALEABLE        |         | 34951-0610                           | 34951-0620             |
|                               |                      |                                                                          |             |     |     |          |           | -                                                                                                                    | - | 6 |                 |         |                                      |                        |
| MX150 ASSY RCP 2X3 CPA BK A/4 | 334720674            | A-BLACK                                                                  | GCP         | PLR | CPA | M        | R         | -                                                                                                                    | - | - | SALEABLE        |         | 34951-0610                           | 34951-0620             |
|                               |                      |                                                                          |             |     |     |          |           | -                                                                                                                    | 5 | 6 |                 |         |                                      |                        |
| MX150 ASSY RCP 2X3 CPA BK A/5 | 334720675            | A-BLACK                                                                  | GCP         | PLR | CPA | M        | R         | -                                                                                                                    | - | - | SALEABLE        |         | 34951-0610                           | 34951-0620             |
|                               |                      |                                                                          |             |     |     |          |           | -                                                                                                                    | - | 6 |                 |         |                                      |                        |
| MX150 ASSY RCP 2X3 CPA LG B/4 | 334720676            | B-LIGHT GRAY                                                             | GCP         | PLR | CPA | M        | R         | 1                                                                                                                    | - | - | SALEABLE        |         | 34951-0610                           | 34951-0620             |
|                               |                      |                                                                          |             |     |     |          |           | -                                                                                                                    | 5 | - |                 |         |                                      |                        |
| MX150 ASSY RCP 2X3 LG B/4     | 334720677            | B-LIGHT GRAY                                                             | GCP         | PLR |     | M        | R         | 1                                                                                                                    | - | - | SALEABLE        |         | 34951-0610                           | 34951-0620             |
|                               |                      |                                                                          |             |     |     |          |           | -                                                                                                                    | 5 | - |                 |         |                                      |                        |
| MX150 ASSY RCP 2X3 LG B/4     | 334720678            | B-LIGHT GRAY                                                             | GCP         | PLR |     | M        | R         | -                                                                                                                    | - | - | SALEABLE        |         | 34951-0610                           | 34951-0620             |
|                               |                      |                                                                          |             |     |     |          |           | -                                                                                                                    | 5 | 6 |                 |         |                                      |                        |
| MX150 ASSY RCP 2X3 CPA BK A/3 | 334720679            | A-BLACK                                                                  | GCP         | PLR | CPA | M        | R         | 1                                                                                                                    | 2 | 3 | SALEABLE        |         | 34951-0610                           | 34951-0620             |
|                               |                      |                                                                          |             |     |     |          |           | -                                                                                                                    | - | - |                 |         |                                      |                        |
| MX150 ASSY RCP 2X3 BK A/3     | 334720680            | A-BLACK                                                                  | GCP         | PLR |     | M        | R         | 1                                                                                                                    | 2 | 3 | SALEABLE        |         | 34951-0610                           | 34951-0620             |
|                               |                      |                                                                          |             |     |     |          |           | -                                                                                                                    | - | - |                 |         |                                      |                        |
| MX150 ASSY RCP 2X3 CPA BK A/5 | 334720681            | A-BLACK                                                                  | GCP         | PLR | CPA | M        | R         | -                                                                                                                    | 2 | - | SALEABLE        |         | 34951-0610                           | 34951-0620             |
|                               |                      |                                                                          |             |     |     |          |           | -                                                                                                                    | - | - |                 |         |                                      |                        |
| MX150 ASSY RCP 2X3 CPA YW A/6 | 334720682            | A-YELLOW                                                                 | GCO         | PLR | CPA | M        | R         | -                                                                                                                    | - | - | SALEABLE        |         | 34951-0610                           | 34951-0620             |
|                               |                      |                                                                          |             |     |     |          |           | -                                                                                                                    | - | - |                 |         |                                      |                        |



MX150 RECEPTACLE 2X3 SEALED ASSEMBLY MAT SEAL  
BOM AND PIN OUT SHEET

| ASSEMBLY DESCRIPTION             | ASSEMBLY PART NUMBER | COMPONENT                                                                |             |     |     |          |           | BLOCKED TERMINALS                                                                                                    |   |   | STATUS          | COMMENT          | OPTIONAL ATTACHMENTS SOLD SEPARATELY |                        |
|----------------------------------|----------------------|--------------------------------------------------------------------------|-------------|-----|-----|----------|-----------|----------------------------------------------------------------------------------------------------------------------|---|---|-----------------|------------------|--------------------------------------|------------------------|
|                                  |                      | THE PRESENCE OF AN ABBREVIATION INDICATES THE PRESENCE OF THAT COMPONENT |             |     |     |          |           | CAVITY WITH A NUMBER INDICATES BLOCKED TERMINAL POSITION<br>CAVITY WITHOUT A NUMBER INDICATES OPEN TERMINAL POSITION |   |   |                 |                  | BACKSHELL WITH RIBS                  | BACKSHELL WITHOUT RIBS |
|                                  |                      | HOUSING KEY/COLOR                                                        | GROMMET CAP | PLR | CPA | MAT SEAL | RING SEAL |                                                                                                                      |   |   |                 |                  |                                      |                        |
| MX150 ASSY RCP 2X3 BK A/2        | 334720683            | A-BLACK                                                                  | GCP         | PLR |     | M        | R         | -                                                                                                                    | - | 3 | SALEABLE        |                  | 34951-0610                           | 34951-0620             |
|                                  |                      |                                                                          |             |     |     |          |           | 4                                                                                                                    | 5 | 6 |                 |                  |                                      |                        |
| MX150 ASSY RCP 2X3 CPA BK A/4    | 334720684            | A-BLACK                                                                  | GCP         | PLR | CPA | M        | R         | -                                                                                                                    | 2 | 3 | SALEABLE        |                  | 34951-0610                           | 34951-0620             |
|                                  |                      |                                                                          |             |     |     |          |           | -                                                                                                                    | - | - |                 |                  |                                      |                        |
| MX150 ASSY RCP 2X3 CPA LG B/0    | 334720685            | B-LIGHT GRAY                                                             | GCP         | PLR | CPA | M        | R         | 1                                                                                                                    | 2 | 3 | SALEABLE        |                  | 34951-0610                           | 34951-0620             |
|                                  |                      |                                                                          |             |     |     |          |           | 4                                                                                                                    | 5 | 6 |                 |                  |                                      |                        |
| MX150 ASSY RCP 2X3 CPA LG B/4    | 334720686            | B-LIGHT GRAY                                                             | GCP         | PLR | CPA | M        | R         | -                                                                                                                    | 2 | 3 | SALEABLE        |                  | 34951-0610                           | 34951-0620             |
|                                  |                      |                                                                          |             |     |     |          |           | -                                                                                                                    | - | - |                 |                  |                                      |                        |
| MX150 ASSY RCP 2X3 BK A/3        | 334720687            | A-BLACK                                                                  | GCP         | PLR |     | M        | R         | 1                                                                                                                    | - | 3 | SALEABLE        |                  | 34951-0610                           | 34951-0620             |
|                                  |                      |                                                                          |             |     |     |          |           | 4                                                                                                                    | - | - |                 |                  |                                      |                        |
| MX150 ASSY RCP 2X3 CPA BK A/3    | 334720688            | A-BLACK                                                                  | GCP         | PLR | CPA | M        | R         | -                                                                                                                    | - | - | SALEABLE        |                  | 34951-0610                           | 34951-0620             |
|                                  |                      |                                                                          |             |     |     |          |           | 4                                                                                                                    | 5 | 6 |                 |                  |                                      |                        |
| MX150 ASSY RCP 2X3 CPA BK A/5    | 334720689            | A-BLACK                                                                  | GCP         | PLR | CPA | M        | R         | -                                                                                                                    | - | - | SALEABLE        |                  | 34951-0610                           | 34951-0620             |
|                                  |                      |                                                                          |             |     |     |          |           | 4                                                                                                                    | - | - |                 |                  |                                      |                        |
| MX150 ASSY RCP 2X3 CPA LG B/5    | 334720690            | B-LIGHT GRAY                                                             | GCP         | PLR | CPA | M        | R         | -                                                                                                                    | - | - | SALEABLE        |                  | 34951-0610                           | 34951-0620             |
|                                  |                      |                                                                          |             |     |     |          |           | 4                                                                                                                    | - | - |                 |                  |                                      |                        |
| MX150 ASSY RCP 2X3 CPA BK A/3    | 334720691            | A-BLACK                                                                  | GCP         | PLR | CPA | M        | R         | 1                                                                                                                    | - | 3 | SALEABLE        |                  | 34951-0610                           | 34951-0620             |
|                                  |                      |                                                                          |             |     |     |          |           | -                                                                                                                    | 5 | - |                 |                  |                                      |                        |
| MX150 ASSY RCP 2X3 CPA BK A/3    | 334720692            | A-BLACK                                                                  | GCP         | PLR | CPA | M        | R         | -                                                                                                                    | 2 | - | SALEABLE        |                  | 34951-0610                           | 34951-0620             |
|                                  |                      |                                                                          |             |     |     |          |           | 4                                                                                                                    | - | 6 |                 |                  |                                      |                        |
| MX150 ASSY RCP 2X3 CS BK A/6     | 334720701            | A-BLACK-CLIP                                                             | GCO         | PLR |     | M        | R         | -                                                                                                                    | - | - | SALEABLE        |                  | N/A                                  | N/A                    |
|                                  |                      |                                                                          |             |     |     |          |           | -                                                                                                                    | - | - |                 |                  |                                      |                        |
| MX150 ASSY RCP 2X3 CS LG B/6     | 334720702            | B-LIGHT GRAY-CLIP                                                        | GCO         | PLR |     | M        | R         | -                                                                                                                    | - | - | SALEABLE        |                  | N/A                                  | N/A                    |
|                                  |                      |                                                                          |             |     |     |          |           | -                                                                                                                    | - | - |                 |                  |                                      |                        |
| MX150 ASSY RCP 2X3 CS BR C/6     | 334720703            | C-BROWN-CLIP                                                             | GCO         | PLR |     | M        | R         | -                                                                                                                    | - | - | NOT RECOMMENDED | SEE PN 334720714 | N/A                                  | N/A                    |
|                                  |                      |                                                                          |             |     |     |          |           | -                                                                                                                    | - | - |                 |                  |                                      |                        |
| MX150 ASSY RCP 2X3 CS GR D/6     | 334720704            | D-GREEN-CLIP                                                             | GCO         | PLR |     | M        | R         | -                                                                                                                    | - | - | NOT RECOMMENDED | SEE PN 334720715 | N/A                                  | N/A                    |
|                                  |                      |                                                                          |             |     |     |          |           | -                                                                                                                    | - | - |                 |                  |                                      |                        |
| MX150 ASSY RCP 2X3 CS CPA BK A/6 | 334720705            | A-BLACK-CLIP                                                             | GCO         | PLR | CPA | M        | R         | -                                                                                                                    | - | - | SALEABLE        |                  | N/A                                  | N/A                    |
|                                  |                      |                                                                          |             |     |     |          |           | -                                                                                                                    | - | - |                 |                  |                                      |                        |
| MX150 ASSY RCP 2X3 CS CPA LG B/6 | 334720706            | B-LIGHT GRAY-CLIP                                                        | GCO         | PLR | CPA | M        | R         | -                                                                                                                    | - | - | SALEABLE        |                  | N/A                                  | N/A                    |
|                                  |                      |                                                                          |             |     |     |          |           | -                                                                                                                    | - | - |                 |                  |                                      |                        |
| MX150 ASSY RCP 2X3 CS CPA BR C/6 | 334720707            | C-BROWN-CLIP                                                             | GCO         | PLR | CPA | M        | R         | -                                                                                                                    | - | - | NOT RECOMMENDED | SEE PN 334720716 | N/A                                  | N/A                    |
|                                  |                      |                                                                          |             |     |     |          |           | -                                                                                                                    | - | - |                 |                  |                                      |                        |
| MX150 ASSY RCP 2X3 CS CPA GR D/6 | 334720708            | D-GREEN-CLIP                                                             | GCO         | PLR | CPA | M        | R         | -                                                                                                                    | - | - | NOT RECOMMENDED | SEE PN 334720717 | N/A                                  | N/A                    |
|                                  |                      |                                                                          |             |     |     |          |           | -                                                                                                                    | - | - |                 |                  |                                      |                        |
| MX150 ASSY RCP 2X3 CS BK A/5     | 334720709            | A-BLACK-CLIP                                                             | GCP         | PLR |     | M        | R         | -                                                                                                                    | - | 3 | SALEABLE        |                  | N/A                                  | N/A                    |
|                                  |                      |                                                                          |             |     |     |          |           | -                                                                                                                    | - | - |                 |                  |                                      |                        |
| MX150 ASSY RCP 2X3 CS BK A/2     | 334720710            | A-BLACK-CLIP                                                             | GCP         | PLR |     | M        | R         | -                                                                                                                    | 2 | 3 | SALEABLE        |                  | N/A                                  | N/A                    |
|                                  |                      |                                                                          |             |     |     |          |           | 4                                                                                                                    | 5 | - |                 |                  |                                      |                        |
| MX150 ASSY RCP 2X3 CS BK A/4     | 334720711            | A-BLACK-CLIP                                                             | GCP         | PLR |     | M        | R         | -                                                                                                                    | - | - | SALEABLE        |                  | N/A                                  | N/A                    |
|                                  |                      |                                                                          |             |     |     |          |           | -                                                                                                                    | 5 | 6 |                 |                  |                                      |                        |
| MX150 ASSY RCP 2X3 CS BK A/4     | 334720712            | A-BLACK-CLIP                                                             | GCP         | PLR |     | M        | R         | -                                                                                                                    | - | 3 | SALEABLE        |                  | N/A                                  | N/A                    |
|                                  |                      |                                                                          |             |     |     |          |           | 4                                                                                                                    | - | - |                 |                  |                                      |                        |
| MX150 ASSY RCP 2X3 CS LG B/4     | 334720713            | B-LIGHT GRAY-CLIP                                                        | GCP         | PLR |     | M        | R         | 1                                                                                                                    | - | - | SALEABLE        |                  | N/A                                  | N/A                    |
|                                  |                      |                                                                          |             |     |     |          |           | -                                                                                                                    | 5 | - |                 |                  |                                      |                        |
| MX150 ASSY RCP 2X3 CS DG C/6     | 334720714            | C-DARK GRAY-CLIP                                                         | GCO         | PLR |     | M        | R         | -                                                                                                                    | - | - | SALEABLE        |                  | N/A                                  | N/A                    |
|                                  |                      |                                                                          |             |     |     |          |           | -                                                                                                                    | - | - |                 |                  |                                      |                        |
| MX150 ASSY RCP 2X3 CS SG D/6     | 334720715            | D-STONE GRAY-CLIP                                                        | GCO         | PLR |     | M        | R         | -                                                                                                                    | - | - | SALEABLE        |                  | N/A                                  | N/A                    |
|                                  |                      |                                                                          |             |     |     |          |           | -                                                                                                                    | - | - |                 |                  |                                      |                        |
| MX150 ASSY RCP 2X3 CS CPA DG C/6 | 334720716            | C-DARK GRAY-CLIP                                                         | GCO         | PLR | CPA | M        | R         | -                                                                                                                    | - | - | SALEABLE        |                  | N/A                                  | N/A                    |
|                                  |                      |                                                                          |             |     |     |          |           | -                                                                                                                    | - | - |                 |                  |                                      |                        |
| MX150 ASSY RCP 2X3 CS CPA SG D/6 | 334720717            | D-STONE GRAY-CLIP                                                        | GCO         | PLR | CPA | M        | R         | -                                                                                                                    | - | - | SALEABLE        |                  | N/A                                  | N/A                    |
|                                  |                      |                                                                          |             |     |     |          |           | -                                                                                                                    | - | - |                 |                  |                                      |                        |





MX150 RECEPTACLE 2X3 SEALED ASSEMBLY MAT SEAL  
BOM AND PIN OUT SHEET

| ASSEMBLY DESCRIPTION             | ASSEMBLY PART NUMBER | COMPONENT                                                                |             |     |     |          |           | BLOCKED TERMINALS                                                                                                    |   |   | STATUS   | COMMENT | OPTIONAL ATTACHMENTS SOLD SEPARATELY |                        |
|----------------------------------|----------------------|--------------------------------------------------------------------------|-------------|-----|-----|----------|-----------|----------------------------------------------------------------------------------------------------------------------|---|---|----------|---------|--------------------------------------|------------------------|
|                                  |                      | THE PRESENCE OF AN ABBREVIATION INDICATES THE PRESENCE OF THAT COMPONENT |             |     |     |          |           | CAVITY WITH A NUMBER INDICATES BLOCKED TERMINAL POSITION<br>CAVITY WITHOUT A NUMBER INDICATES OPEN TERMINAL POSITION |   |   |          |         | BACKSHELL WITH RIBS                  | BACKSHELL WITHOUT RIBS |
|                                  |                      | HOUSING KEY/COLOR                                                        | GROMMET CAP | PLR | CPA | MAT SEAL | RING SEAL |                                                                                                                      |   |   |          |         |                                      |                        |
| MX150 ASSY RCP 2X3 CS BK A/4     | 334720718            | A-BLACK-CLIP                                                             | GCP         | PLR |     | M        | R         | -                                                                                                                    | - | 3 | SALEABLE |         | N/A                                  | N/A                    |
|                                  |                      |                                                                          |             |     |     |          |           | -                                                                                                                    | - | 6 |          |         |                                      |                        |
| MX150 ASSY RCP 2X3 CS CPA LG B/4 | 334720719            | B-LIGHT GRAY-CLIP                                                        | GCP         | PLR | CPA | M        | R         | 1                                                                                                                    | - | - | SALEABLE |         | N/A                                  | N/A                    |
|                                  |                      |                                                                          |             |     |     |          |           | -                                                                                                                    | 5 | - |          |         |                                      |                        |
| MX150 ASSY RCP 2X3 CS LG B/5     | 334720720            | B-LIGHT GRAY-CLIP                                                        | GCP         | PLR |     | M        | R         | -                                                                                                                    | - | - | SALEABLE |         | N/A                                  | N/A                    |
|                                  |                      |                                                                          |             |     |     |          |           | -                                                                                                                    | 5 | - |          |         |                                      |                        |
| MX150 ASSY RCP 2X3 CS DG C/5     | 334720721            | C-DARK GRAY-CLIP                                                         | GCP         | PLR |     | M        | R         | -                                                                                                                    | - | 3 | SALEABLE |         | N/A                                  | N/A                    |
|                                  |                      |                                                                          |             |     |     |          |           | -                                                                                                                    | - | - |          |         |                                      |                        |
| MX150 ASSY RCP 2X3 CS BK A/3     | 334720722            | A-BLACK-CLIP                                                             | GCP         | PLR |     | M        | R         | -                                                                                                                    | - | - | SALEABLE |         | N/A                                  | N/A                    |
|                                  |                      |                                                                          |             |     |     |          |           | 4                                                                                                                    | 5 | 6 |          |         |                                      |                        |
| MX150 ASSY RCP 2X3 CS BK A/2     | 334720723            | A-BLACK-CLIP                                                             | GCP         | PLR |     | M        | R         | -                                                                                                                    | 2 | 3 | SALEABLE |         | N/A                                  | N/A                    |
|                                  |                      |                                                                          |             |     |     |          |           | -                                                                                                                    | 5 | 6 |          |         |                                      |                        |
| MX150 ASSY RCP 2X3 CS BK A/4     | 334720724            | A-BLACK-CLIP                                                             | GCP         | PLR |     | M        | R         | -                                                                                                                    | 2 | - | SALEABLE |         | N/A                                  | N/A                    |
|                                  |                      |                                                                          |             |     |     |          |           | -                                                                                                                    | - | 6 |          |         |                                      |                        |
| MX150 ASSY RCP 2X3 CS BK A/3     | 334720725            | A-BLACK-CLIP                                                             | GCP         | PLR |     | M        | R         | -                                                                                                                    | - | 3 | SALEABLE |         | N/A                                  | N/A                    |
|                                  |                      |                                                                          |             |     |     |          |           | -                                                                                                                    | 5 | 6 |          |         |                                      |                        |
| MX150 ASSY RCP 2X3 CS BK A/5     | 334720726            | A-BLACK-CLIP                                                             | GCP         | PLR |     | M        | R         | -                                                                                                                    | - | - | SALEABLE |         | N/A                                  | N/A                    |
|                                  |                      |                                                                          |             |     |     |          |           | -                                                                                                                    | - | 6 |          |         |                                      |                        |
| MX150 ASSY RCP 2X3 CS BK A/1     | 334720727            | A-BLACK-CLIP                                                             | GCP         | PLR |     | M        | R         | -                                                                                                                    | 2 | 3 | SALEABLE |         | N/A                                  | N/A                    |
|                                  |                      |                                                                          |             |     |     |          |           | 4                                                                                                                    | 5 | 6 |          |         |                                      |                        |
| MX150 ASSY RCP 2X3 CS BK A/4     | 334720728            | A-BLACK-CLIP                                                             | GCP         | PLR |     | M        | R         | 1                                                                                                                    | - | - | SALEABLE |         | N/A                                  | N/A                    |
|                                  |                      |                                                                          |             |     |     |          |           | -                                                                                                                    | - | 6 |          |         |                                      |                        |
| MX150 ASSY RCP 2X3 CS BK A/0     | 334720729            | A-BLACK-CLIP                                                             | GCP         | PLR |     | M        | R         | 1                                                                                                                    | 2 | 3 | SALEABLE |         | N/A                                  | N/A                    |
|                                  |                      |                                                                          |             |     |     |          |           | 4                                                                                                                    | 5 | 6 |          |         |                                      |                        |
| MX150 ASSY RCP 2X3 CS BK A/5     | 334720730            | A-BLACK-CLIP                                                             | GCP         | PLR |     | M        | R         | -                                                                                                                    | - | - | SALEABLE |         | N/A                                  | N/A                    |
|                                  |                      |                                                                          |             |     |     |          |           | 4                                                                                                                    | - | - |          |         |                                      |                        |
| MX150 ASSY RCP 2X3 CS BK A/4     | 334720731            | A-BLACK-CLIP                                                             | GCP         | PLR |     | M        | R         | -                                                                                                                    | - | - | SALEABLE |         | N/A                                  | N/A                    |
|                                  |                      |                                                                          |             |     |     |          |           | 4                                                                                                                    | - | 6 |          |         |                                      |                        |
| MX150 ASSY RCP 2X3 CS LG B/3     | 334720732            | B-LIGHT GRAY-CLIP                                                        | GCP         | PLR |     | M        | R         | -                                                                                                                    | - | - | SALEABLE |         | N/A                                  | N/A                    |
|                                  |                      |                                                                          |             |     |     |          |           | 4                                                                                                                    | 5 | 6 |          |         |                                      |                        |
| MX150 ASSY RCP 2X3 CPA BK A/4    | 334720733            | A-BLACK                                                                  | GCP         | PLR | CPA | M        | R         | -                                                                                                                    | 2 | - | SALEABLE |         | 34951-0610                           | 34951-0620             |
|                                  |                      |                                                                          |             |     |     |          |           | -                                                                                                                    | 5 | - |          |         |                                      |                        |
| MX150 ASSY RCP 2X3 CS BK A/5     | 334720734            | A-BLACK-CLIP                                                             | GCP         | PLR |     | M        | R         | -                                                                                                                    | - | - | SALEABLE |         | N/A                                  | N/A                    |
|                                  |                      |                                                                          |             |     |     |          |           | -                                                                                                                    | 5 | - |          |         |                                      |                        |
| MX150 ASSY RCP 2X3 BK A/5        | 334720735            | A-BLACK                                                                  | GCP         | PLR |     | M        | R         | -                                                                                                                    | - | - | SALEABLE |         | 34951-0610                           | 34951-0620             |
|                                  |                      |                                                                          |             |     |     |          |           | -                                                                                                                    | 5 | - |          |         |                                      |                        |
| MX150 ASSY RCP 2X3 LG B/3        | 334720736            | B-LIGHT GRAY                                                             | GCP         | PLR |     | M        | R         | -                                                                                                                    | - | - | SALEABLE |         | 34951-0610                           | 34951-0620             |
|                                  |                      |                                                                          |             |     |     |          |           | 4                                                                                                                    | 5 | 6 |          |         |                                      |                        |
| MX150 ASSY RCP 2X3 CPA BK A/5    | 334720737            | A-BLACK                                                                  | GCP         | PLR | CPA | M        | R         | 1                                                                                                                    | - | - | SALEABLE |         | 34951-0610                           | 34951-0620             |
|                                  |                      |                                                                          |             |     |     |          |           | -                                                                                                                    | - | - |          |         |                                      |                        |
| MX150 ASSY RCP 2X3 CPA LG B/5    | 334720738            | B-LIGHT GRAY                                                             | GCP         | PLR | CPA | M        | R         | 1                                                                                                                    | - | - | SALEABLE |         | 34951-0610                           | 34951-0620             |
|                                  |                      |                                                                          |             |     |     |          |           | -                                                                                                                    | - | - |          |         |                                      |                        |
| MX150 ASSY RCP 2X3 CS CPA BK A/2 | 334720739            | A-BLACK-CLIP                                                             | GCP         | PLR | CPA | M        | R         | 1                                                                                                                    | 2 | - | SALEABLE |         | N/A                                  | N/A                    |
|                                  |                      |                                                                          |             |     |     |          |           | -                                                                                                                    | 5 | 6 |          |         |                                      |                        |
| MX150 ASSY RCP 2X3 CS CPA BK A/2 | 334720740            | A-BLACK-CLIP                                                             | GCP         | PLR | CPA | M        | R         | -                                                                                                                    | 2 | 3 | SALEABLE |         | N/A                                  | N/A                    |
|                                  |                      |                                                                          |             |     |     |          |           | 4                                                                                                                    | 5 | - |          |         |                                      |                        |
| MX150 ASSY RCP 2X3 BK A/4        | 334720741            | A-BLACK                                                                  | GCP         | PLR |     | M        | R         | -                                                                                                                    | - | 3 | SALEABLE |         | 34951-0610                           | 34951-0620             |
|                                  |                      |                                                                          |             |     |     |          |           | -                                                                                                                    | - | 6 |          |         |                                      |                        |
| MX150 ASSY RCP 2X3 BK A/3        | 334720742            | A-BLACK                                                                  | GCP         | PLR |     | M        | R         | 1                                                                                                                    | - | - | SALEABLE |         | 34951-0610                           | 34951-0620             |
|                                  |                      |                                                                          |             |     |     |          |           | -                                                                                                                    | 5 | 6 |          |         |                                      |                        |
| MX150 ASSY RCP 2X3 LG B/3        | 334720743            | B-LIGHT GRAY                                                             | GCP         | PLR |     | M        | R         | 1                                                                                                                    | - | - | SALEABLE |         | 34951-0610                           | 34951-0620             |
|                                  |                      |                                                                          |             |     |     |          |           | -                                                                                                                    | 5 | 6 |          |         |                                      |                        |
| MX150 ASSY RCP 2X3 CS CPA BK A/5 | 334720744            | A-BLACK-CLIP                                                             | GCP         | PLR | CPA | M        | R         | -                                                                                                                    | - | 3 | SALEABLE |         | N/A                                  | N/A                    |
|                                  |                      |                                                                          |             |     |     |          |           | -                                                                                                                    | - | - |          |         |                                      |                        |



MX150 RECEPTACLE 2X3 SEALED ASSEMBLY MAT SEAL  
BOM AND PIN OUT SHEET

| ASSEMBLY DESCRIPTION             | ASSEMBLY PART NUMBER | COMPONENT                                                                |             |     |     |          |           | BLOCKED TERMINALS                                                                                                    |   |   | STATUS   | COMMENT | OPTIONAL ATTACHMENTS SOLD SEPARATELY |                        |
|----------------------------------|----------------------|--------------------------------------------------------------------------|-------------|-----|-----|----------|-----------|----------------------------------------------------------------------------------------------------------------------|---|---|----------|---------|--------------------------------------|------------------------|
|                                  |                      | THE PRESENCE OF AN ABBREVIATION INDICATES THE PRESENCE OF THAT COMPONENT |             |     |     |          |           | CAVITY WITH A NUMBER INDICATES BLOCKED TERMINAL POSITION<br>CAVITY WITHOUT A NUMBER INDICATES OPEN TERMINAL POSITION |   |   |          |         | BACKSHELL WITH RIBS                  | BACKSHELL WITHOUT RIBS |
|                                  |                      | HOUSING KEY/COLOR                                                        | GROMMET CAP | PLR | CPA | MAT SEAL | RING SEAL |                                                                                                                      |   |   |          |         |                                      |                        |
| MX150 ASSY RCP 2X3 CS BK A/4     | 334720745            | A-BLACK-CLIP                                                             | GCP         | PLR |     | M        | R         | 1                                                                                                                    | - | - | SALEABLE |         | N/A                                  | N/A                    |
|                                  |                      |                                                                          |             |     |     |          |           | 4                                                                                                                    | - | - |          |         |                                      |                        |
| MX150 ASSY RCP 2X3 CPA LG B/3    | 334720746            | B-LIGHT GRAY                                                             | GCP         | PLR | CPA | M        | R         | -                                                                                                                    | - | - | SALEABLE |         | 34951-0610                           | 34951-0620             |
|                                  |                      |                                                                          |             |     |     |          |           | 4                                                                                                                    | 5 | 6 |          |         |                                      |                        |
| MX150 ASSY RCP 2X3 CPA BK A/2    | 334720747            | A-BLACK                                                                  | GCP         | PLR | CPA | M        | R         | -                                                                                                                    | 2 | 3 | SALEABLE |         | 34951-0610                           | 34951-0620             |
|                                  |                      |                                                                          |             |     |     |          |           | 4                                                                                                                    | 5 | - |          |         |                                      |                        |
| MX150 ASSY RCP 2X3 DG C/5        | 334720748            | C-DARK GRAY                                                              | GCP         | PLR |     | M        | R         | -                                                                                                                    | - | - | SALEABLE |         | 34951-0610                           | 34951-0620             |
|                                  |                      |                                                                          |             |     |     |          |           | -                                                                                                                    | - | 6 |          |         |                                      |                        |
| MX150 ASSY RCP 2X3 DG C/0        | 334720749            | C-DARK GRAY                                                              | GCP         | PLR |     | M        | R         | 1                                                                                                                    | 2 | 3 | SALEABLE |         | 34951-0610                           | 34951-0620             |
|                                  |                      |                                                                          |             |     |     |          |           | 4                                                                                                                    | 5 | 6 |          |         |                                      |                        |
| MX150 ASSY RCP 2X3 SG D/0        | 334720750            | D-STONE GRAY                                                             | GCP         | PLR |     | M        | R         | 1                                                                                                                    | 2 | 3 | SALEABLE |         | 34951-0610                           | 34951-0620             |
|                                  |                      |                                                                          |             |     |     |          |           | 4                                                                                                                    | 5 | 6 |          |         |                                      |                        |
| MX150 ASSY RCP 2X3 BK A/4        | 334720751            | A-BLACK                                                                  | GCP         | PLR |     | M        | R         | -                                                                                                                    | 2 | 3 | SALEABLE |         | 34951-0610                           | 34951-0620             |
|                                  |                      |                                                                          |             |     |     |          |           | -                                                                                                                    | - | - |          |         |                                      |                        |
| MX150 ASSY RCP 2X3 CS CPA BK A/3 | 334720752            | A-BLACK-CLIP                                                             | GCP         | PLR | CPA | M        | R         | 1                                                                                                                    | - | - | SALEABLE |         | N/A                                  | N/A                    |
|                                  |                      |                                                                          |             |     |     |          |           | -                                                                                                                    | 5 | 6 |          |         |                                      |                        |
| MX150 ASSY RCP 2X3 CS CPA BK A/5 | 334720753            | A-BLACK-CLIP                                                             | GCP         | PLR | CPA | M        | R         | -                                                                                                                    | - | - | SALEABLE |         | N/A                                  | N/A                    |
|                                  |                      |                                                                          |             |     |     |          |           | -                                                                                                                    | - | 6 |          |         |                                      |                        |
| MX150 ASSY RCP 2X3 CPA BK A/5    | 334720754            | A-BLACK                                                                  | GCP         | PLR | CPA | M        | R         | -                                                                                                                    | - | - | SALEABLE |         | 34951-0610                           | 34951-0620             |
|                                  |                      |                                                                          |             |     |     |          |           | -                                                                                                                    | 5 | - |          |         |                                      |                        |
| MX150 ASSY RCP 2X3 CS CPA BK A/4 | 334720755            | A-BLACK-CLIP                                                             | GCP         | PLR | CPA | M        | R         | -                                                                                                                    | - | - | SALEABLE |         | N/A                                  | N/A                    |
|                                  |                      |                                                                          |             |     |     |          |           | -                                                                                                                    | 5 | 6 |          |         |                                      |                        |
| MX150 ASSY RCP 2X3 CPA BK A/2    | 334720756            | A-BLACK                                                                  | GCP         | PLR | CPA | M        | R         | 1                                                                                                                    | 2 | 3 | SALEABLE |         | 34951-0610                           | 34951-0620             |
|                                  |                      |                                                                          |             |     |     |          |           | 4                                                                                                                    | - | - |          |         |                                      |                        |
| MX150 ASSY RCP 2X3 LG B/5        | 334720757            | B-LIGHT GRAY                                                             | GCP         | PLR |     | M        | R         | 1                                                                                                                    | - | - | SALEABLE |         | 34951-0610                           | 34951-0620             |
|                                  |                      |                                                                          |             |     |     |          |           | -                                                                                                                    | - | - |          |         |                                      |                        |
| MX150 ASSY RCP 2X3 CS BK A/3     | 334727001            | A-BLACK-CLIP                                                             | GCP         | PLR |     | M        | R         | -                                                                                                                    | - | 3 | SALEABLE |         | N/A                                  | N/A                    |
|                                  |                      |                                                                          |             |     |     |          |           | 4                                                                                                                    | - | 6 |          |         |                                      |                        |
| MX150 ASSY RCP 2X3 CPA LG B/3    | 334727002            | B-LIGHT GRAY                                                             | GCP         | PLR | CPA | M        | R         | 1                                                                                                                    | - | - | SALEABLE |         | 34951-0610                           | 34951-0620             |
|                                  |                      |                                                                          |             |     |     |          |           | -                                                                                                                    | 5 | 6 |          |         |                                      |                        |
| MX150 ASSY RCP 2X3 DG C/5        | 334727003            | C-DARK GRAY                                                              | GCP         | PLR |     | M        | R         | -                                                                                                                    | - | - | SALEABLE |         | 34951-0610                           | 34951-0620             |
|                                  |                      |                                                                          |             |     |     |          |           | -                                                                                                                    | 5 | - |          |         |                                      |                        |
| MX150 ASSY RCP 2X3 LG B/5        | 334727004            | B-LIGHT GRAY                                                             | GCP         | PLR |     | M        | R         | -                                                                                                                    | - | - | SALEABLE |         | 34951-0610                           | 34951-0620             |
|                                  |                      |                                                                          |             |     |     |          |           | -                                                                                                                    | - | 6 |          |         |                                      |                        |
| MX150 ASSY RCP 2X3 CPA SG D/5    | 334727005            | D-STONE GRAY                                                             | GCP         | PLR | CPA | M        | R         | 1                                                                                                                    | - | - | SALEABLE |         | 34951-0610                           | 34951-0620             |
|                                  |                      |                                                                          |             |     |     |          |           | -                                                                                                                    | - | - |          |         |                                      |                        |
| MX150 ASSY RCP 2X3 CS SG D/5     | 334727006            | D-STONE GRAY-CLIP                                                        | GCP         | PLR |     | M        | R         | 1                                                                                                                    | - | - | SALEABLE |         | N/A                                  | N/A                    |
|                                  |                      |                                                                          |             |     |     |          |           | -                                                                                                                    | - | - |          |         |                                      |                        |
| MX150 ASSY RCP 2X3 CS CPA SG D/5 | 334727007            | D-STONE GRAY-CLIP                                                        | GCP         | PLR | CPA | M        | R         | 1                                                                                                                    | - | - | SALEABLE |         | N/A                                  | N/A                    |
|                                  |                      |                                                                          |             |     |     |          |           | -                                                                                                                    | - | - |          |         |                                      |                        |
| MX150 ASSY RCP 2X3 CS CPA DG C/5 | 334727008            | C-DARK GRAY-CLIP                                                         | GCP         | PLR | CPA | M        | R         | 1                                                                                                                    | - | - | SALEABLE |         | N/A                                  | N/A                    |
|                                  |                      |                                                                          |             |     |     |          |           | -                                                                                                                    | - | - |          |         |                                      |                        |
| MX150 ASSY RCP 2X3 CPA DG C/5    | 334727009            | C-DARK GRAY                                                              | GCP         | PLR | CPA | M        | R         | 1                                                                                                                    | - | - | SALEABLE |         | 34951-0610                           | 34951-0620             |
|                                  |                      |                                                                          |             |     |     |          |           | -                                                                                                                    | - | - |          |         |                                      |                        |
| MX150 ASSY RCP 2X3 CS BK A/3     | 334727010            | A-BLACK-CLIP                                                             | GCP         | PLR |     | M        | R         | -                                                                                                                    | 2 | - | SALEABLE |         | N/A                                  | N/A                    |
|                                  |                      |                                                                          |             |     |     |          |           | -                                                                                                                    | 5 | 6 |          |         |                                      |                        |
| MX150 ASSY RCP 2X3 CPA YW A/2    | 334727011            | A-YELLOW                                                                 | GCP         | PLR | CPA | M        | R         | 1                                                                                                                    | 2 | 3 | SALEABLE |         | 34951-0610                           | 34951-0620             |
|                                  |                      |                                                                          |             |     |     |          |           | 4                                                                                                                    | - | - |          |         |                                      |                        |
| MX150 ASSY RCP 2X3 CPA DG C/2    | 334727012            | C-DARK GRAY                                                              | GCP         | PLR | CPA | M        | R         | -                                                                                                                    | - | 3 | SALEABLE |         | 34951-0610                           | 34951-0620             |
|                                  |                      |                                                                          |             |     |     |          |           | 4                                                                                                                    | 5 | 6 |          |         |                                      |                        |
| MX150 ASSY RCP 2X3 CPA LG B/4    | 334727013            | B-LIGHT GRAY                                                             | GCP         | PLR | CPA | M        | R         | -                                                                                                                    | - | - | SALEABLE |         | 34951-0610                           | 34951-0620             |
|                                  |                      |                                                                          |             |     |     |          |           | -                                                                                                                    | 5 | 6 |          |         |                                      |                        |
| MX150 ASSY RCP 2X3 BK A/4        | 334727014            | A-BLACK                                                                  | GCP         | PLR |     | M        | R         | -                                                                                                                    | - | - | SALEABLE |         | 34951-0610                           | 34951-0620             |
|                                  |                      |                                                                          |             |     |     |          |           | 4                                                                                                                    | 5 | - |          |         |                                      |                        |



MX150 RECEPTACLE 2X3 SEALED ASSEMBLY MAT SEAL  
BOM AND PIN OUT SHEET

| ASSEMBLY DESCRIPTION             | ASSEMBLY PART NUMBER | COMPONENT                                                                |             |     |     |          |           | BLOCKED TERMINALS                                                                                                    |   |   | STATUS   | COMMENT | OPTIONAL ATTACHMENTS SOLD SEPARATELY |                        |
|----------------------------------|----------------------|--------------------------------------------------------------------------|-------------|-----|-----|----------|-----------|----------------------------------------------------------------------------------------------------------------------|---|---|----------|---------|--------------------------------------|------------------------|
|                                  |                      | THE PRESENCE OF AN ABBREVIATION INDICATES THE PRESENCE OF THAT COMPONENT |             |     |     |          |           | CAVITY WITH A NUMBER INDICATES BLOCKED TERMINAL POSITION<br>CAVITY WITHOUT A NUMBER INDICATES OPEN TERMINAL POSITION |   |   |          |         | BACKSHELL WITH RIBS                  | BACKSHELL WITHOUT RIBS |
|                                  |                      | HOUSING KEY/COLOR                                                        | GROMMET CAP | PLR | CPA | MAT SEAL | RING SEAL |                                                                                                                      |   |   |          |         |                                      |                        |
| MX150 ASSY RCP 2X3 CS BK A/2     | 334727015            | A-BLACK-CLIP                                                             | GCP         | PLR |     | M        | R         | 1                                                                                                                    | - | 3 | SALEABLE |         | N/A                                  | N/A                    |
|                                  |                      |                                                                          |             |     |     |          |           | 4                                                                                                                    | - | 6 |          |         |                                      |                        |
| MX150 ASSY RCP 2X3 CS CPA BK A/5 | 334727016            | A-BLACK-CLIP                                                             | GCP         | PLR | CPA | M        | R         | -                                                                                                                    | - | - | SALEABLE |         | N/A                                  | N/A                    |
|                                  |                      |                                                                          |             |     |     |          |           | -                                                                                                                    | 5 | - |          |         |                                      |                        |
| MX150 ASSY RCP 2X3 CPA DG C/3    | 334727017            | C-DARK GRAY                                                              | GCP         | PLR | CPA | M        | R         | -                                                                                                                    | - | - | SALEABLE |         | 34951-0610                           | 34951-0620             |
|                                  |                      |                                                                          |             |     |     |          |           | 4                                                                                                                    | 5 | 6 |          |         |                                      |                        |
| MX150 ASSY RCP 2X3 CPA DG C/4    | 334727018            | C-DARK GRAY                                                              | GCP         | PLR | CPA | M        | R         | -                                                                                                                    | - | - | SALEABLE |         | 34951-0610                           | 34951-0620             |
|                                  |                      |                                                                          |             |     |     |          |           | -                                                                                                                    | 5 | 6 |          |         |                                      |                        |
| MX150 ASSY RCP 2X3 LG B/3        | 334727019            | B-LIGHT GRAY                                                             | GCP         | PLR |     | M        | R         | -                                                                                                                    | 2 | - | SALEABLE |         | 34951-0610                           | 34951-0620             |
|                                  |                      |                                                                          |             |     |     |          |           | -                                                                                                                    | 5 | 6 |          |         |                                      |                        |
| MX150 ASSY RCP 2X3 CS CPA LG B/4 | 334727020            | B-LIGHT GRAY-CLIP                                                        | GCP         | PLR | CPA | M        | R         | -                                                                                                                    | - | - | SALEABLE |         | N/A                                  | N/A                    |
|                                  |                      |                                                                          |             |     |     |          |           | -                                                                                                                    | 5 | 6 |          |         |                                      |                        |
| MX150 ASSY RCP 2X3 CS CPA BK A/4 | 334727021            | A-BLACK-CLIP                                                             | GCP         | PLR | CPA | M        | R         | -                                                                                                                    | - | 3 | SALEABLE |         | N/A                                  | N/A                    |
|                                  |                      |                                                                          |             |     |     |          |           | 4                                                                                                                    | - | - |          |         |                                      |                        |
| MX150 ASSY RCP 2X3 CPA BK A/4    | 334727022            | A-BLACK                                                                  | GCP         | PLR | CPA | M        | R         | -                                                                                                                    | - | - | SALEABLE |         | 34951-0610                           | 34951-0620             |
|                                  |                      |                                                                          |             |     |     |          |           | 4                                                                                                                    | - | 6 |          |         |                                      |                        |
| MX150 ASSY RCP 2X3 CS LG B/3     | 334727023            | B-LIGHT GRAY-CLIP                                                        | GCP         | PLR |     | M        | R         | -                                                                                                                    | 2 | - | SALEABLE |         | N/A                                  | N/A                    |
|                                  |                      |                                                                          |             |     |     |          |           | -                                                                                                                    | 5 | 6 |          |         |                                      |                        |
| MX150 ASSY RCP 2X3 CS CPA BK A/2 | 334727024            | A-BLACK-CLIP                                                             | GCP         | PLR | CPA | M        | R         | 1                                                                                                                    | - | 3 | SALEABLE |         | N/A                                  | N/A                    |
|                                  |                      |                                                                          |             |     |     |          |           | 4                                                                                                                    | - | 6 |          |         |                                      |                        |
| MX150 ASSY RCP 2X3 CPA BK A/3    | 334727025            | A-BLACK                                                                  | GCP         | PLR | CPA | M        | R         | 1                                                                                                                    | - | - | SALEABLE |         | 34951-0610                           | 34951-0620             |
|                                  |                      |                                                                          |             |     |     |          |           | 4                                                                                                                    | 5 | - |          |         |                                      |                        |
| MX150 ASSY RCP 2X3 CS CPA BK A/2 | 334727026            | A-BLACK-CLIP                                                             | GCP         | PLR | CPA | M        | R         | -                                                                                                                    | - | 3 | SALEABLE |         | N/A                                  | N/A                    |
|                                  |                      |                                                                          |             |     |     |          |           | 4                                                                                                                    | 5 | 6 |          |         |                                      |                        |
| MX150 ASSY RCP 2X3 CS CPA BK A/3 | 334727027            | A-BLACK-CLIP                                                             | GCP         | PLR | CPA | M        | R         | -                                                                                                                    | - | 3 | SALEABLE |         | N/A                                  | N/A                    |
|                                  |                      |                                                                          |             |     |     |          |           | 4                                                                                                                    | 5 | - |          |         |                                      |                        |
| MX150 ASSY RCP 2X3 CPA BK A/2    | 334727028            | A-BLACK                                                                  | GCP         | PLR | CPA | M        | R         | 1                                                                                                                    | 2 | - | SALEABLE |         | 34951-0610                           | 34951-0620             |
|                                  |                      |                                                                          |             |     |     |          |           | 4                                                                                                                    | 5 | - |          |         |                                      |                        |
| MX150 ASSY RCP 2X3 CPA BK A/4    | 334727029            | A-BLACK                                                                  | GCP         | PLR | CPA | M        | R         | -                                                                                                                    | - | 3 | SALEABLE |         | 34951-0610                           | 34951-0620             |
|                                  |                      |                                                                          |             |     |     |          |           | -                                                                                                                    | - | 6 |          |         |                                      |                        |
| MX150 ASSY RCP 2X3 CPA BK A/2    | 334727030            | A-BLACK                                                                  | GCP         | PLR | CPA | M        | R         | -                                                                                                                    | - | 3 | SALEABLE |         | 34951-0610                           | 34951-0620             |
|                                  |                      |                                                                          |             |     |     |          |           | 4                                                                                                                    | 5 | 6 |          |         |                                      |                        |
| MX150 ASSY RCP 2X3 CS CPA LG B/5 | 334727031            | B-LIGHT GRAY-CLIP                                                        | GCP         | PLR | CPA | M        | R         | -                                                                                                                    | - | - | SALEABLE |         | N/A                                  | N/A                    |
|                                  |                      |                                                                          |             |     |     |          |           | -                                                                                                                    | 5 | - |          |         |                                      |                        |
| MX150 ASSY RCP 2X3 CPA LG B/3    | 334727032            | B-LIGHT GRAY                                                             | GCP         | PLR | CPA | M        | R         | -                                                                                                                    | 2 | - | SALEABLE |         | 34951-0610                           | 34951-0620             |
|                                  |                      |                                                                          |             |     |     |          |           | -                                                                                                                    | 5 | 6 |          |         |                                      |                        |








SHEET DESCRIPTION


CONFIGURATIONS

C8

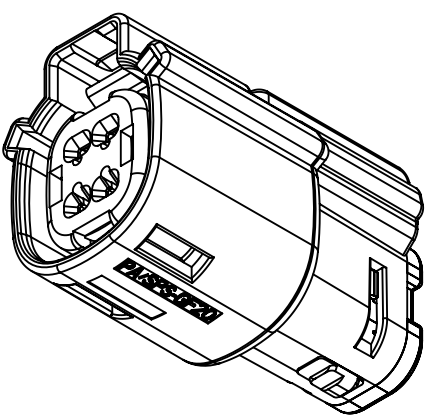


2X2 - STD.  
2X2 - TRNS. - SILICONE FREE  
2X2 - MID-VOLT


B

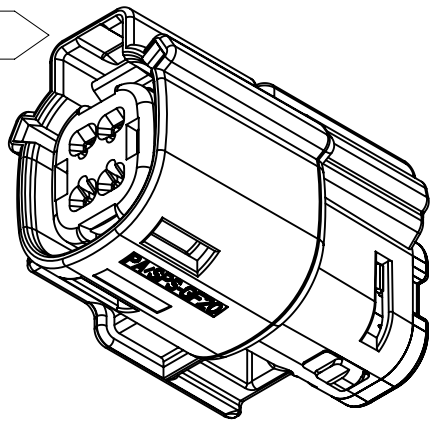

2X2 - STD. - WITH CLIPSLOT \*

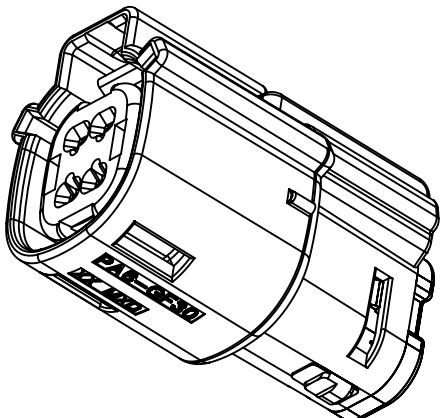


† 2X2 - UL V0

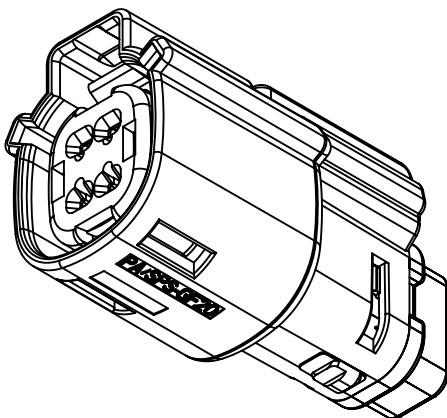


2X2 - STD. - LENGTHENED


C8

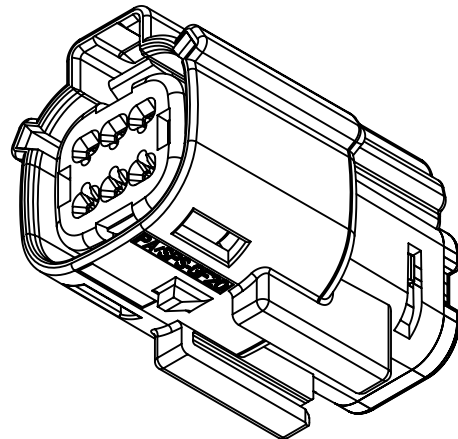


2X3 - STD. - WITH CLIPSLOT  
2X3 - MID-VOLT. - WITH CLIPSLOT

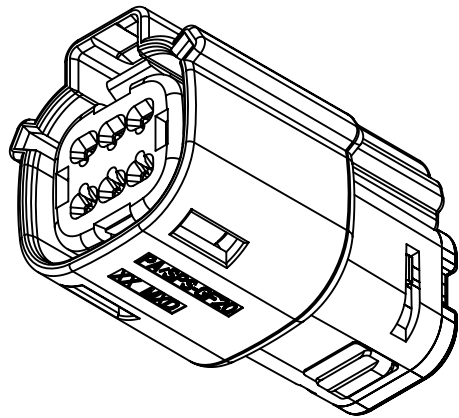


2X3 - STD.  
2X3 - TRNS. - CONTAINS SILICONE

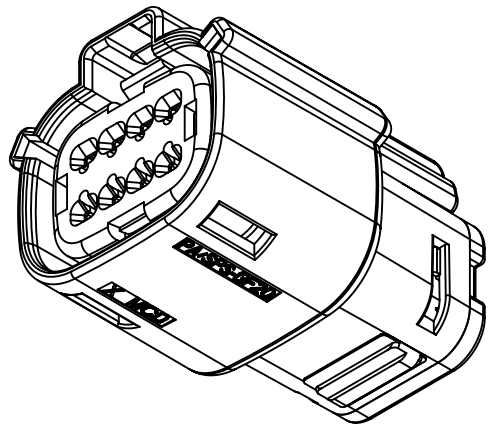


2X4 - STD.

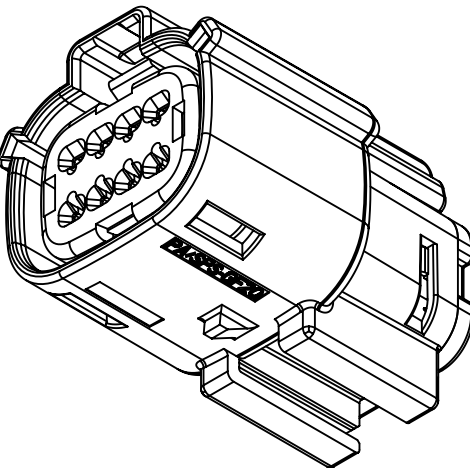


2X4 - STD. - WITH CLIPSLOT \*

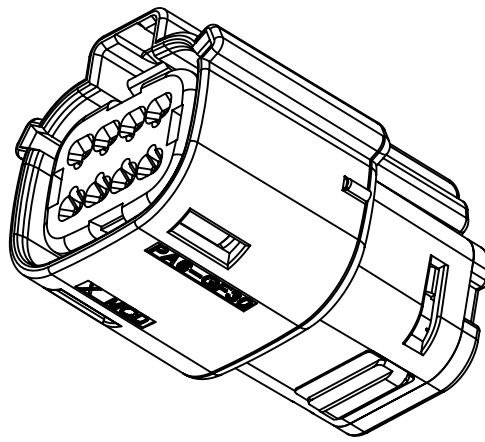

† 2X4 - UL V0

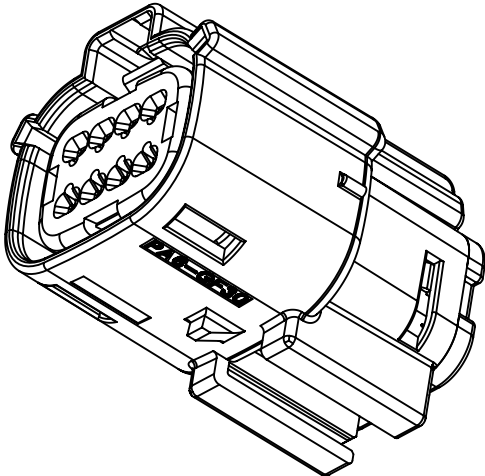


† 2X4 - UL V0-WITH CLIPSLOT\*

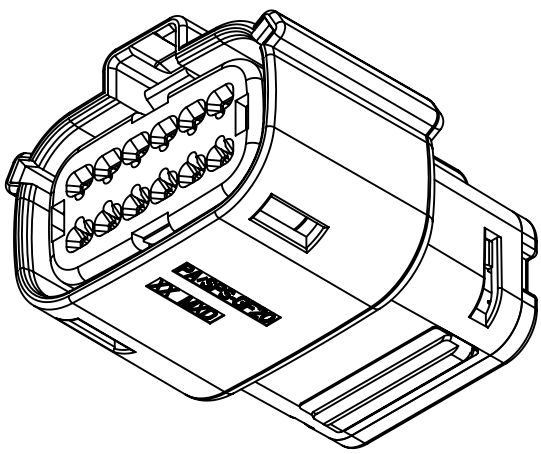

2X6 - STD.

C1


† 2X6 - TRNS.

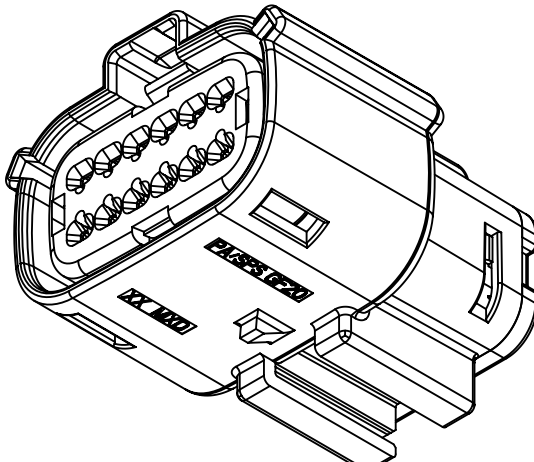


2X6 - STD. - WITH CLIPSLOT \*

C1

† 2X6 - TRNS. - WITH CLIPSLOT \*

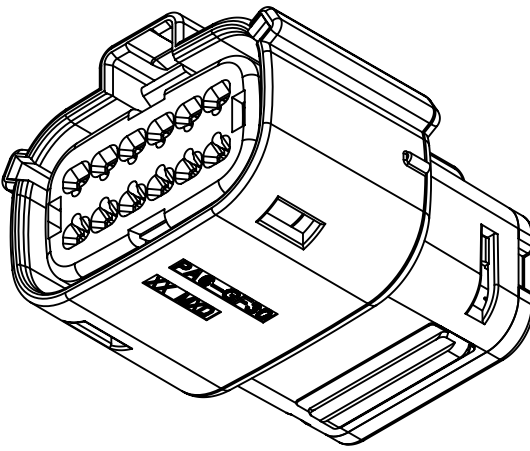


† 2X6 - UL V0

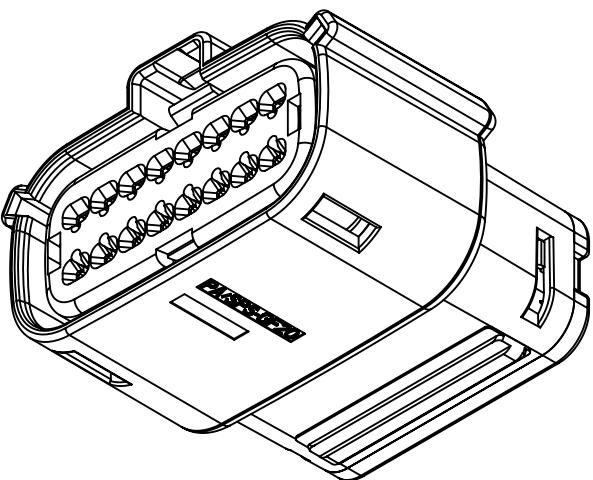


2X8 - STD.

B

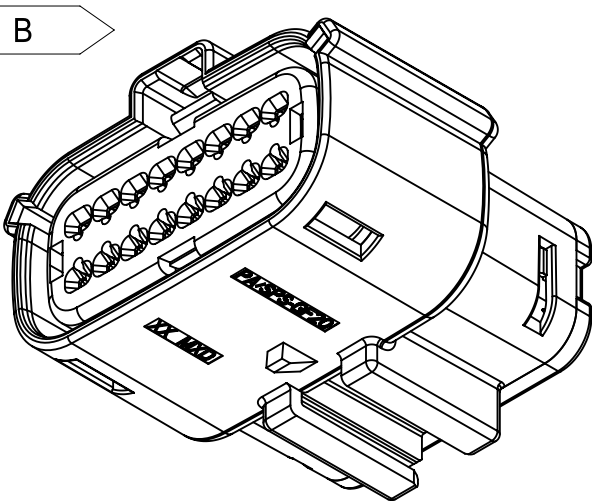


2X8 - STD. - WITH CLIPSLOT \*

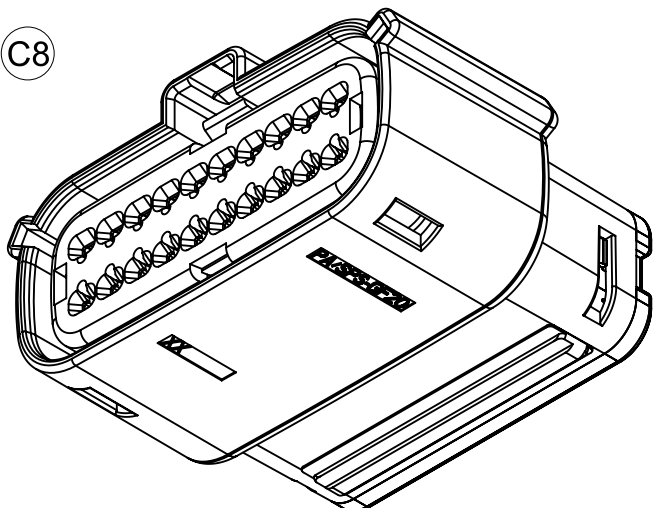


2X10 - STD.  
2X10 - MID-VOLT.

C8

C

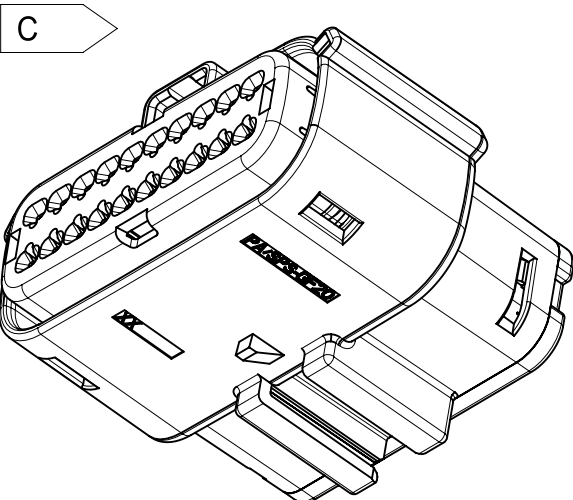

2X10 - STD. - WITH CLIPSLOT \*

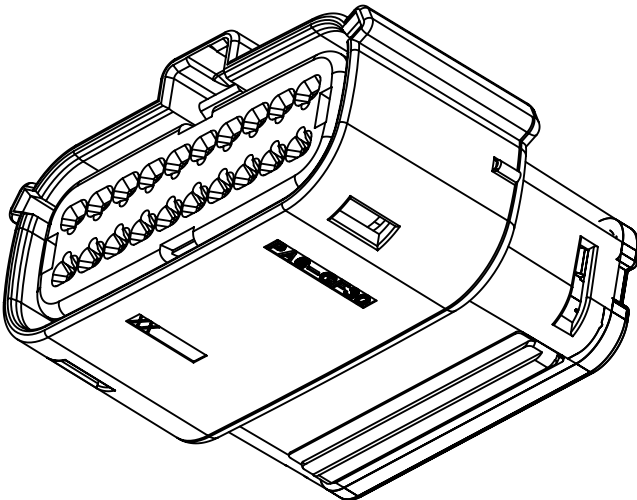

† 2X10 - UL V0

\* WITH CLIPSLOT CONFIGURATION DOES NOT  
MEET THE USCAR PACKAGING FRAME REQUIREMENTS  
† MINOR GEOMETRY DIFFERENCE THAN STANDARD CONFIGURATION  
SEE NOTES 1a & 2a-b FOR MORE INFORMATION


|                                                      |                                                                                                                                               |                        |         |         |                                      |        |                                                                                                                                                  |                 |  |                |                                                                            |              |  |          |  |
|------------------------------------------------------|-----------------------------------------------------------------------------------------------------------------------------------------------|------------------------|---------|---------|--------------------------------------|--------|--------------------------------------------------------------------------------------------------------------------------------------------------|-----------------|--|----------------|----------------------------------------------------------------------------|--------------|--|----------|--|
| FUNCTIONAL SYMBOLS                                   | THIS DRAWING CONTAINS INFORMATION THAT IS PROPRIETARY TO MOLEX ELECTRONIC TECHNOLOGIES, LLC AND SHOULD NOT BE USED WITHOUT WRITTEN PERMISSION |                        |         |         |                                      |        |                                                                                                                                                  |                 |  |                | <div>molex</div> <div>MX150 RCPT</div> <div>DUAL ROW SEALED ASSEMBLY</div> |              |  |          |  |
|                                                      | DIMENSION UNITS                                                                                                                               |                        | SCALE   |         | CURRENT REV DESC: SEE REVISION TABLE |        |                                                                                                                                                  |                 |  |                |                                                                            |              |  |          |  |
|                                                      | MM                                                                                                                                            |                        | 1:1     |         |                                      |        |                                                                                                                                                  |                 |  |                |                                                                            |              |  |          |  |
|                                                      | GENERAL TOLERANCES (UNLESS SPECIFIED)                                                                                                         |                        |         |         |                                      |        |                                                                                                                                                  |                 |  |                |                                                                            |              |  |          |  |
|                                                      | ANGULAR TOL                                                                                                                                   |                        | ±       |         | 1°                                   |        | STATUS: Production<br>DRWN: Yuki Song<br>CHK'D: Elvis Song<br>APPR: Isong05<br><div>2025-07-16</div> <div>2025-07-17</div> <div>2025-07-17</div> |                 |  |                |                                                                            |              |  |          |  |
|                                                      | 4 PLACES                                                                                                                                      |                        | ±       |         |                                      |        |                                                                                                                                                  |                 |  |                |                                                                            |              |  |          |  |
|                                                      | 3 PLACES                                                                                                                                      |                        | ±       |         |                                      |        |                                                                                                                                                  |                 |  |                |                                                                            |              |  |          |  |
|                                                      | 2 PLACES                                                                                                                                      |                        | ± 0.100 |         |                                      |        |                                                                                                                                                  |                 |  |                |                                                                            |              |  |          |  |
|                                                      | 1 PLACE                                                                                                                                       |                        | ± 0.20  |         |                                      |        |                                                                                                                                                  |                 |  |                |                                                                            |              |  |          |  |
|                                                      | 0 PLACES                                                                                                                                      |                        | ±       |         |                                      |        |                                                                                                                                                  |                 |  |                |                                                                            |              |  |          |  |
| DRAFT WHERE APPLICABLE MUST REMAIN WITHIN DIMENSIONS |                                                                                                                                               | THIRD ANGLE PROJECTION |         | DRAWING |                                      | SERIES |                                                                                                                                                  | DOCUMENT NUMBER |  | DOC TYPE       |                                                                            | DOC PART     |  | REVISION |  |
|                                                      |                                                                                                                                               |                        |         | A1-SIZE |                                      | 33472  |                                                                                                                                                  | SD-33472-0001   |  | PSD            |                                                                            | 001          |  | C11      |  |
|                                                      |                                                                                                                                               |                        |         |         |                                      |        |                                                                                                                                                  | MATERIAL NUMBER |  | CUSTOMER       |                                                                            | SHEET NUMBER |  |          |  |
|                                                      |                                                                                                                                               |                        |         |         |                                      |        |                                                                                                                                                  |                 |  | GENERAL MARKET |                                                                            | 2 OF 11      |  |          |  |




SHEET DESCRIPTION

KEY CONFIGURATIONS


2X2

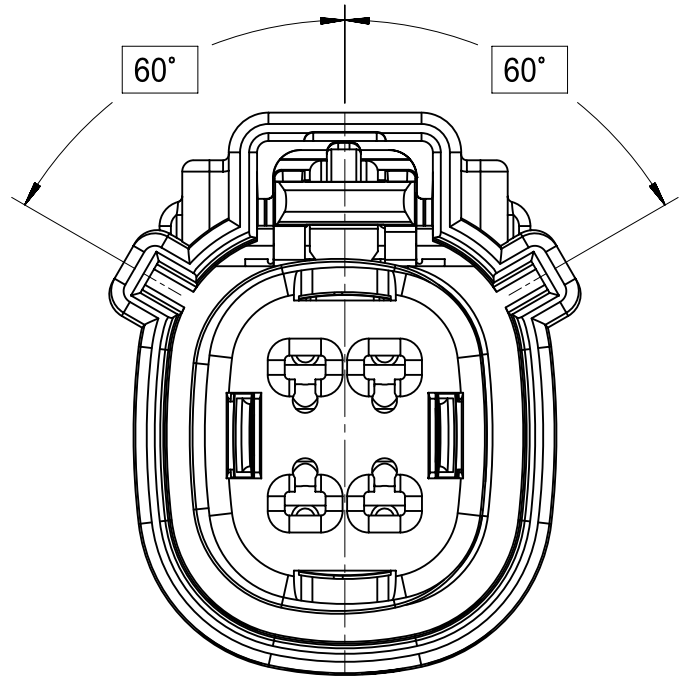


KEY A

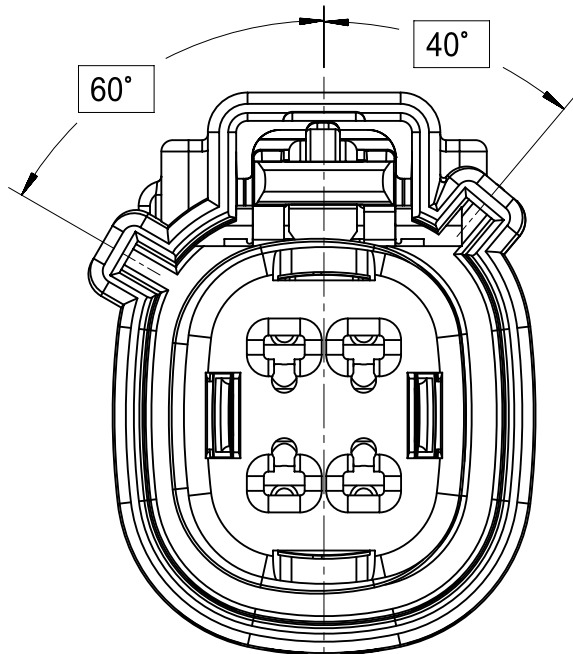

KEY B

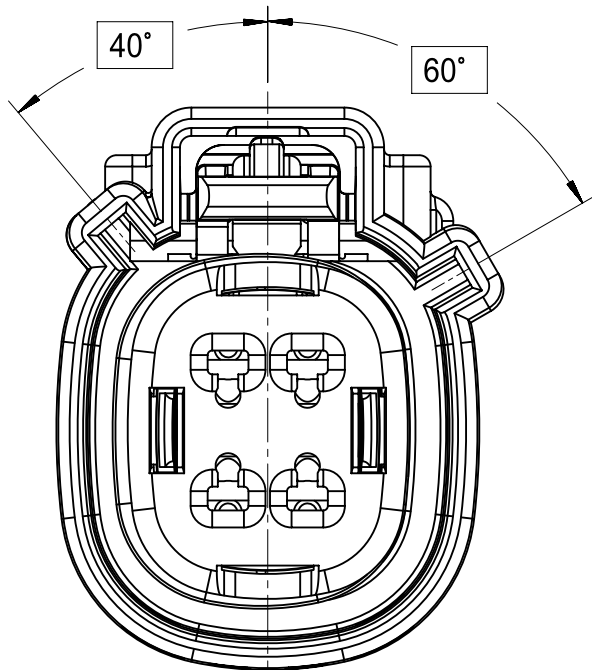


KEY C

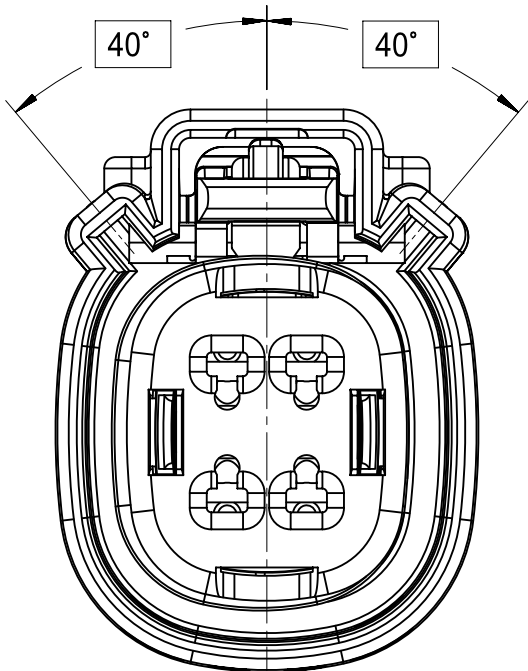


KEY D


2X3

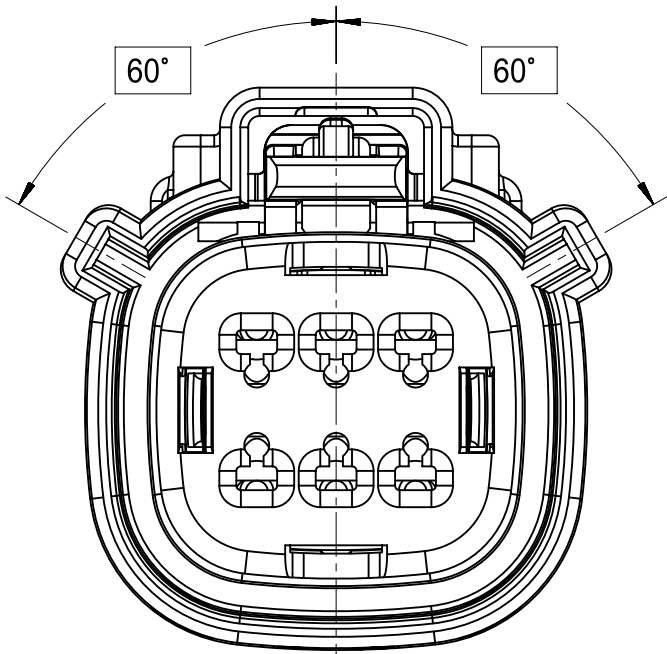


KEY A

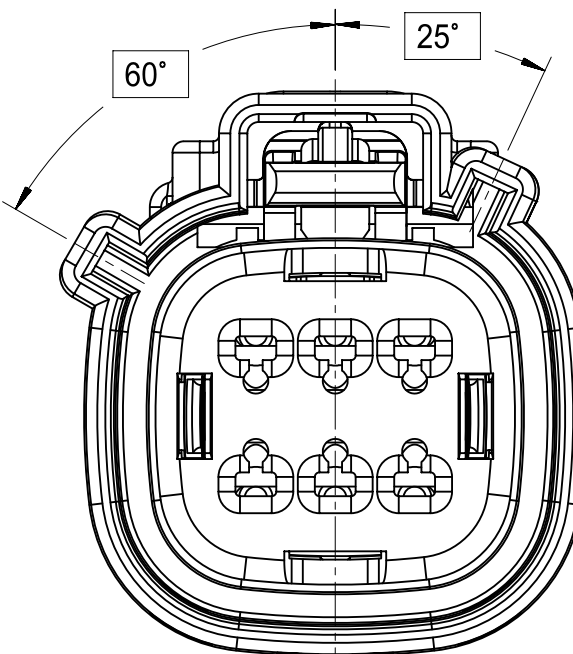

KEY B

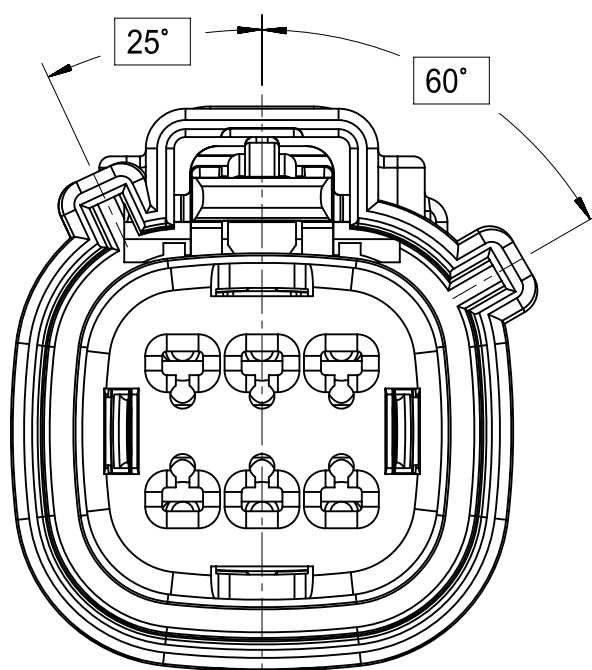


KEY C

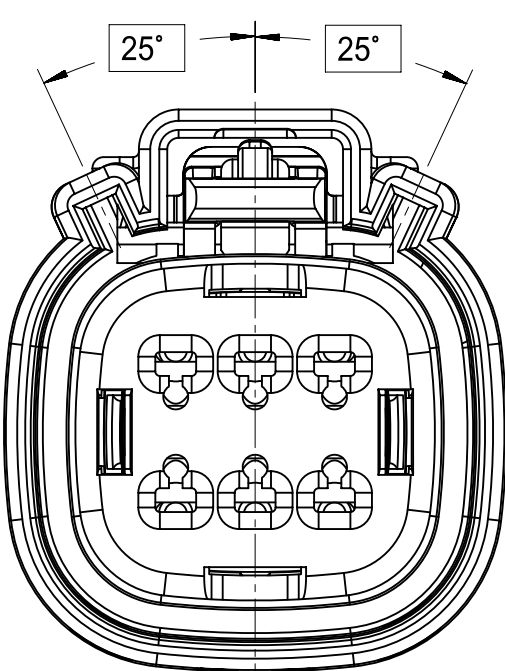


KEY D


2X4

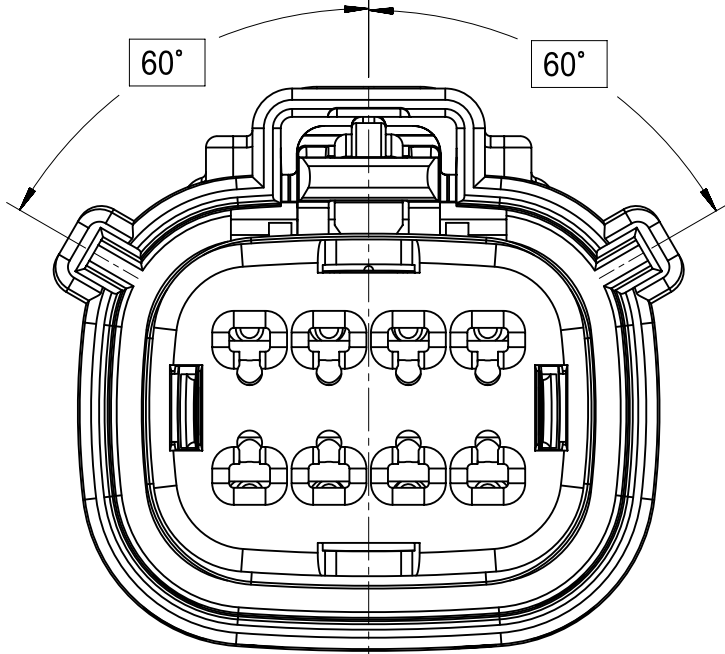


KEY A

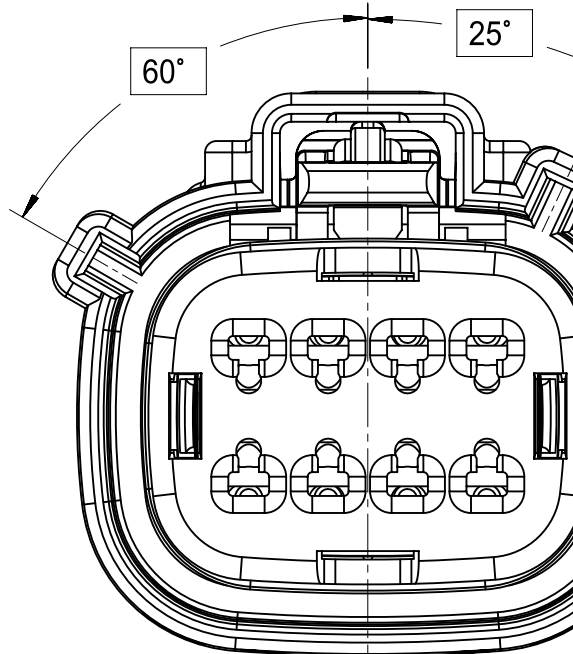

KEY B

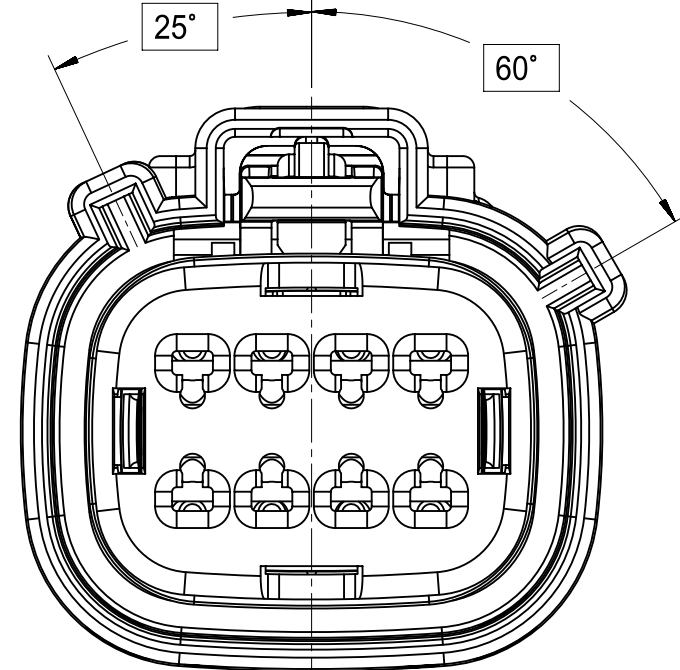

KEY C

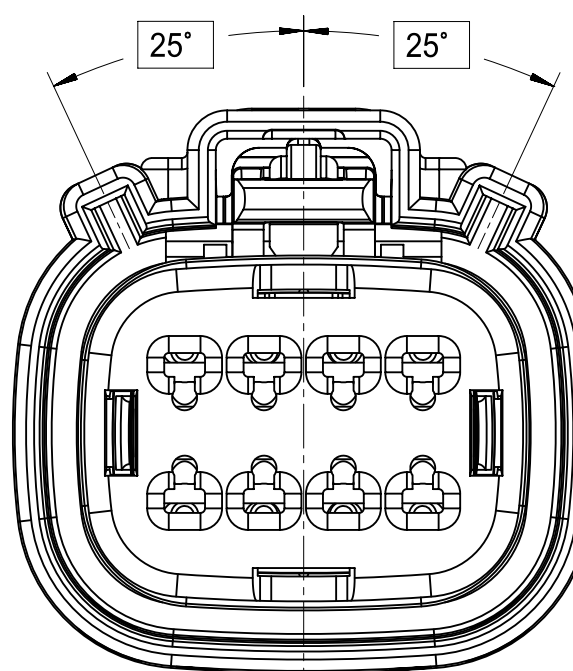

KEY D

FUNCTIONAL SYMBOLS

$\frac{F}{A}$

= 0

$\frac{F}{C}$

= 0

$\frac{F}{D}$

= 0

DIVISIONAL SYMBOLS

THIS DRAWING CONTAINS INFORMATION THAT IS PROPRIETARY TO MOLEX ELECTRONIC TECHNOLOGIES, LLC AND SHOULD NOT BE USED WITHOUT WRITTEN PERMISSION

DIMENSION UNITS

MM

SCALE

1:1

GENERAL TOLERANCES (UNLESS SPECIFIED)

ANGULAR TOL ± 1°

4 PLACES ±

3 PLACES ±

2 PLACES ± 0.100

1 PLACE ± 0.20

0 PLACES ±

DRAFT WHERE APPLICABLE MUST REMAIN WITHIN DIMENSIONS

STATUS: Production

DRWN: Yuki Song

CHK'D: Elvis Song

APPR: Isong05

2025-07-16

2025-07-17

2025-07-17

THIRD ANGLE PROJECTION

DRAWING

A1-SIZE

SERIES

33472

CURRENT REV DESC: SEE REVISION TABLE

PRODUCT CUSTOMER DRAWING

DOCUMENT NUMBER

SD-33472-0001

CUSTOMER

GENERAL MARKET

DOC TYPE

PSD

DOC PART

001

REVISION

C11

SHEET NUMBER


3 OF 11




SHEET DESCRIPTION

KEY CONFIGURATIONS CONT.


2X6

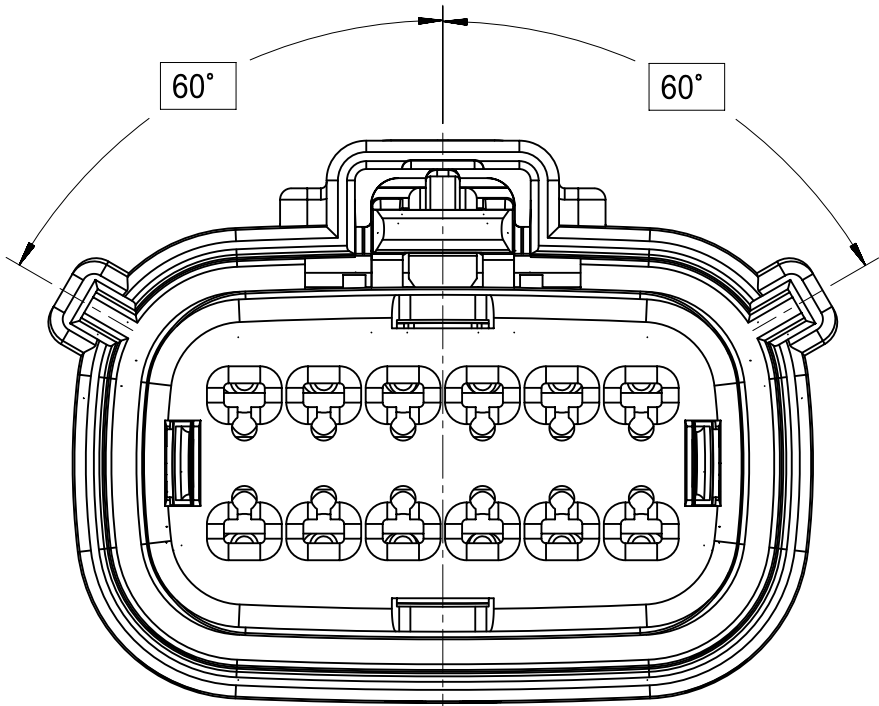


KEY A

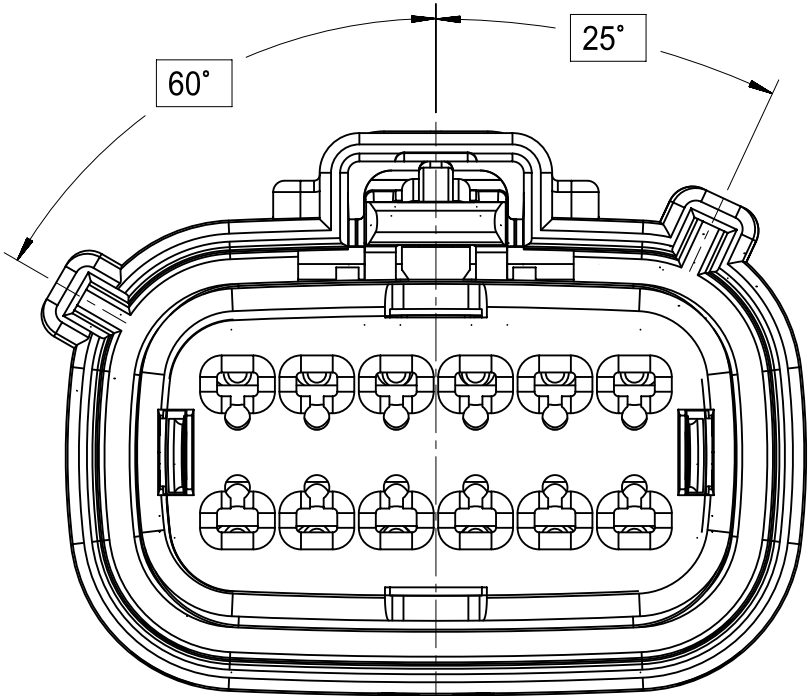

KEY B

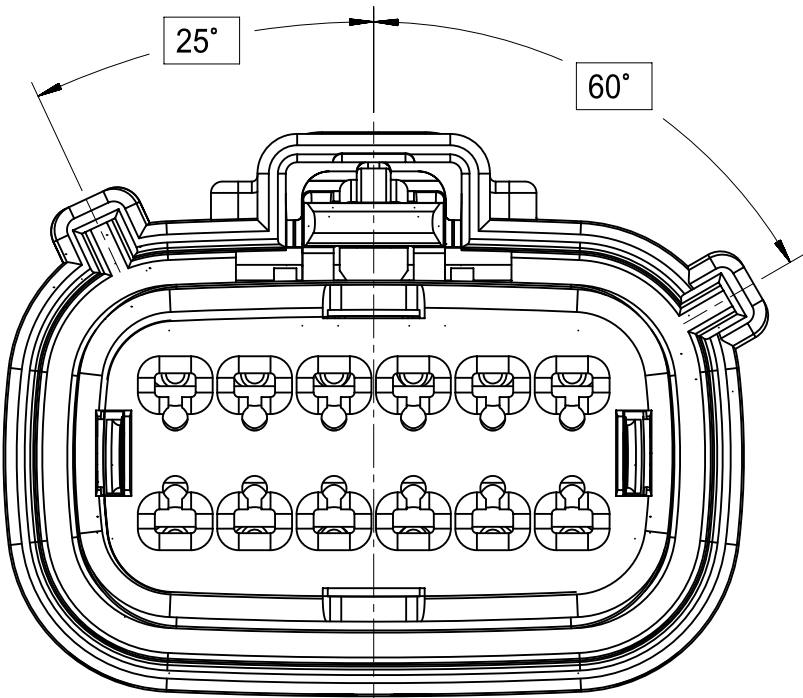


KEY C

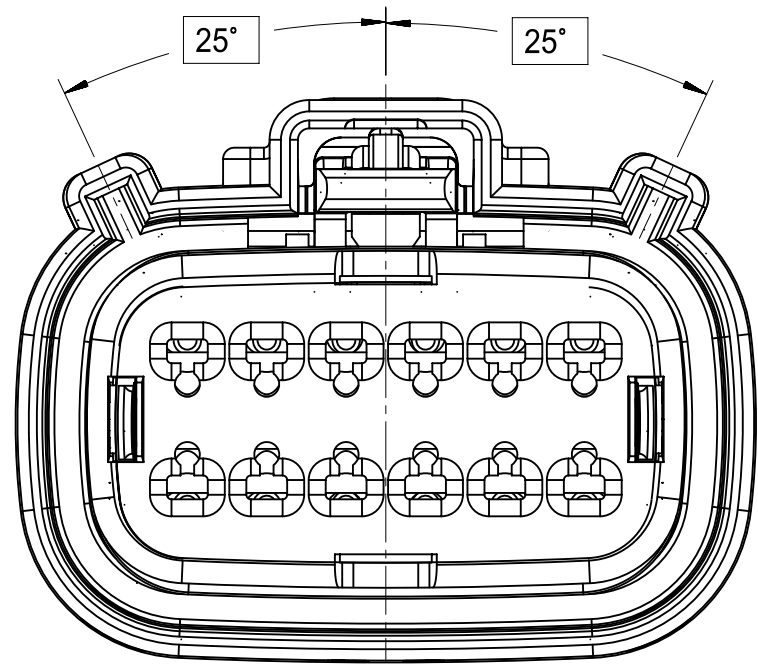


KEY D


2X8

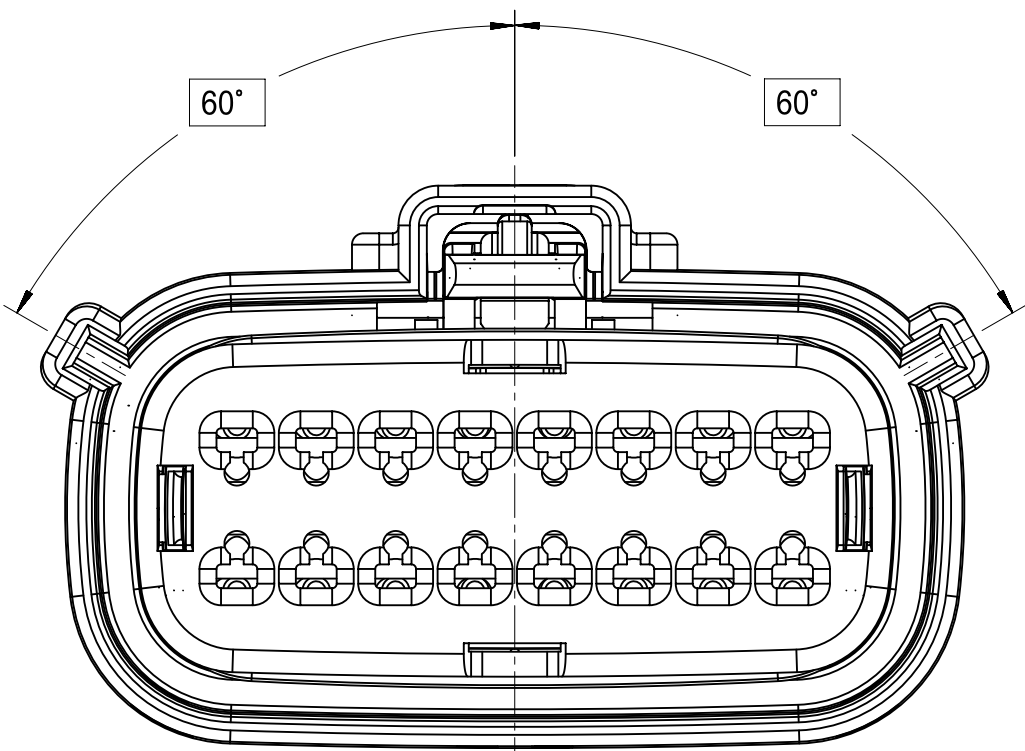


KEY A

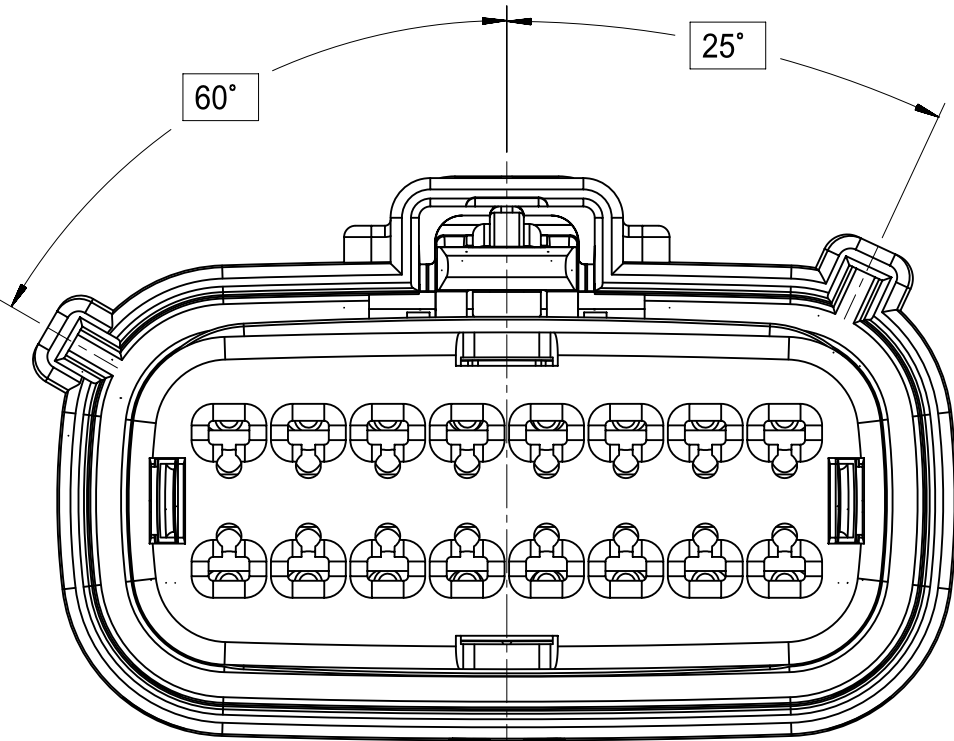

KEY B

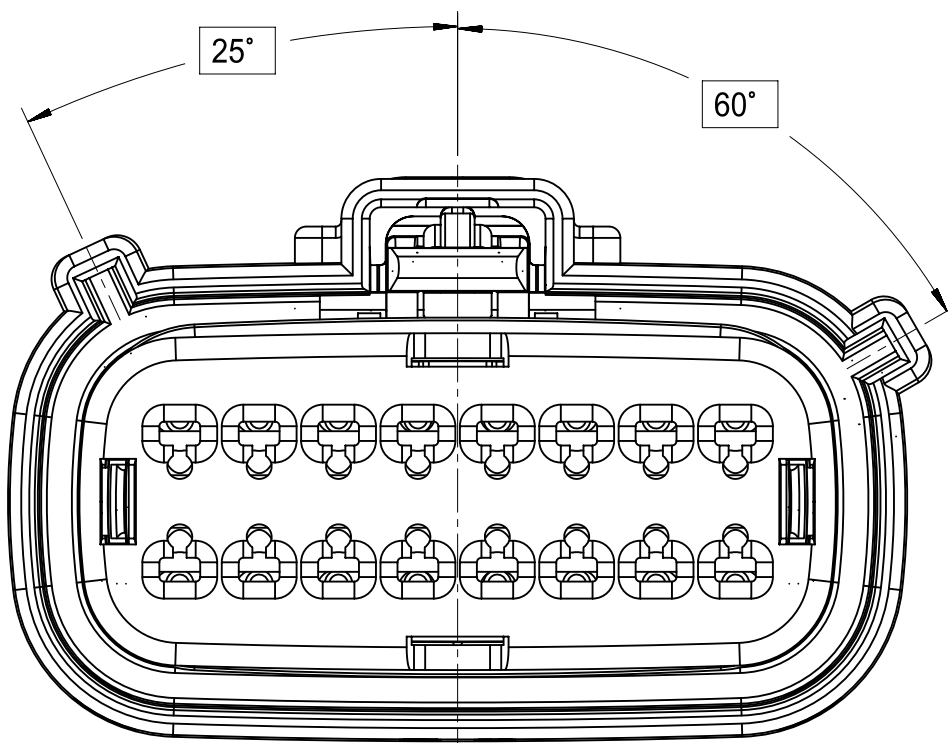


KEY C

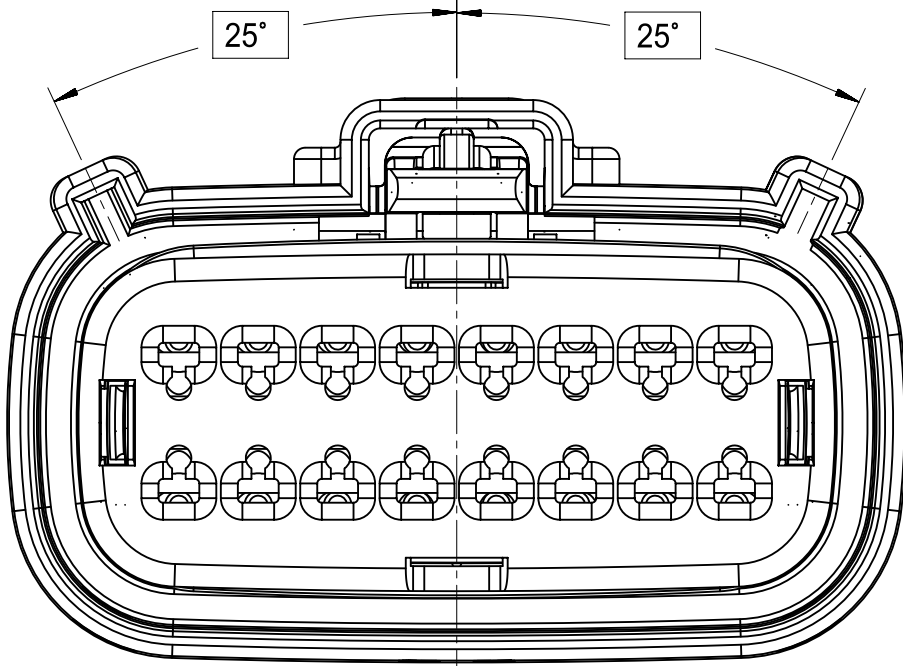


KEY D


2X10

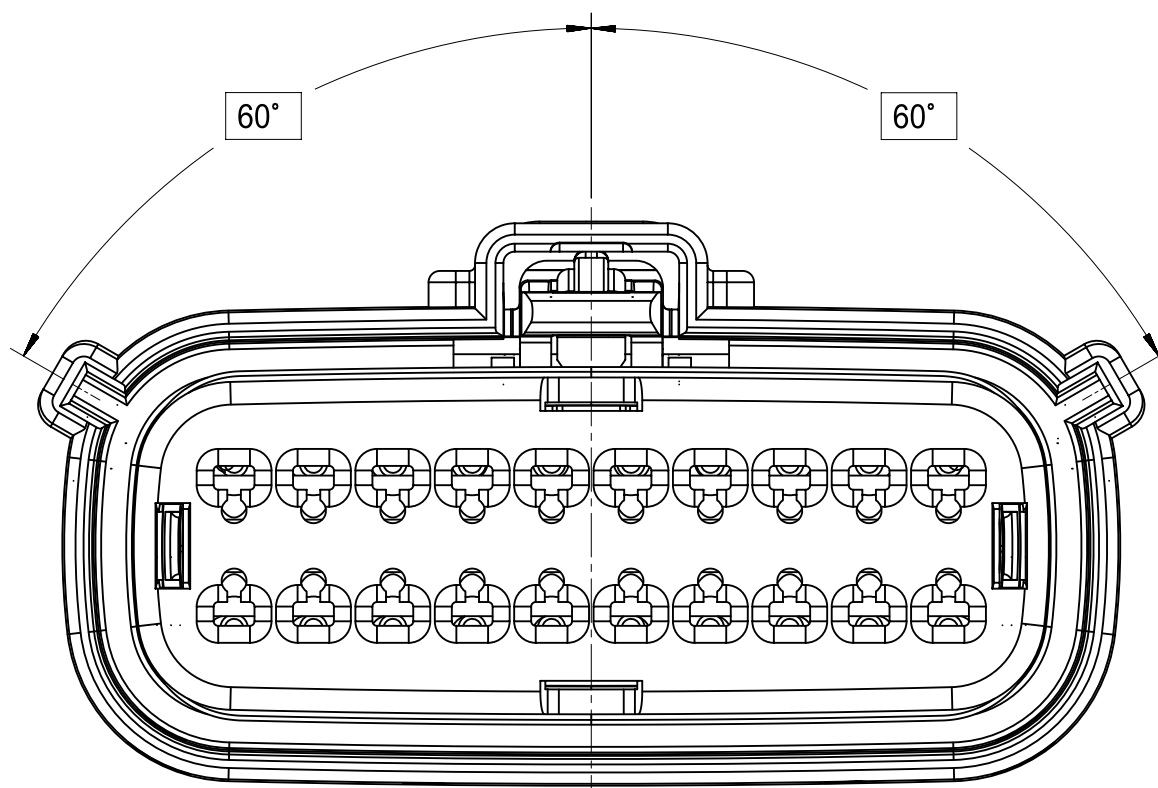


KEY A

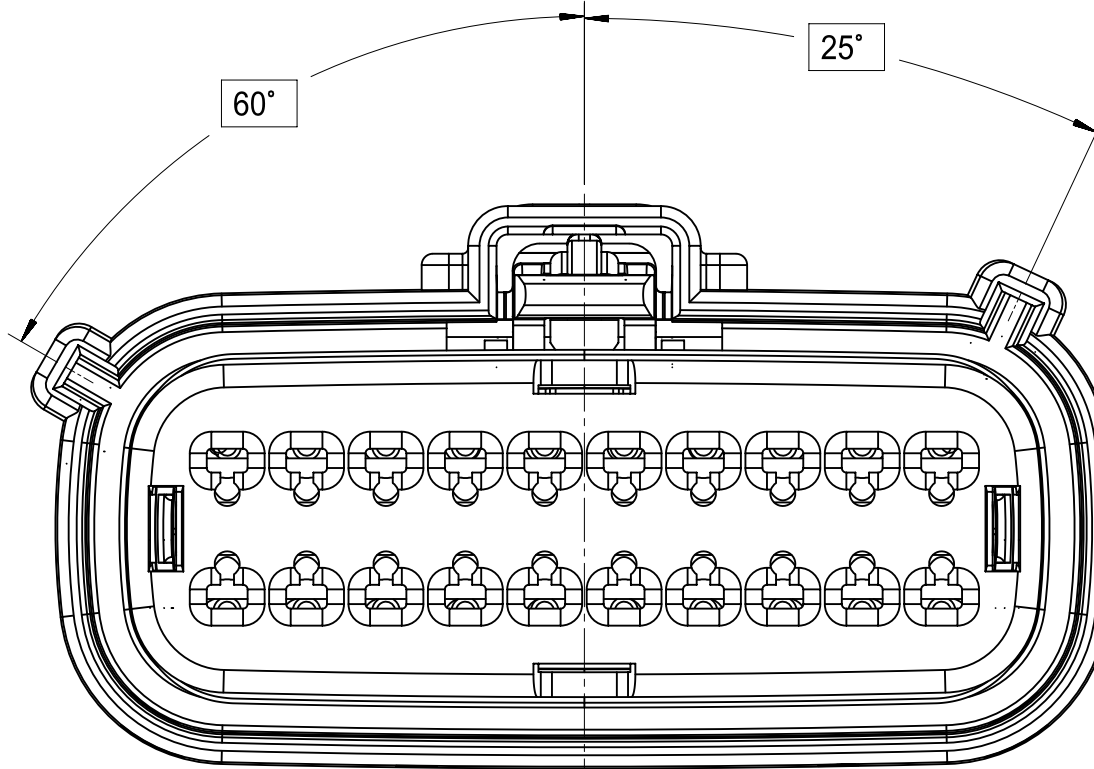

KEY B

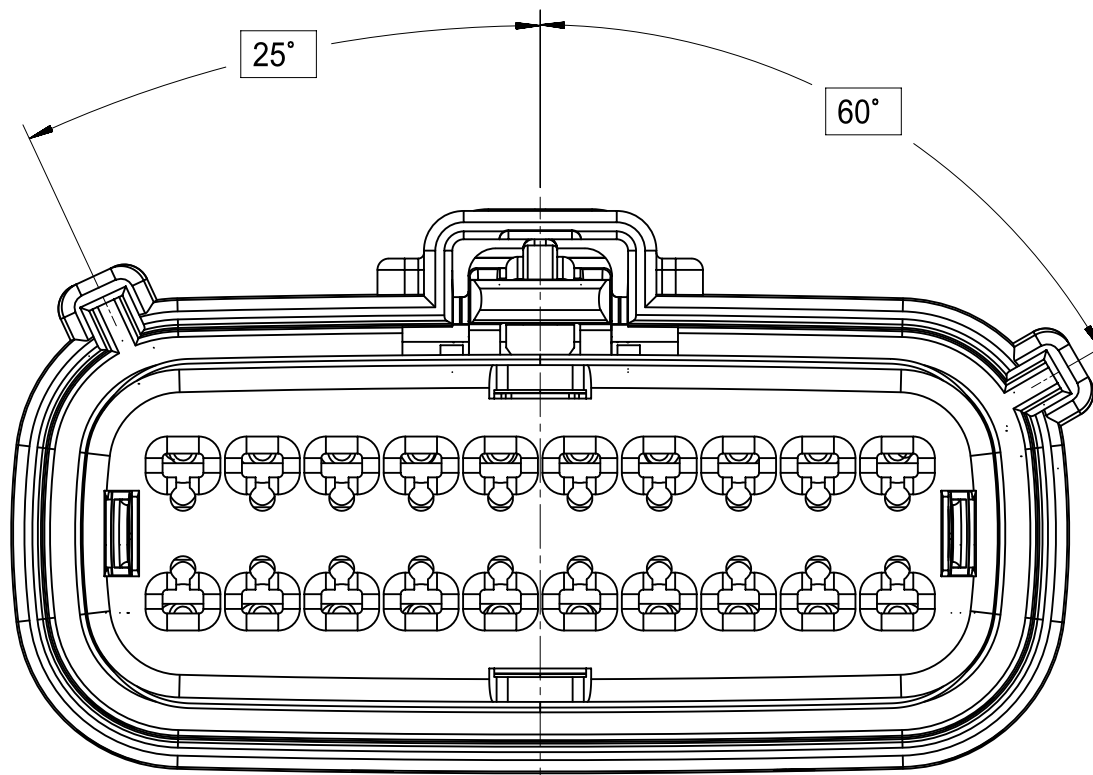

KEY C

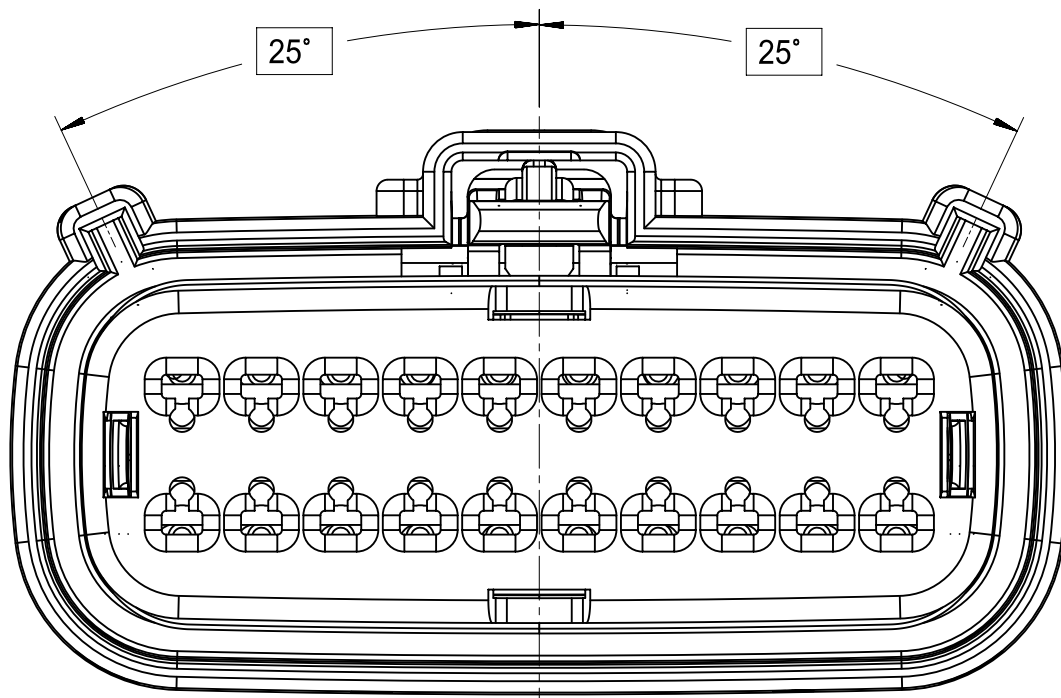

KEY D

|                                                                           |                                                                                                                                               |            |                                      |                 |        |                |          |              |
|---------------------------------------------------------------------------|-----------------------------------------------------------------------------------------------------------------------------------------------|------------|--------------------------------------|-----------------|--------|----------------|----------|--------------|
| FUNCTIONAL SYMBOLS<br>E/A = 0<br>E/C = 0<br>E/P = 0<br>DIVISIONAL SYMBOLS | THIS DRAWING CONTAINS INFORMATION THAT IS PROPRIETARY TO MOLEX ELECTRONIC TECHNOLOGIES, LLC AND SHOULD NOT BE USED WITHOUT WRITTEN PERMISSION |            | CURRENT REV DESC: SEE REVISION TABLE |                 |        |                |          |              |
|                                                                           | DIMENSION UNITS                                                                                                                               | SCALE      |                                      |                 |        |                |          |              |
|                                                                           | MM                                                                                                                                            | 1:1        |                                      |                 |        |                |          |              |
|                                                                           | GENERAL TOLERANCES (UNLESS SPECIFIED)                                                                                                         |            |                                      |                 |        |                |          |              |
|                                                                           | ANGULAR TOL                                                                                                                                   | ±          | 1°                                   |                 |        |                |          |              |
|                                                                           | 4 PLACES                                                                                                                                      | ±          |                                      |                 |        |                |          |              |
|                                                                           | 3 PLACES                                                                                                                                      | ±          |                                      |                 |        |                |          |              |
|                                                                           | 2 PLACES                                                                                                                                      | ±          | 0.100                                |                 |        |                |          |              |
|                                                                           | 1 PLACE                                                                                                                                       | ±          | 0.20                                 |                 |        |                |          |              |
|                                                                           | 0 PLACES                                                                                                                                      | ±          |                                      |                 |        |                |          |              |
|                                                                           | DRAFT WHERE APPLICABLE MUST REMAIN WITHIN DIMENSIONS                                                                                          |            | THIRD ANGLE PROJECTION               | DRAWING         | SERIES |                |          |              |
|                                                                           |                                                                                                                                               |            |                                      | A1-SIZE         | 33472  |                |          |              |
| STATUS: Production                                                        |                                                                                                                                               | 2025-07-16 |                                      | DOCUMENT NUMBER |        | DOC TYPE       | DOC PART | REVISION     |
| DRWN: Yuki Song                                                           |                                                                                                                                               | 2025-07-17 |                                      | SD-33472-0001   |        | PSD            | 001      | C11          |
| CHK'D: Elvis Song                                                         |                                                                                                                                               | 2025-07-17 |                                      | MATERIAL NUMBER |        | CUSTOMER       |          | SHEET NUMBER |
| APPR: Isong05                                                             |                                                                                                                                               |            |                                      |                 |        | GENERAL MARKET |          | 4 OF 11      |

molex

MX150 RCPT  
DUAL ROW SEALED ASSEMBLY

PRODUCT CUSTOMER DRAWING



|                 |          |          |          |
|-----------------|----------|----------|----------|
| DOCUMENT NUMBER | DOC TYPE | DOC PART | REVISION |
| SD-33472-0001   | PSD      | 001      | C11      |

|                 |                |              |
|-----------------|----------------|--------------|
| MATERIAL NUMBER | CUSTOMER       | SHEET NUMBER |
|                 | GENERAL MARKET | 4 OF 11      |












SHEET DESCRIPTION

RECEPTACLE CONNECTOR ASSEMBLY

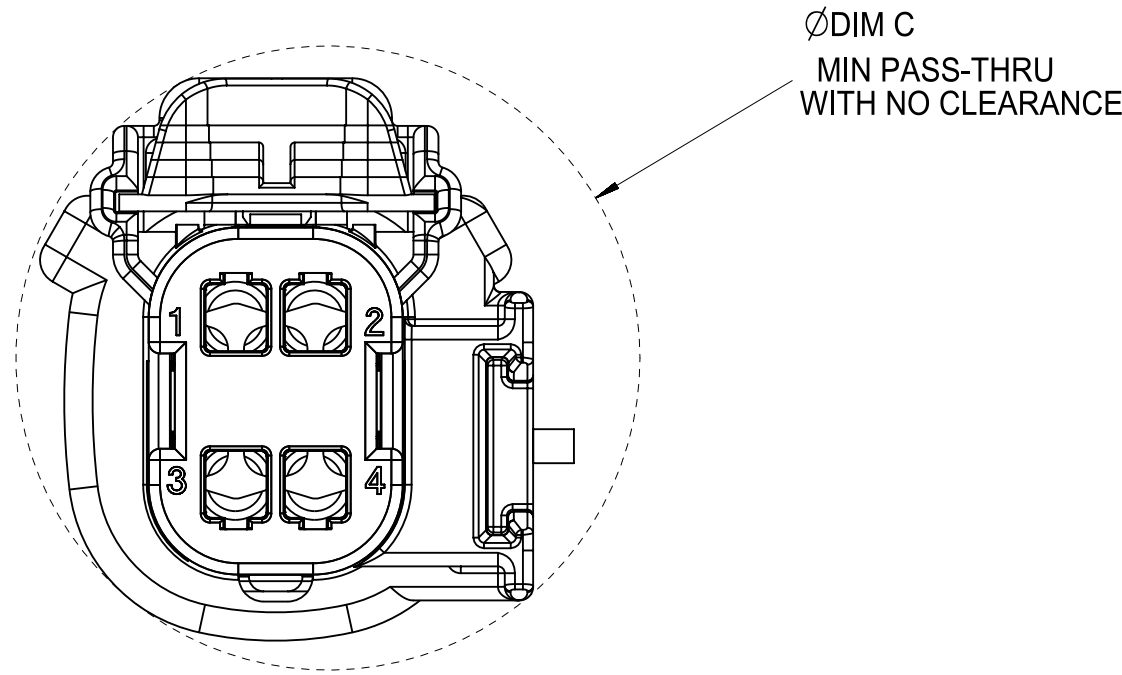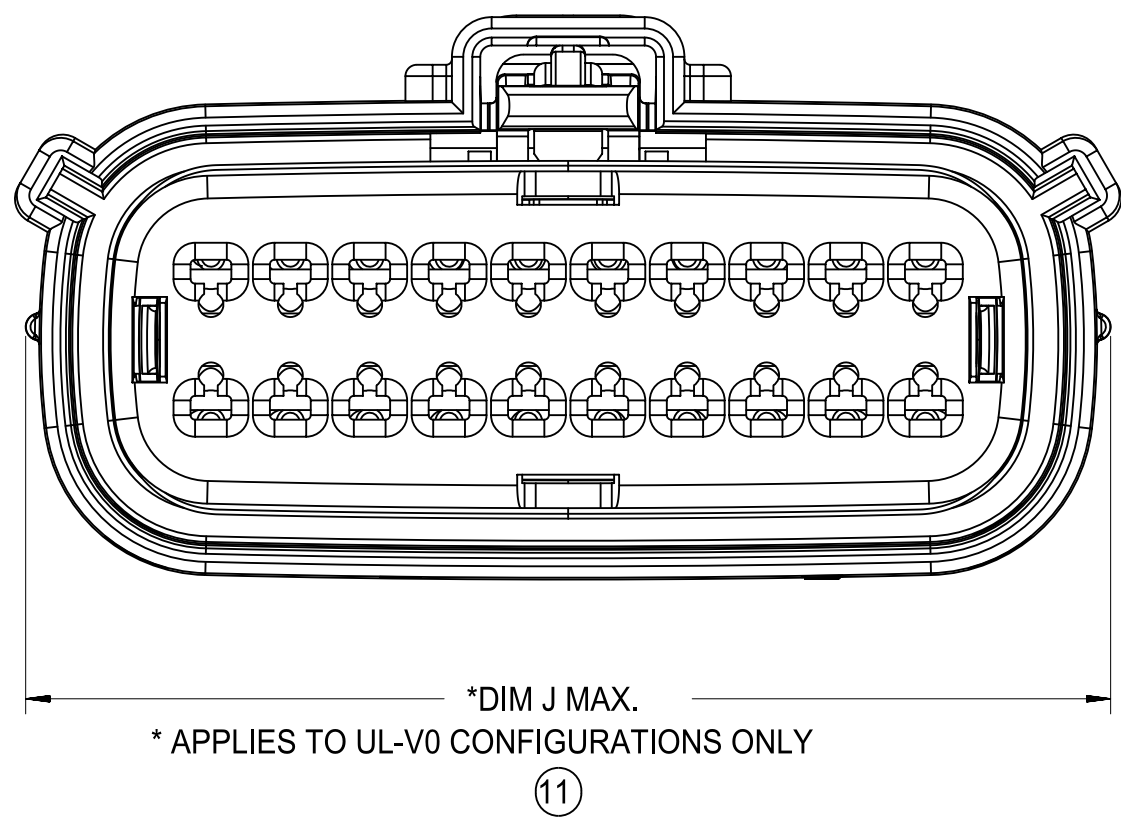

B APPLIES TO 2X2 - STD. - WITH CLIPSLOT ONLY

| CHARTED DIMENSIONS |            |      |       |       |       |       |           |       |
|--------------------|------------|------|-------|-------|-------|-------|-----------|-------|
| DESCRIPTION        | DIMENSIONS |      |       |       |       |       |           |       |
|                    | A          | B    | C     | D     | E     | F     | G         | J     |
| 2X2 W/O CLIPSLOT   | 18.75      | 1.75 | 25.45 | 24.90 | 37.65 | N/A   | 2.75±0.50 |       |
| 2X2 W/ CLIPSLOT    | 18.75      | 1.75 | 27.65 | 24.90 | 37.65 | N/A   | 2.75±0.50 |       |
| 2X2 LENGTHENED     | 18.75      | 1.75 | 25.45 | 24.90 | 42.25 | N/A   | 2.75±0.50 | 20.04 |
| 2X3 W/ CLIPSLOT    | 22.25      | 3.5  | 30.50 | N/A   | 37.65 | 27.96 | 4.0±0.4   |       |
| 2X3 W/O CLIPSLOT   | 22.25      | 3.5  | 26.24 | 24.90 | 37.65 | N/A   | 4.0±0.4   |       |
| 2X4 W/ CLIPSLOT    | 25.75      | 1.75 | 31.50 | N/A   | 37.65 | 28.00 | 2.75±0.50 | 27.04 |
| 2X4 W/O CLIPSLOT   | 25.75      | 1.75 | 29.19 | 24.90 | 37.65 | N/A   | 2.75±0.50 | 27.04 |
| 2X6 W/ CLIPSLOT    | 32.75      | 1.75 | 35.58 | N/A   | 37.65 | 27.76 | 2.75±0.50 |       |
| 2X6 W/O CLIPSLOT   | 32.75      | 1.75 | 35.58 | 24.90 | 37.65 | N/A   | 2.75±0.50 | 34.04 |
| 2X8 W/O CLIPSLOT   | 39.80      | 1.75 | 42.25 | 24.90 | 37.65 | N/A   | 4.0±0.4   |       |
| 2X8 W/ CLIPSLOT    | 39.80      | 1.75 | 42.25 | N/A   | 37.65 | 27.80 | 4.0±0.4   |       |
| 2X10 W/O CLIPSLOT  | 46.75      | 1.75 | 49.95 | 24.90 | 37.65 | N/A   | 2.75±0.50 | 48.04 |
| 2X10 W/ CLIPSLOT   | 46.75      | 1.75 | 49.95 | N/A   | 37.65 | 27.80 | 2.75±0.50 |       |

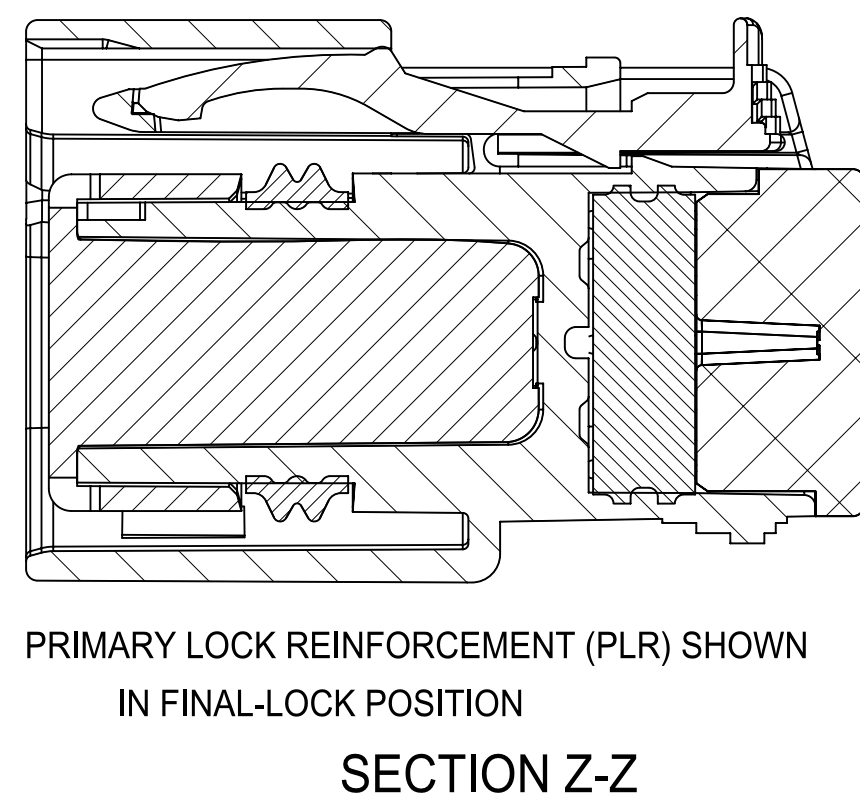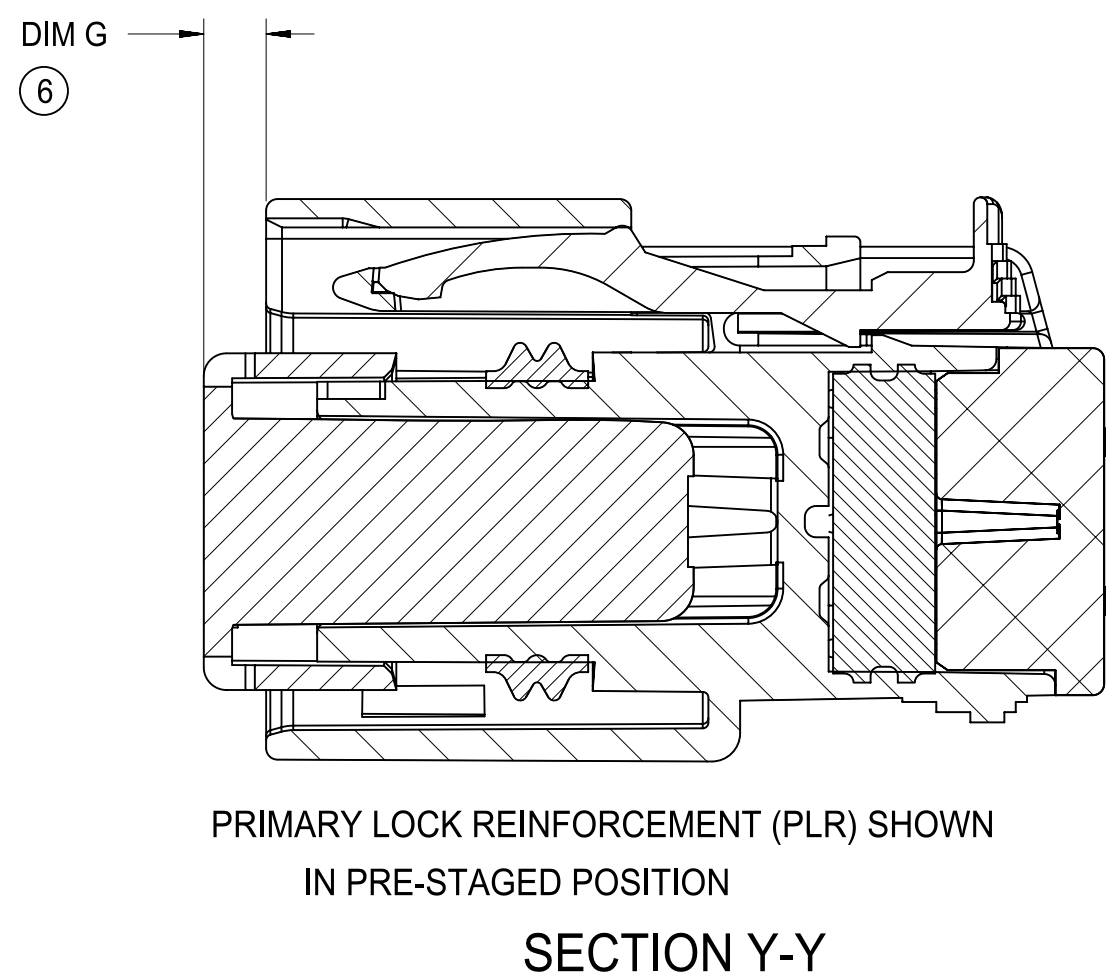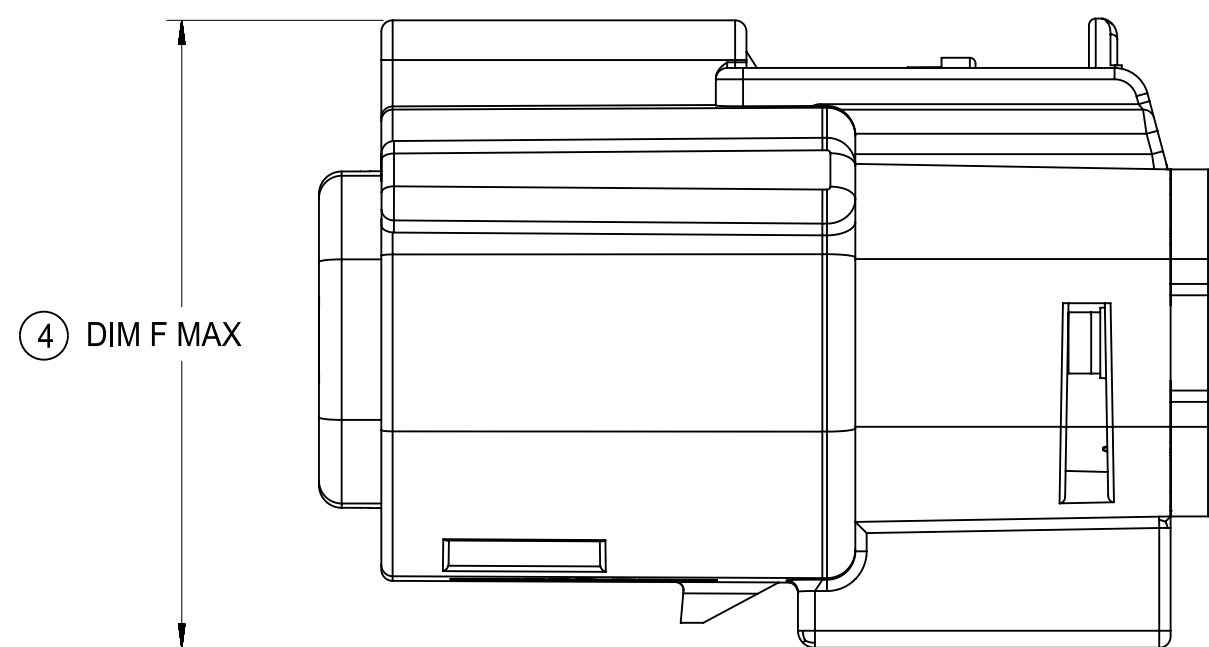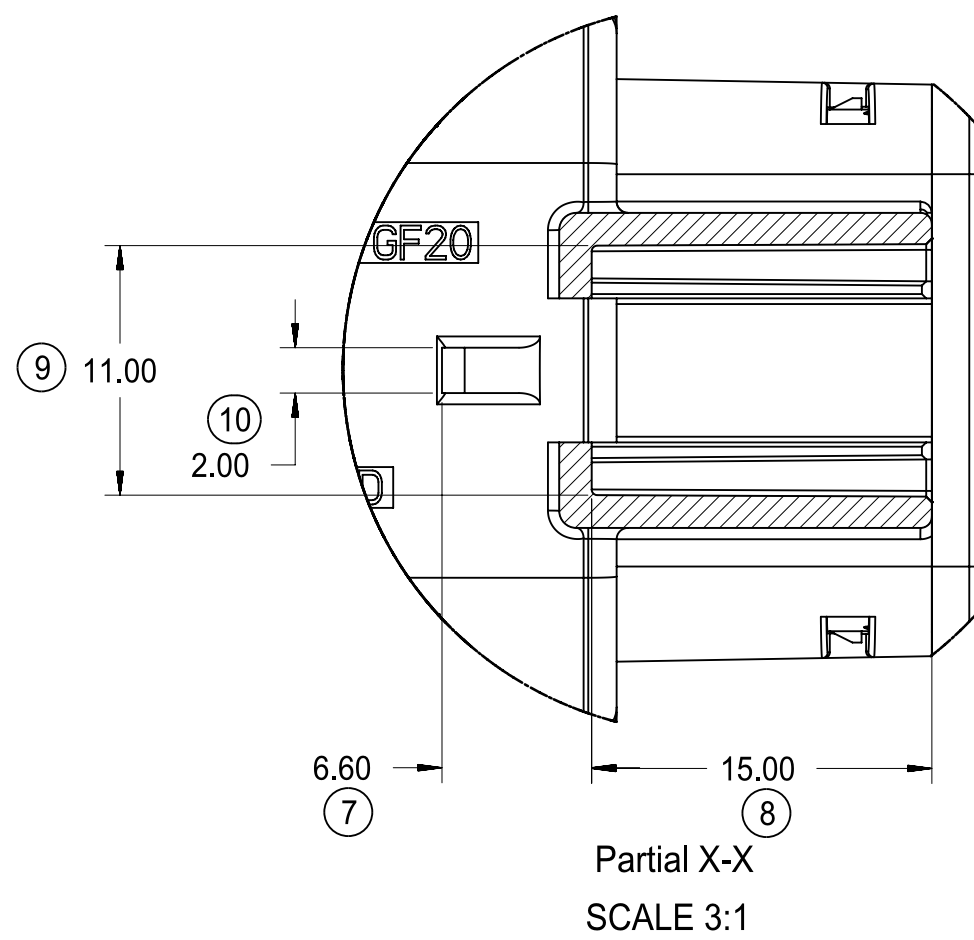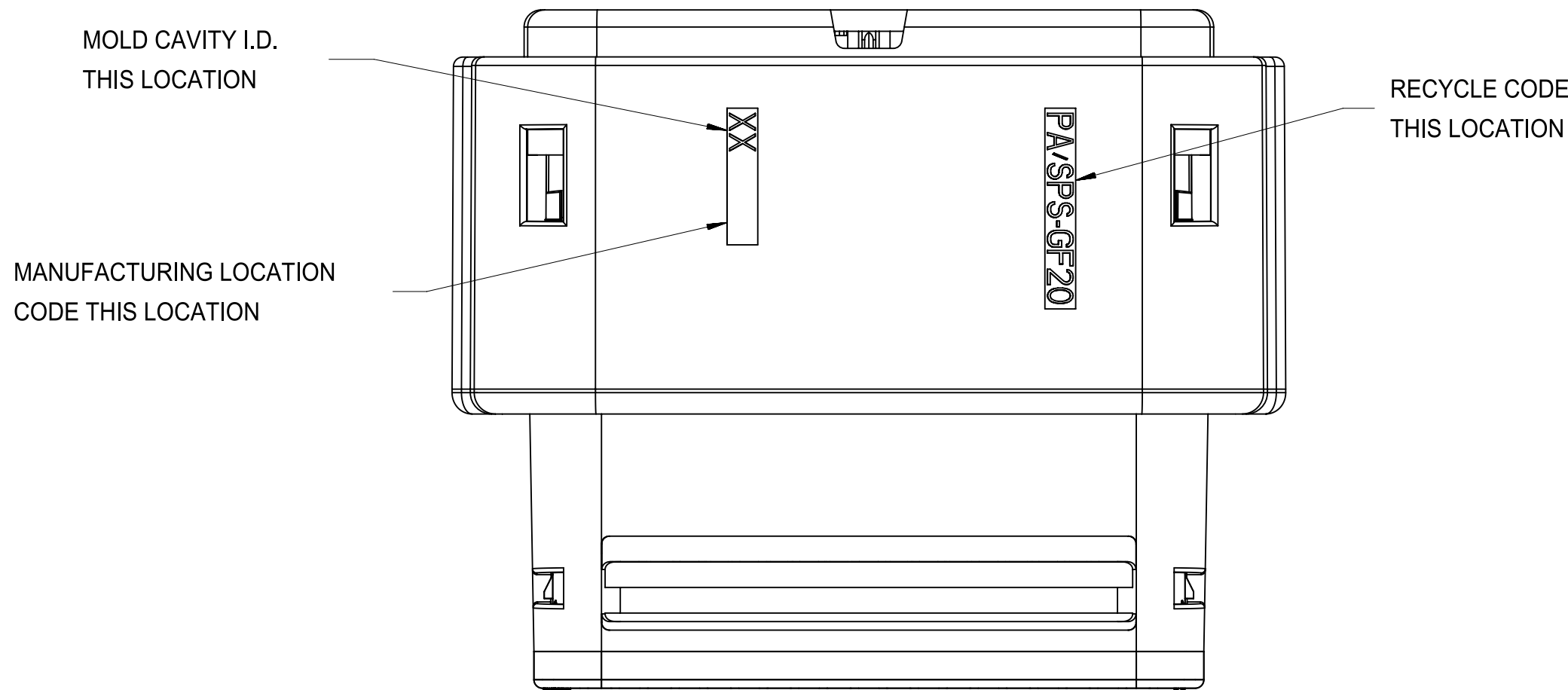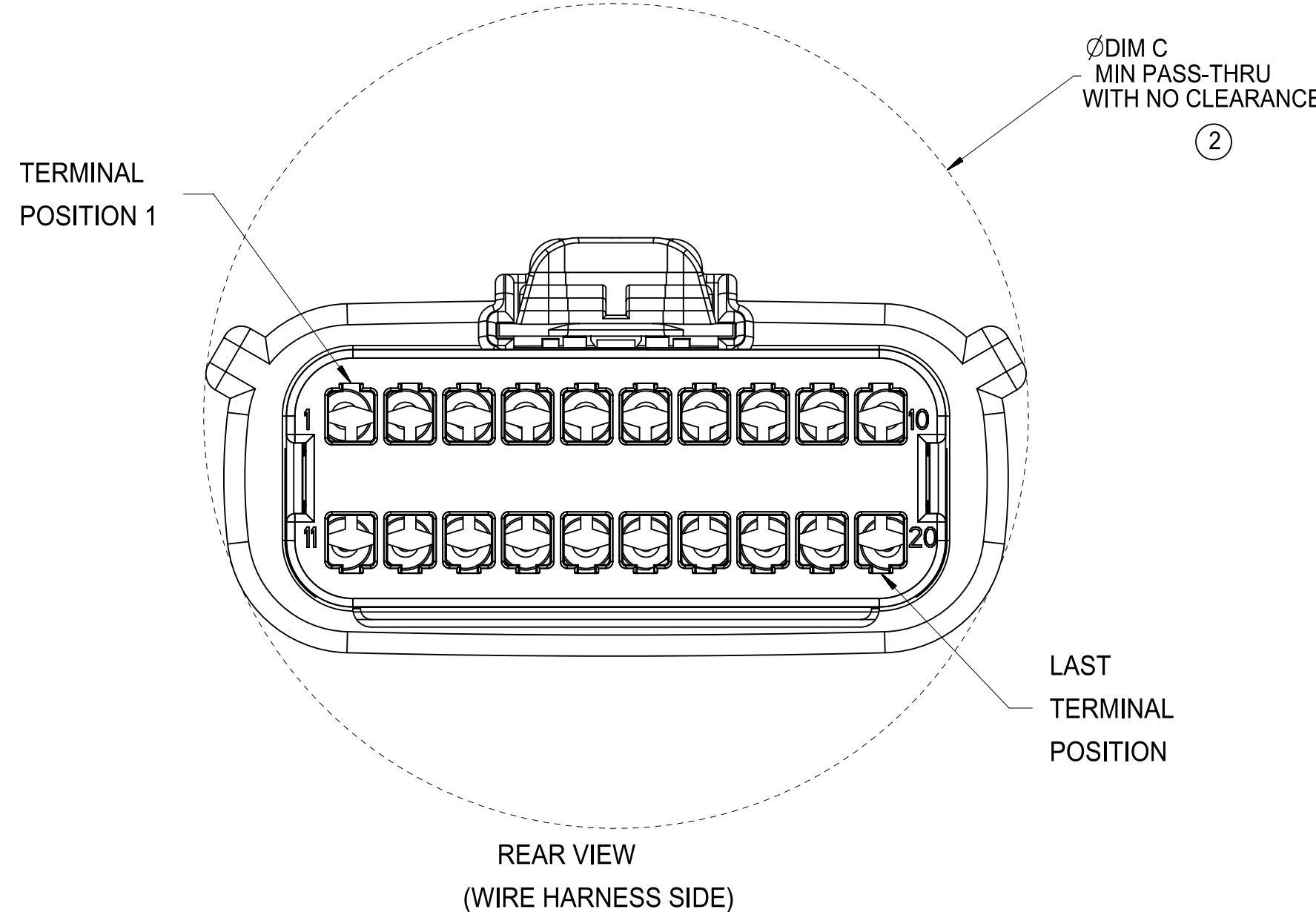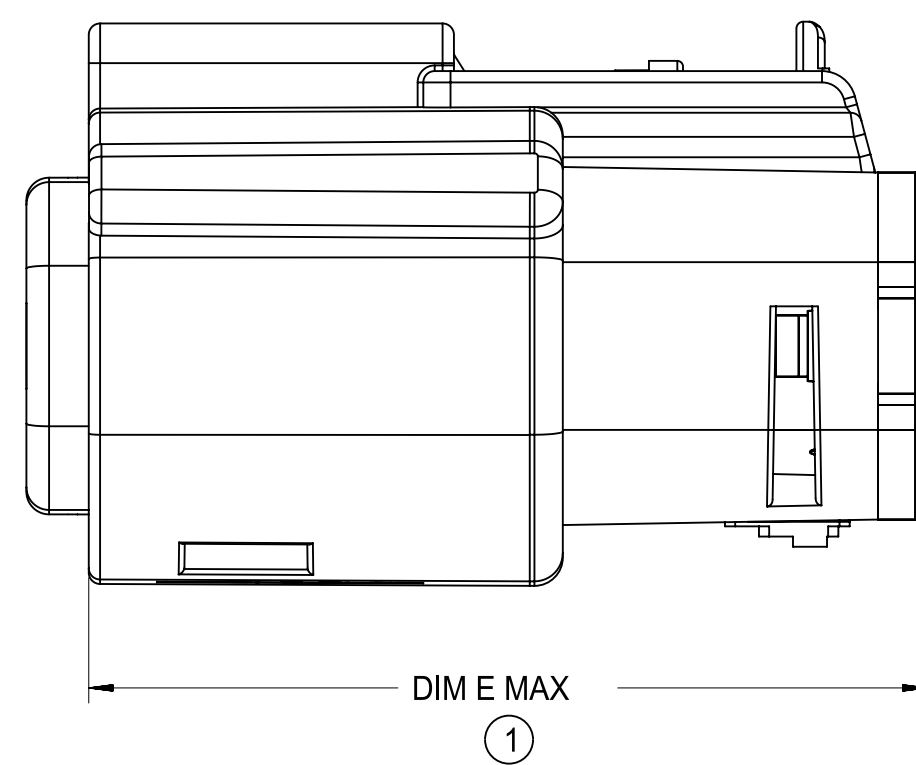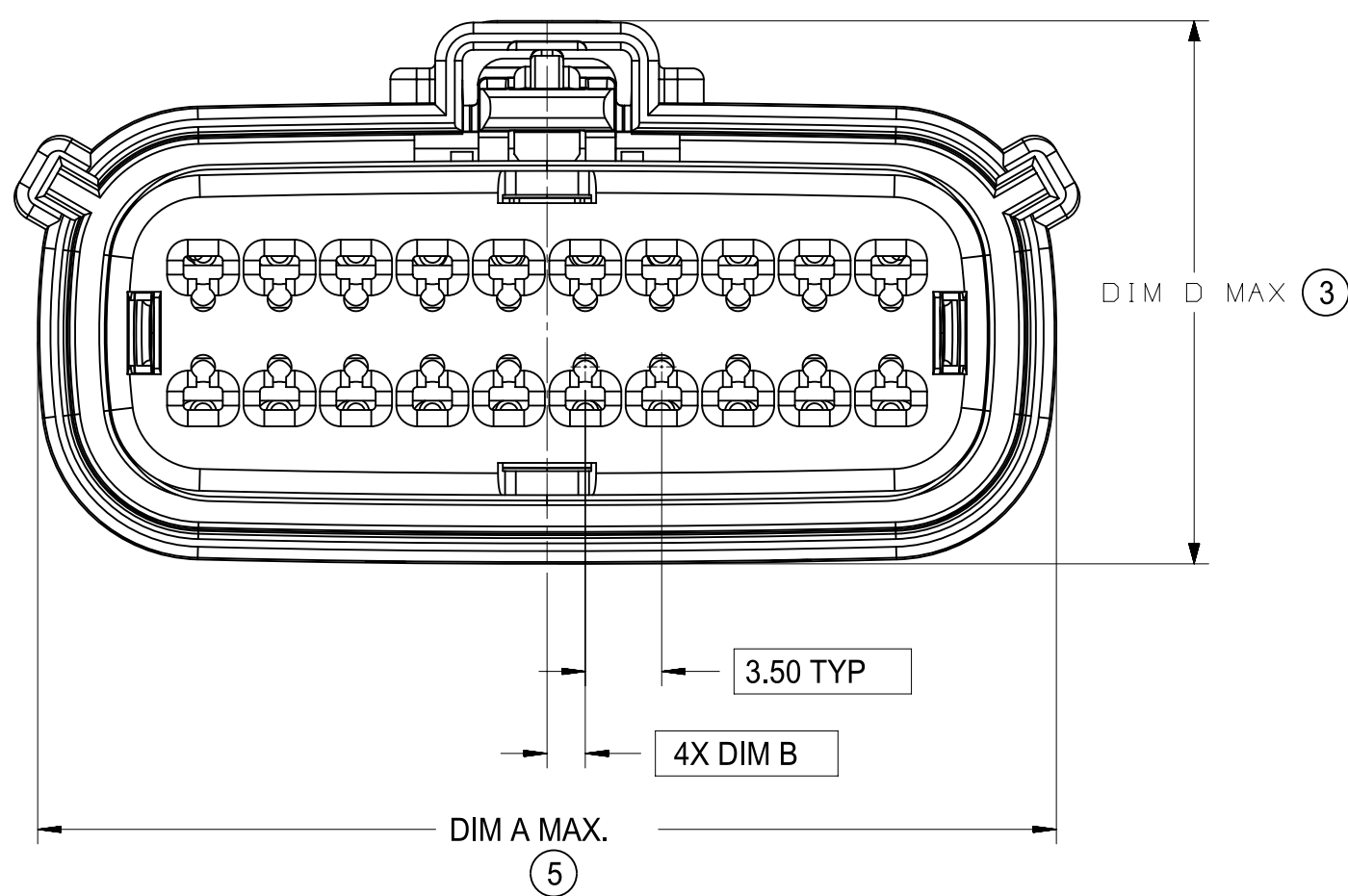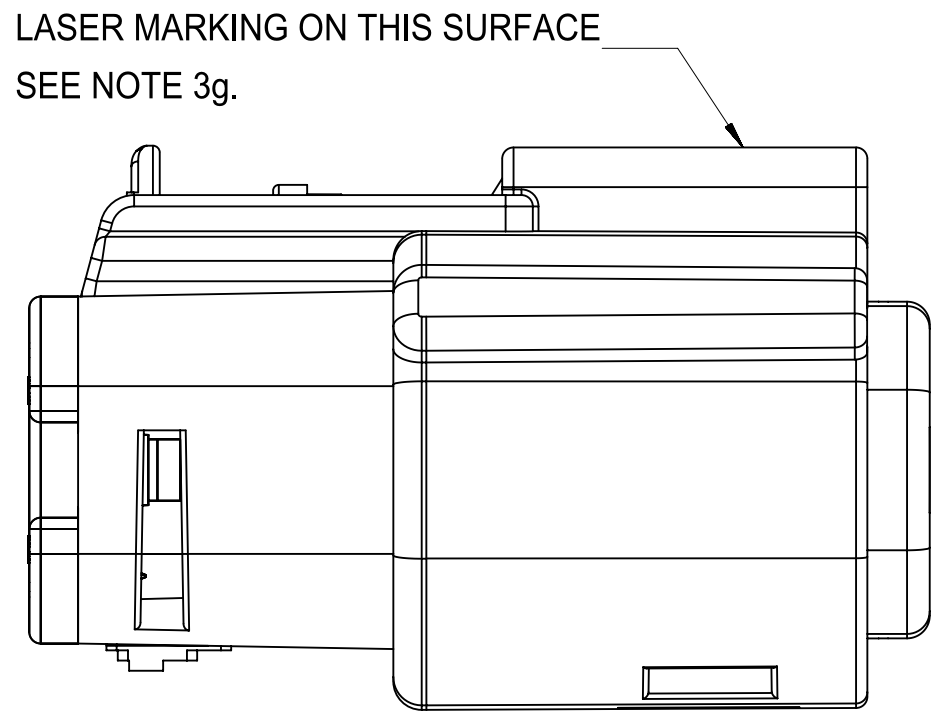






|                                                                                                                                                     |                                                                                                                                               |         |       |                                                                                                                                                                                                                                                                                                                                                                                                 |                                      |            |  |       |  |                        |
|-----------------------------------------------------------------------------------------------------------------------------------------------------|-----------------------------------------------------------------------------------------------------------------------------------------------|---------|-------|-------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------|--------------------------------------|------------|--|-------|--|------------------------|
| FUNCTIONAL SYMBOLS                                                                                                                                  | THIS DRAWING CONTAINS INFORMATION THAT IS PROPRIETARY TO MOLEX ELECTRONIC TECHNOLOGIES, LLC AND SHOULD NOT BE USED WITHOUT WRITTEN PERMISSION |         |       |                                                                                                                                                                                                                                                                                                                                                                                                 |                                      |            |  |       |  |                        |
| <div><div>FA</div><div>= 0</div></div> <div><div>FE</div><div>= 0</div></div> <div><div>FED</div><div>= 0</div></div> <div>DIVISIONAL SYMBOLS</div> | DIMENSION UNITS                                                                                                                               |         | SCALE |                                                                                                                                                                                                                                                                                                                                                                                                 | CURRENT REV DESC: SEE REVISION TABLE |            |  |       |  |                        |
|                                                                                                                                                     | MM                                                                                                                                            |         | 1:1   |                                                                                                                                                                                                                                                                                                                                                                                                 |                                      |            |  |       |  |                        |
|                                                                                                                                                     | GENERAL TOLERANCES (UNLESS SPECIFIED)                                                                                                         |         |       |                                                                                                                                                                                                                                                                                                                                                                                                 |                                      |            |  |       |  |                        |
|                                                                                                                                                     | ANGULAR TOL                                                                                                                                   |         | ± 1°  |                                                                                                                                                                                                                                                                                                                                                                                                 |                                      |            |  |       |  |                        |
|                                                                                                                                                     | 4 PLACES                                                                                                                                      |         | ±     |                                                                                                                                                                                                                                                                                                                                                                                                 |                                      |            |  |       |  |                        |
| 3 PLACES                                                                                                                                            |                                                                                                                                               | ±       |       | <div>molex</div> <div>MX150 RCPT</div> <div>DUAL ROW SEALED ASSEMBLY</div> <div>PRODUCT CUSTOMER DRAWING</div> <div>DOCUMENT NUMBER</div> <div>DOC TYPE</div> <div>DOC PART</div> <div>REVISION</div> <div>SD-33472-0001</div> <div>PSD</div> <div>001</div> <div>C11</div> <div>MATERIAL NUMBER</div> <div>CUSTOMER</div> <div>SHEET NUMBER</div> <div>GENERAL MARKET</div> <div>5 OF 11</div> |                                      |            |  |       |  |                        |
| 2 PLACES                                                                                                                                            |                                                                                                                                               | ± 0.100 |       |                                                                                                                                                                                                                                                                                                                                                                                                 |                                      |            |  |       |  |                        |
| 1 PLACE                                                                                                                                             |                                                                                                                                               | ± 0.20  |       |                                                                                                                                                                                                                                                                                                                                                                                                 |                                      |            |  |       |  |                        |
| 0 PLACES                                                                                                                                            |                                                                                                                                               | ±       |       |                                                                                                                                                                                                                                                                                                                                                                                                 |                                      |            |  |       |  |                        |
| DRAFT WHERE APPLICABLE MUST REMAIN WITHIN DIMENSIONS                                                                                                |                                                                                                                                               |         |       |                                                                                                                                                                                                                                                                                                                                                                                                 |                                      |            |  |       |  | THIRD ANGLE PROJECTION |
|                                                                                                                                                     |                                                                                                                                               |         |       |                                                                                                                                                                                                                                                                                                                                                                                                 |                                      | A1-SIZE    |  | 33472 |  |                        |
|                                                                                                                                                     |                                                                                                                                               |         |       | STATUS: Production                                                                                                                                                                                                                                                                                                                                                                              |                                      | 2025-07-16 |  |       |  |                        |
|                                                                                                                                                     |                                                                                                                                               |         |       | DRWN: Yuki Song                                                                                                                                                                                                                                                                                                                                                                                 |                                      | 2025-07-17 |  |       |  |                        |
|                                                                                                                                                     |                                                                                                                                               |         |       | CHK'D: Elvis Song                                                                                                                                                                                                                                                                                                                                                                               |                                      | 2025-07-17 |  |       |  |                        |
|                                                                                                                                                     |                                                                                                                                               |         |       | APPR: Isong05                                                                                                                                                                                                                                                                                                                                                                                   |                                      |            |  |       |  |                        |








|                     |
|---------------------|
| SHEET DESCRIPTION   |
| SCHLEMMER BACKSHELL |

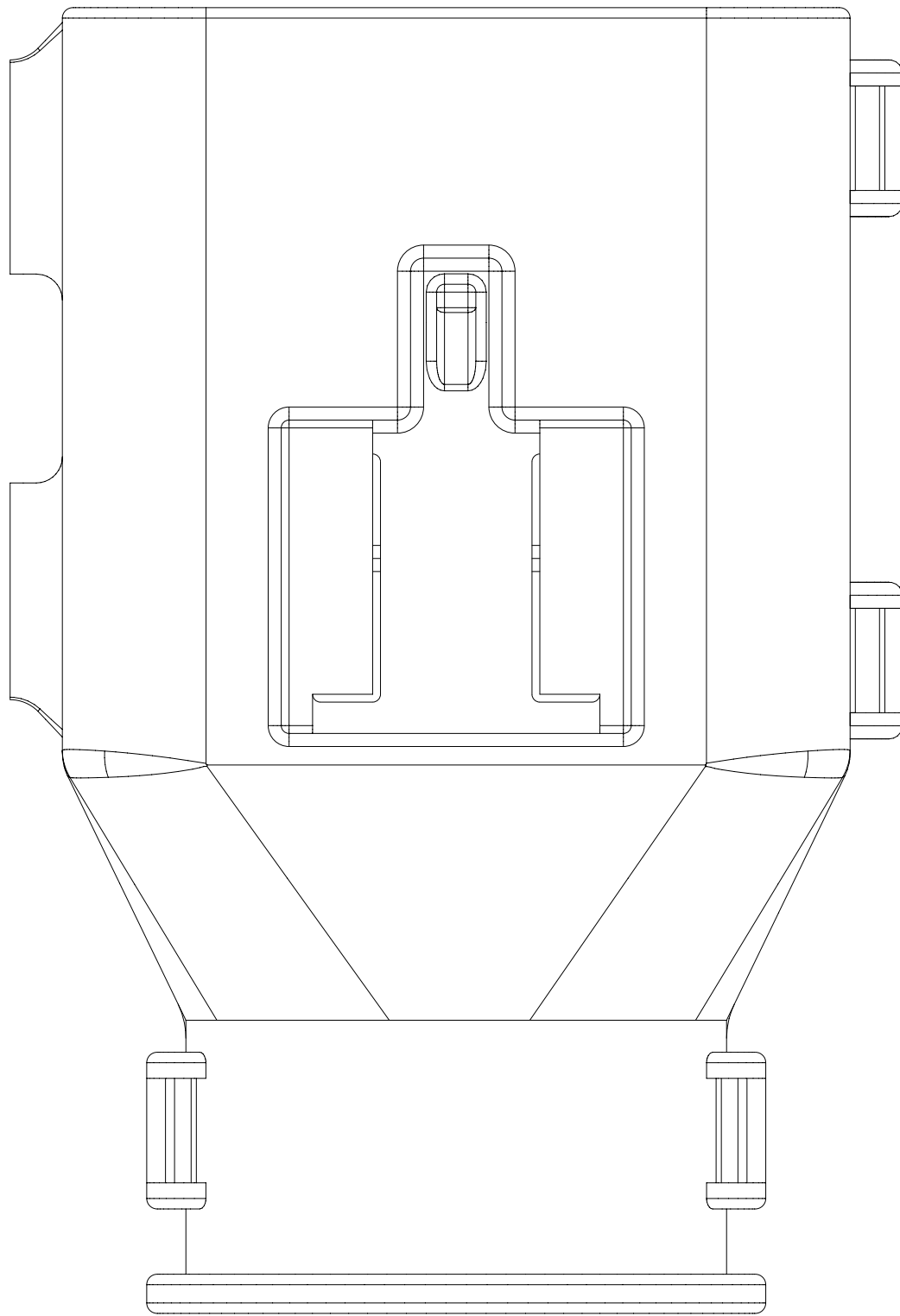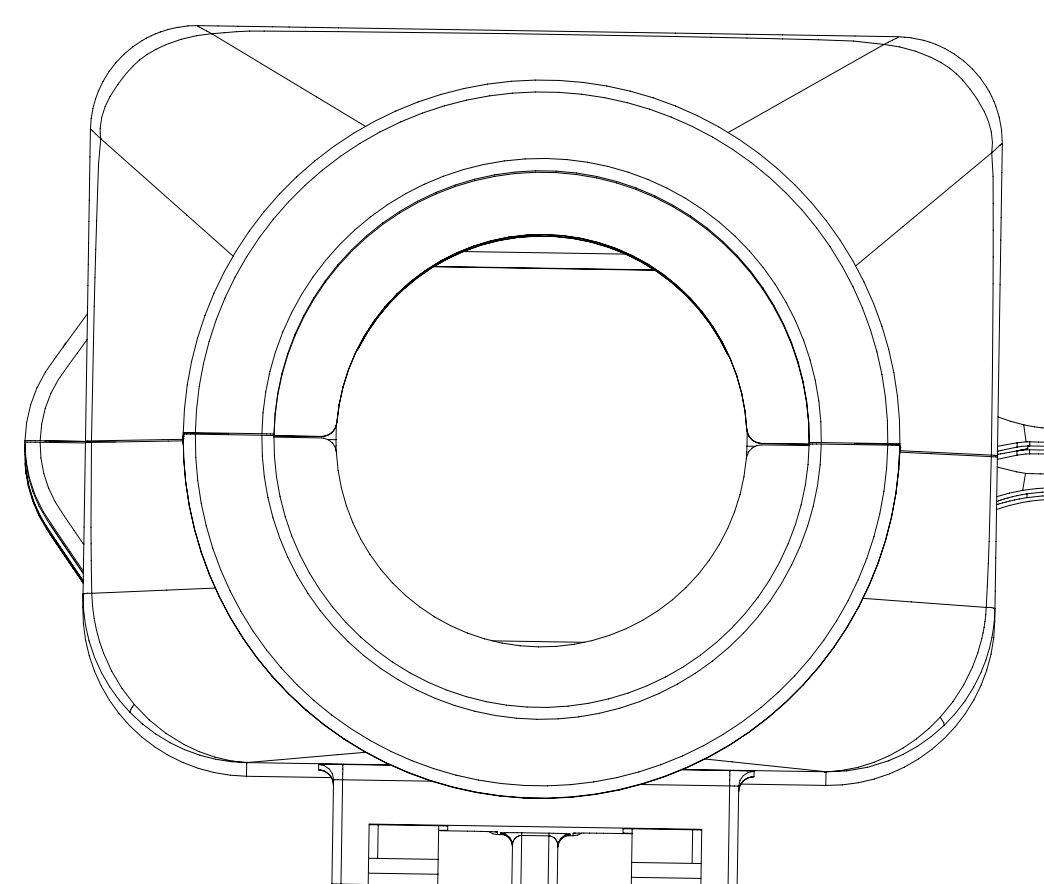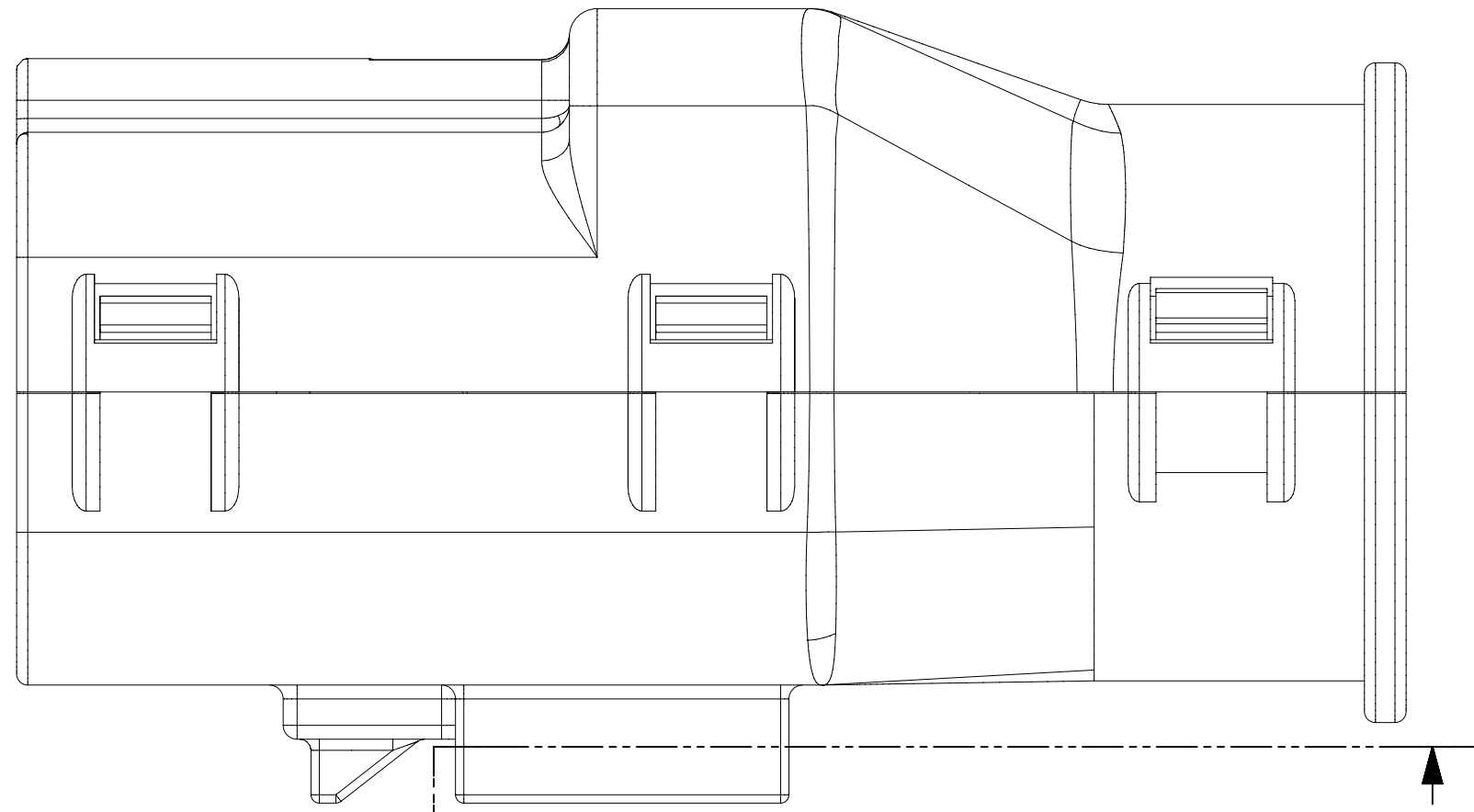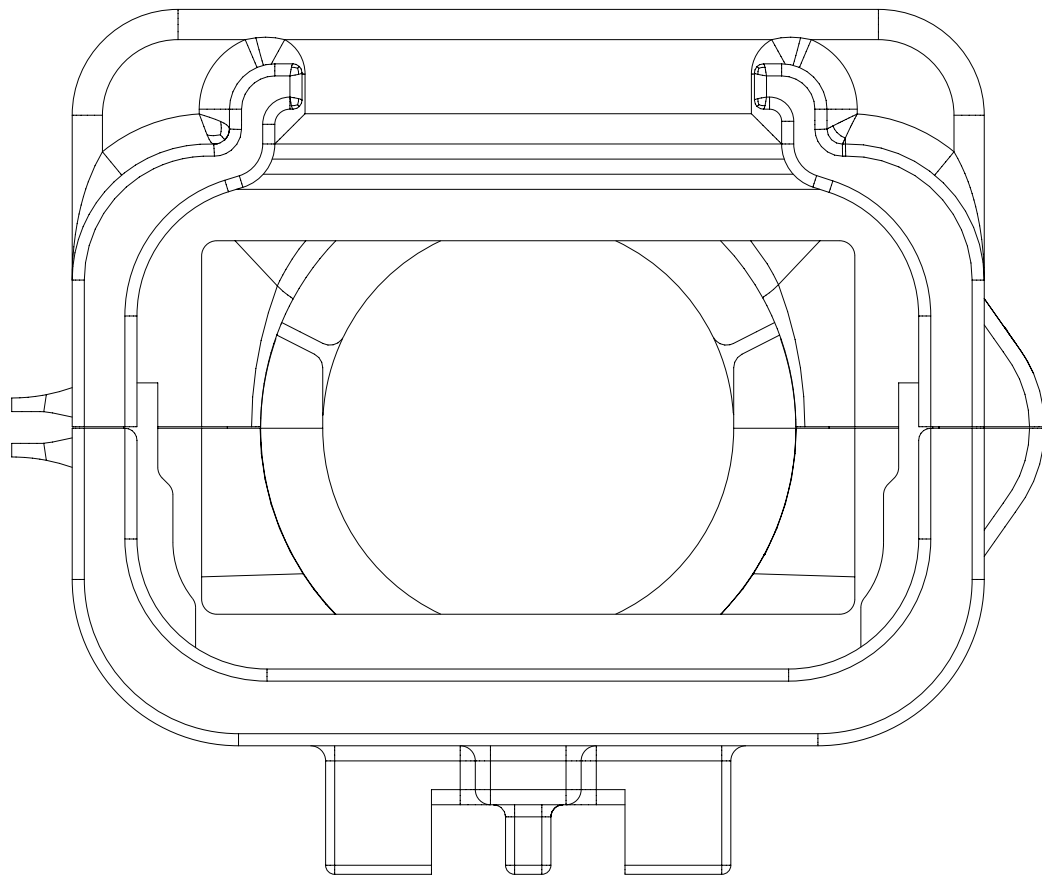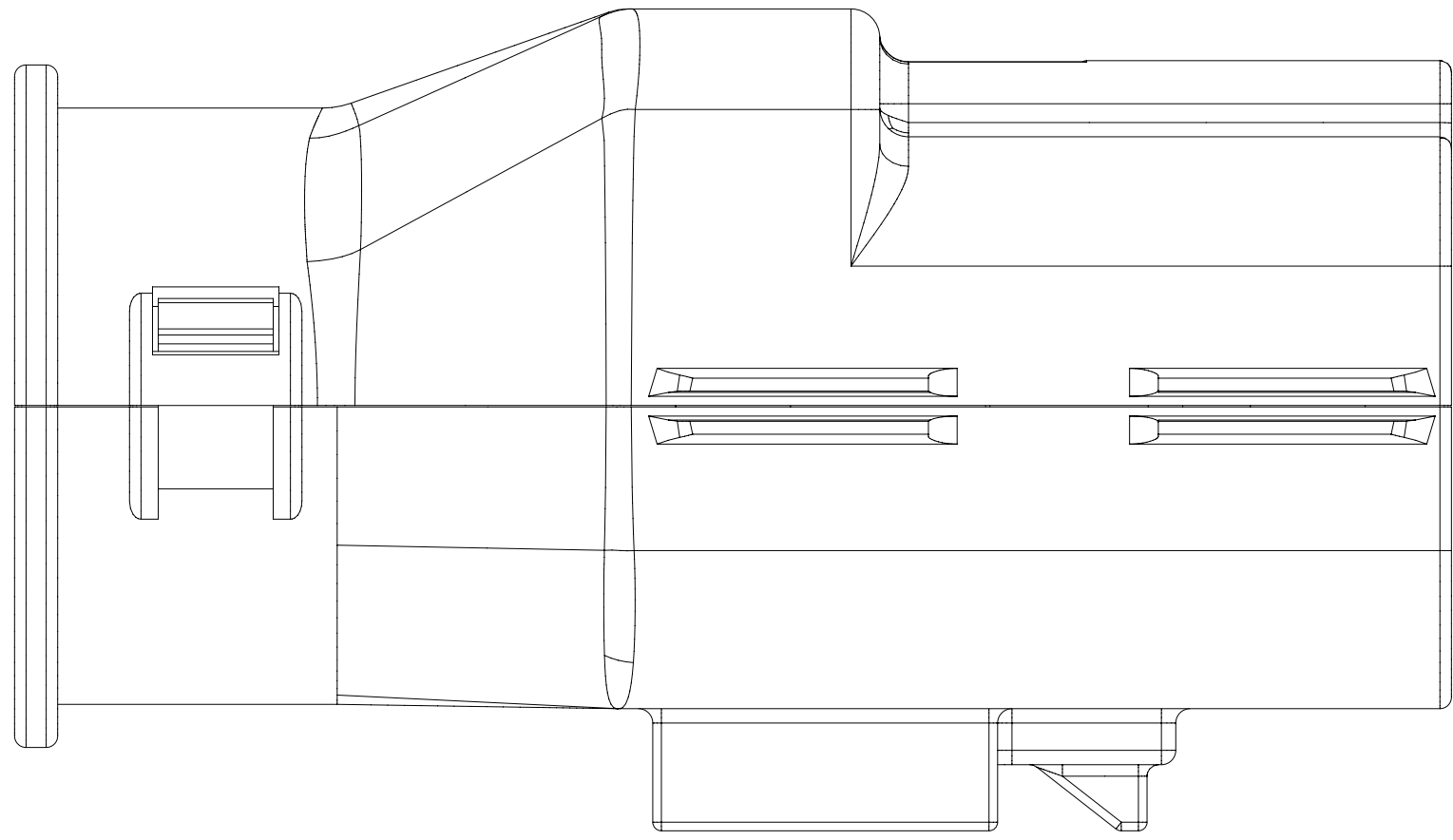

V

V

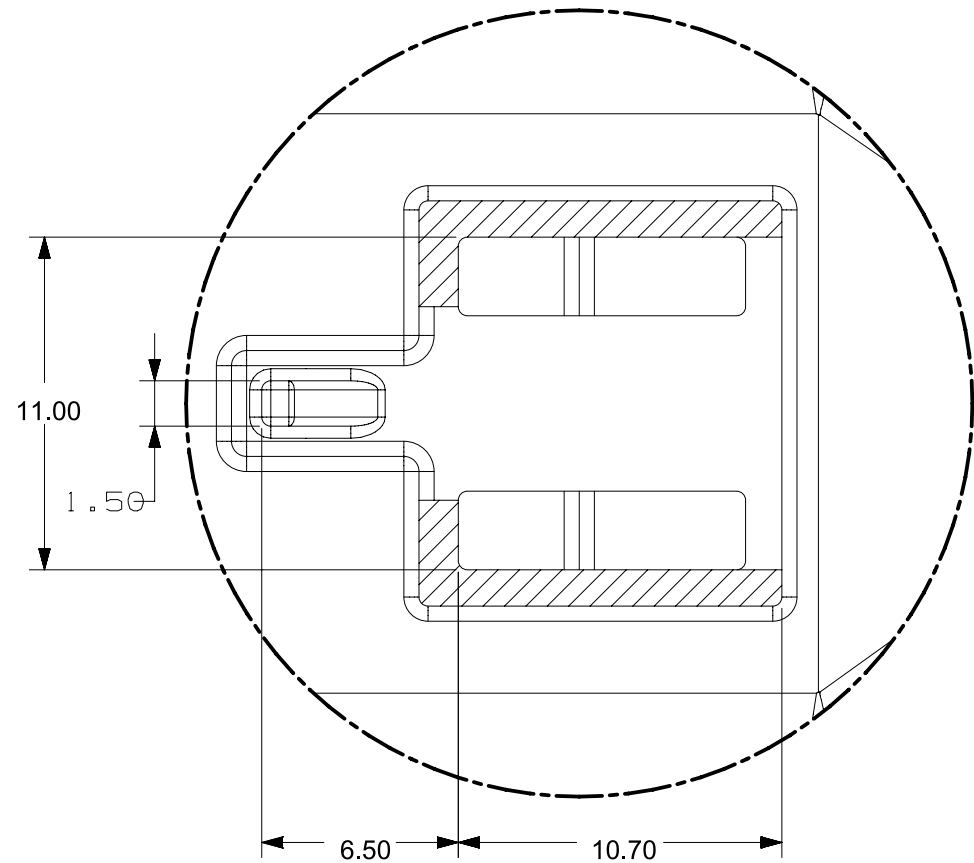

Partial V-V  
SCALE 4:1

|                                                                                                                                                                                                                                                               |                                       |                                                            |       |  |                                                                             |  |                                              |  |                                         |  |                        |  |                        |  |                        |  |                |  |  |  |
|---------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------|---------------------------------------|------------------------------------------------------------|-------|--|-----------------------------------------------------------------------------|--|----------------------------------------------|--|-----------------------------------------|--|------------------------|--|------------------------|--|------------------------|--|----------------|--|--|--|
| THIS DRAWING CONTAINS INFORMATION THAT IS PROPRIETARY TO MOLEX ELECTRONIC TECHNOLOGIES, LLC AND SHOULD NOT BE USED WITHOUT WRITTEN PERMISSION                                                                                                                 |                                       |                                                            |       |  |                                                                             |  |                                              |  |                                         |  |                        |  |                        |  |                        |  |                |  |  |  |
| FUNCTIONAL SYMBOLS<br><div><div><div><div><math>\frac{F}{A}</math></div><div>= 0</div></div><div><div><math>\frac{F}{C}</math></div><div>= 0</div></div><div><div><math>\frac{F}{D}</math></div><div>= 0</div></div></div><div>DIVISIONAL SYMBOLS</div></div> | DIMENSION UNITS                       |                                                            | SCALE |  | CURRENT REV DESC: SEE REVISION TABLE                                        |  |                                              |  |                                         |  |                        |  |                        |  |                        |  |                |  |  |  |
|                                                                                                                                                                                                                                                               | MM                                    |                                                            | 4:1   |  |                                                                             |  |                                              |  |                                         |  |                        |  |                        |  |                        |  |                |  |  |  |
|                                                                                                                                                                                                                                                               | GENERAL TOLERANCES (UNLESS SPECIFIED) |                                                            |       |  |                                                                             |  |                                              |  |                                         |  |                        |  |                        |  |                        |  |                |  |  |  |
|                                                                                                                                                                                                                                                               | ANGULAR TOL    ±    1°                |                                                            |       |  |                                                                             |  |                                              |  |                                         |  |                        |  |                        |  |                        |  |                |  |  |  |
|                                                                                                                                                                                                                                                               | 4 PLACES                              |                                                            | ±     |  | STATUS: Production<br>DRWN: Yuki Song<br>CHK'D: Elvis Song<br>APPR: Isong05 |  | 2025-07-16<br>2025-07-17<br>2025-07-17       |  | DOCUMENT NUMBER<br><b>SD-33472-0001</b> |  | DOC TYPE<br><b>PSD</b> |  | DOC PART<br><b>001</b> |  | REVISION<br><b>C11</b> |  |                |  |  |  |
| 3 PLACES                                                                                                                                                                                                                                                      |                                       | ±                                                          |       |  |                                                                             |  |                                              |  |                                         |  |                        |  |                        |  |                        |  |                |  |  |  |
| 2 PLACES                                                                                                                                                                                                                                                      |                                       | ± 0.100                                                    |       |  |                                                                             |  |                                              |  |                                         |  |                        |  |                        |  |                        |  |                |  |  |  |
| 1 PLACE                                                                                                                                                                                                                                                       |                                       | ± 0.20                                                     |       |  |                                                                             |  |                                              |  |                                         |  |                        |  |                        |  |                        |  |                |  |  |  |
| 0 PLACES                                                                                                                                                                                                                                                      |                                       | ±                                                          |       |  |                                                                             |  |                                              |  |                                         |  |                        |  |                        |  |                        |  |                |  |  |  |
|                                                                                                                                                                                                                                                               |                                       | DRAFT WHERE APPLICABLE<br>MUST REMAIN<br>WITHIN DIMENSIONS |       |  |                                                                             |  | THIRD ANGLE PROJECTION                       |  | DRAWING                                 |  | SERIES                 |  | MATERIAL NUMBER        |  | CUSTOMER               |  | SHEET NUMBER   |  |  |  |
|                                                                                                                                                                                                                                                               |                                       | <div><div><div><div></div><div></div></div></div></div>    |       |  |                                                                             |  | <div><div><div></div><div></div></div></div> |  | <b>A1-SIZE</b>                          |  | <b>33472</b>           |  |                        |  | <b>GENERAL MARKET</b>  |  | <b>7 OF 11</b> |  |  |  |





[illegible]









| SHEET DESCRIPTION              |
|--------------------------------|
| MOLEX BACKSHELL CONFIGURATIONS |

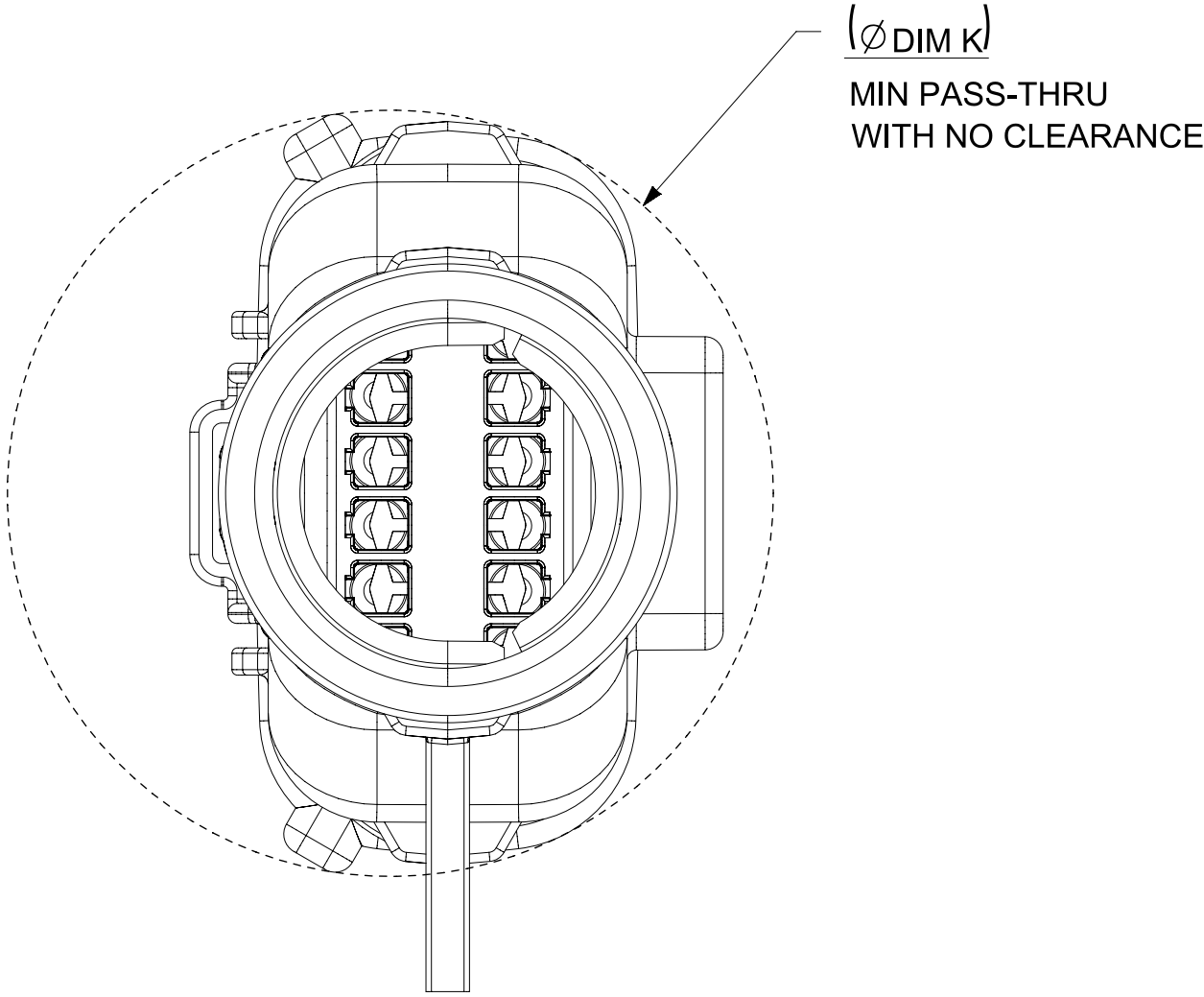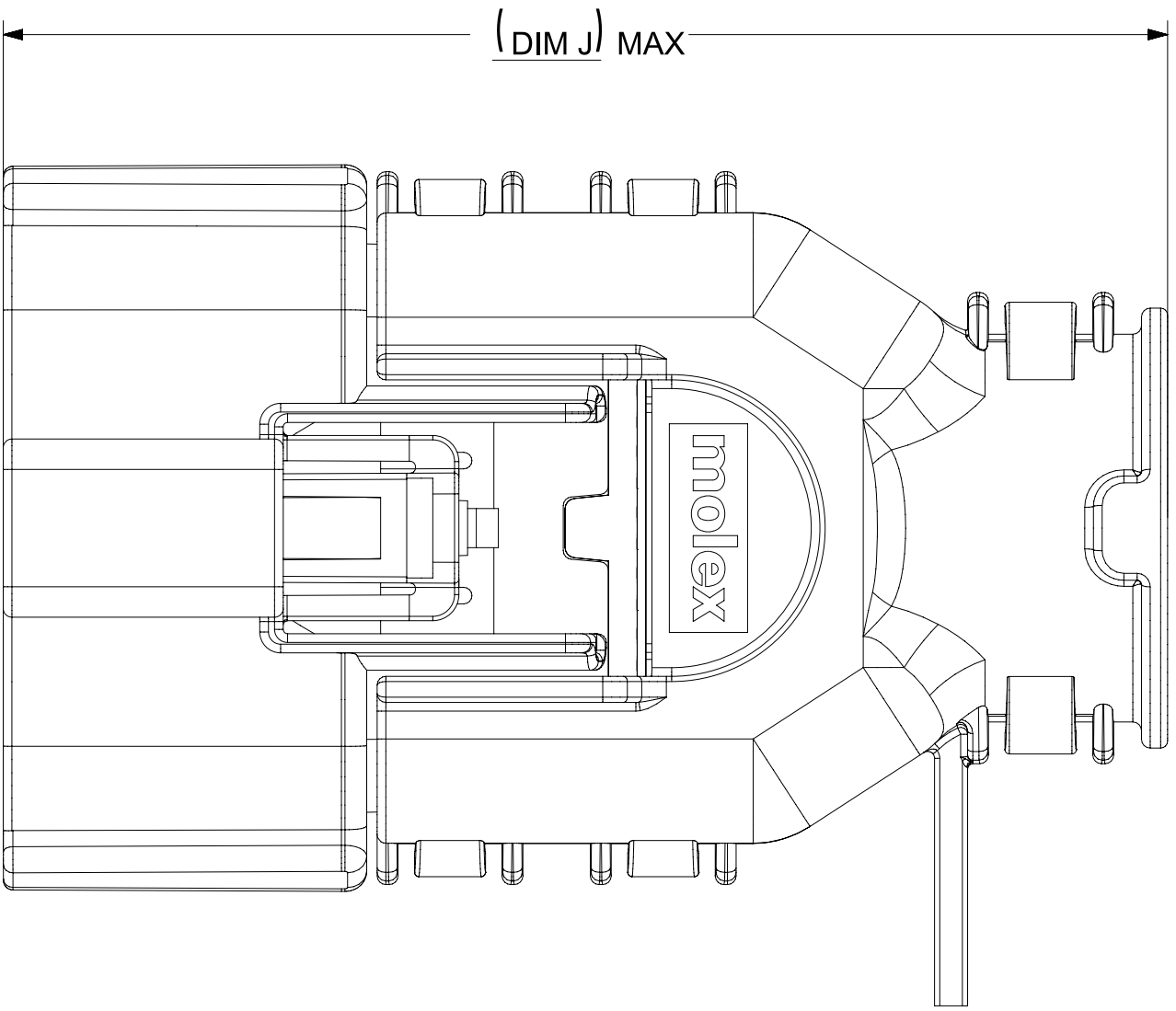

RECEPTACLE SEALED ASSEMBLY WITH RECEPTACLE BACKSHELL

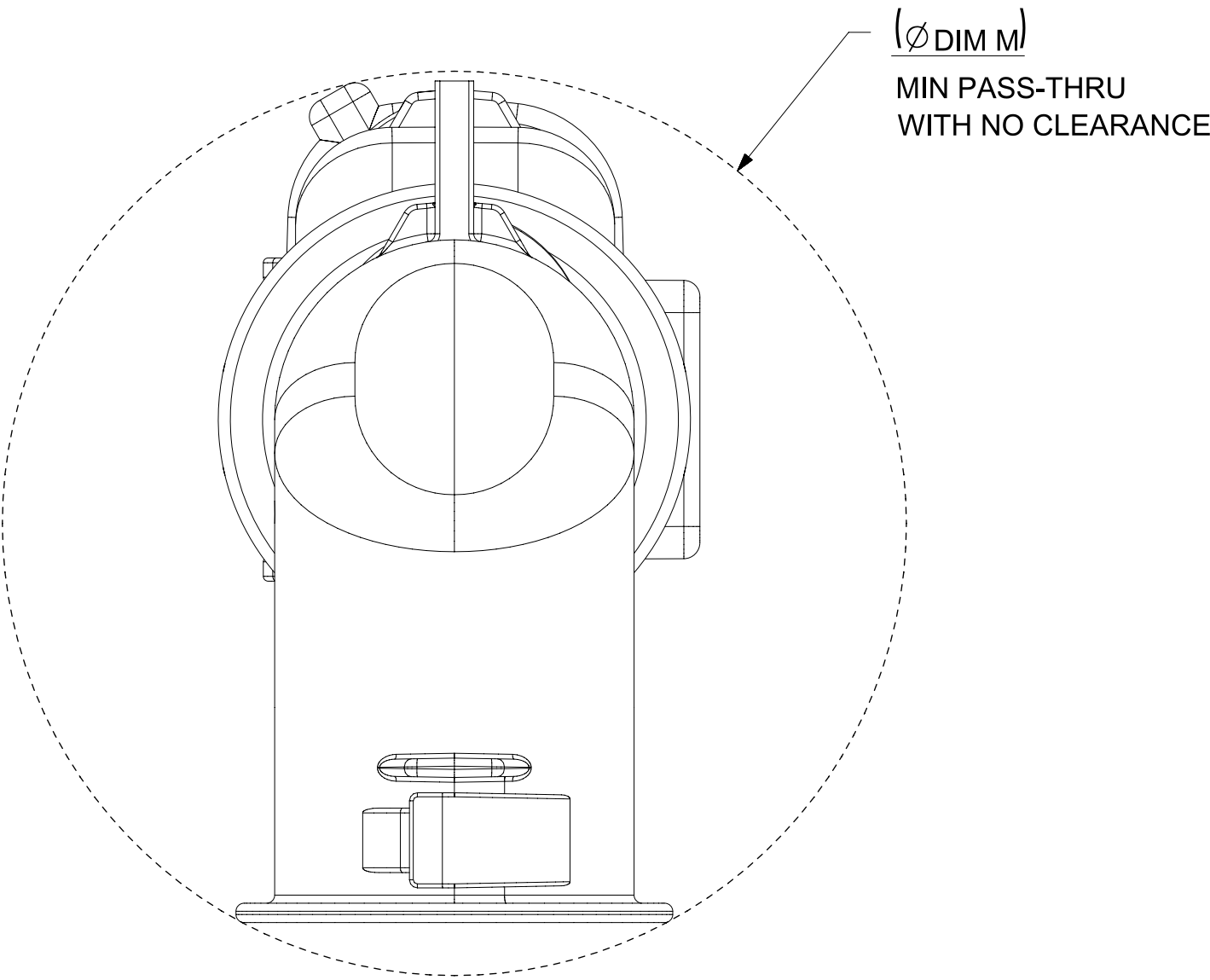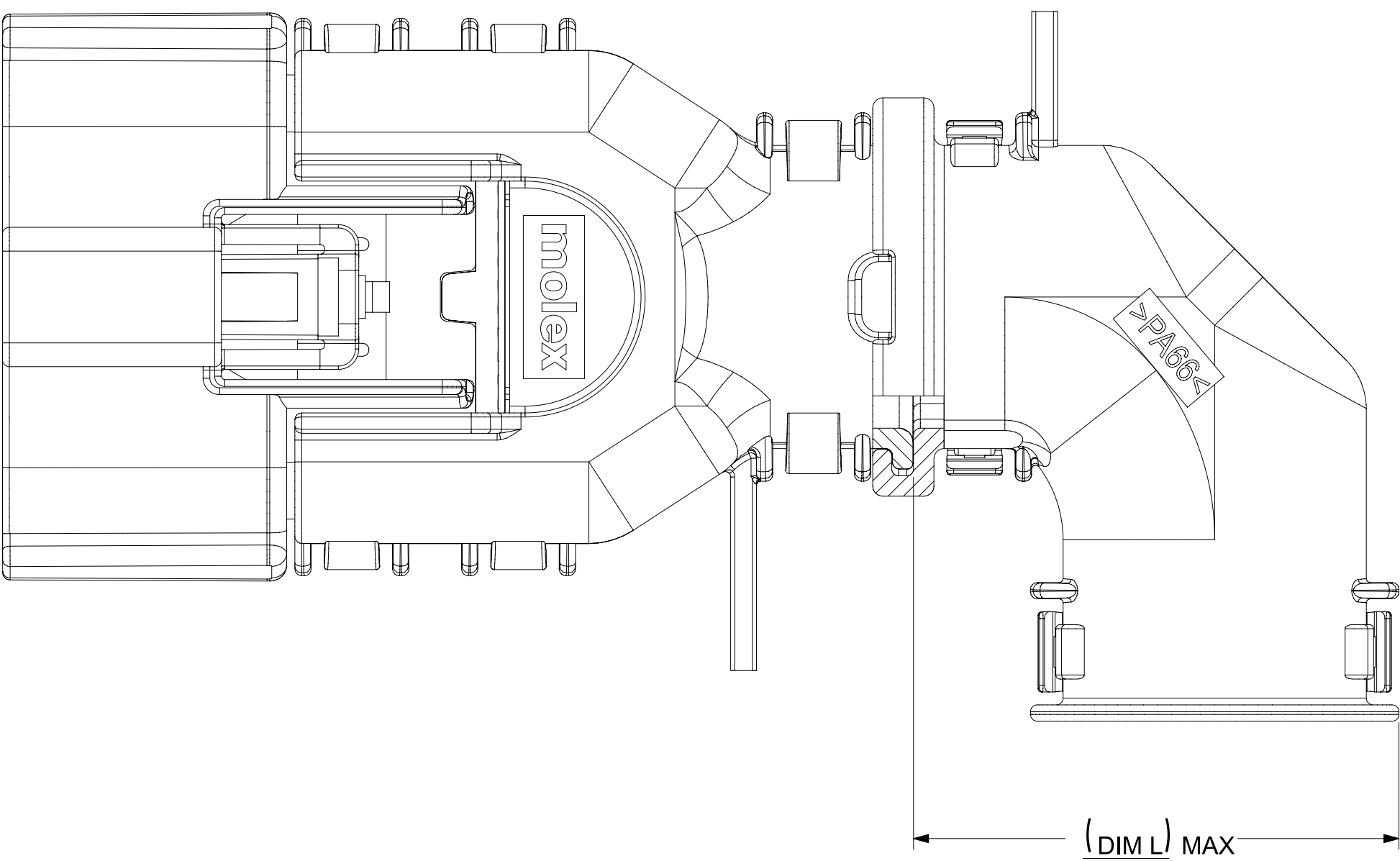

ADD THE VALUE OF 'L' TO THE TOTAL DIMENSION  
WHENEVER ADAPTOR IS USED

| CHARTED DIMENSIONS |            |       |       |       |
|--------------------|------------|-------|-------|-------|
| DESCRIPTION        | DIMENSIONS |       |       |       |
|                    | J          | K     | L     | M     |
| 2X2 W/O CLIPSLOT   | TBD        | TBD   | TBD   | TBD   |
| 2X2 W/ CLIP SLOT   | TBD        | TBD   | TBD   | TBD   |
| 2X2 LENGTHENED     | TBD        | TBD   | TBD   | TBD   |
| 2X4 W/ CLIPSLOT    | 58.39      | 32.85 | 32.10 | 44.26 |
| 2X4 W/O CLIPSLOT   | N/A        | N/A   | N/A   | N/A   |
| 2X8 W/ CLIPSLOT    | 67.19      | 42.65 | 36.10 | 56.49 |
| 2X8 W/O CLIPSLOT   | N/A        | N/A   | N/A   | N/A   |
| 2X10 W/ CLIPSLOT   | 67.19      | 42.65 | 36.10 | 56.49 |
| 2X10 W/O CLIPSLOT  | N/A        | N/A   | N/A   | N/A   |

- B
- B
- C

| FUNCTIONAL SYMBOLS | THIS DRAWING CONTAINS INFORMATION THAT IS PROPRIETARY TO MOLEX ELECTRONIC TECHNOLOGIES, LLC AND SHOULD NOT BE USED WITHOUT WRITTEN PERMISSION |                |                        |          |                                                                                                                                                                                                                                                                                                                                                                                                                                         |  |        |  |  |  |                 |          |          |          |               |     |     |     |                 |          |              |  |  |                |          |  |
|--------------------|-----------------------------------------------------------------------------------------------------------------------------------------------|----------------|------------------------|----------|-----------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------|--|--------|--|--|--|-----------------|----------|----------|----------|---------------|-----|-----|-----|-----------------|----------|--------------|--|--|----------------|----------|--|
|                    | DIMENSION UNITS                                                                                                                               |                | SCALE                  |          | CURRENT REV DESC: SEE REVISION TABLE                                                                                                                                                                                                                                                                                                                                                                                                    |  |        |  |  |  |                 |          |          |          |               |     |     |     |                 |          |              |  |  |                |          |  |
|                    | MM                                                                                                                                            |                | 2.5:1                  |          | <div>molex</div> <div>MX150 RCPT<br/>DUAL ROW SEALED ASSEMBLY</div> <div>PRODUCT CUSTOMER DRAWING</div> <table><tr><th>DOCUMENT NUMBER</th><th>DOC TYPE</th><th>DOC PART</th><th>REVISION</th></tr><tr><td>SD-33472-0001</td><td>PSD</td><td>001</td><td>C11</td></tr><tr><th>MATERIAL NUMBER</th><th>CUSTOMER</th><th colspan="2">SHEET NUMBER</th></tr><tr><td></td><td>GENERAL MARKET</td><td colspan="2">10 OF 11</td></tr></table> |  |        |  |  |  | DOCUMENT NUMBER | DOC TYPE | DOC PART | REVISION | SD-33472-0001 | PSD | 001 | C11 | MATERIAL NUMBER | CUSTOMER | SHEET NUMBER |  |  | GENERAL MARKET | 10 OF 11 |  |
|                    | DOCUMENT NUMBER                                                                                                                               | DOC TYPE       | DOC PART               | REVISION |                                                                                                                                                                                                                                                                                                                                                                                                                                         |  |        |  |  |  |                 |          |          |          |               |     |     |     |                 |          |              |  |  |                |          |  |
|                    | SD-33472-0001                                                                                                                                 | PSD            | 001                    | C11      |                                                                                                                                                                                                                                                                                                                                                                                                                                         |  |        |  |  |  |                 |          |          |          |               |     |     |     |                 |          |              |  |  |                |          |  |
|                    | MATERIAL NUMBER                                                                                                                               | CUSTOMER       | SHEET NUMBER           |          |                                                                                                                                                                                                                                                                                                                                                                                                                                         |  |        |  |  |  |                 |          |          |          |               |     |     |     |                 |          |              |  |  |                |          |  |
|                    |                                                                                                                                               | GENERAL MARKET | 10 OF 11               |          |                                                                                                                                                                                                                                                                                                                                                                                                                                         |  |        |  |  |  |                 |          |          |          |               |     |     |     |                 |          |              |  |  |                |          |  |
|                    | GENERAL TOLERANCES (UNLESS SPECIFIED)                                                                                                         |                |                        |          |                                                                                                                                                                                                                                                                                                                                                                                                                                         |  |        |  |  |  |                 |          |          |          |               |     |     |     |                 |          |              |  |  |                |          |  |
|                    | ANGULAR TOL ± 1°                                                                                                                              |                |                        |          |                                                                                                                                                                                                                                                                                                                                                                                                                                         |  |        |  |  |  |                 |          |          |          |               |     |     |     |                 |          |              |  |  |                |          |  |
|                    | 4 PLACES ±                                                                                                                                    |                |                        |          |                                                                                                                                                                                                                                                                                                                                                                                                                                         |  |        |  |  |  |                 |          |          |          |               |     |     |     |                 |          |              |  |  |                |          |  |
| 3 PLACES ±         |                                                                                                                                               |                |                        |          |                                                                                                                                                                                                                                                                                                                                                                                                                                         |  |        |  |  |  |                 |          |          |          |               |     |     |     |                 |          |              |  |  |                |          |  |
| 2 PLACES ± 0.100   |                                                                                                                                               |                |                        |          |                                                                                                                                                                                                                                                                                                                                                                                                                                         |  |        |  |  |  |                 |          |          |          |               |     |     |     |                 |          |              |  |  |                |          |  |
| 1 PLACE ± 0.20     |                                                                                                                                               |                |                        |          |                                                                                                                                                                                                                                                                                                                                                                                                                                         |  |        |  |  |  |                 |          |          |          |               |     |     |     |                 |          |              |  |  |                |          |  |
| 0 PLACES ±         |                                                                                                                                               |                |                        |          |                                                                                                                                                                                                                                                                                                                                                                                                                                         |  |        |  |  |  |                 |          |          |          |               |     |     |     |                 |          |              |  |  |                |          |  |
| DIVISIONAL SYMBOLS | STATUS: Production                                                                                                                            |                |                        |          | 2025-07-16                                                                                                                                                                                                                                                                                                                                                                                                                              |  |        |  |  |  |                 |          |          |          |               |     |     |     |                 |          |              |  |  |                |          |  |
|                    | DRWN: Yuki Song                                                                                                                               |                |                        |          | 2025-07-17                                                                                                                                                                                                                                                                                                                                                                                                                              |  |        |  |  |  |                 |          |          |          |               |     |     |     |                 |          |              |  |  |                |          |  |
|                    | CHK'D: Elvis Song                                                                                                                             |                |                        |          | 2025-07-17                                                                                                                                                                                                                                                                                                                                                                                                                              |  |        |  |  |  |                 |          |          |          |               |     |     |     |                 |          |              |  |  |                |          |  |
|                    | APPR: Isong05                                                                                                                                 |                |                        |          | 2025-07-17                                                                                                                                                                                                                                                                                                                                                                                                                              |  |        |  |  |  |                 |          |          |          |               |     |     |     |                 |          |              |  |  |                |          |  |
|                    | DRAFT WHERE APPLICABLE MUST REMAIN WITHIN DIMENSIONS                                                                                          |                | THIRD ANGLE PROJECTION |          | DRAWING                                                                                                                                                                                                                                                                                                                                                                                                                                 |  | SERIES |  |  |  |                 |          |          |          |               |     |     |     |                 |          |              |  |  |                |          |  |
|                    |                                                                                                                                               |                |                        |          | A1-SIZE                                                                                                                                                                                                                                                                                                                                                                                                                                 |  | 33472  |  |  |  |                 |          |          |          |               |     |     |     |                 |          |              |  |  |                |          |  |
|                    |                                                                                                                                               |                |                        |          |                                                                                                                                                                                                                                                                                                                                                                                                                                         |  |        |  |  |  |                 |          |          |          |               |     |     |     |                 |          |              |  |  |                |          |  |
|                    |                                                                                                                                               |                |                        |          |                                                                                                                                                                                                                                                                                                                                                                                                                                         |  |        |  |  |  |                 |          |          |          |               |     |     |     |                 |          |              |  |  |                |          |  |
|                    |                                                                                                                                               |                |                        |          |                                                                                                                                                                                                                                                                                                                                                                                                                                         |  |        |  |  |  |                 |          |          |          |               |     |     |     |                 |          |              |  |  |                |          |  |
|                    |                                                                                                                                               |                |                        |          |                                                                                                                                                                                                                                                                                                                                                                                                                                         |  |        |  |  |  |                 |          |          |          |               |     |     |     |                 |          |              |  |  |                |          |  |

molex













MX150 RCPT  
DUAL ROW SEALED ASSEMBLY

PRODUCT CUSTOMER DRAWING

|                 |          |          |          |
|-----------------|----------|----------|----------|
| DOCUMENT NUMBER | DOC TYPE | DOC PART | REVISION |
| SD-33472-0001   | PSD      | 001      | C11      |


|                 |                |              |
|-----------------|----------------|--------------|
| MATERIAL NUMBER | CUSTOMER       | SHEET NUMBER |
|                 | GENERAL MARKET | 10 OF 11     |



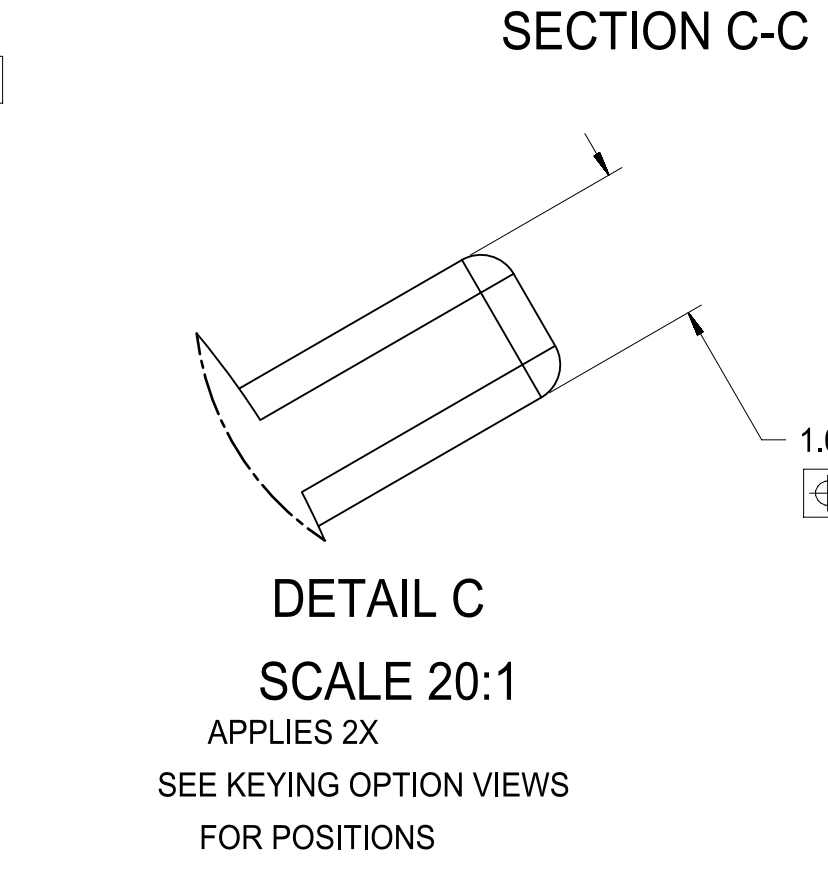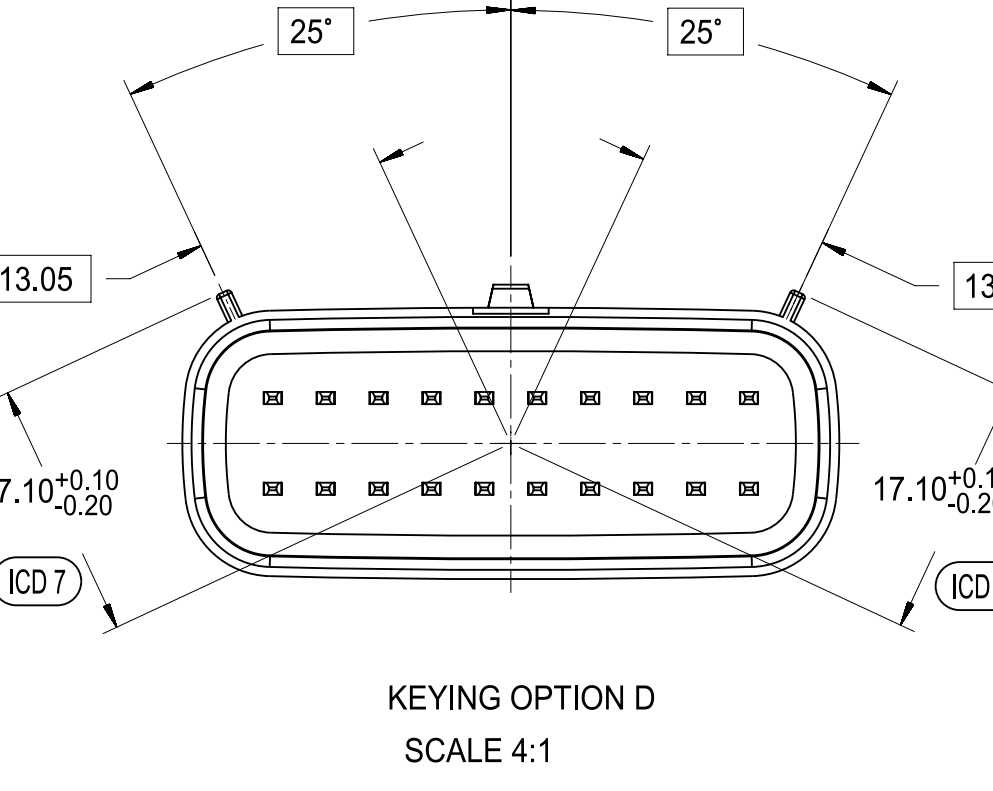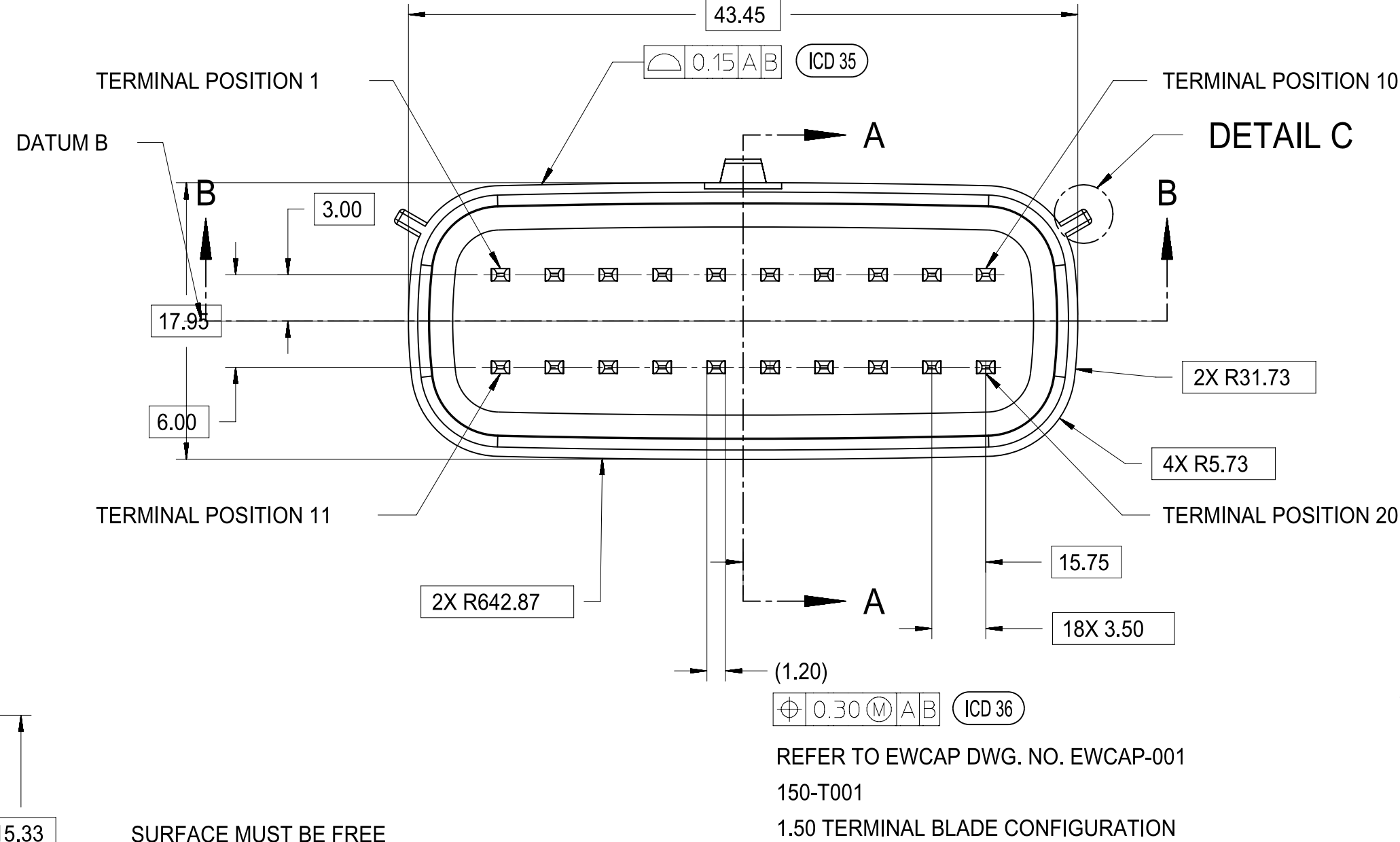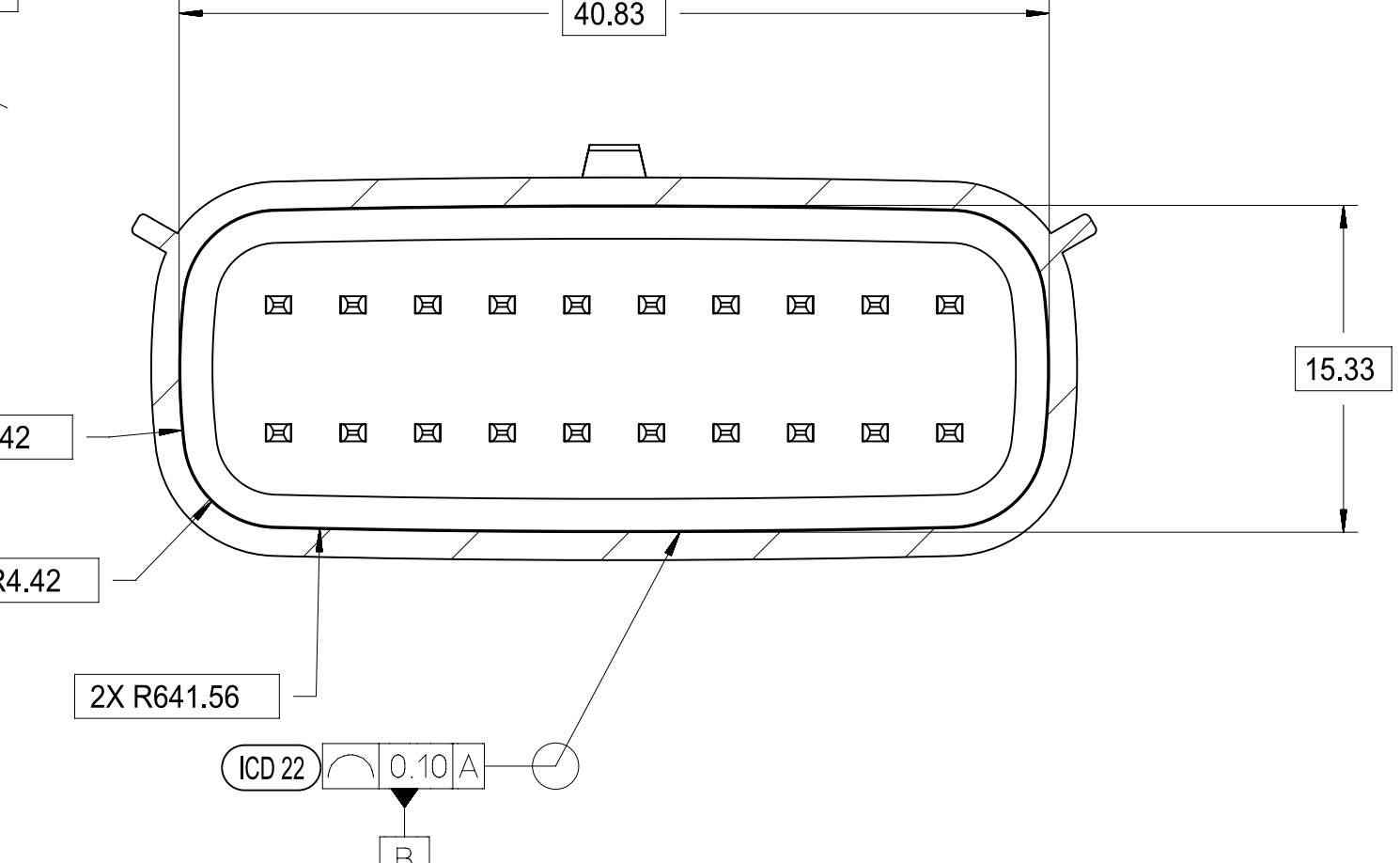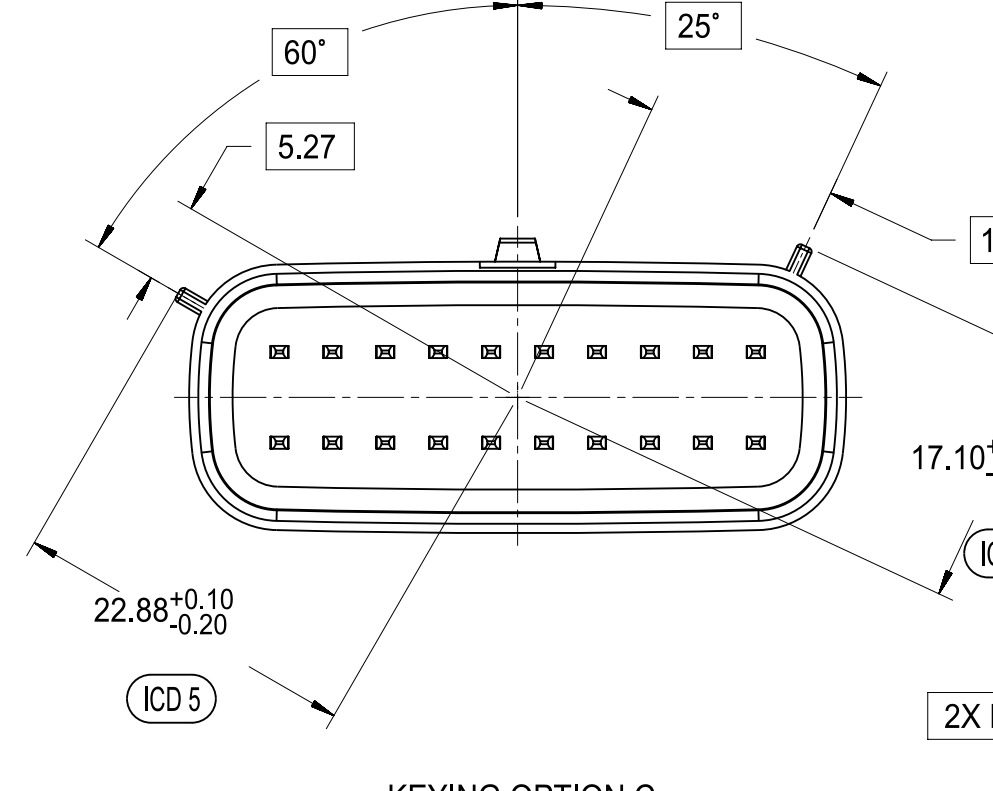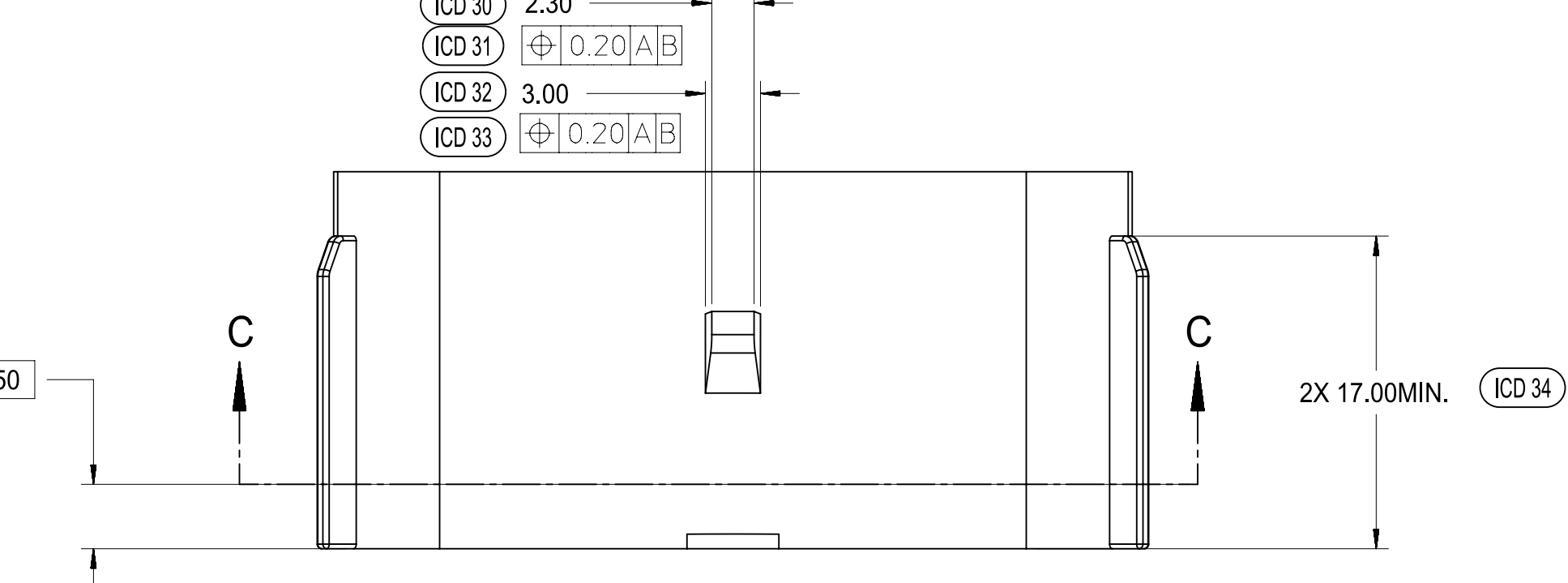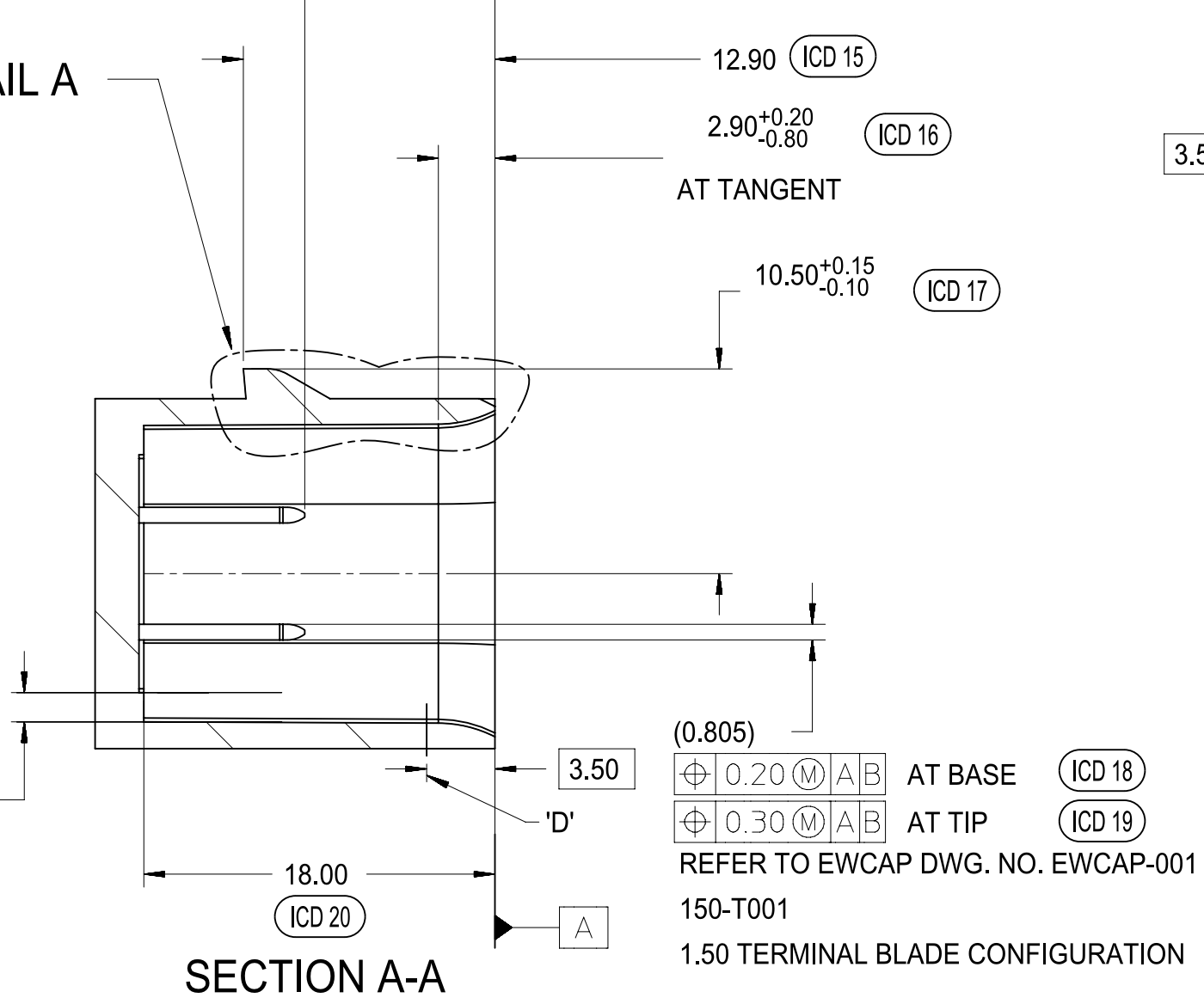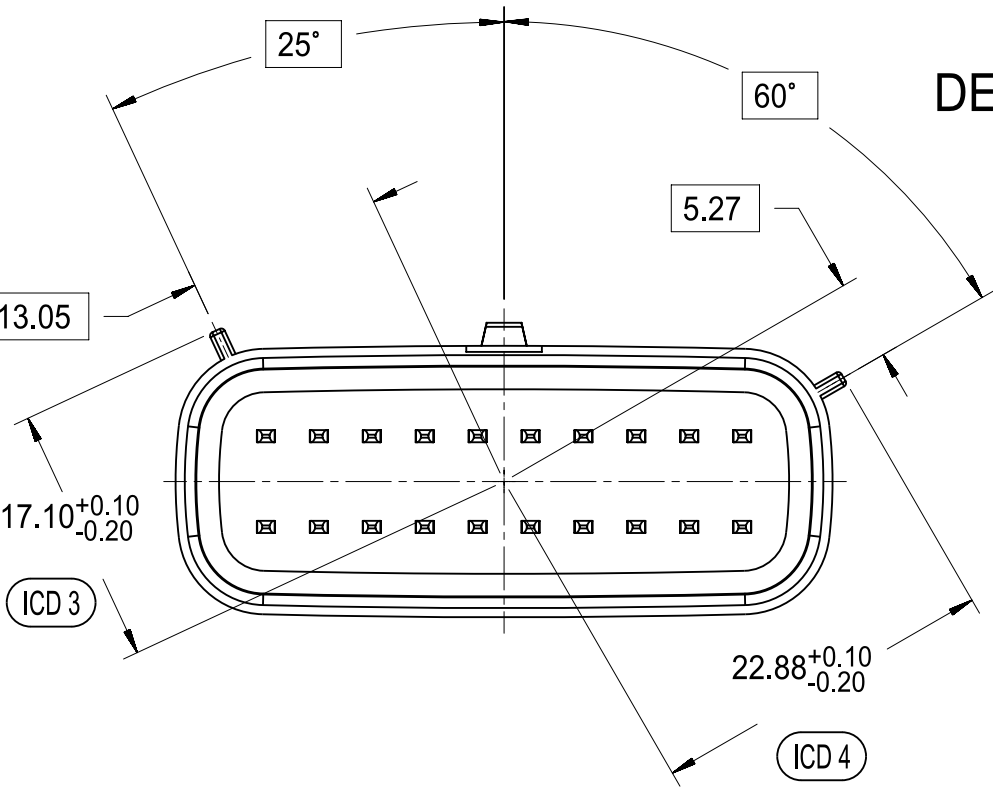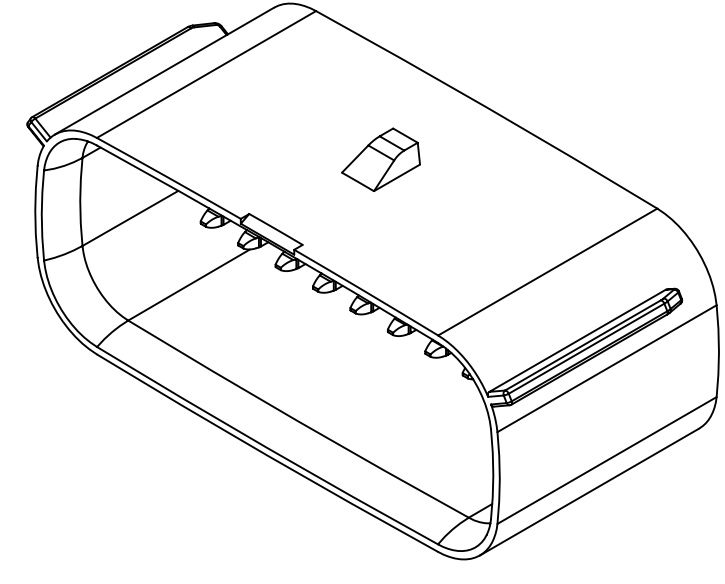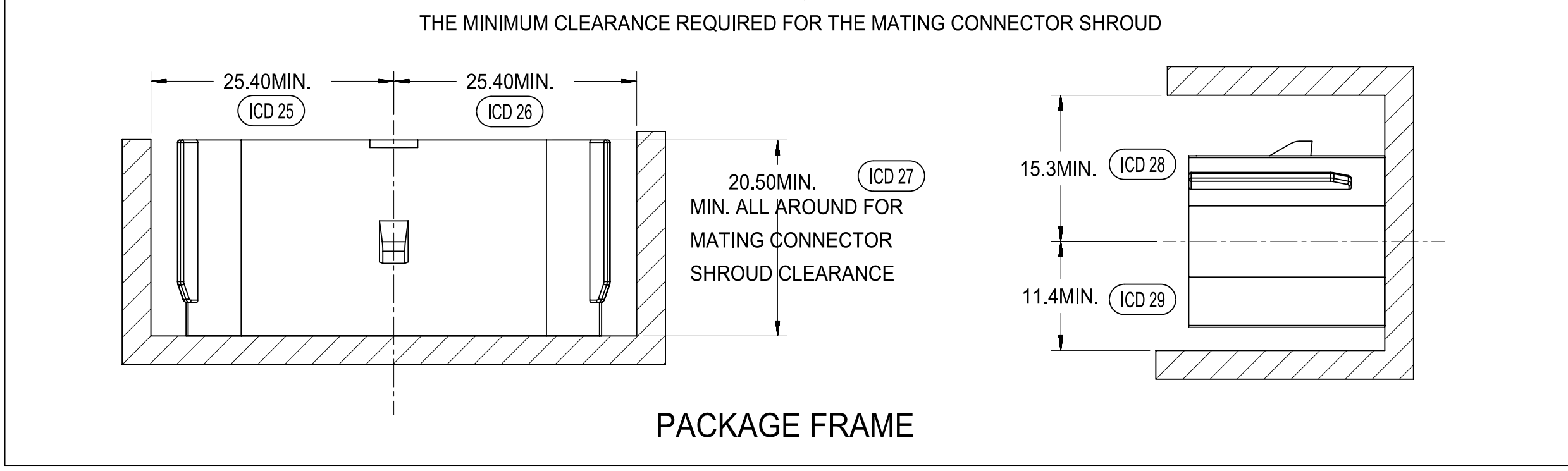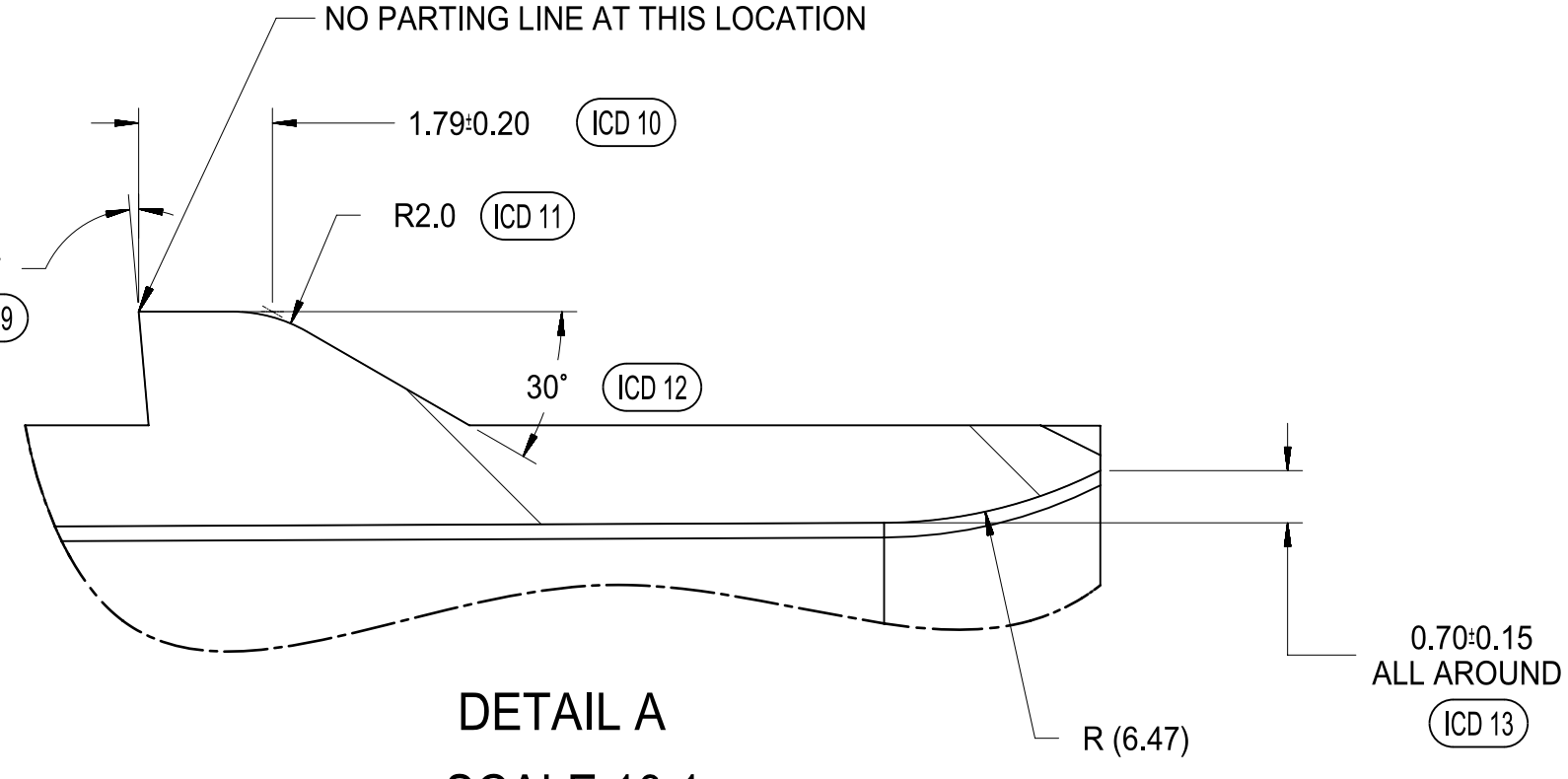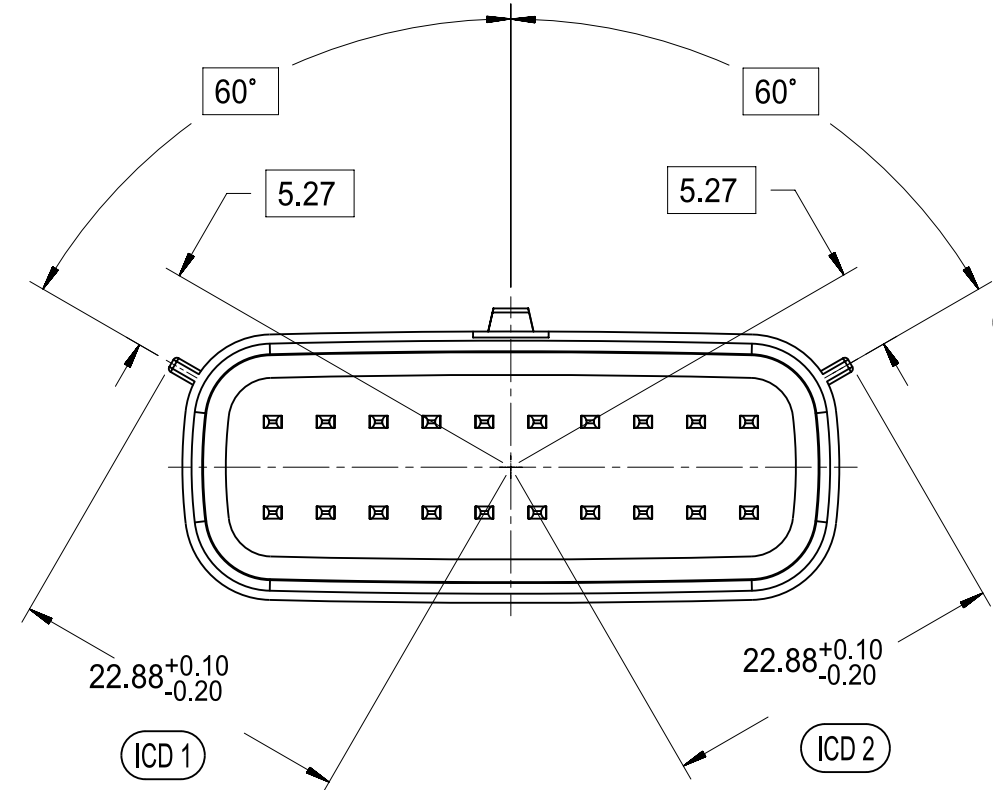

SURFACE MUST BE FREE OF SURFACE DEFECTS AND PARTING LINES FOR SEALING ALL AROUND

CONSTRUCTION BELOW THIS SURFACE IS NOT CONTROLLED BY EWCAP. NO PLASTIC FEATURES MAY EXTEND ABOVE THIS SURFACE.

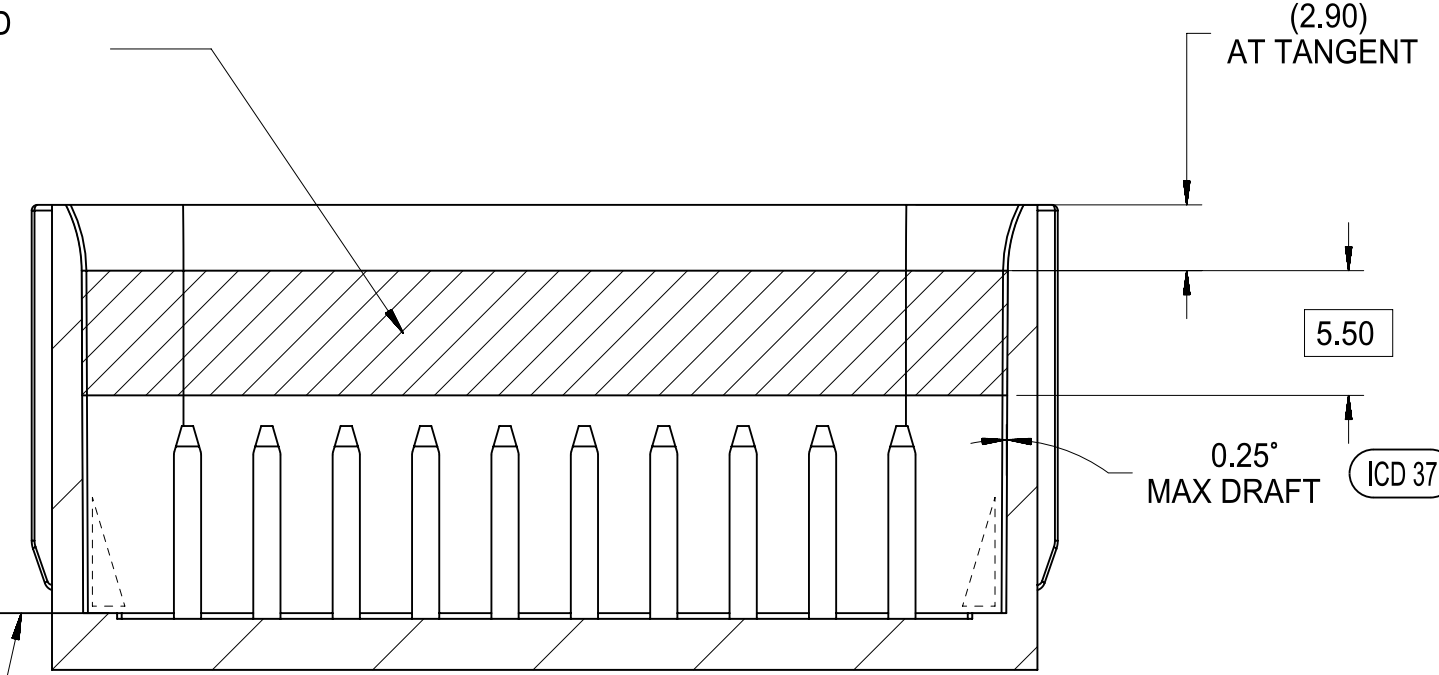

- MATING INTERFACE NOTES: VALID UNLESS OTHERWISE SPECIFIED
- GENERAL:
    - DESIGNED TO MATE WITH MOLEX CONNECTOR 33472-2XXX & 160008-0XXX & 160074-0XXX. A FULL SHROUD ON THE MATING CONNECTOR IS REQUIRED TO INSURE THAT THE CONNECTOR-HEADER POLARIZATION FEATURES (OPTIONS A THRU D) WILL FUNCTION. THE FULL SHROUD ALSO PREVENTS SCOOP DAMAGE TO THE HEADER PINS. REFER TO 'SAE/USCAR-12 CONNECTOR DESIGN GUIDE LINES' FOR ADDITIONAL INFORMATION.
    - PARTS MUST BE IN COMPLIANCE TO MOLEX CHEMICAL SUBSTANCES FOR PRODUCTS AND PACKAGING SPECIFICATION: ES-40000-5016.
    - FLAMMABILITY REQUIREMENT: PER ISO3795 OR GM3191.
      - BURN RATE 100mm/MIN MAXIMUM
      - MATERIAL MUST BE SELF EXTINGUISHING
  - MATERIALS:
    - MATERIAL: SPS/NYLON GF20, REGRIND 20% MAX BY WEIGHT.
    - STANDARD COLORS FOR POLARIZATION (SEE KEYING OPTIONS TABLE). DEVIATION REQUIRES APPROVAL OF AUTHORIZED PERSON.
    - FOR BLADE BASE MATERIAL, PLATING AND PROCESS LUBRICANT:
      - TIN: - BASE MATERIAL: COPPER ALLOY, CONDUCTIVITY >=60% IACS AT 20°C; TENSILE STRENGTH >= 410 N/mm<sup>2</sup> P. - BARRIER MATERIAL: NICKEL DEPOSIT FROM NICKEL SULFAMATE PLATING SOLUTION W/O ANY ADDITIVES. THICKNESS: 1.25 - 2.25 MICROMETERS.
      - TOP LAYER: 100% ELECTRO-DEPOSITED TIN, MATTE FINISH. THICKNESS: 2.5 - 4.0 MICROMETERS.
      - SILVER: - BARRIER MATERIAL: ELECTRO-DEPOSITED DUCTILE SULPHAMATE NICKEL. THICKNESS: 1.25 - 2.25 MICROMETERS.
      - TOP LAYER: ELECTRO-DEPOSITED SEMI-BRIGHT PURE SILVER (0.5% MAX IMPURITIES) OVER NICKEL ANTI-TARNISH TREATMENT EVERBRIGHT WS. THICKNESS: 1.9 - 3.3 MICROMETERS.
    - BLADES MUST CONFORM TO ES-40000-5007, EXCEPT FOR SPECULAR REFLECTIVITY - SECTION 6.0.
    - ANY PROCESS LUBRICANT REMAINING ON THE TERMINAL MUST NOT VARNISH OR DEGRADE IT'S ELECTRICAL PERFORMANCE UP TO A MAXIMUM CLASS AMBIENT TEMPERATURE PER SAE USCAR-2 FOR 1008 HOURS, PROCESS LUBRICANTS SHOULD BE APPROVED BY THE RESPONSIBLE ENGINEER.
    - INFORMATION FOR BLADE DESIGN WAS DEVELOPED FROM EWCAP DWG: EWCAP-001.
  - GEOMETRY:
    - THIS IS A 100% CAD GENERATED PART. THE CAD MATHEMATICAL DATA IS THE MASTER FOR THIS PART. FOR DIMENSIONAL OR ANY INFORMATION NOT SHOWN ON THIS DRAWING, ANALYZE THE CAD MODEL.
    - GEOMETRIC DIMENSIONS AND TOLERANCES PER ASME Y14.5M - 1994.
    - GENERAL TOLERANCES: SEE TITLE BLOCK.
    - EDGES AND UNDIMENSIONED DETAILS PER ISO13715.
  - MANUFACTURING:
    - DRAFT TO BE WITHIN TOLERANCE. PLUS DRAFT - INDICATES A DIMENSION REPRESENTS THE SMALLEST SIZE OF A FEATURE. DRAFT WILL ADD MATERIAL. MINUS DRAFT - INDICATES A DIMENSION REPRESENTS THE LARGEST SIZE OF A FEATURE. DRAFT WILL REMOVE MATERIAL.
    - ALLOWABLE FLASH MAX 0.20 HIGH BY MAX 0.13 THICK.
    - ALLOWABLE SPLIT/PARTING LINE MISMATCH 0.2 MAX.
    - VISUAL DEFECTS SHALL MEET COSMETIC STANDARD PS-45499-002 (Class B).
    - NO EXTERNAL MOLD RELEASE AGENT ALLOWED DURING MANUFACTURING.
    - NO PARTING LINES, NO DRAFT, MISMATCHES OR EJECTOR MARKS PERMISSIBLE WITHIN SEALING SURFACE. SEALING SURFACE TOOLING TO BE PROCESSED TO A SURFACE FINISH OF NTMA #70 (400 PAPER) MINIMUM.

| FUNCTIONAL SYMBOLS |  | THIS DRAWING CONTAINS INFORMATION THAT IS PROPRIETARY TO MOLEX ELECTRONIC TECHNOLOGIES, LLC AND SHOULD NOT BE USED WITHOUT WRITTEN PERMISSION |  | CURRENT REV DESC: SEE REVISION TABLE |  | molex                               |  |  |  |
|--------------------|--|-----------------------------------------------------------------------------------------------------------------------------------------------|--|--------------------------------------|--|-------------------------------------|--|--|--|
| E/A = 0            |  | DIMENSION UNITS                                                                                                                               |  | SCALE                                |  | MX150 RCPT DUAL ROW SEALED ASSEMBLY |  |  |  |
| E/C = 0            |  | MM                                                                                                                                            |  | 1:1                                  |  | PRODUCT CUSTOMER DRAWING            |  |  |  |
| E/P = 0            |  | GENERAL TOLERANCES (UNLESS SPECIFIED)                                                                                                         |  | ANGULAR TOL                          |  | DOCUMENT NUMBER                     |  |  |  |
| DIVISIONAL SYMBOLS |  | 4 PLACES                                                                                                                                      |  | ±                                    |  | SD-33472-0001                       |  |  |  |
|                    |  | 3 PLACES                                                                                                                                      |  | ±                                    |  | DOC TYPE: PSD                       |  |  |  |
|                    |  | 2 PLACES                                                                                                                                      |  | ± 0.100                              |  | DOC PART: 001                       |  |  |  |
|                    |  | 1 PLACE                                                                                                                                       |  | ± 0.20                               |  | REVISION: C11                       |  |  |  |
|                    |  | 0 PLACES                                                                                                                                      |  | ±                                    |  |                                     |  |  |  |
|                    |  | DRAFT WHERE APPLICABLE MUST REMAIN WITHIN DIMENSIONS                                                                                          |  | THIRD ANGLE PROJECTION               |  | MATERIAL NUMBER                     |  |  |  |
|                    |  |                                                                                                                                               |  | DRAWING                              |  | CUSTOMER                            |  |  |  |
|                    |  |                                                                                                                                               |  | SERIES                               |  | GENERAL MARKET                      |  |  |  |
|                    |  |                                                                                                                                               |  | A1-SIZE                              |  | SHEET NUMBER                        |  |  |  |
|                    |  |                                                                                                                                               |  | 33472                                |  | 11 OF 11                            |  |  |  |

|                 |        |                        |
|-----------------|--------|------------------------|
| 150-S-020-2-D02 | D      | STONE GRAY             |
| 150-S-020-2-C02 | C      | DK GRAY                |
| 150-S-020-2-B02 | B      | LT GRAY                |
| 150-S-020-2-A02 | A      | BLACK                  |
| P/N             | OPTION | MATING CONNECTOR COLOR |







