



321 6342

**SERIES 7 Quick Mini thickness Gauges/Pocket thickness Gauges**

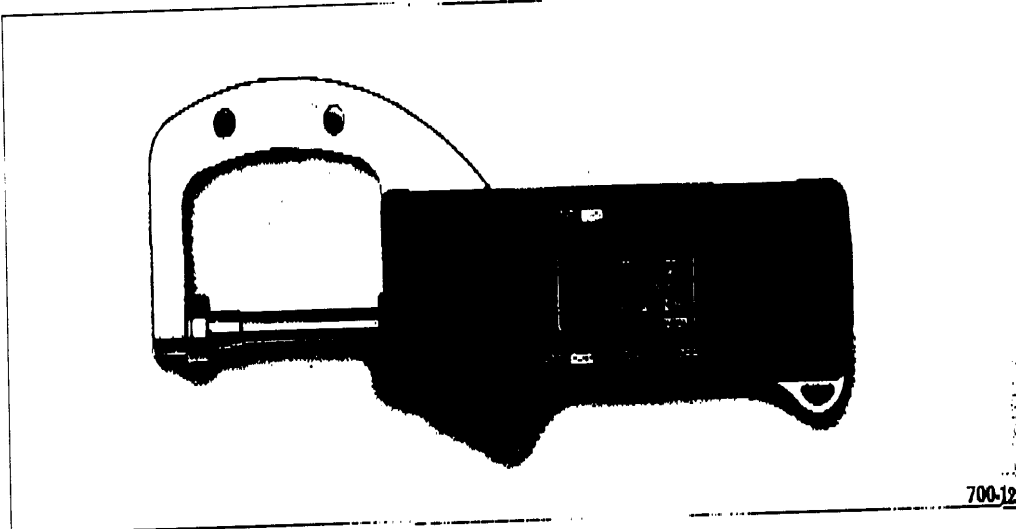

700-122

Measurement in Decimals  
 May be used for metric and imperial units  
 resolution: 0.01mm


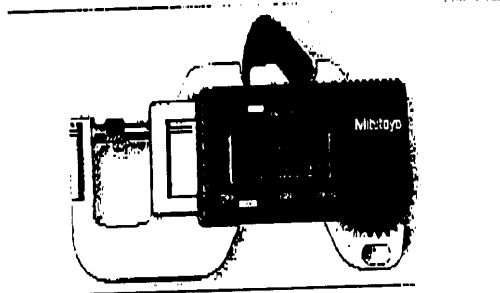


Series 7 Quick Mini model

RESOLUTION	RANGE	ACCURACY	NO.
0.01mm/ 0.0005"	0-12mm/ 0-0.5"	±0.02mm/ ±0.001"	700-118
0.01mm/ 0.0005"	0-25mm/ 0-1"	±0.02mm/ ±0.001"	700-122

**Features**

- ✓ Compact pocket sized Digimatic thickness gauge
- ✓ Imperial/metric conversion
- ✓ Measuring faces are hardened, ground and lapped

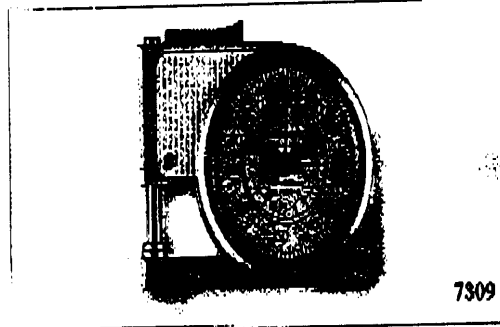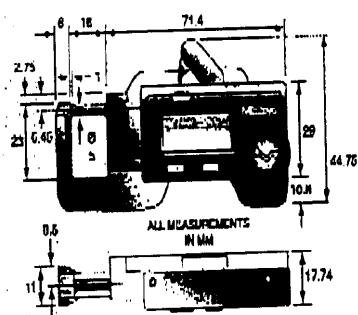

7309

Measurement in Decimals  
 May be used for metric and imperial units  
 resolution: 0.01mm

Series 7 Pocket thickness model

GRADUATION	RANGE	ACCURACY	NO.
0.01mm 0.001"	0-10mm 0-0.4"	±20µm ±0.001"	7309 7308

**Features**

- ✓ Compact pocket sized thickness gauge
- ✓ Preloaded spindle to provide a constant 0.2N (or less) measuring force
- ✓ Measuring faces are hardened, ground and lapped
- ✓ Easy zero adjustment

