

658-510

658-546

ST 18/3poles Male parts

coding


black/white green




ST 18/3

6/12



single screw connector
strain relief for two round cables
diameter 4.5–10.0 mm
or one flat cable

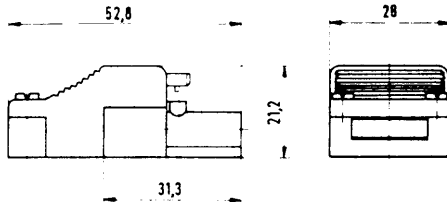

single screw connector
strain relief for one round cable
diameter 6.5–8.3 mm

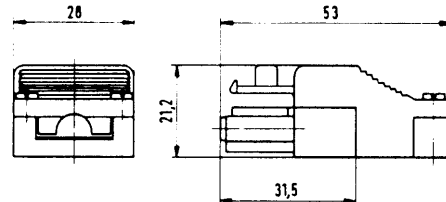


single screw connector
strain relief for two round cables
diameter 4.5–10.0 mm
or one flat cable

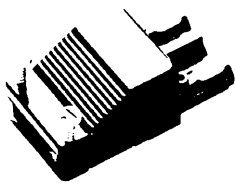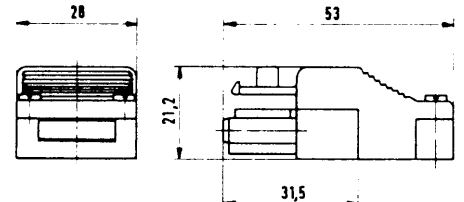


female part assembled
with strain relief without locking device

black	93.631.3253.0	100
white	93.631.3250.0	100
green/black ¹⁾	93.631.3750.0	100

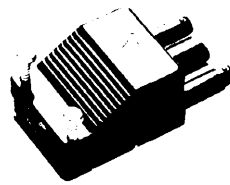

male part assembled
with strain relief without locking device

black	93.732.3353.0	100
white	93.732.3350.0	100
green/black ¹⁾	93.732.3750.0	100

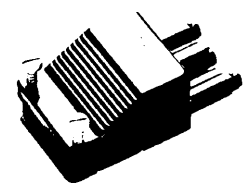

male part assembled
with strain relief without locking device

black	93.632.3353.0	100
white	93.632.3350.0	100
green/black ¹⁾	93.632.3750.0	100

female part assembled
with strain relief with locking device

black	93.631.4253.0	100
white	93.631.4250.0	100
green/black ¹⁾	93.631.4750.0	100

male part assembled
with strain relief with locking device

black	93.732.4353.0	100
white	93.732.4350.0	100
green/black ¹⁾	93.732.4750.0	100

male part assembled
with strain relief with locking device

black	93.632.4353.0	100
white	93.632.4350.0	100
green/black ¹⁾	93.632.4750.0	100

female part unassembled
with strain relief without locking device

black	93.831.3253.0	200
white	93.831.3250.0	200
green/black ¹⁾	93.831.3750.0	200

male part unassembled
with strain relief without locking device

black	93.932.3353.0	200
white	93.932.3250.0	200
green/black ¹⁾	93.932.3750.0	200

male part unassembled
with strain relief without locking device

black	93.832.3353.0	200
white	93.832.3350.0	200
green/black ¹⁾	93.832.3750.0	200

female part unassembled
with strain relief with locking device


black	93.831.4253.0	200
white	93.831.4250.0	200
green/black ¹⁾	93.831.4750.0	200

male part unassembled
with strain relief with locking device

black	93.932.4353.0	200
white	93.932.4350.0	200
green/black ¹⁾	93.932.4750.0	200


male part unassembled
with strain relief with locking device

black	93.832.4353.0	200
white	93.832.4350.0	200
green/black ¹⁾	93.832.4750.0	200

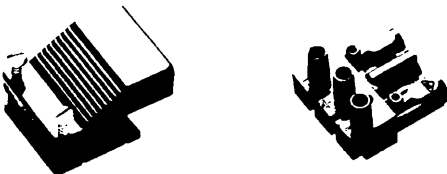


female part

black	93.031.3253.0	200
white	93.031.3250.0	200
green	93.031.3750.0	200

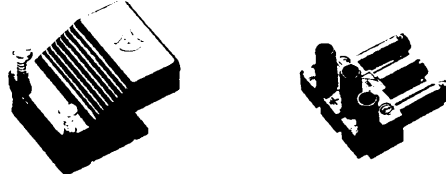

male part

black	93.032.3353.0	200	10,2
white	93.032.3350.0	200	11,0
green	93.032.3750.0	200	10,9

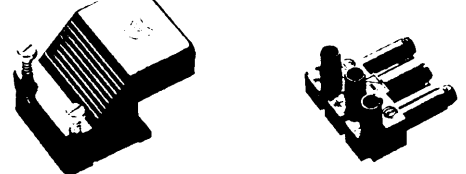

male part

black	93.032.3353.0	200
white	93.032.3350.0	200
green	93.032.3750.0	200

strain relief complete with top and bottom part
without locking device

black	27.410.5153.0	200
white	27.410.5150.0	200

strain relief complete with top and bottom part
without locking device

black	27.410.8153.0	200	6,9
white	27.410.8150.0	200	7,4

strain relief complete with top and bottom part
without locking device

black	27.410.5153.0	200
white	27.410.5150.0	200

strain relief complete with top and bottom part
with locking device

black	27.410.5553.0	200
white	27.410.5550.0	200

strain relief complete with top and bottom part
with locking device

black	27.410.8353.0	200	7,6
white	27.410.8350.0	200	7,3

strain relief complete with top and bottom part
with locking device

black	27.410.5353.0	200
white	27.410.5350.0	200

¹⁾ female part green, strain relief black
(attention - watch coding!)

¹⁾ male part green, strain relief black
(attention - watch coding!)

¹⁾ male part green, strain relief black
(attention - watch coding!)