

313-543 to 580

EXTENSION LEAD FOUR SQUARE

duraplug



EXL 4133 WHI

PORTABLE SOCKETS FOUR WAY

duraplug



FC 4134 WHI

 
FC 4135 BLK

PORTABLE SOCKETS FOUR SQUARE

duraplug




FC 4133 WHI



FC 4133 BLK

PORTABLE SOCKET FILTERED

 duraplug




744 WHI

TRAILING SOCKETS


duraplug



 FC 133 WHI



FCT 133 WHI

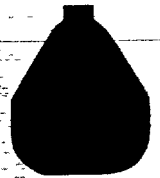

FC 153 BLK

EXL 4133 WHI
EXL 4133 WHI DPK
3 amp with neon and metre cable

1
1
10

FC 4134 WHI
FC 4134 WHI DPK
FC 4134 BLK
FC 4134 BLK DPK
13 amp with fuse and neon

1
1
1
1

FC 4135 WHI
FC 4135 BLK
13 amp with switch and neon

1
1

FC 4136 WHI
FC 4136 BLK
13 amp with switch, fuse and neon

1
1

FC 4133 WHI
FC 4133 WHI DPK
FC 4133 BLK
13 amp with neon

1
1
1

744 WHI
13 amp with switch, neon and fuse

1

FC 133 WHI
FC 133 WHI DPK
FC 133 BLK
FC 133 BLK DPK
13 amp Single Outlet

10
10
10
10

FCT 133 WHI
FCT 133 WHI DPK
FCT 133 BLK
FCT 133 BLK DPK
13 amp Twin Outlet

10
10
1
1

FC 153 BLK
15 amp Single Outlet Round Pin

10

Fitted with BASEC (I-HAR) 25mm PVC cable and EPF 133 Duraplug with P/C cover. The sockets are manufactured in high impact ABS/Polycarbonate.
BS.1363/A: 1984

Manufactured in high impact ABS/Polycarbonate incorporating optional wall mounting holes and equal length wire stripping.

Dimensions:
317 x 68 x 31mm
BS.1363/A: 1984

Manufactured in high impact ABS/Polycarbonate incorporating equal length wire stripping.

BS.1363/A: 1984

Fitted with a fuse carrier and 13 amp fuse to BS.1362. The socket is manufactured in high impact ABS/Polycarbonate. Can also be wall mounted.

Dimensions:
317 x 68 x 31mm

Specification:
Max Power 3.14kW
Response time (Varistor) center than 20ns

See the MK Technical Supplement for further details.
BS.1363/A: 1984

FC 133 and FCT 133
Manufactured from tough ABS/Polycarbonate with rubber cover. All internal component parts are retained in the base for ease of wiring.

BS.1363/A: 1984

FC 153
Manufactured from rubber with nylon shutter.

BS.546

Dimensions:
FC 133 79 x 62 x 29mm
FCT 133 80 x 125 x 29mm
FC 153 67 x 53 x 33mm

