


Adapters for special connections. ø 4 mm safety socket for accepting ø 4 mm safety test leads or any other ø 4 mm Multilam plug.

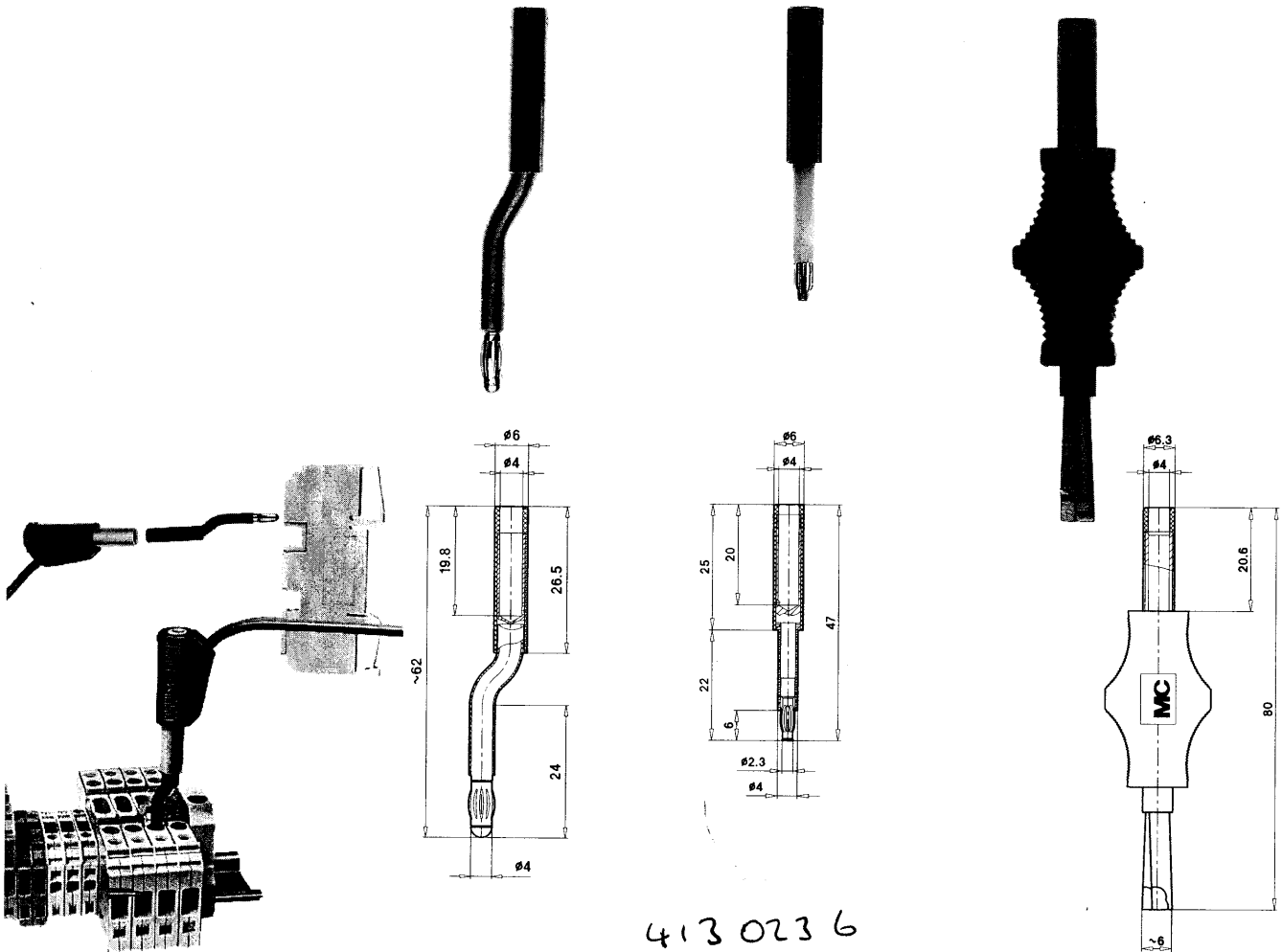

413 023 6
413 024 8

Type	A-SLK4-RG	PS2,3	SPPK4
Rated voltage	These adapters – even in conjunction with safety test leads – can only be used at a rated voltage of 30 V _{AC} / 60 V _{DC} !		
Rated current	25 A	25 A	6 A
Contact resistance	–	0.6 mΩ	–
Function	with ø 4 mm Multilam plug and socket for connecting into rail mounted terminals	test plug, suitable for installation terminals with M3 thread.	adapter with double blades for contacting slotted-head screw. Tensioned by combined pressing-pushing movement of handling part
Insulation	PA and shrinkable tubing	PA	PA
Operating temperature	-40°C ... +80°C	-40°C ... +80°C	-40°C ... +80°C
Metal parts, plating	brass, nickel-plated	ø 2.3 mm plug with Multilam, brass, silver-plated	socket: brass, nickel-plated blades: special spring steel
Standard colours*	black	21 - 22	black
Order No.	24.0164-21	24.0100-*	24.0240-21

Consult supplementary label !	RZ 002	RZ 002	RZ 002
-------------------------------	--------	--------	--------

*Colour code	20 green-yellow	21 black	22 red	23 blue	24 yellow	25 green	26 violet	27 brown	28 grey	29 white	30 orange	33 transparent
--------------	--------------------	-------------	-----------	------------	--------------	-------------	--------------	-------------	------------	-------------	--------------	-------------------