

 
## General data

Other accessories

## Content

<b>Accessories</b>	<b>5 - 22</b>
Lamp extractor	5 - 22
Fixing spanner	5 - 23
RAFIX 22QR/FS, fixing spanner for ring nut and front ring	5 - 23
Disassembly tool	5 - 24
LUMOTAST FK/25 socket connector, 4-pin	5 - 24
LUMOTAST FK/25 flat ribbon cable 10 cm with socket connector and male quick connector, AMP 4-pin	5 - 24
LUMOTAST FK/25 flat ribbon cable, 4-wire, 1 m long	5 - 25
Plug-in socket for PCB, LUMOTAST FK/25	5 - 25
Keylock switch, plug-in socket	5 - 25
Adapter for 90° mounting, keylock switch for PCB	5 - 26
LUMOTAST 75 IP40/65 protective cap	5 - 26
LUMOTAST 75 sealing cap	5 - 26
Signal lamp Ø22.3 mm, sealing ring for IP65	5 - 27
O-ring	5 - 27
Pushbutton 16.2 mm, protection against contact	5 - 27
Signal lamps, protection against contact	5 - 28
LUMOTAST 75 IP40/65 blanking cap, black	5 - 28
LUMOTAST 25, RAFIX 16 blanking cap complete with sealing disc and ring nut	5 - 29

**Accessories**



**Lamp extractor**



Short text	Feature 1	Feature 2	Order no.
Lamp extractor for lamp diameter 4 mm	lamp diameter 4 mm		<b>1.90.900.001/0000</b>
Lamp extractor for T 4.5/5.5, lamp diameter 4 mm	lamp diameter 4 mm		<b>1.90.900.002/0000</b>
Lamp extractor for lamp diameter 5 mm	lamp diameter 5 mm		<b>1.90.900.003/0000</b>
Lamp extractor for lamp diameter 5-6 mm	lamp diameter 5 - 6 mm		<b>1.90.900.004/0000</b>
Lamp extractor for lamp diameter 7 mm	lamp diameter 7mm		<b>1.90.900.005/0000</b>
Lamp extractor for lamp diameter 10.4 mm	lamp diameter 10.4 mm		<b>1.90.900.006/0000</b>
Lamp extractor for lamp diameter 11 mm	lamp diameter 11 mm		<b>1.90.900.007/0000</b>
Lamp extractor for lamp diameter 14 mm	lamp diameter 14 mm		<b>1.90.900.008/0000</b>
Lamp extractor for lamp diameter 16-17 mm	lamp diameter 16-17 mm		<b>1.90.900.009/0000</b>

5

Others

**Fixing spanner**




Short text	Feature 1	Feature 2	Order no.
Fixing spanner M 18, M 19			<b>5.58.002.017/0105</b>
Fixing spanner M 20, M 22, for ring nut			<b>5.58.002.018/0105</b>
Fixing spanner M 15, M 16			<b>5.58.002.019/0105</b>
Fixing spanner M 25, M 30			<b>5.58.002.020/0105</b>
Fixing spanner M 9, M 10			<b>5.58.002.025/0105</b>
Fixing spanner M 11, M 13			<b>5.58.002.026/0105</b>
Fixing spanner M 8			<b>5.58.002.027/7705</b>
Fixing spanner, hexagon, for RAFIX 16			<b>5.58.002.034/0100</b>

**RAFIX 22QR/FS, fixing spanner for ring nut and front ring**



Short text	Feature 1	Feature 2	Order no.
Fixing spanner for ring nut and front ring			<b>5.05.800.062/0000</b>

**Disassembly tool**

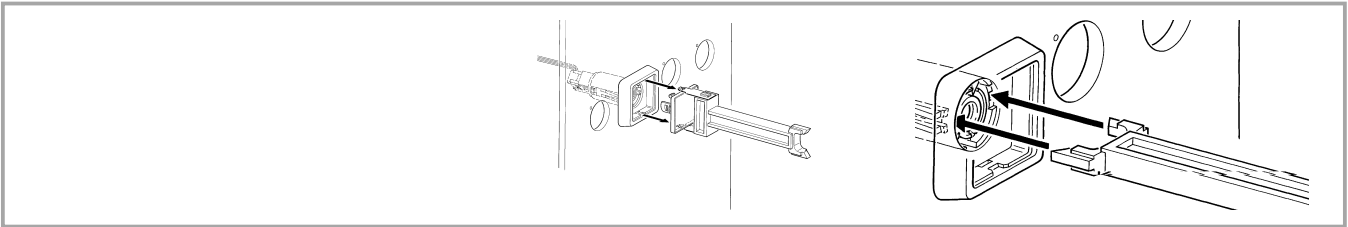

Short text	Feature 1	Feature 2	Order no.
Disassembly tool for LUMOTAST 25, RAFIX 16			<b>5.05.800.042/0000</b>
Disassembly tool for LUMOTAST FK			<b>5.05.800.041/0000</b>


**LUMOTAST FK/25 socket connector, 4-pin**



 Short text	Feature 1	Feature 2	Order no.
Socket connector, 4-pin			<b>5.92.025.368/0000</b>

LUMOTAST	FK/	SCflat
----------	-----	--------


**LUMOTAST FK/25 flat ribbon cable, 4-wire, 1 m long**



Pict.: flat ribbon


Short text	Feature 1	Feature 2	Order no.
Flat ribbon cable, 4-wire, 1 m long			<b>5.37.700.124/0000</b>

**Plug-in socket for PCB, LUMOTAST FK/25**

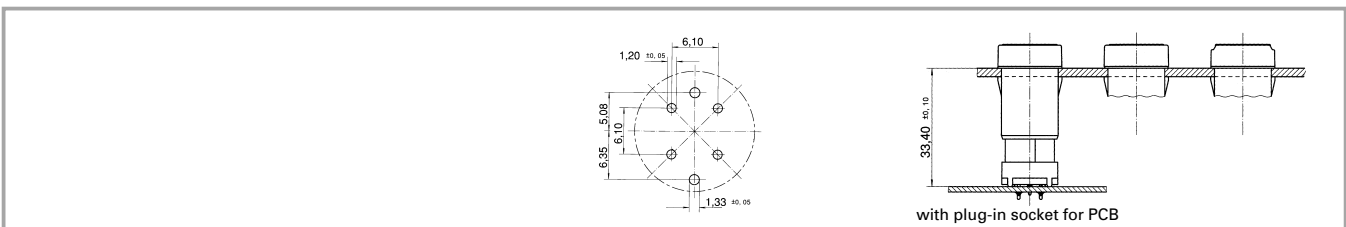

Short text	Feature 1	Feature 2	Order no.
Plug-in socket for PCB			<b>5.00.645.036/0000</b>

**Keylock switch, plug-in socket**

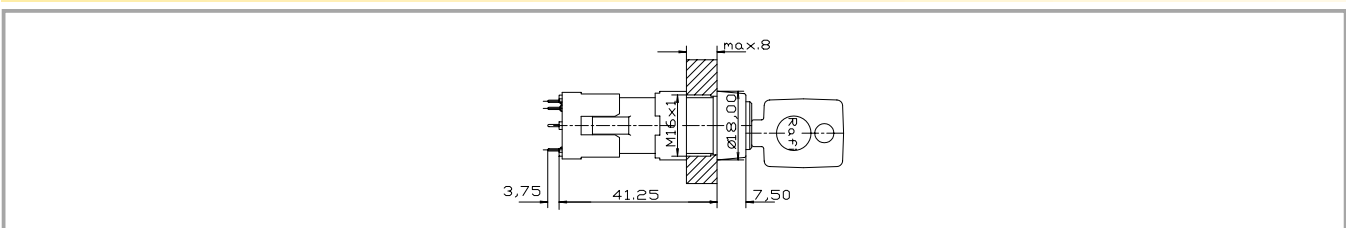

Short text	Feature 1	Feature 2	Order no.
Plug-in socket for PCB mounting			<b>5.05.510.298/0000</b>

**5**

Others

**Adapter for 90° mounting, keylock switch for PCB**



 
Short text	Feature 1	Feature 2	Order no.
Adapter for 90° mounting			5.00.642.008/0000

**LUMOTAST 75 IP40/65 protective cap**



Short text	Feature 1	Feature 2	Order no.
Protective cap (for 18 x 24 collar)			5.05.800.027/0000
Protective cap (for 18 x 18 collar)			5.05.800.030/0000

**LUMOTAST 75 sealing cap**




Short text	Feature 1	Feature 2	Order no.
Sealing cap IP65 (for 18 x 24 collar)	18 x 24 mm		5.05.200.008/0000
Sealing cap IP65 (for 18 x 18 collar)	18 x 18 mm		5.05.200.009/0000

5

Others

**Signal lamp Ø22.3 mm, sealing ring for IP65**

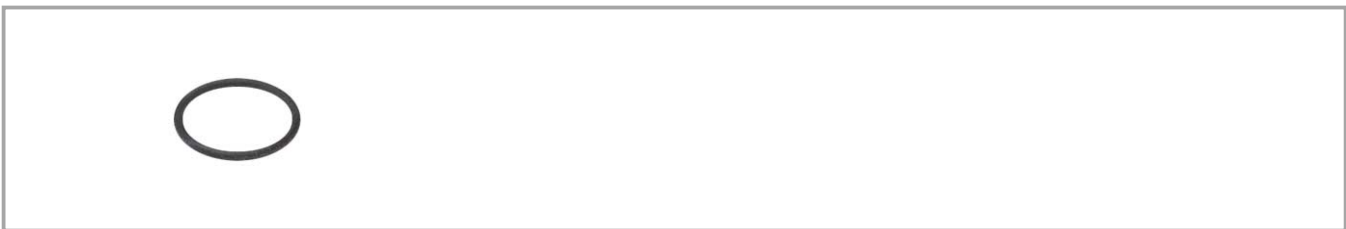

Short text	Feature 1	Feature 2	Order no.
Sealing ring for IP65			5.30.075.010/0100

**O-ring**




Short text	Feature 1	Feature 2	Order no.
O-ring, black, for blocking the operating stroke			5.30.120.009/0100
O-ring, black, for blocking the operating stroke			5.30.120.009/0100
O-ring for keylock switch			5.30.120.015/0100
O-ring, black, 17.0 x 1.5, for blocking RF 19H keys			5.30.125.003/0100

**Pushbutton 16.2 mm, protection against contact**




Short text	Feature 1	Feature 2	Order no.
Protection against contact to VBG 4			5.55.101.715/0200

 **Signal lamps, protection against contact**



Short text	Feature 1	Feature 2	Order no.
Protection against contact to VBG 4			5.50.240.063/0209
Protection against contact to VBG 5			5.50.240.065/0200

**LUMOTAST 75 IP40/65 blanking cap, black**

 

Short text	Feature 1	Feature 2	Order no.
Blanking cap, black, to cover spare holes, dimensions 18 x 18 mm			5.52.006.020/0103
Blanking cap, black, to cover spare holes, dimensions 18 x 24 mm			5.52.006.021/0100
Blanking cap, black, to cover spare holes, round 18 mm			5.52.006.022/0100



**LUMOTAST 25, RAFIX 16 blanking cap complete with sealing disc and ring nut**



Short text	Feature 1	Feature 2	Order no.
Blanking cap complete with sealing disc and ring nut, square			<b>5.05.800.049/0100</b>
Blanking cap complete with sealing disc and ring nut, round			5.05.800.050/0100
Blanking cap complete with sealing disc and ring nut, square, alignable without gaps			5.05.800.051/0100