


# Tool Clips

708-1492 = 80025

## Tool Clip Type No. 80

(CLOSED TYPE)

Standard Material – Carbon Spring Steel  
 Standard Finish – Zinc Plate, Polythene Coated  
 Certain sizes available in Stainless Steel

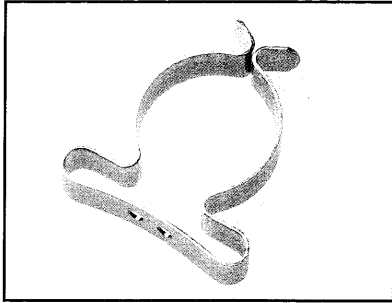

Zinc Plate	Code No.		To Grip Diameter	
	Polythene Coated		inch	mm
	White	Black		
80025	80025WP	80025BP	0.250	6
80037	80037WP	80037BP	0.375	10
80050	80050WP	80050BP	0.500	13
80062	80062WP	80062BP	0.625	16
80075	80075WP	80075BP	0.750	19
80100	80100WP	80100BP	1.000	25
80112	80112WP	80112BP	1.125	28
80125	80125WP	80125BP	1.250	32
80150	80150WP	80150BP	1.500	38
80200	80200WP	80200BP	2.000	51

## Tool Clip Display Boxes


All popular sizes of Tool Clips, in all finishes, are available in an attractive point of sale display box.

Type 80		Type 81	
Code No.	Finish	Code No.	Finish
80000	Zinc	81000	Zinc
80000WP	White Polythene	81000WP	White Polythene
80000BP	Black Polythene	81000BP	Black Polythene

## Tool Clip Type No. 82

(WITH BACK PLATE)

Standard Material – Carbon Spring Steel  
 Standard Finish – Black Enamel  
 Certain sizes available in Stainless Steel

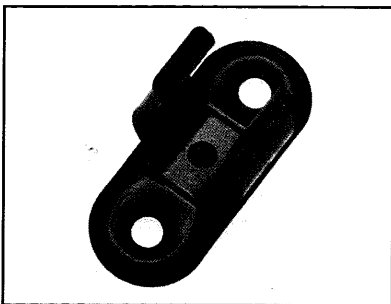


Code No.	To Grip Diameter	
	inch	mm
82037	0.375	10
82050	0.500	13
82062	0.625	16
82075	0.750	19
82087	0.875	22
82100	1.000	25
82112	1.125	28
82125	1.250	32
82150	1.500	38


## Tool Clip Type No. 81

(OPEN TYPE)

Standard Material – Carbon Spring Steel  
 Standard Finish – Zinc Plate, Polythene Coated  
 Certain sizes available in Stainless Steel

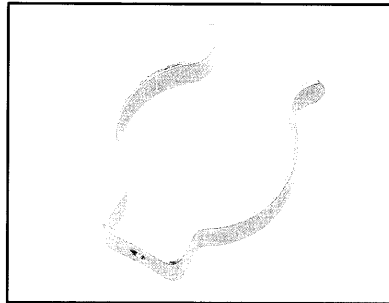


Zinc Plate	Code No.		To Grip Diameter	
	Polythene Coated		inch	mm
	White	Black		
81025	81025WP	81025BP	0.250	6
81037	81037WP	81037BP	0.375	10
81050	81050WP	81050BP	0.500	13
81062	81062WP	81062BP	0.625	16
81075	81075WP	81075BP	0.750	19
81100	81100WP	81100BP	1.000	25
81112	81112WP	81112BP	1.125	28
81125	81125WP	81125BP	1.250	32
81150	81150WP	81150BP	1.500	38
81200	81200WP	81200BP	2.000	51

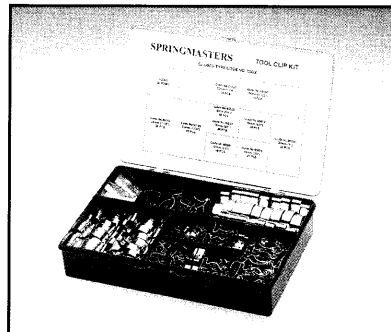

## Tool Clip Type No. 83

(SUPER CLIP)

Standard Material – Carbon Spring Steel  
 Standard Finish – Zinc Plate, Polythene Coated  
 Certain sizes available in Stainless Steel

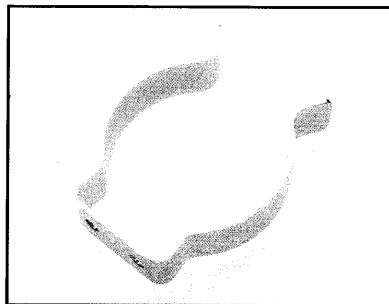

Zinc Plate	Code No.		To Grip Diameter	
	Polythene Coated		inch	mm
	White	Black		
83175	83175WP	83175BP	1.750	44
83250	83250WP	83250BP	2.500	64
83300	83300WP	83300BP	3.000	76
83350	83350WP	83350BP	3.500	89
83400	83400WP	83400BP	4.000	102
83450	83450WP	83450BP	4.500	114

HARDWARE PRODUCTS AND CLIPS