




similar DIN 3125, ISO 2725

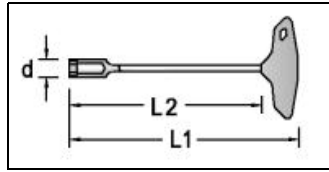

### 33 T Socket wrench

with T-handle

Blue T-handle, non-slip grained surface, with hole for hanging. Head depth 25 mm. GEDORE vanadium steel 31CrV3, mat. No. 1.2208, chrome-plated.

Code	No.	mm	L <sub>1</sub>	L <sub>2</sub>	d	
1531301	33 T 5	5.0	227.5	195	8.0	160
6353320	33 T 5,5	5.5	227.5	195	8.0	95
6357580	33 T 6	6.0	227.5	195	9.0	100
6357660	33 T 7	7.0	227.5	195	11.0	120
6357740	33 T 8	8.0	227.5	195	12.0	130
6357820	33 T 9	9.0	227.5	195	13.0	150
6357900	33 T 10	10.0	227.5	195	14.0	160
6353400	33 T 11	11.0	269.0	230	16.0	180
6353590	33 T 12	12.0	269.0	230	17.0	185
6358040	33 T 13	13.0	269.0	230	18.0	200

### Socket Set 3/8"

With forged, tempered hexagon, bi-hexagon or UD profile sockets, hand-operated, and accessories made from GEDORE vanadium steel 31CrV3, mat. No. 1.2208. Supplied in GEDORIT blue sheet steel case.

U-3 Set with fine toothed, dial change ratchet



### 30 G Socket set

17 pieces

Dimensions: 318 x 118 x 37 mm

Code	No.	Ratchet	Sockets	Accessories	
6235980	30 GMU-3	U-3	30 6 7 8 9 10 11 13 14 15 16 17 19 mm	3087 3090-5 -10 3095	1.9



DIN 3122, ISO 3315 - DIN 3123, ISO 3316



1993 U-20

### 1993 U-20 Ratchet

1/2" square drive

For hand-operated sockets and accessories with square drive as per DIN 3120 - C 12.5, ISO 1174 ball locking device. GEDORE vanadium steel 31CrV3, mat. No. 1.2208, chrome-plated.

6

Reversible ratchet with lever change, push button release, locks in middle position, oval head, dual-material handle, non-slip, hanging hole.

Code	No.	Description	L mm	H mm	
1436686	1993 U-20	Reversible ratchet 1/2"	270	37.5	530