




DEUTSCH
INDUSTRIAL

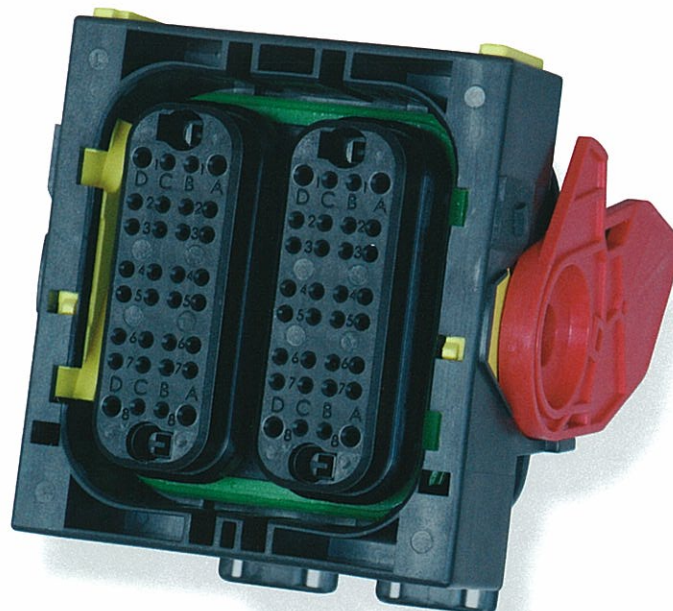


Strike Connector

SRK06 FL* 64A 00* Plug


10 Keyways and
Color Marking

A	B
C	D
E	F
G	H
I	J

Open Position

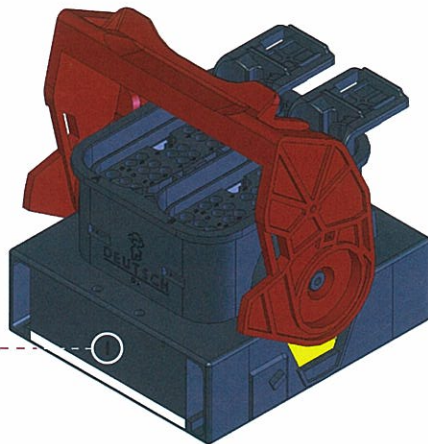

Closed Position

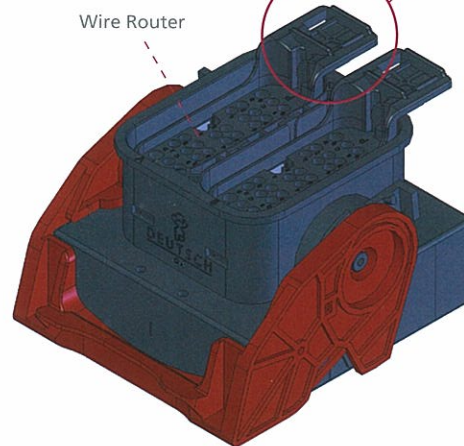

Cable Attachment
Options

001 standard/
none



002 90°



003 180°



SRK06 FL * 64A 00* Plug

Contacts 56 x size 20 (7,5A max) & 8 x size 16 (13 A max)

Socket Size & Type	Part No.	Wire Gauge Range	OD	Crimp DWG	Hand Crimp Tool	Production Crimp Tool
16	1062-14-01**	16 & 14 AWG / 1,0 - 2,0mm ²	0.095-0.134 2,41-3,4mm	0425-203-000	DTT-16-00 DTT-16-01	DCT-1620-02-00
16	1062-16-01**	18, 16 & 14 AWG / 0,75 - 2,0mm ²	0.075-0.115 1,90-2,92mm	0425-203-000	DTT-16-00 DTT-16-01	DCT-1620-02-00
16	1062-16-06**	20, 18 & 16 AWG / 0,50 - 1,0mm ²	0.055-0.083 1,40-2,10mm	0425-203-000	DTT-16-00 DTT-16-01	DCT-1620-02-00
16	1062-16-07**	18, 16 & 14 AWG / 0,75 - 2,0mm ²	0.075-0.115 1,90-2,90mm	0425-203-000	DTT-16-00 DTT-16-01	DCT-1620-02-00
16	1062-16-1222	16, 14 & 12 AWG / 1,0 - 2,5mm ²	0.075 - 0.138 1,90 - 3,4mm	0425-039-000	DTT-16-02	DCT-16-02-01
20	1062-20-01**	20, 18 & 16 AWG / 0,5 - 1,5mm ²	0.075-0.108 1,90-2,75mm	0425-207-000	DTT-20-00	DCT-1620-02-00
20	1062-20-02**	20, 18 & 16 AWG / 0,5 - 1,5mm ²	0.050-0.085 1,3-2,15mm	0425-207-000	DTT-20-02	DCT-1620-02-00

**See envelop drawing for plating options

Sealing Plugs: Size 20: P/N 0413-204-2005, Size 16: P/N 114017

Accessories

Backshells for corrugated conduit NW 22 & NW 26
and option for tie wrap fastening to harnesses.



SRK BS FL 90 001



SRK BS FL ST 001

Consult "How to use plug
module 32A" documentation

