

Product

Auto Transformer


Type No.

SAT 100

Technical Details

Safety Standards	VDE 0570, EN 61558-1 with EN 61558-2-13
Designated Voltage	Input: 230Vac
Designated Voltage	Output: 115Vac
Designated Current	Output: 0,869Aac
Designated Frequency	50-60Hz.
Protection Index	IP 20
Protection Class	I
Insulation Class	A (105°C)
Ambient Temperature	Max. 40°C
Short-Circuit Protection	Short-circuit-proof
Protection Device	Fuse-Link 5x20mm 0,8AT in output circuit
Input Connector	Approx. 2m flexible 3 core cable with a BS 1363 three pin plug
Output Connector	Approx. 1m flexible 3 core cable with USA 15A/125V three pin socket
Construction	Plastic enclosure
Weight	approx. 1,9Kg

 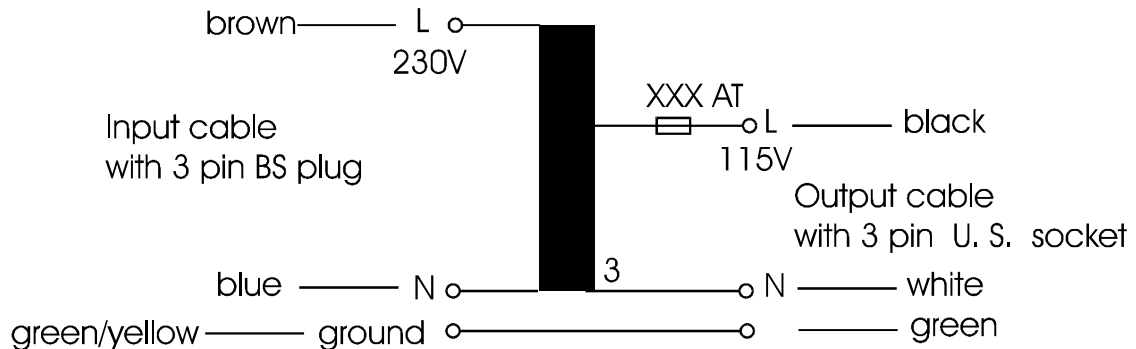


Schematic Plan



Description

Short-circuit-proof auto transformer fully encapsulated in plastic enclosure.
 Integrated fuse protection against short circuit and overload.
 No isolation from mains.

Marking:

 www.block-trafo.de	SAT 100 Autotransformer 100VA Spartransformator 50-60Hz ta 40°C Cl.A IP 20
	
 VDE 0570 / EN 61558	Input: 230V - 0,46Aac Output: 115V - 0,87Aac — 0,8AT
This Transformer does not provide isolation from mains voltage Der Transformator besitzt keine galvanische Trennung zum Netz	

Approvals:

-

Dimensions

