

Product

Auto Transformer

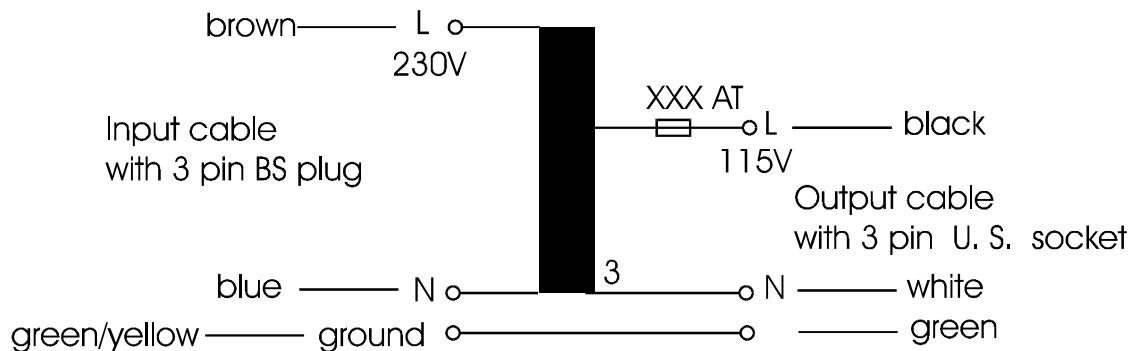
Type No.

SAT 200

Technical Details

Safety Standards	VDE 0570, EN 61558-1 with EN 61558-2-13
Designated Voltage	Input: 230Vac
Designated Voltage	Output: 115Vac
Designated Current	Output: 1,74Aac
Designated Frequency	50-60Hz.
Protection Index	IP 20
Protection Class	I
Insulation Class	A (105°C)
Ambient Temperature	Max. 40°C
Short-Circuit Protection	Short-circuit-proof
Protection Device	Fuse-Link 5x20mm 1,6AT in output circuit
Input Connector	Approx. 2m flexible 3 core cable with a BS 1363 three pin plug
Output Connector	Approx. 1m flexible 3 core cable with USA 15A/125V three pin socket
Construction	Plastic enclosure
Weight	approx. 2,361Kg

 

 
Schematic Plan



Description

Short-circuit-proof auto transformer fully encapsulated in plastic enclosure.
Integrated fuse protection against short circuit and overload.
No isolation from mains.

Marking:

	SAT 200
www.block-trafo.de	200VA
Autotransformer	50-60Hz
Spartransformator	
VDE 0570/EN 61558 ta.40°C Cl.A IP 20	
Input: 230V - 0,92A	Output: 115V - 1,74A  1,6AT
▽ This Transformer does not provide isolation from mains voltage ▽ ▽ Der Transformator besitzt keine galvanische Trennung zum Netz ▽	

Approvals:

-

Dimensions

