

# ID PAL™ Labeling Tool

## Professional Labeling with a Difference

▶ Labels that Stick ▶ Easy to Use ▶ Saves Time and Money



### ID PAL Labeling Tool

| Part Number      | Description                           |
|------------------|---------------------------------------|
| 81000 IDPAL      | ID PAL Labeling Tool - North America* |
| 81001 IDPAL-INTL | ID PAL Labeling Tool - International* |

\* Includes full label cartridge (PAL-750-439)

### ACCESSORIES

| Part Number    | Description                   |
|----------------|-------------------------------|
| 81002 IDPAL-AC | ID PAL AC Adapter             |
| 81003 IDPAL-IG | ID PAL Impact Guards          |
| 81004 IDPAL-HC | ID PAL Hardside Carrying Case |

### SYMBOLS

Press **FUNCTION** + Character

| Character | Symbol | Character | Symbol | Character | Symbol |
|-----------|--------|-----------|--------|-----------|--------|
| A         | !      | K         | '      | U         | ~      |
| B         | @      | L         | .      | V         | ²      |
| C         | #      | M         | "      | W         | φ      |
| D         | \$     | N         | /      | X         | ±      |
| E         | %      | O         | \      | 4         | ¢      |
| F         | &      | P         | °      | 5         | €      |
| G         | *      | Q         | _      | 6         | ℓ      |
| H         | (      | R         | ±      | 7         | -      |
| I         | )      | S         | '      | 8         | +      |
| J         | :      | T         | Ω      | 9         | =      |

Prints as 

ID PAL is an affordable, easy-to-use, portable thermal transfer printer designed for the field, not the office. The rugged design has been tested to withstand harsh environments and a tough four foot drop test to concrete.

ID PAL uses Brady high performance labeling materials. The labels stay in place on your toughest surfaces, from wire and cable to highly textured plastic. As a result ID PAL eliminates the confusion caused by faded, smeared or poorly written labels, or labels that fall off leaving unidentified wires.

- ▶ Prints Brady-quality labels
- ▶ Easy-to-peel labels
- ▶ Fits great in your hand
- ▶ Job-tough construction
- ▶ Easy-to-see bright red color
- ▶ Quick, top-load, drop-in cartridge
- ▶ Built-in industrial cutter
- ▶ Intuitive keyboard with electrical and datacomm symbols
- ▶ Special wire marking mode with 10 preset lengths
- ▶ Prints upper and lower case characters
- ▶ Multiple line printing and serialization
- ▶ Automatic shut-off
- ▶ Six month warranty (12 months if registered)

### SPECIFICATIONS

|                         |   |
|-------------------------|---|
| Print method:           | Thermal transfer (non smearing)                               |
| Weight:                 | 1.2 lbs. (0.55 kg) with batteries and tape cartridge included |
| Dimensions (L x W x H): | 9.0 x 4.5 x 2.5 inches<br>(228.6 x 114.3 x 63.5 mm)           |
| Power source:           | 6 AA-size batteries<br>print over 3500 1" (25.4 mm) labels    |
| Operating temperature:  | 40° - 120° F (4° - 49° C)                                     |
| Agency Approvals:       | FCC Class A approved  |

### FIVE FONT SIZES

|    |       |
|----|-------|
| 7  | POINT |
| 10 | POINT |
| 14 | POINT |
| 20 | POINT |
| 28 | POINT |

▶ **LABELS FOR MULTIPLE APPLICATIONS**  
Choose from Three Label Types

**WIRE**



- ▶ Built-in leader for wrapping wire/cable
- ▶ Choose from 10 pre-programmed lengths: 0.75", 1", 1.2", 1.5", 2", 2.5", 3", 4", 5", 6"



**BANNER**




- ▶ Prints up to two lines of text

**GENERAL**



- ▶ Prints up to four lines of text

▶ **EASY-PEEL LABEL**

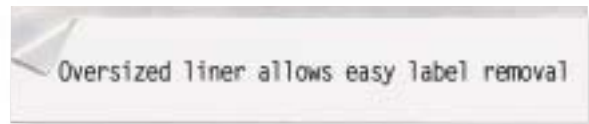

Oversized liner allows easy label removal

▶ **LESS LABEL WASTE RESULTS IN MORE LABELS**



ID PAL label



Competitor label

**LABEL CARTRIDGE SELECTION CHART**

| Application | Material/Color                     | Max. Service Temperature | 3/8" (9mm)   | Label Width 1/2" (12mm) | 3/4" (9mm)   | Roll Length Feet (m) | Agency Approvals |
|-------------|------------------------------------|--------------------------|--------------|-------------------------|--------------|----------------------|------------------|
|             | Nylon Cloth B-499 / Black on White | 194 (90) 30 days         | PAL-375-499+ | PAL-500-499+            | PAL-750-499+ | 19' (5.8)            |                  |
|             | Vinyl B-439 / Black on White*      | 104 (40) 30 days         | PAL-375-439+ | PAL-500-439+            | PAL-750-439+ | 21' (6.4)            |                  |
|             | Polyester B-430 / Black on Clear   | 212 (100) 30 days        | PAL-375-430+ | PAL-500-430+            | PAL-750-430+ | 21' (6.4)            |                  |
|             | Polyester B-423 / Black on White   | 248 (120) 30 days        | PAL-375-423+ | PAL-500-423+            | PAL-750-423+ | 21' (6.4)            |                  |

Plus... each cartridge comes preloaded with its own application-specific ribbon.

\* Available in other colors  
+ Catalog Number

**Application Key**

- Smooth/Flat Surface
- Textured Surface
- Wire/Cable/Curved Surface
- Highly Textured Surface



Identification Solutions & Specialty Tapes

www.bradyid.com

Australia 1-800-620-816  
Belgium 32-(0)-152-457-811  
Brazil 55-11-3686-4720  
Canada 1-800-263-6179  
China (Beijing) 86-10-6517-1260  
China (Wuxi) 86-510-528-2222  
England 44-(0)-1295-228-200  
France 00-33-1-69-29-67-00

**WORLDWIDE LOCATIONS**

Germany 49-(0)-607-196-03  
Hong Kong 852-2359-3149  
Italy 39-02-967-00-507  
Japan 81-45-461-3600  
Korea 82-2-400-8418  
Latin America 1-414-540-5560  
Malaysia 60-4-283-3980  
Mexico 525-399-6963

New Zealand 61-2-8717-2200  
Philippines 632-658-2077  
Singapore 65-775-2077  
Sweden 46-(0)-859-005-730  
Taiwan 88-(6)-2-2345-1430  
Thailand 66-2-943-0777  
U.S.A. 1-800-537-8791



Y95178B

www.bradyidpal.com

©2002 BRADY Worldwide, Inc. Printed in U.S.A.  
Specifications subject to change without notice.  
All rights reserved. Y95178B  
3-KK-02-VAM-10 Effective 3-02  
AN ISO REGISTERED COMPANY