


## Prototyping Board



### RE321-LF

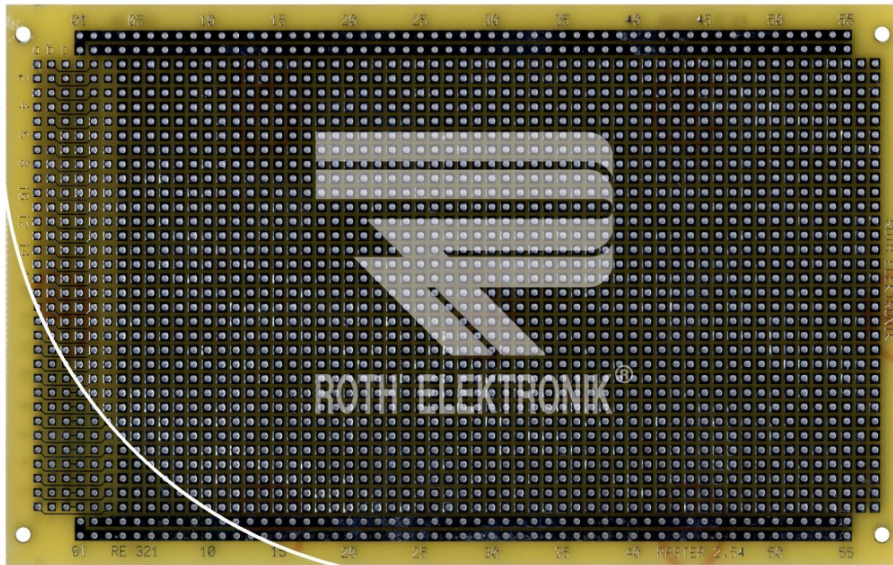

- EPOXY fibre-glass FR4 1.5 mm double-sided 35 µm CU (pth)
- hot air leveling (HAL-leadfree)
- 36 x 55 single-hole conductor 2.0 mm Ø
- hole spacing 2.54 x 2.54 mm
- hole dia 1,0 mm
- connector 32/ 64/ 96-channel DIN 41612
- grid 2.54 mm type C
- size 100 x 160 mm