


Terminal Strips 0.8 mm Ø/AWG 20 "s" Pin Spacings 2.5 mm / 0.098 in and 2.54 mm / 0.1 in; Series 250

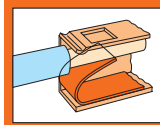

Pin spacing 2.5 mm / 0.098 in
0.4 – 0.8 mm Ø "s" ① | AWG 26 – 20 "s"
250 V/2.5 kV/2 | 300 V, 2 A
2 A | 300 V, 2 A

Pin spacing 2.54 mm / 0.1 in
0.4 – 0.8 mm Ø "s" ① | AWG 26 – 20 "s"
250 V/2.5 kV/2 | 300 V, 2 A
2 A | 300 V, 2 A

8.5 – 9.5 mm / 0.35 in

8.5 – 9.5 mm / 0.35 in

*




*



No. of poles	Item No.	Pack.-unit pcs	Item No.	No. of poles	Item No.	Pack.-unit pcs
1-conductor terminal strips with push button, 1 solder pin/pole staggered, grey, with test slot for test pin up to 1.3 mm Ø			Additional item nos. for colored terminal strips for pin spacings 2.5 mm/0.098 in and 2.54 mm/0.1 in			
2	250-402	720 (4x180)	black .../000-004 ●	2	250-1402	720 (4x180)
3	250-403	520 (4x130)	red .../000-005 ●	3	250-1403	520 (4x130)
4	250-404	400 (4x100)	blue .../000-006 ●	4	250-1404	400 (4x100)
5	250-405	340 (4 x 85)	orange .../000-012 ●	5	250-1405	320 (4 x 80)
6	250-406	280 (4 x 70)	light grey .../000-009 ●	6	250-1406	280 (4 x 70)
7	250-407	240 (4 x 60)	violet .../000-024 ●	7	250-1407	240 (4 x 60)
8	250-408	220 (4 x 55)	white .../000-050 ●	8	250-1408	200 (4 x 50)
9	250-409	200 (4 x 50)	other colors upon request	9	250-1409	180 (4 x 45)
10	250-410	180 (4 x 45)		10	250-1410	160 (4 x 40)
11	250-411	160 (4 x 40)		11	250-1411	160 (4 x 40)
12	250-412	140 (4 x 35)	Ordering example	12	250-1412	140 (4 x 35)
13	250-413	140 (4 x 35)	Terminal strip, pin spacing 2.5 mm/0.098 in,	13	250-1413	120 (4 x 30)
14	250-414	120 (4 x 30)	8 poles, orange	14	250-1414	120 (4 x 30)
15	250-415	120 (4 x 30)	1 solder pin staggered	15	250-1415	120 (4 x 30)
16	250-416	100 (4 x 25)	250-480/000-012	16	250-1416	100 (4 x 25)
17	250-417	100 (4 x 25)		17	250-1417	100 (4 x 25)
18	250-418	80 (4 x 20)		18	250-1418	80 (4 x 20)
19	250-419	100 (4 x 25)		19	250-1419	100 (4 x 25)
20	250-420	80 (4 x 20)		20	250-1420	80 (4 x 20)
21	250-421	80 (4 x 20)		21	250-1421	80 (4 x 20)
22	250-422	80 (4 x 20)	① 0.2 mm ² – 0.5 mm ² "f-st"	22	250-1422	80 (4 x 20)
23	250-423	80 (4 x 20)		23	250-1423	60 (4 x 15)
24	250-424	60 (4 x 15)		24	250-1424	60 (4 x 15)

Accessories (marker strips see section 11)

	Test pin, 1 mm/0.039 in Ø 735-500 1 Test wire for sold. onto test plug		Test pin, 1 mm/0.039 in Ø 735-500 1 Test wire for sold. onto test plug
--	--	--	--

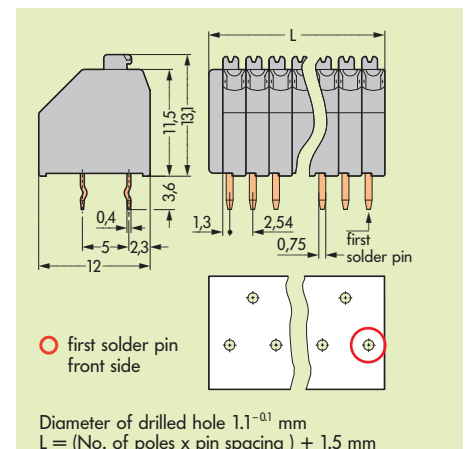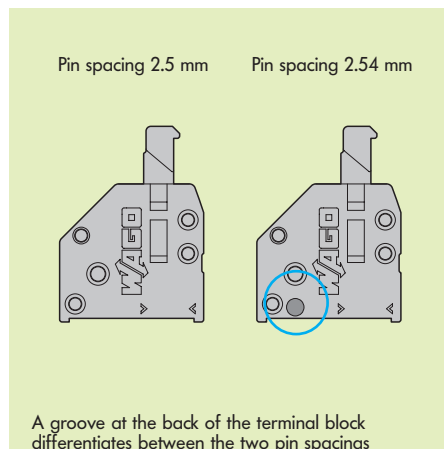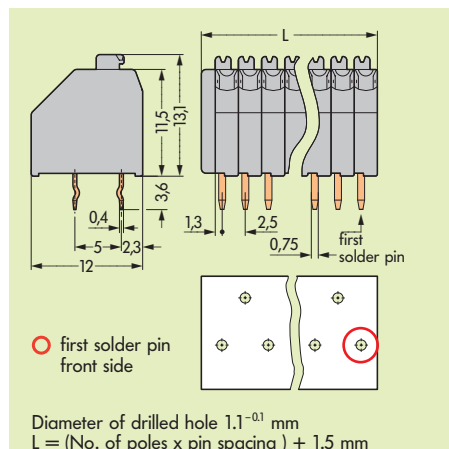

* Approvals with corresponding ratings see pages 12.3 ff.