




TYPE - CF90IP65



Contact your local Sales Representative
[Click Here for Printable Version](#)

				NPT	Threaded	Fittings		
Cat #	US Trade Size	MM	NW	Thread Size	Unit Pack	Part #	Standard Carton	Part #
CF-140A	1/4"	10	7	PG-7	1	90195	-	-
CF-516A	5/16"	12	10	PG-9	1	90180	-	-
CF-20	3/8"	16	12	1/2" NPT	25	90211	100	90212
CF-21	1/2"	20	17	1/2" NPT	25	90231	50	90232
CF-22	3/4"	25	23	3/4" NPT	10	90251	30	90252
CF-23	1"	32	29	1" NPT	10	90271	20	90272
CF-24	1-1/4"	40	36	1-1/4" NPT	5	90291	10	90292
CF-25	1-1/2"	50	48	1-1/2" NPT	2	90311	10	90312

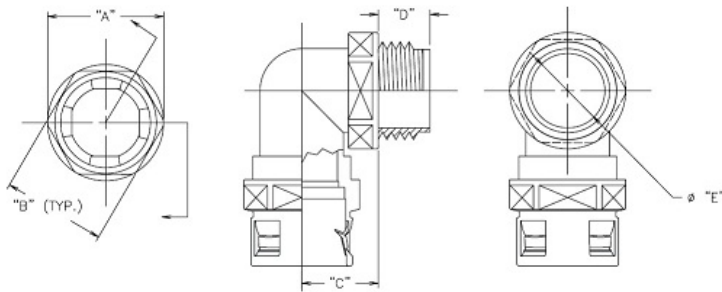

Cat #	U. S. Trade Size	Thread Size	A	B	C	D	E
CF-140A	1/4"	PG-7					
CF-516A	5/16"	PG-9	.775	.735	.665	.360	.410
CF-20	3/8"	1/2" NPT	.920	.820	.750	.480	.560
CF-21	1/2"	1/2" NPT	1.160	1.085	.800	.510	.650
CF-22	3/4"	3/4" NPT	1.525	1.140	.970	.600	.820
CF-23	1"	1" NPT	1.730	1.570	1.180	.570	1.030
CF-24	1-1/4"	1-1/4" NPT	2.085	1.965	1.600	.690	1.390
CF-25	1-1/2"	1-1/2" NPT	2.680	2.575	1.940	.710	1.475

TYPE - CF90IP65

IP 65 is the equivalent to NEMA 4 and can withstand spraying water from entering.

Plastic Used: NYLON [See the Chemical Resistance Guide](#)

High Mech. Strength	Listed For Direct Burial	Halogen Free	Low Fire Hazard	Accepts Standard Liquidtight Fittings	Self Extinguish	EMI/RFI Shielding	Oil Resistance	Acid Resistance