

Louvered Hanging Systems




- Take back valuable floor space – maximize parts storage and handling efficiency.
- Louvered Panels used with AkroBins® offer the ultimate in storage flexibility.*
- Secure stationary racks to the wall or floor and wall-mountable panels to a solid structure.
- Six different models are available to accommodate up to 288 AkroBins.
- Easy, one-person assembly.

*AkroBins sold separately, see page 4.

Formed from 16-gauge cold-rolled steel for strength and durability

Attractive durable powder coated finish stands up to heavy-duty use

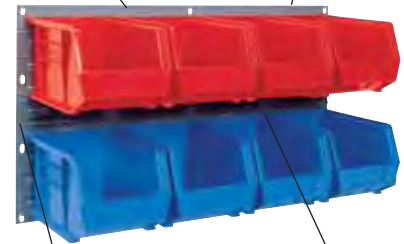

Horizontal ribs provide added strength

Louvers securely support AkroBins

30653 Louvered Floor Rack shown with 30239 AkroBins.



Develop a customized storage system by grouping any of our Louvered Panels.



30626
Double-Sided Snap Fastener Louvered Floor Rack
(Snap fasteners greatly reduce rack assembly time.)
36" L x 20" W x 60" H
914 x 508 x 1524 mm.
700 lb. capacity.



30653
Louvered Floor Rack
35³/₄" L x 32" W x 75¹/₈" H
908 x 813 x 1908 mm.
2000 lb. capacity.



30618
Louvered Panel
18" L x 19" H
457 x 483 mm.
160 lb. capacity.



30636
Louvered Panel
35³/₄" L x 19" H
908 x 483 mm.
160 lb. capacity.



98636
Bench Rack
36" L x 8" W x 21" H
914 x 203 x 533 mm.
120 lb. capacity.



98600
Bench Rack
27³/₄" L x 8" W x 21" H
705 x 203 x 533 mm.
120 lb. capacity.

Ordering Information:

Louvered Panels And Bench Racks

Use this chart to determine the quantity of same-size AkroBins required to fill each panel. AkroBins sold separately.

Model No.	Description	Ctn. Qty.	AkroBins Model No. (Bin Wt. Capacity)									
			30210 (10 lbs.)	30220 (10 lbs.)	30224 (30 lbs.)	30230 (30 lbs.)	30234 (50 lbs.)	30235 (50 lbs.)	30239 (50 lbs.)	30240 (60 lbs.)	30250 (75 lbs.)	30255 (60 lbs.)
30618	18" x 19" Louvered Panel	4	16	16	12	9	9	-	-	-	-	3
30636	35 ³ / ₄ " x 19" Louvered Panel	4	32	32	24	18	18	9	8	8	4	6
	35 ³ / ₄ " x 37" (2 Panels)		72	72	36	36	36	18	16	16	8	12
	35 ³ / ₄ " x 55" (3 Panels)		104	104	54	54	54	27	28	28	14	18
	35 ³ / ₄ " x 73" (4 Panels)		144	144	72	72	72	36	36	36	18	24
98600	27 ³ / ₄ " Bench Rack	1	30	30	18	12	12	6	6	6	-	-
98636	36" Bench Rack	1	40	40	24	18	18	9	8	8	4	6

Coming Soon!
Single-Sided Louvered Rack

Louvered Floor Racks

Use this chart to determine the quantity of same-size AkroBins required to fill each floor rack.

Model No.	Description	Dimensions			AkroBins Model Number (Bin Wt. Capacity)												
		Inches			mm			30210 (10 lbs.)	30220 (10 lbs.)	30230 (30 lbs.)	30234 (30 lbs.)	30235 (50 lbs.)	30239 (50 lbs.)	30240 (60 lbs.)	30250 (75 lbs.)	30255 (60 lbs.)	
30626	Double-Sided Snap Fastener Louvered Rack	36	20	60	914	508	1524	192	192	144	108	108	54	48	48	24	36
30653	Louvered Floor Rack	35 ³ / ₄	32	75 ¹ / ₈	908	813	1908	288	288	192	144	144	72	72	72	36	48