

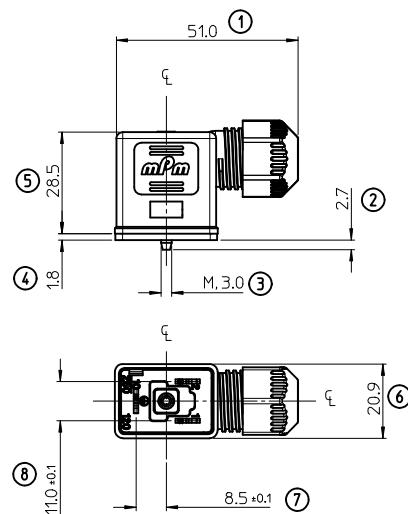


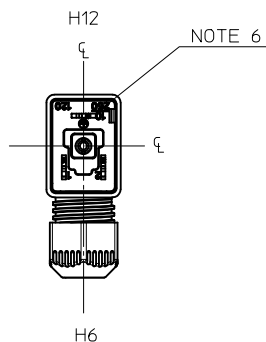

NOTES:

1. FOR SPECIFIC PART NUMBERS PLEASE CONTACT SALES OR CONSULT THE INTELLIGENT PART NUMBERS IN THE TABLE ATTACHED
2. PACKAGING SPECIFICATION: PLEASE SEE PK-121201-001
3. PRODUCT SPECIFICATION: PLEASE SEE PS-121201-001
4. CABLE SIZES 4 - 9 MM DIAMETER
5. TIGHTENING TORQUES: SEE PS-121201-001
6. GROUND POSITION SHOWN H12

LAST INSPECTION NUMBER 8

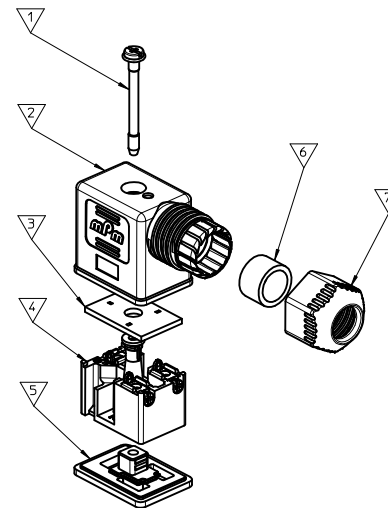

ITEM	DESCRIPTION
1	31mm M3 SCREW WITH GASKET
2	TYPE B COVER
3	PCB
4	TYPE B IND INSERT
5	TYPE B GASKET
6	GROMMET
7	EXTERNAL NUT

S22200NC410R**

SERIES _____
 S22= EXTERNAL THREAD FORM B INDUSTRIAL
 POLES _____
 2= 2 POLE
 THREAD _____
 00 = EXTERNAL THREAD
 MATERIAL AND HOUSING COLOR _____
 G= PA6 GRAY, N= PA6 BLACK, W= PA6 BLACK V0,
 B= WHITE, T= TRANSPARENT
 CIRCUIT _____
 SEE DETAILS IN CATALOGUE
 VOLTAGE _____
 SEE DETAILS IN CATALOGUE
 GROUND POSITION _____
 0= UNMOUNTED, 2= H12, 3=H3, 6 =H6 & 9= H9
 SCREW AND GASKET _____
 R= INTEGRATED NBR GASKET AND IP67 SCREW
 S= INTEGRATED SILICON GASKET AND IP67 SCREW
 NON STANDARD PACKAGING _____
 CN= BULK PACK UN-MOUNTED
 SN= BULK PACK MOUNTED
 67= NEUTRAL PACKAGING

ADDED OPTIONS		QUALITY SYMBOLS		GENERAL TOLERANCES (UNLESS SPECIFIED)		DIMENSION STYLE		SCALE		DESIGN UNITS		THIRD ANGLE PROJECTION	
EC NO: WEU2011-0371		DRAWN:JCARTON		2011/01/25		MM ONLY		1:1		METRIC		THIRD ANGLE PROJECTION	
CHKD: CHIKO		APPR:LEOLAN		2011/02/11		DRAWN BY		DATE		TITLE		EXTERNAL THREAD S22	
						DMAHER_WEU		2010/03/15				SERIES 121208	
						CHECKED BY		DATE					
						APPROVED BY		DATE		MOLEX INCORPORATED			
						JWALLACE		2010/03/24					
						MATERIAL NO.		DOCUMENT NO.		SD-121208-001		SHEET NO.	
						SIZE		A2		THIS DRAWING CONTAINS INFORMATION THAT IS PROPRIETARY TO MOLEX INCORPORATED AND SHOULD NOT BE USED WITHOUT WRITTEN PERMISSION		1 OF 6	

13	12	11	10	9	8	7	6	5	4	3	2	1
----	----	----	----	---	---	---	---	---	---	---	---	---

Part No	MPM Part No	DESCRIPTION	CIRCUIT	VOLTAGE	INDICATOR
1212080034	S22200TA010R	TYPE B IND TRANSPARENT	A0	12v	LAMP/NEON
1212080035	S22200TA020R	TYPE B IND TRANSPARENT	A0	24v	LAMP/NEON
1212080036	S22200TA030R	TYPE B IND TRANSPARENT	A0	48v	LAMP/NEON
1212080037	S22200TA040R	TYPE B IND TRANSPARENT	A0	115v	LAMP/NEON
1212080038	S22200TA050R	TYPE B IND TRANSPARENT	A0	230v	LAMP/NEON

Part No	MPM Part No	DESCRIPTION	CIRCUIT	VOLTAGE	INDICATOR
1212080039	S22200TA110R	TYPE B IND TRANSPARENT	A1	12v	RED LED
1212080040	S22200TA120R	TYPE B IND TRANSPARENT	A1	24v	RED LED
1212080041	S22200TA130R	TYPE B IND TRANSPARENT	A1	48v	RED LED
1212080042	S22200TA140R	TYPE B IND TRANSPARENT	A1	115v	RED LED
1212080043	S22200TA150R	TYPE B IND TRANSPARENT	A1	230v	RED LED
1212080044	S22200TA1A0R	TYPE B IND TRANSPARENT	A1	12v	GREEN LED
1212080045	S22200TA1B0R	TYPE B IND TRANSPARENT	A1	24v	GREEN LED
1212080046	S22200TA1C0R	TYPE B IND TRANSPARENT	A1	48v	GREEN LED
1212080047	S22200TA1D0R	TYPE B IND TRANSPARENT	A1	115v	GREEN LED
1212080048	S22200TA1E0R	TYPE B IND TRANSPARENT	A1	230v	GREEN LED
1212080049	S22200TA1G0R	TYPE B IND TRANSPARENT	A1	12v	AMBER LED
1212080050	S22200TA1H0R	TYPE B IND TRANSPARENT	A1	24v	AMBER LED
1212080051	S22200TA1K0R	TYPE B IND TRANSPARENT	A1	48v	AMBER LED
1212080052	S22200TA1L0R	TYPE B IND TRANSPARENT	A1	115v	AMBER LED
1212080053	S22200TA1M0R	TYPE B IND TRANSPARENT	A1	230v	AMBER LED

Part No	MPM Part No	DESCRIPTION	CIRCUIT	VOLTAGE	INDICATOR
1212080054	S22200TC310R	TYPE B IND TRANSPARENT	C3	12v	RED LED
1212080055	S22200TC320R	TYPE B IND TRANSPARENT	C3	24v	RED LED
1212080056	S22200TC330R	TYPE B IND TRANSPARENT	C3	48v	RED LED
1212080057	S22200TC340R	TYPE B IND TRANSPARENT	C3	115v	RED LED
1212080058	S22200TC350R	TYPE B IND TRANSPARENT	C3	230v	RED LED
1212080059	S22200TC3A0R	TYPE B IND TRANSPARENT	C3	12v	GREEN LED
1212080060	S22200TC3B0R	TYPE B IND TRANSPARENT	C3	24v	GREEN LED
1212080061	S22200TC3C0R	TYPE B IND TRANSPARENT	C3	48v	GREEN LED
1212080062	S22200TC3D0R	TYPE B IND TRANSPARENT	C3	115v	GREEN LED
1212080063	S22200TC3E0R	TYPE B IND TRANSPARENT	C3	230v	GREEN LED
1212080064	S22200TC3G0R	TYPE B IND TRANSPARENT	C3	12v	AMBER LED
1212080065	S22200TC3H0R	TYPE B IND TRANSPARENT	C3	24v	AMBER LED
1212080066	S22200TC3K0R	TYPE B IND TRANSPARENT	C3	48v	AMBER LED
1212080067	S22200TC3L0R	TYPE B IND TRANSPARENT	C3	115v	AMBER LED
1212080068	S22200TC3M0R	TYPE B IND TRANSPARENT	C3	230v	AMBER LED

Part No	MPM Part No	DESCRIPTION	CIRCUIT	VOLTAGE	INDICATOR
1212080069	S22200TC410R	TYPE B IND TRANSPARENT	C4	12v	RED LED
1212080070	S22200TC420R	TYPE B IND TRANSPARENT	C4	24v	RED LED
1212080071	S22200TC430R	TYPE B IND TRANSPARENT	C4	48v	RED LED
1212080072	S22200TC440R	TYPE B IND TRANSPARENT	C4	115v	RED LED
1212080073	S22200TC450R	TYPE B IND TRANSPARENT	C4	230v	RED LED
1212080074	S22200TC4A0R	TYPE B IND TRANSPARENT	C4	12v	GREEN LED
1212080075	S22200TC4B0R	TYPE B IND TRANSPARENT	C4	24v	GREEN LED
1212080076	S22200TC4C0R	TYPE B IND TRANSPARENT	C4	48v	GREEN LED
1212080077	S22200TC4D0R	TYPE B IND TRANSPARENT	C4	115v	GREEN LED
1212080078	S22200TC4E0R	TYPE B IND TRANSPARENT	C4	230v	GREEN LED
1212080079	S22200TC4G0R	TYPE B IND TRANSPARENT	C4	12v	AMBER LED
1212080080	S22200TC4H0R	TYPE B IND TRANSPARENT	C4	24v	AMBER LED
1212080081	S22200TC4K0R	TYPE B IND TRANSPARENT	C4	48v	AMBER LED
1212080082	S22200TC4L0R	TYPE B IND TRANSPARENT	C4	115v	AMBER LED
1212080083	S22200TC4M0R	TYPE B IND TRANSPARENT	C4	230v	AMBER LED

Part No	MPM Part No	DESCRIPTION	CIRCUIT	VOLTAGE	INDICATOR
1212080084	S22200TD010R	TYPE B IND TRANSPARENT	D0	12v	VDR
1212080085	S22200TD020R	TYPE B IND TRANSPARENT	D0	24v	VDR
1212080086	S22200TD030R	TYPE B IND TRANSPARENT	D0	48v	VDR
1212080087	S22200TD040R	TYPE B IND TRANSPARENT	D0	115v	VDR
1212080088	S22200TD050R	TYPE B IND TRANSPARENT	D0	230v	VDR

Part No	MPM Part No	DESCRIPTION	CIRCUIT	VOLTAGE	INDICATOR
1212080093	S22200NE050R	TYPE B IND BLACK	E0	230v	DIODE

Part No	MPM Part No	DESCRIPTION - BULK PACKED
1212080001	S22200BC432RSN	48V RED LED NBR GASKET
1212080033	S22200TC422RSN	24V RED LED NBR GASKET

SEE SHEET 1 EC NO: WEU2011-0371 DRAWN:JCARTON 2011/01/25 CHKD: APPR:EFOLAN 2011/02/11	DESCRIPTION REV	QUALITY SYMBOLS ▽=0 ▽=0	GENERAL TOLERANCES (UNLESS SPECIFIED)		DIMENSION STYLE MM ONLY		SCALE 1:1	DESIGN UNITS METRIC	THIRD ANGLE PROJECTION			
				mm	INCH	DRAWN BY DMAHER_WEU	DATE 2010/03/15	TITLE EXTERNAL THREAD S22 SERIES 121208				
			4 PLACES	± ---	± ---	CHECKED BY	DATE	APPROVED BY JWALLACE 2010/03/24	DATE 2010/03/24	MOLEX MOLEX INCORPORATED	DOCUMENT NO. SD-121208-001	SHEET NO. 2 OF 6
			3 PLACES	± ---	± ---							
			2 PLACES	± 0.1	± ---							
			1 PLACE	± 0.2	± ---							
			ANGULAR ± ---°		DRAFT WHERE APPLICABLE MUST REMAIN WITHIN DIMENSIONS		SEE TABLES		THIS DRAWING CONTAINS INFORMATION THAT IS PROPRIETARY TO MOLEX INCORPORATED AND SHOULD NOT BE USED WITHOUT WRITTEN PERMISSION			
							SIZE A2					

1b_frame_A2_P_AM_T Rev. E 2006/04/15	12	11	10	9	8	7	6	5	4	3	2	1
---	----	----	----	---	---	---	---	---	---	---	---	---

Part No	MPM Part No	DESCRIPTION	CIRCUIT	VOLTAGE	INDICATOR
1212080094	S22200TS010R	TYPE B IND TRANSPARENT	S0	12v	RED LED
1212080095	S22200TS020R	TYPE B IND TRANSPARENT	S0	24v	RED LED
1212080096	S22200TS030R	TYPE B IND TRANSPARENT	S0	48v	RED LED
1212080097	S22200TS040R	TYPE B IND TRANSPARENT	S0	115v	RED LED
1212080098	S22200TS050R	TYPE B IND TRANSPARENT	S0	230v	RED LED
1212080099	S22200TS0A0R	TYPE B IND TRANSPARENT	S0	12v	GREEN LED
1212080100	S22200TS0B0R	TYPE B IND TRANSPARENT	S0	24v	GREEN LED
1212080101	S22200TS0C0R	TYPE B IND TRANSPARENT	S0	48v	GREEN LED
1212080102	S22200TS0D0R	TYPE B IND TRANSPARENT	S0	115v	GREEN LED
1212080103	S22200TS0E0R	TYPE B IND TRANSPARENT	S0	230v	GREEN LED
1212080104	S22200TS0G0R	TYPE B IND TRANSPARENT	S0	12v	AMBER LED
1212080105	S22200TS0H0R	TYPE B IND TRANSPARENT	S0	24v	AMBER LED
1212080106	S22200TS0K0R	TYPE B IND TRANSPARENT	S0	48v	AMBER LED
1212080107	S22200TS0L0R	TYPE B IND TRANSPARENT	S0	115v	AMBER LED
1212080108	S22200TS0M0R	TYPE B IND TRANSPARENT	S0	230v	AMBER LED

Part No	MPM Part No	DESCRIPTION	CIRCUIT	VOLTAGE	INDICATOR
1212080109	S22200NS110R	TYPE B IND BLACK	S1	12v	NO LED
1212080110	S22200NS120R	TYPE B IND BLACK	S1	24v	NO LED
1212080111	S22200NS130R	TYPE B IND BLACK	S1	48v	NO LED
1212080112	S22200NS140R	TYPE B IND BLACK	S1	115v	NO LED
1212080113	S22200NS150R	TYPE B IND BLACK	S1	230v	NO LED

Part No	MPM Part No	DESCRIPTION	CIRCUIT	VOLTAGE	INDICATOR
1212080114	S22200TA010RCN	TYPE B IND TRANSPARENT	A0	12v	LAMP/NEON
1212080115	S22200TA020RCN	TYPE B IND TRANSPARENT	A0	24v	LAMP/NEON
1212080116	S22200TA030RCN	TYPE B IND TRANSPARENT	A0	48v	LAMP/NEON
1212080117	S22200TA040RCN	TYPE B IND TRANSPARENT	A0	115v	LAMP/NEON
1212080118	S22200TA050RCN	TYPE B IND TRANSPARENT	A0	230v	LAMP/NEON

Part No	MPM Part No	DESCRIPTION	CIRCUIT	VOLTAGE	INDICATOR
1212080119	S22200TA110RCN	TYPE B IND TRANSPARENT	A1	12v	RED LED
1212080120	S22200TA120RCN	TYPE B IND TRANSPARENT	A1	24v	RED LED
1212080121	S22200TA130RCN	TYPE B IND TRANSPARENT	A1	48v	RED LED
1212080122	S22200TA140RCN	TYPE B IND TRANSPARENT	A1	115v	RED LED
1212080123	S22200TA150RCN	TYPE B IND TRANSPARENT	A1	230v	RED LED
1212080124	S22200TA1A0RCN	TYPE B IND TRANSPARENT	A1	12v	GREEN LED
1212080125	S22200TA1B0RCN	TYPE B IND TRANSPARENT	A1	24v	GREEN LED
1212080126	S22200TA1C0RCN	TYPE B IND TRANSPARENT	A1	48v	GREEN LED
1212080127	S22200TA1D0RCN	TYPE B IND TRANSPARENT	A1	115v	GREEN LED
1212080128	S22200TA1E0RCN	TYPE B IND TRANSPARENT	A1	230v	GREEN LED
1212080129	S22200TA1G0RCN	TYPE B IND TRANSPARENT	A1	12v	AMBER LED
1212080130	S22200TA1H0RCN	TYPE B IND TRANSPARENT	A1	24v	AMBER LED
1212080131	S22200TA1K0RCN	TYPE B IND TRANSPARENT	A1	48v	AMBER LED
1212080132	S22200TA1L0RCN	TYPE B IND TRANSPARENT	A1	115v	AMBER LED
1212080133	S22200TA1M0RCN	TYPE B IND TRANSPARENT	A1	230v	AMBER LED

Part No	MPM Part No	DESCRIPTION	CIRCUIT	VOLTAGE	INDICATOR
1212080134	S22200TC310RCN	TYPE B IND TRANSPARENT	C3	12v	RED LED
1212080135	S22200TC320RCN	TYPE B IND TRANSPARENT	C3	24v	RED LED
1212080136	S22200TC330RCN	TYPE B IND TRANSPARENT	C3	48v	RED LED
1212080137	S22200TC340RCN	TYPE B IND TRANSPARENT	C3	115v	RED LED
1212080138	S22200TC350RCN	TYPE B IND TRANSPARENT	C3	230v	RED LED
1212080139	S22200TC3A0RCN	TYPE B IND TRANSPARENT	C3	12v	GREEN LED
1212080140	S22200TC3B0RCN	TYPE B IND TRANSPARENT	C3	24v	GREEN LED
1212080141	S22200TC3C0RCN	TYPE B IND TRANSPARENT	C3	48v	GREEN LED
1212080142	S22200TC3D0RCN	TYPE B IND TRANSPARENT	C3	115v	GREEN LED
1212080143	S22200TC3E0RCN	TYPE B IND TRANSPARENT	C3	230v	GREEN LED
1212080144	S22200TC3G0RCN	TYPE B IND TRANSPARENT	C3	12v	AMBER LED
1212080145	S22200TC3H0RCN	TYPE B IND TRANSPARENT	C3	24v	AMBER LED
1212080146	S22200TC3K0RCN	TYPE B IND TRANSPARENT	C3	48v	AMBER LED
1212080147	S22200TC3L0RCN	TYPE B IND TRANSPARENT	C3	115v	AMBER LED
1212080148	S22200TC3M0RCN	TYPE B IND TRANSPARENT	C3	230v	AMBER LED

SEE SHEET 1

EC NO: WEU2011-0371

DRWN:JCARTON

CHKD:

APPR:LEOLAN

2011/01/25

2011/02/11

DESCRIPTION

REV

QUALITY SYMBOLS

▽=0

▽=0

GENERAL TOLERANCES (UNLESS SPECIFIED)

	mm	INCH
4 PLACES	± ---	± ---
3 PLACES	± ---	± ---
2 PLACES	± 0.1	± ---
1 PLACE	± 0.2	± ---
ANGULAR ± ---°		

DRAFT WHERE APPLICABLE
MUST REMAIN
WITHIN DIMENSIONS

DIMENSION STYLE

MM ONLY

DRAWN BY	DATE
DMAHER_WEU	2010/03/15
CHECKED BY	DATE
APPROVED BY	DATE
JWALLACE	2010/03/24
MATERIAL NO.	

SIZE

A2

SCALE

1:1

DESIGN UNITS

METRIC

THIRD ANGLE PROJECTION

TITLE

EXTERNAL THREAD S22
SERIES 121208

MOLEX INCORPORATED

DOCUMENT NO.

SD-121208-001

SHEET NO.

3 OF 6

THIS DRAWING CONTAINS INFORMATION THAT IS PROPRIETARY TO MOLEX
INCORPORATED AND SHOULD NOT BE USED WITHOUT WRITTEN PERMISSION

Part No	MPM Part No	DESCRIPTION	CIRCUIT	VOLTAGE	INDICATOR
1212080149	S22200TC410RCN	TYPE B IND TRANSPARENT	C4	12v	RED LED
1212080150	S22200TC420RCN	TYPE B IND TRANSPARENT	C4	24v	RED LED
1212080151	S22200TC430RCN	TYPE B IND TRANSPARENT	C4	48v	RED LED
1212080152	S22200TC440RCN	TYPE B IND TRANSPARENT	C4	115v	RED LED
1212080153	S22200TC450RCN	TYPE B IND TRANSPARENT	C4	230v	RED LED
1212080154	S22200TC4A0RCN	TYPE B IND TRANSPARENT	C4	12v	GREEN LED
1212080155	S22200TC4B0RCN	TYPE B IND TRANSPARENT	C4	24v	GREEN LED
1212080156	S22200TC4C0RCN	TYPE B IND TRANSPARENT	C4	48v	GREEN LED
1212080157	S22200TC4D0RCN	TYPE B IND TRANSPARENT	C4	115v	GREEN LED
1212080158	S22200TC4E0RCN	TYPE B IND TRANSPARENT	C4	230v	GREEN LED
1212080159	S22200TC4G0RCN	TYPE B IND TRANSPARENT	C4	12v	AMBER LED
1212080160	S22200TC4H0RCN	TYPE B IND TRANSPARENT	C4	24v	AMBER LED
1212080161	S22200TC4K0RCN	TYPE B IND TRANSPARENT	C4	48v	AMBER LED
1212080162	S22200TC4L0RCN	TYPE B IND TRANSPARENT	C4	115v	AMBER LED
1212080163	S22200TC4M0RCN	TYPE B IND TRANSPARENT	C4	230v	AMBER LED

Part No	MPM Part No	DESCRIPTION	CIRCUIT	VOLTAGE	INDICATOR
1212080164	S22200TD010RCN	TYPE B IND TRANSPARENT	D0	12v	VDR
1212080165	S22200TD020RCN	TYPE B IND TRANSPARENT	D0	24v	VDR
1212080166	S22200TD030RCN	TYPE B IND TRANSPARENT	D0	48v	VDR
1212080167	S22200TD040RCN	TYPE B IND TRANSPARENT	D0	115v	VDR
1212080168	S22200TD050RCN	TYPE B IND TRANSPARENT	D0	230v	VDR

Part No	MPM Part No	DESCRIPTION	CIRCUIT	VOLTAGE	INDICATOR
1212080173	S22200NE050RCN	TYPE B IND BLACK	EO	230v	DIODE

Part No	MPM Part No	DESCRIPTION	CIRCUIT	VOLTAGE	INDICATOR
1212080174	S22200TS010RCN	TYPE B IND TRANSPARENT	S0	12v	RED LED
1212080175	S22200TS020RCN	TYPE B IND TRANSPARENT	S0	24v	RED LED
1212080176	S22200TS030RCN	TYPE B IND TRANSPARENT	S0	48v	RED LED
1212080177	S22200TS040RCN	TYPE B IND TRANSPARENT	S0	115v	RED LED
1212080178	S22200TS050RCN	TYPE B IND TRANSPARENT	S0	230v	RED LED
1212080179	S22200TS0A0RCN	TYPE B IND TRANSPARENT	S0	12v	GREEN LED
1212080180	S22200TS0B0RCN	TYPE B IND TRANSPARENT	S0	24v	GREEN LED
1212080181	S22200TS0C0RCN	TYPE B IND TRANSPARENT	S0	48v	GREEN LED
1212080182	S22200TS0D0RCN	TYPE B IND TRANSPARENT	S0	115v	GREEN LED
1212080183	S22200TS0E0RCN	TYPE B IND TRANSPARENT	S0	230v	GREEN LED
1212080184	S22200TS0G0RCN	TYPE B IND TRANSPARENT	S0	12v	AMBER LED
1212080185	S22200TS0H0RCN	TYPE B IND TRANSPARENT	S0	24v	AMBER LED
1212080186	S22200TS0K0RCN	TYPE B IND TRANSPARENT	S0	48v	AMBER LED
1212080187	S22200TS0L0RCN	TYPE B IND TRANSPARENT	S0	115v	AMBER LED
1212080188	S22200TS0M0RCN	TYPE B IND TRANSPARENT	S0	230v	AMBER LED

Part No	MPM Part No	DESCRIPTION	CIRCUIT	VOLTAGE	INDICATOR
1212080189	S22200NS110RCN	TYPE B IND BLACK	S1	12v	NO LED
1212080190	S22200NS120RCN	TYPE B IND BLACK	S1	24v	NO LED
1212080191	S22200NS130RCN	TYPE B IND BLACK	S1	48v	NO LED
1212080192	S22200NS140RCN	TYPE B IND BLACK	S1	115v	NO LED
1212080193	S22200NS150RCN	TYPE B IND BLACK	S1	230v	NO LED

Part No	MPM Part No	DESCRIPTION	CIRCUIT	VOLTAGE	INDICATOR
1212080194	S22200TA012RSN	TYPE B IND TRANSPARENT	A0	12v	LAMP/NEON
1212080195	S22200TA022RSN	TYPE B IND TRANSPARENT	A0	24v	LAMP/NEON
1212080196	S22200TA032RSN	TYPE B IND TRANSPARENT	A0	48v	LAMP/NEON
1212080197	S22200TA042RSN	TYPE B IND TRANSPARENT	A0	115v	LAMP/NEON
1212080198	S22200TA052RSN	TYPE B IND TRANSPARENT	A0	230v	LAMP/NEON

SEE SHEET 1 EC NO: WEU2011-0371 DRAWN: CARTON 2011/01/25 CHKD: APPR: EFOLAN 2011/02/11	DESCRIPTION REV	QUALITY SYMBOLS ▽=0 ▽=0	GENERAL TOLERANCES (UNLESS SPECIFIED) mm INCH 4 PLACES ± --- ± --- 3 PLACES ± --- ± --- 2 PLACES ± 0.1 ± --- 1 PLACE ± 0.2 ± --- ANGULAR ± ---°	DIMENSION STYLE MM ONLY DRAWN BY DATE DMAHER_WEU 2010/03/15 CHECKED BY DATE APPROVED BY DATE JWALLACE 2010/03/24 MATERIAL NO.	SCALE 1:1 DESIGN UNITS METRIC FIRST ANGLE PROJECTION	TITLE EXTERNAL THREAD S22 SERIES 121208
		DRAFT WHERE APPLICABLE MUST REMAIN WITHIN DIMENSIONS			MOLEX INCORPORATED	
		SEE TABLES			DOCUMENT NO. SD-121208-001	SHEET NO. 4 OF 6
		THIS DRAWING CONTAINS INFORMATION THAT IS PROPRIETARY TO MOLEX INCORPORATED AND SHOULD NOT BE USED WITHOUT WRITTEN PERMISSION				

Part No	MPM Part No	DESCRIPTION	CIRCUIT	VOLTAGE	INDICATOR
1212080254	S22200TS012RSN	TYPE B IND TRANSPARENT	S0	12v	RED LED
1212080255	S22200TS022RSN	TYPE B IND TRANSPARENT	S0	24v	RED LED
1212080256	S22200TS032RSN	TYPE B IND TRANSPARENT	S0	48v	RED LED
1212080257	S22200TS042RSN	TYPE B IND TRANSPARENT	S0	115v	RED LED
1212080258	S22200TS052RSN	TYPE B IND TRANSPARENT	S0	230v	RED LED
1212080259	S22200TS0A2RSN	TYPE B IND TRANSPARENT	S0	12v	GREEN LED
1212080260	S22200TS0B2RSN	TYPE B IND TRANSPARENT	S0	24v	GREEN LED
1212080261	S22200TS0C2RSN	TYPE B IND TRANSPARENT	S0	48v	GREEN LED
1212080262	S22200TS0D2RSN	TYPE B IND TRANSPARENT	S0	115v	GREEN LED
1212080263	S22200TS0E2RSN	TYPE B IND TRANSPARENT	S0	230v	GREEN LED
1212080264	S22200TS0G2RSN	TYPE B IND TRANSPARENT	S0	12v	AMBER LED
1212080265	S22200TS0H2RSN	TYPE B IND TRANSPARENT	S0	24v	AMBER LED
1212080266	S22200TS0K2RSN	TYPE B IND TRANSPARENT	S0	48v	AMBER LED
1212080267	S22200TS0L2RSN	TYPE B IND TRANSPARENT	S0	115v	AMBER LED
1212080268	S22200TS0M2RSN	TYPE B IND TRANSPARENT	S0	230v	AMBER LED

Part No	MPM Part No	DESCRIPTION	CIRCUIT	VOLTAGE	INDICATOR
1212080269	S22200NS112RSN	TYPE B IND BLACK	S1	12v	NO LED
1212080270	S22200NS122RSN	TYPE B IND BLACK	S1	24v	NO LED
1212080271	S22200NS132RSN	TYPE B IND BLACK	S1	48v	NO LED
1212080272	S22200NS142RSN	TYPE B IND BLACK	S1	115v	NO LED
1212080273	S22200NS152RSN	TYPE B IND BLACK	S1	230v	NO LED

SEE SHEET 1

EC NO: WEU2011-0371

DRWNG: CARTON

CHKD: CHIKO

APPR: EFOLAN

2011/01/25

2011/02/11

DESCRIPTION

REV

QUALITY SYMBOLS

=0

=0

GENERAL TOLERANCES (UNLESS SPECIFIED)

	mm	INCH
4 PLACES	± ---	± ---
3 PLACES	± ---	± ---
2 PLACES	± 0.1	± ---
1 PLACE	± 0.2	± ---
ANGULAR ± ---°		

DRAFT WHERE APPLICABLE
MUST REMAIN
WITHIN DIMENSIONS

DIMENSION STYLE

MM ONLY

DRAWN BY

DATE

CHECKED BY

DATE

APPROVED BY

DATE

MATERIAL NO.

SCALE

1:1

DESIGN UNITS

METRIC

 FIRST ANGLE PROJECTION

TITLE

EXTERNAL THREAD S22
SERIES 121208

 MOLEX INCORPORATED

DOCUMENT NO.

SD-121208-001

SHEET NO.

6 OF 6

SIZE

A2

THIS DRAWING CONTAINS INFORMATION THAT IS PROPRIETARY TO MOLEX
INCORPORATED AND SHOULD NOT BE USED WITHOUT WRITTEN PERMISSION