


Luminaire Pushwire Connectors 2 & 3 pole

Specification:-

Housing Polyamide 66
 Metal Part Plated Brass / Steel spring
 Voltage(V) 450
 Ampere(A) 10 (for operation)

Wiring Capacity (mm ²)	Wiring Holes (a) + (b)	Wiring Hole (c)
Installation / User- side(with press- release button)	0.5-2.5	0.5-0.75
Factory / Internal - side	0.5-1.5	0.5-0.75
(without press- release button)	solid only	solid only

- Comply with IEC/EN60998-2-2
- Pushwire "Quick-Connection"
- Easy mounting (with 'fixing - snaps')
- Ready for use with 'Cable - Clamps' (our P02-SR2) for 'strain - relief'
- Printing on Press-release Button: upon user's requirement

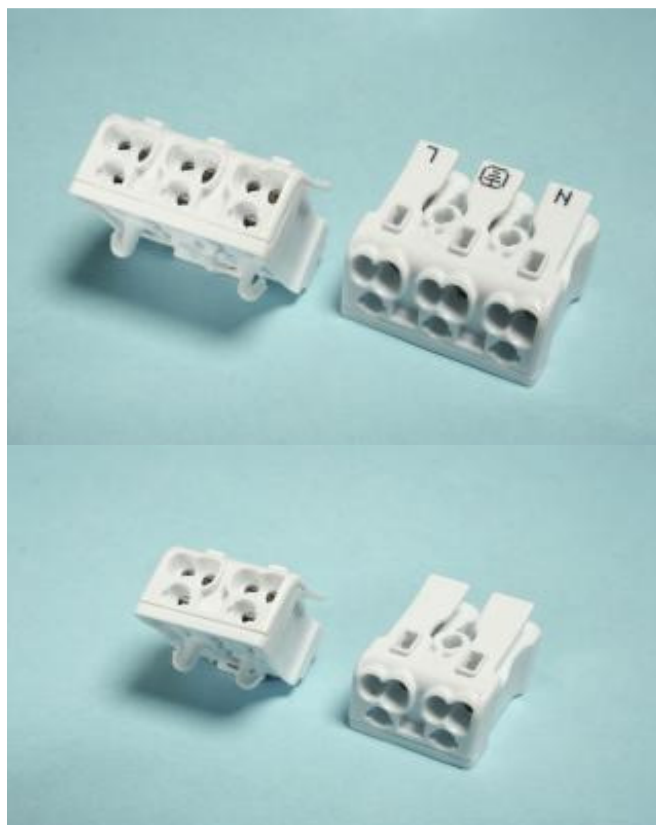


Tel :-

01933 234400

Fax :-

01933 234411

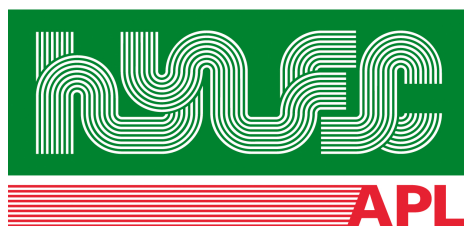

Web :- www.hylec-apl.com

Email :- sales@hylec-apl.com

Making The Right Connections