


MBT Coated Range

- 3 strap widths available
- Polyester coated
- High tensile strength
- Manufactured from Marine Grade 316 Stainless Steel
- Tough and corrosion resistant

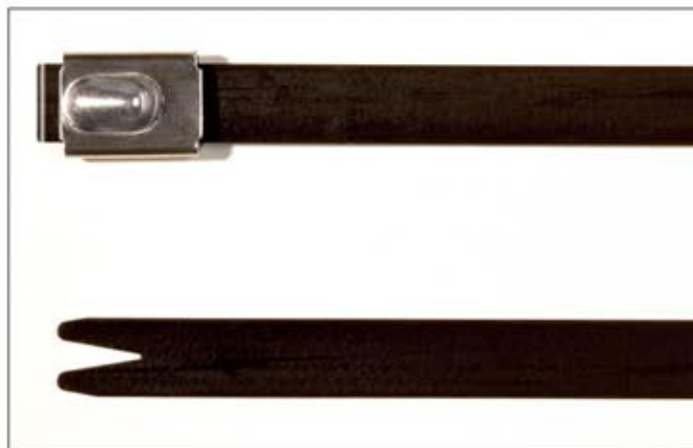

MBT Fully Coated Stainless Steel Ties - 316 Marine Grade Stainless Steel

Reference	Overall Length		Strap Width		Minimum Tensile Strength		Maximum Cable Diameter		Pack Qty
	mm	in	mm	in	lbs	N			
MBT5SFC	127	5.0	4.6	0.18	105	467	25	1.0	100
MBT8SFC	201	7.9	4.6	0.18	105	467	50	2.0	100
MBT12SFC	300	12	4.6	0.18	105	467	76	3.0	100
MBT14SFC	362	14.3	4.6	0.18	105	467	76	3.0	100
MBT20SFC	521	20.5	4.6	0.18	105	467	152	6.0	100
MBT27SFC	681	26.8	4.6	0.18	105	467	203	8.0	100
MBT33SFC	838	33.0	4.6	0.18	105	467	254	10.0	100
MBT8HFC	201	7.9	7.9	0.31	175	779	50	2.0	50
MBT12HFC	300	12	7.9	0.31	175	779	76	3.0	50
MBT14HFC	362	14.3	7.9	0.31	175	779	102	4.0	50
MBT20HFC	521	20.5	7.9	0.31	175	779	152	6.0	50
MBT27HFC	681	26.8	7.9	0.31	175	779	203	8.0	50
MBT33HFC	838	33.0	7.9	0.31	175	779	254	10.0	50
MBT14XHFC	362	14.3	12.3	0.48	350	1558	102	4.0	50
MBT20XHFC	521	20.5	12.3	0.48	350	1558	152	6.0	50
MBT27XHFC	681	26.8	12.3	0.48	350	1558	203	8.0	50
MBT33XHFC	838	33.0	12.3	0.48	350	1558	254	10.0	50

* see page 175 for suitable tensioning tool.

MBT Kit

- Includes MBT 304 Stainless Steel cable ties, THT Ratchet Installation
- Tool, and strong plastic carry case
- Kit contains popular sizes of cable ties
- Easy to use reversible ratchet tool
- Ideal for Mechanical & Electrical Contractors and many other applications.

Product	Quantity
MBT14SS	30
MBT14HS	30
MBT8HS 20	
MBT8SS	20
MBT5SS	20
THT	1

Reference 111-01422

