

Louvered Hanging Systems




30653 Louvered Floor Rack shown with 30239 AkroBins.

- Take back valuable floor space – maximize parts storage and handling efficiency.
- Louvered Panels used with AkroBins® offer the ultimate in storage flexibility.*
- Secure stationary racks to the wall or floor and wall-mountable panels to a solid structure.
- Six different models are available to accommodate up to 288 AkroBins.
- Easy, one-person assembly.

*AkroBins sold separately, see page 4.

Formed from 16-gauge cold-rolled steel for strength and durability

Attractive durable powder coated finish stands up to heavy-duty use

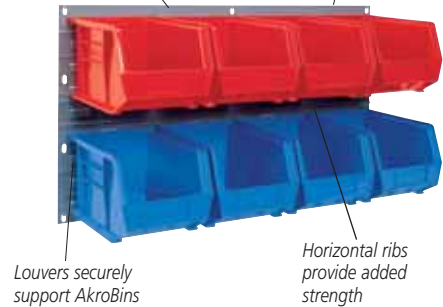

Louvers securely support AkroBins

Horizontal ribs provide added strength



Develop a customized storage system by grouping any of our Louvered Panels.



30626 Double-Sided Snap Fastener Louvered Floor Rack

(Snap fasteners greatly reduce rack assembly time.)

36" L x 20" W x 60" H
914 x 508 x 1524 mm.
700 lb. capacity.



30653 Louvered Floor Rack

35¾" L x 32" W x 75⅛" H
908 x 813 x 1908 mm.
2000 lb. capacity.



30618 Louvered Panel
18" L x 19" H
457 x 483 mm.
160 lb. capacity.



98636 Bench Rack
36" L x 8" W x 21" H
914 x 203 x 533 mm.
120 lb. capacity.



30636 Louvered Panel
35¾" L x 19" H
908 x 483 mm.
160 lb. capacity.



98600 Bench Rack
27¾" L x 8" W x 21" H
705 x 203 x 533 mm.
120 lb. capacity.

Ordering Information:

Louvered Panels And Bench Racks

Use this chart to determine the quantity of same-size AkroBins required to fill each panel.

Model No.	Description	Ctn. Qty.	AkroBins Model No. (Bin Wt. Capacity)									
			30210 (10 lbs.)	30220 (10 lbs.)	30224 (30 lbs.)	30230 (30 lbs.)	30234 (50 lbs.)	30235 (50 lbs.)	30239 (50 lbs.)	30240 (60 lbs.)	30250 (75 lbs.)	30255 (60 lbs.)
30618	18" x 19" Louvered Panel	4	16	16	12	9	9	-	-	-	-	3
30636	35¾" x 19" Louvered Panel	4	32	32	24	18	18	9	8	8	4	6
	35¾" x 37" (2 Panels)		72	72	36	36	36	18	16	16	8	12
	35¾" x 55" (3 Panels)		104	104	54	54	54	27	28	28	14	18
	35¾" x 73" (4 Panels)		144	144	72	72	72	36	36	36	18	24
98600	27¾" Bench Rack	1	30	30	18	12	12	6	6	6	-	-
98636	36" Bench Rack	1	40	40	24	18	18	9	8	8	4	6

Louvered Floor Racks

Use this chart to determine the quantity of same-size AkroBins required to fill each floor rack.

Model No.	Description	Dimensions						AkroBins Model Number (Bin Wt. Capacity)									
		Inches			mm			30210 (10 lbs.)	30220 (10 lbs.)	30224 (30 lbs.)	30230 (30 lbs.)	30234 (50 lbs.)	30235 (50 lbs.)	30239 (50 lbs.)	30240 (60 lbs.)	30250 (75 lbs.)	30255 (60lbs.)
30626	Double-Sided Snap Fastener Louvered Rack	36	20	60	914	508	1524	192	192	144	108	108	54	48	48	24	36
30653	Louvered Floor Rack	35¾	32	75⅛	908	813	1908	288	288	192	144	144	72	72	72	36	48


Rail Hanging Systems



- Rail systems offer an economical storage solution to get the most from your AkroBins.
- Single and double rail units provide more flexibility in bin placement and hold multiple sizes of AkroBins.*
- Mobile kit available to mobilize two-sided racks.
- Steel rail is ideal for work stations.

*AkroBins sold separately, see page 4.

Rails securely support AkroBins

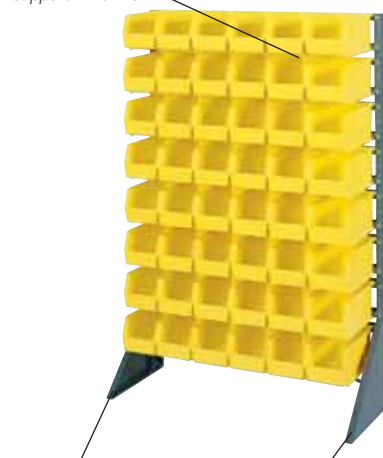

Heavy-duty steel for strength and durability

Attractive, durable powder coated finish stands up to heavy-duty use

Bench racks, wall-mount, and single- or double-sided models are available to create a complete storage system.



30006
1-Sided, 12 Rail
250 lb. capacity.



30008
1-Sided, 16 Rail
250 lb. capacity.



30012
2-Sided Rack, 12 Rail
500 lb. capacity.



30016
2-Sided Rack, 16 Rail
500 lb. capacity.



30812
Bin Cart w/ Casters
14-gauge steel work top. 250 lb. capacity.



30812 Bin Cart shown with 30230 AkroBins.

Ordering Information:

Rail Racks & Bin Cart

Use this chart to determine the quantity of same-size AkroBins required to fill each rack and cart.

Model No.	Description	Ctn. Qty.	Dimensions						AkroBins Model Number (Bin Wt. Capacity)									
			Inches			mm			30210 (10 lbs.)	30220 (10 lbs.)	30224 (30 lbs.)	30230 (30 lbs.)	30234 (50 lbs.)	30235 (50 lbs.)	30239 (50 lbs.)	30240 (60 lbs.)	30250 (75 lbs.)	30255 (60 lbs.)
30006	Rack, 1-Sided, 12 Rail	2	36	14 1/8	53	914	359	1346	96	96	-	-	-	-	24	24	12	-
30008	Rack, 1-Sided, 16 Rail	3	36	14 1/8	53	914	359	1346	-	-	48	48	48	24	-	-	-	16
30012	Rack, 2-Sided, 12 Rail	2	36	20	53	914	508	1346	192	192	-	-	-	-	48	48	24	-
30016	Rack, 2-Sided, 16 Rail	3	36	20	53	914	508	1346	-	-	96	96	96	48	-	-	-	32
30812	Bin Cart	2	38 1/2	24	36 1/2	978	610	927	96	96	64	48	48	24	24	24	12	16



Two-Sided Racks can be mobilized with the mobile kit.

Mobile Kit – Casters & Handle

Model No.	Ctn. Qty.	Fits Hanging System No.
30424	1	30012, 30016

Steel Rail

Use this chart to determine the quantity of same-size AkroBins required to fill the steel rail.

Model No.	Ctn. Qty.	Dimensions				AkroBins Model Number (Bin Wt. Capacity)					
		Inches		mm		30210 (10 lbs.)	30220 (10 lbs.)	30224 (30 lbs.)	30230 (30 lbs.)	30234 (50 lbs.)	30255 (60 lbs.)
30148	1	48	3	1219	76	11	11	11	8	6	3

30148
Steel Rail

Wall-mountable unit accepts 6 sizes of AkroBins. 110 lb. capacity.

