

QUINT-BAT/24DC/ 3.4AH

Order No.: 2866349




<http://eshop.phoenixcontact.co.uk/phoenix/treeViewClick.do?UID=2866349>

Rechargeable battery module, lead AGM, VRLA technology, 24 V DC, 3.4 Ah. Connection via male cable lug, 14 mm.



Please note that the data given here has been taken from the online catalog. For comprehensive information and data, please refer to the user documentation at <http://www.download.phoenixcontact.com>. The General Terms and Conditions of Use apply to Internet downloads.

Commercial data

EAN	 4 017918 959746
Pack	1
Customs tariff	85072098
Country of Origin	CN
Catalog page information	Page 590 (IF-2009)

Technical data

Input data

Nominal input voltage	24 V DC
-----------------------	---------

Output data

Nominal output voltage	24 V DC
Output current	max. 25 A
Connection in parallel	Yes, for increasing the buffer period
Connection in series	No
Output fuse	25 A

General data

Disposal	Used batteries must not be thrown away with household waste, they should instead be disposed of in accordance with applicable national regulations. They can also be returned to Phoenix Contact or the manufacturer.
Width	112 mm
Height	145 mm
Depth	123 mm
Net weight	3.5 kg
Memory medium	battery 3.4 Ah
Degree of protection	IP20
Protection class	III
Ambient temperature (operation)	0 °C ... 40 °C
Ambient temperature (storage/transport)	0 °C ... 40 °C
Shipbuilding approval	Germanischer Lloyd (EMC 2), ABS

Certificates




Certification GL

Accessories

Item	Designation	Description
Fuse		
0913757	SI FORM C 25 A DIN 72581	Flat-type plug-in fuse, type C, color code: white, nominal current: 25 A
General		
2866857	QUINT-ADAPTER/4	Assembly adapter for QUINT-BAT/24DC... on 35mm rail

Drawings

Block diagram

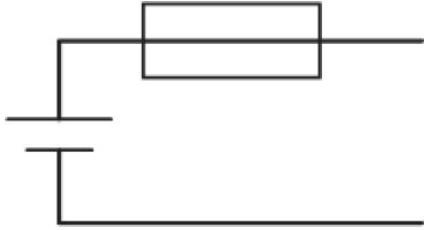

Address

PHOENIX CONTACT Ltd
Halesfield 13
Telford / Shropshire / TF7 4PG,England
Phone 01952 681 700
Fax 01952 681 799
<http://www.phoenixcontact.co.uk>



Phoenix Contact Ltd.
Technical modifications reserved;