



► **AIRTOOLS**

SILENT YET POWERFUL, POWERFUL YET LIGHTWEIGHT, LIGHTWEIGHT YET DURABLE

Generations of proud professionals have developed their skills together with Bahco tools since 1886 and already in the middle of last century Bahco has been synonymous with high quality air tools.


We are proud to present a strong comeback in the air tools business with a range of unique products. A range that incorporates Bahco's spirit of innovation and unrelenting quality. A range of silent yet powerful, powerful yet lightweight, lightweight yet durable tools, designed for high demands, from the toughest job to the most accurate precision job, from the smallest car to the largest truck.

In other words a complete range of professional air tools for everyday use!



BAHCO - THE CHOICE OF TRUE PROFESSIONALS

AIR TOOL ICONS

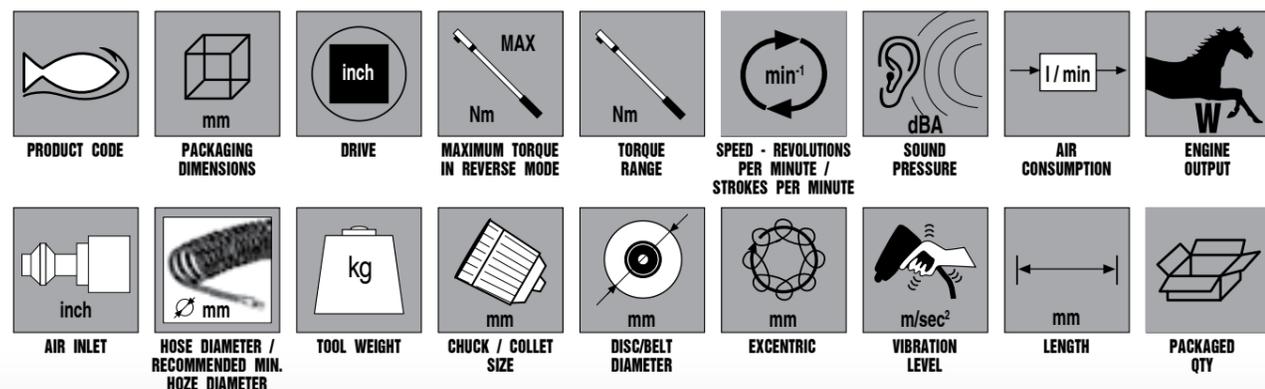

BAHCO AIR TOOLS SPECIAL FEATURES

FAST AND EASY!



TRUE ONE HAND DIRECTION AND POWER CONTROL KNOB

- Easy to change direction with one hand
- Easy to change power output with one hand



DURABLE AND LIGHTWEIGHT!



ONE PIECE MAGNESIUM HOUSING

Atomic number 12 (Magnesium) is prized for its lightness and strength. Its ions are essential to all living cells and the 11th most abundant element in the earth's crust

- Significantly lower weight
- Significantly increased durability



SILENT AND LIGHTWEIGHT!



COMPOSITE HOUSING AND HEXAGONAL RUBBER SLEEVE

- Significantly lower weight
- Significantly lower sound pressure
- Significantly lower vibration levels
- Great insulation against cold air
- User friendly grip

BP816 Impact wrench 3/8"	BP824 Reciprocating saw	BP825 Reversible drill 13 mm
BP815 Impact wrench 1/2"	BP801 Random orbital sander 5 mm	BP820 Ratchet 3/8"
BP817 Impact wrench 3/4"	BP610 Random orbital sander 2.5 mm	BP821 Ratchet 1/2"
BP823 5" Disc grinder	BP826 Reversible screwdriver 1.800 RPM	BP822 Mini grinder
BP110 Cut-off tool	BP827 Reversible screwdriver 800 RPM	BP115 Angle grinder
BP814 Impact wrench 3/8"	BP117 Low Revolution Grinder	BP822E Extended die grinder

POWERFUL DURABILITY!



TWIN HAMMER MECHANISM

- Reliable system for continuous torque increase with two hammers
- Resilient to air pressure fluctuations
- Consisting of surprisingly few parts
- Easy lubrication from the outside without dismantling the housing

BP816 Impact wrench 3/8"	BP817 Impact wrench 3/4"	BP900L Long anvil impact wrench 1"
BP815 Impact wrench 1/2"	BP900 Impact wrench 1"	BPM915 Impact wrench 1/2"
BPM916 Impact wrench 3/8"	BPM914 Mini impact wrench 1/2"	

THE CHOICE IS YOURS! EXTRA POWERFUL & SILENT or EXTRA SILENT & POWERFUL!



EXCHANGEABLE MUFFLER SYSTEM

- Adapt the performance of the tool after your demands!
- Attach either one or two of the included optional mufflers and decrease the sound level remarkably with just a nominal power loss



SMOOTH OPERATION!



SWIVEL CONNECTION

- Allows the air hose to follow the tool naturally
- Higher comfort when operating

BP816 Impact wrench 3/8"	BP820 Ratchet 3/8"	BP115 Angle grinder
BP815 Impact wrench 1/2"	BP822 Mini grinder	

A FAMILY WITH ATTITUDE!

EXTREME POWER!

The 8 VANES TWIN HAMMER mechanism delivers maximum power at minimum air consumption in no time



MAINTENANCE FREE!

We know you DON'T have time to lubricate your gun. Now you DON'T have to feel guilty about it because you DON'T NEED TO DO IT!

The exceptional OIL BATH lubrication system with high grade synthetic racing oil ensures a MAINTENANCE FREE TOOL and LONG LIFETIME

SMART DESIGN

Flat rubber covered top ensures a stable grip. Supplied with a black vinyl protection boot

CLUMSY?

No worries! The well balanced ONE PIECE MAGNESIUM HOUSING ensures extreme durability



CONFUSED? FORWARD? REVERSE? MAX? MIN?

Change DIRECTION and POWER output in 1 SECOND with ONE HAND! No need to WASTE TIME by USING TWO HANDS any more



EXTRA SILENT & POWERFUL or EXTRA POWERFUL & SILENT?

The system with optional mufflers gives YOU the CHOICE to quickly adapt the tool to YOUR DEMANDS and needs! Use 0, 1 or 2 of the included mufflers! With no muffler the power is maximized, with 2 mufflers the sound is minimized

[mag-NEE-zee-əm]

IMPACT WRENCH 1/2"

THE CHOICE IS YOURS!

Muffler	MAX Nm	% Nm	dB(A)	%
0	1098 Nm		102.5 dBA	
1	1015 Nm	-7,6%	92.5 dBA	-316 %
2	935 Nm	-14,8%	86.6 dBA	-623 %

BPM915 100x250x250 1/2 1098 -813 5.700 ≤1025 6,6 178 1/2 10 2,02

[mag-NEE-zee-əm]

MINI IMPACT WRENCH 1/2"

THE CHOICE IS YOURS!

Muffler	MAX Nm	% Nm	dB(A)	%
0	440 Nm		99.1 dBA	
1	414 Nm	-6%	90.3 dBA	-275 %

BPM914 100x250x200 1/2 440 -300 10.700 ≤99,1 4,54 68 1/2 10 1,03

[mag-NEE-zee-əm]

IMPACT WRENCH 3/8"

THE CHOICE IS YOURS!

Muffler	MAX Nm	% Nm	dB(A)	%
0	440 Nm		99.1 dBA	
1	414 Nm	-6%	90.3 dBA	-275 %

BPM916 100x250x200 3/8 440 -300 10.700 ≤99,1 4,54 68 3/8 10 1,03

POWERFUL YET LIGHTWEIGHT!



BP814 merely 1.2 kg and striking a maximum torque of 410 Nm in reverse

▶ MINI IMPACT WRENCH 1/2"



- Composite housing
- Twin hammer mechanism
- Air exhaust in handle
- Swivel connection

BP814 60x187x195 1/2 410 220-360 10.000 88 6,53 85 1/4 10 1,2

▶ IMPACT WRENCH 3/8"



- Composite housing
- Twin hammer mechanism
- Air exhaust in handle
- Swivel connection

BP816 60x187x195 3/8 410 220-360 10.000 88 6,53 85 1/4 10 1,20

▶ 3/8" IMPACT WRENCH SET



- Includes:
- One BP816
 - Eleven impact sockets
 - One 1/4" threaded male coupler
 - Supplied in robust plastic case with foam inlay (compatible with Bahco tool trolley modular system, T12)

BP816K1 108x371x321 10-24 2,2

▶ IMPACT WRENCH 1/2"



- Composite housing
- Twin hammer mechanism
- Air exhaust in handle
- Swivel connection

BP815	78x215x210	1/2	825	320-620	7.000	84	5,00	130	1/4	10	1,95
-------	------------	-----	-----	---------	-------	----	------	-----	-----	----	------

▶ 1/2" IMPACT WRENCH SET



- Includes:
- One BP815
 - Eleven impact sockets
 - One 1/4" threaded male coupler
 - Supplied in robust plastic case with foam inlay (compatible with Bahco tool trolley modular system, T12)

BP815K1	108x371x321	10-24	3,2
---------	-------------	-------	-----

FOR THE LARGE ONES!

▶ IMPACT WRENCH 3/4"



- Composite housing
- Twin hammer mechanism
- Air exhaust in handle

BP817	100x290x250	3/4	1.800	340x950	4.500	88	4,30	190	3/8	10	3,95
-------	-------------	-----	-------	---------	-------	----	------	-----	-----	----	------



BP900L impressive 2.800 Nm!

▶ EXTRA POWERFUL IMPACT WRENCH 1"



- Extremely powerful
- Air exhaust in handle
- Pin clutch mechanism

BP405	115x335x280	1	3.796	813-1.898	4.000	92	5,10	235	1/2	13	11,80
-------	-------------	---	-------	-----------	-------	----	------	-----	-----	----	-------

▶ IMPACT WRENCH 1"



- Heavy duty model
- Twin hammer mechanism
- 2" anvil
- Air exhaust in handle
- Power control in both directions

BP900	260x720x360	1	2.800	1.200-2.700	3.900	99	11,60	1.840	1/2	13	12,00
-------	-------------	---	-------	-------------	-------	----	-------	-------	-----	----	-------

▶ LONG ANVIL IMPACT WRENCH 1"



- Heavy duty model
- Twin hammer mechanism
- 6" anvil for great accessibility
- Air exhaust in handle
- Power control in both directions

BP900L	260x720x360	1	2.800	1.200-2.700	3.900	99	11,60	1.840	1/2	13	12,50
--------	-------------	---	-------	-------------	-------	----	-------	-------	-----	----	-------

▶ RATCHET 1/4"



- Speed control system for accurate operation
- Extra compact

BP700	45x210x75	1/4	164	0-27	300	94	3,60	65	1/4	10	0,50
-------	-----------	-----	-----	------	-----	----	------	----	-----	----	------

▶ RATCHET 3/8"



- Speed control system for accurate operation
- Hexagonal rubber sleeve
- Air exhaust control system
- Swivel connection

BP820	60x235x60	3/8	201	0-31	0-270	85	<2,50	78	1/4	10	0,50
-------	-----------	-----	-----	------	-------	----	-------	----	-----	----	------

▶ RATCHET 1/2"



- Speed control system for accurate operation
- Hexagonal rubber sleeve
- Air exhaust control system
- Swivel connection

BP821	56x280x65	1/2	260	0-67	150	80	2,60	120	1/4	10	1,20
-------	-----------	-----	-----	------	-----	----	------	-----	-----	----	------



All technical specifications are stated at the recommended working pressure of 6.2 bar

THE LONG & STRONG!

EASY TO HANDLE!

Balanced lightweight house for superior control and comfortable usage

COMFORTABLE TO HANDLE!

Soft grip handle with increased comfort, reduced vibration, and increased insulation against cold

HEAVY WORK LOAD?

No worries! The "stop lock" pins prevent ratchet pawl lock up and assures increased tool life

EXTRA SILENT & POWERFUL or EXTRA POWERFUL & SILENT?

The muffler bypass system gives YOU the choice to quickly adapt the tool to YOUR DEMANDS and needs!

BP921	70x330x90	308	1/2	7-95	7-67	260	200	≤ 94,9	≤ 5,2	127	1/2	10	1,4
-------	-----------	-----	-----	------	------	-----	-----	--------	-------	-----	-----	----	-----

MUFFLER BYPASS SYSTEM			
Muffler	MAX Nm	% Nm	dBa
	95 Nm		94.9 dBA
	67 Nm	-30%	87.9 dBA
			-224%

▶ MINI RATCHET 1/4"



- Soft grip handle
- Hard coated motor plates
- Large lightweight selector knob
- All ball bearing construction and high strength alloy steel gear system
- Supplied with a black protection boot

BP919	50x280x100	180	1/4	47	0-47	235	85	2,5	40	1/4	10	0,6
-------	------------	-----	-----	----	------	-----	----	-----	----	-----	----	-----

▶ MINI RATCHET 3/8"



- Balanced lightweight housing
- Soft grip handle
- Hard coated motor plates
- Large lightweight selector knob
- All ball bearing construction and high strength alloy steel gear system
- Supplied with a black protection boot

BP920	50x280x100	180	3/8	47	0-47	235	85	2,5	40	3/8	10	0,6
-------	------------	-----	-----	----	------	-----	----	-----	----	-----	----	-----

WHEN ACCESSIBILITY & POWER IS CRUCIAL



The long & strong! 308 mm long, 95 Nm strong!

All technical specifications are stated at the recommended working pressure of 6.2 bar

THE PRECISE!

EASY TO HANDLE

Top mounted forward / reverse switch allowing one hand operation for easy usage

ALSO A PERFECTIONIST?

Precise 0,0635 mm CHUCK RUNOUT for precision drilling yielding a high quality job, ALWAYS!

IN A HURRY?

The 0,45 HP motor with 5 vanes provides MAXIMUM DRILLING POWER to get the job done faster

NEED FOR CONTROL?

REVERSIBLE VARIABLE SPEED TRIGGER for increased control of drilling speed

CLEVER DESIGN

User friendly design with forefinger support increases the precision in all drilling

COMFORTABLE TO HANDLE

Soft grip handle ensures a great working day

▶ HIGH PRECISION DRILL 13 mm



- Top mounted forward / reverse switch
- Internal ball bearing construction
- Supplied with integrated support handle and drill container

BP926	229	13	336	450	0-34	80	<2,50	108	1/4	10	1,3
-------	-----	----	-----	-----	------	----	-------	-----	-----	----	-----

▶ HIGH PRECISION DRILL 10 mm



- Top mounted forward / reverse switch
- Internal ball bearing construction


BP925	178	10	336	2.500	0-6,0	80	<2,50	99	1/4	10	1
-------	-----	----	-----	-------	-------	----	-------	----	-----	----	---

▶ REVERSIBLE DRILL 13 mm



- Composite housing
- Removable and adjustable handle
- Forward / reverse lever ensures quick and easy change of direction
- Air exhaust in the handle for pleasant operation
- Quick chuck
- Rubber grip handle

BP825	220x155x45	13	373	450	88	<2,50	105	1/4	10	1,35
-------	------------	----	-----	-----	----	-------	-----	-----	----	------

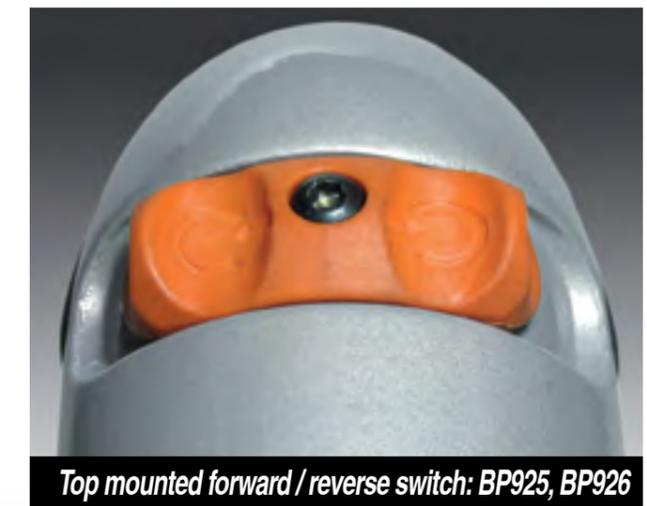

Top mounted forward / reverse switch: BP925, BP926

All technical specifications are stated at the recommended working pressure of 6.2 bar

 
▶ BELT SANDER 10 mm



Belts 25 pcs 80 grits - Suitable for BP212




- Adjustable arm
- Including three belts 80, 100 and 120 grits



▶ ORBITAL SANDER 5 mm



 - For central vacuum systems
- Composite housing



▶ PISTOL GRIP SANDER



- Top mounted forward / reverse switch



Accessories suitable for BP204

Description	BP2044PAD	BP20425180	BP20425220
3" Velcro pad			
25 pcs, 180 grit			
25 pcs, 220 grit			
25 pcs, 320 grit			
25 pcs, 800 grit			

▶ BELT SANDER 20 mm



Belts 25 pcs 100 grits - Suitable for BP222



- Adjustable arm
- Including two belts 100 and 120 grits



▶ ORBITAL SANDER 2,5 mm



- For central vacuum systems
- Composite housing



Pad - Suitable for BP601 and BP610



▶ PISTOL GRIP SANDER SET



Including:

- BP204
- 1 x 3" Velcro pad
- 10 x 180 grits, 3" pads
- 10 x 220 grits, 3" pads
- 10 x 320 grits, 3" pads
- 10 x 800 grits, 3" pads



▶ REVERSIBLE SCREWDRIVER 1.800 RPM



 
- Composite motor housing
- Two speed trigger
- External adjustable clutch design
 - Forward: Adjustable torque
 - Reverse: Full torque
- Reversible bar on both sides for easy change of direction



▶ REVERSIBLE SCREWDRIVER 800 RPM



- Composite motor housing
- Two speed trigger
- External adjustable clutch design
 - Forward: Adjustable torque
 - Reverse: Full torque
- Reversible bar on both sides for easy change of direction



WHEN TOTAL CONTROL IS A MUST!



The unique clutch design of BP826 and BP827 ensures a total torque control!

WHEN REAL POWER IS A MUST!



▶ LOW REVOLUTION GRINDER



- Speed control system
- Hexagonal rubber sleeve
- Safety trigger

Exhaust hose for die grinder



BP117EH

BP117	50x243x172	3/6	2.500	85	4,53	170	1/4	1

▶ DISC GRINDER



- Composite housing
- Safety trigger

BP823	108x285x147	3 & 6	10.000	83	<2,50	340	1/4	1,80

▶ AIR RIVETER



- Rivet capacity;
3,2 mm
4,0 mm
4,8 mm
6,4 mm

BP125	349x543x397	19	1330	1/4	2,0

▶ CUT OFF TOOL



- Speed control system
- Rubber sleeve
- Safety trigger
- Swivel connection

BP110	81x190x86	3/6	18.000	98	<2,50	113	1/4	0,90

▶ MINI DIE GRINDER



- 3 and 6 mm collet for improved flexibility
- Hexagonal rubber sleeve
- Safety trigger
- Air exhaust control system for pleasant operation
- Swivel connection

BP822	55x200x98	3 & 6	201	25.000	85	4,53	170	1/4	10	0,67

▶ RECIPROCATING SAW



- Composite housing
- Safety trigger mechanism
- Directional exhaust system
- Swivel connection
- Three car body saw blades included

BP824	50x340x90	10.000	85	3,70	160	1/4	10	0,50

Car body saw blades - Suitable for BP824

	mm-teeth	
3845-18-10P	90-18	
3845-24-10P	90-24	
3845-32-10P	90-32	

▶ NEEDLE SCALER



- Heavy duty
- Low vibration

BP127	70x370x190	3.700	97	8,70	159	1/4	10	2,60

▶ ANGLE GRINDER



- Hexagonal rubber sleeve
- Safety trigger
- Air exhaust control system
- Swivel connection

BP115	36x145x75	6	201	20.000	79	<2,50	113	1/4	10	0,59

▶ EXTENDED DIE GRINDER



- 3 and 6 mm collet for improved flexibility
- Hexagonal rubber sleeve
- Safety trigger
- Air exhaust control system for pleasant operation
- Swivel connection
- 95 mm long neck for increased accessibility

BP822E	55x243x172	3 & 6	201	25.000	89	4,53	113	1/4	10	0,80

Abbrasive wheels - Suitable for BP822, BP115 and BP822E

	BP420M	25	67		BP430M	12	55
	BP421M	14	53		BP431M	13	48
	BP422M	26	46		BP432M	15	44
	BP423M	25	53		BP433M	14	43
	BP424M	19	57		BP434M	13	42

For Bahco's extensive range of rotary burrs suitable for BP822, BP822E and BP115 please see the Bahco catalogue, www.bahco.com

▶ CARTRIDGE APPLICATOR



- Enables fast and efficient application of European standard cartridges

BP215	92x310x175	80	1/4	10	1,00

All technical specifications are stated at the recommended working pressure of 6.2 bar

All technical specifications are stated at the recommended working pressure of 6.2 bar

THE SLUGGER! AIR HAMMER SET

THE FASTEST

The unique quick chuck makes chisel change a piece of cake



HARD HITTING!

The 76 MM LONG STROKE of the EXTRA HEAVY HARD STEEL PISTON ensures striking power as you have never experienced before

DURABLE & SMART

Built of only the most heavy duty materials, solid HIGH GRADE STEEL BARREL, KEVLAR reinforced flutter disc, INBUILT AIR FILTER. All to ensure MAXIMUM TOOL LIFE



SO SMOOTH...

Even if the power is tremendous, the vibration is nominal. ONLY 1.5m/s² thanks to the dual elastomer cushions that absorb almost all vibration

COMPLETE

Supplied in robust plastic case including FIVE CHISELS for a wide area of applications

EASY HANDLING

Built in four position air regulator and direct multi-port frontal exhaust ensures comfortable usage

BP909K	108x371x321	10	229	2.500	94	1,5	60	1/4	10	2,1
--------	-------------	----	-----	-------	----	-----	----	-----	----	-----

Accessory chisels - Suitable for BP909K

Type	Shank	Included in BP909K
BP909TF Turning, flat	Round 10.2mm	Yes
BP909TWF Turning, wide flat	Round 10.2mm	Yes
BP909TTP Turning, tapered punch	Round 10.2mm	Yes
BP909TE Turning, edge claw	Round 10.2mm	Yes
BP909TH Turning, hammer	Round 10.2mm	
BP909TSP Turning, straight punch	Round 10.2mm	Yes
BP909NF Non - turning, flat	Round 10.2mm	
BP909NE Non - turning edge claw	Round 10.2mm	

▶ PAINT GUN SET

- High volume at low pressure
- High precision provides high quality painting
- Spare nozzle sets covering five diameters
- No seal component design for much longer operation life
- Precise air cap keeps the outlet less than 10PSI
- One piece aluminum housing



BPHVLP01	155x225x200	2-2.8	600	410	1/4	5-40	1,00
----------	-------------	-------	-----	-----	-----	------	------

Accessories available loose and included with the BPHVLP01

Description
BPHVLP0110 Nozzle set 1.0 mm
BPHVLP0112 Nozzle set 1.2 mm
BPHVLP0114 Nozzle set 1.4 mm
BPHVLP0117 Nozzle set 1.7 mm
BPHVLP0120 Nozzle set 2.0 mm

▶ BLOW GUN

- Steel nozzle
- Meets O.S.H.A requirements
- Brass inlet



BP218	19x200x85	≤ 11	410	1/4	0,135
-------	-----------	------	-----	-----	-------

WHEN FLEXIBILITY IS A MUST!



Thanks to the double collets included in the BP822, it can drive both 3 and 6 mm inserts

▶ FEMALE MULTI-PROFILE COUPLER 1/4"



Suitable male profiles

- ISO6150B
- ARO210
- European (German)
- Italian

- Works with four standard male connector profiles
- Security lock enabling the operator to turn on and off the air flow, providing a safer and more simplified operation
 - The tool cannot be disconnected unless the air flow is turned off
 - Simplified operation - ease the connection of the male profile since the air flow can be cut
- Steel construction with composite coating, making it extremely durable
- Air flow: 1,600 l/min at 6.0 bar
- Maximum pressure: 14 bar
- Plug diameter: 6 mm

BPQCF14	30x70x30	10	0,090
---------	----------	----	-------

▶ PNEUMATIC WINDSCREEN REMOVER



- Robust design
- Pipe away exhaust
- Low vibration, <2.5 m/s²
- Noise reducing hose

BP233	43x275x75	80,5	<2,5	260	1/4	10	1,20
-------	-----------	------	------	-----	-----	----	------

Blades - Suitable for BP233

Description
BPBK30 Offset comma shaped blades pair in blister
BPBG5725 Offset 13mm shaped blades pair in blister
BPBG9057 Offset 13mm shaped blades pair in blister
BPBU18 U shaped blades pair in blister
BPBU24 U shaped blades pair in blister
BPBU36 U shaped blades pair in blister
BPBU60 U shaped blades pair in blister
BPBU90 U shaped blades pair in blister
BPBG3515 Straight blades pair in blister
BPBG3525A Straight blades pair in blister
BPBG3525B Straight blades pair in blister
BPBSC156 Scraper pair in blister

▶ MAGNETIC HOLDER



- Equipped with extra strong magnets that easily holds a 3/4" impact wrench, four impact sockets and one torque tool
- Painted with special and durable paint to avoid damage of the stored tools

BP500	125x390x135	1,03
-------	-------------	------

▶ SPIRAL HOSES



- Polyurethane hose with fixed male threaded connector at both ends


BPH1010	90x530x90	10-13	10	1/4-1/4	0,86
BPH1310	90x530x90	13-18	10	1/2-1/2	1,00

▶ PNEUMATIC MARKER



- For fast and secure marking
- Low vibration
- Low air consumption

BP799	17x200x17	13,000	78	<2,00	28	1/4	10	0,22
-------	-----------	--------	----	-------	----	-----	----	------

 

▶ AIR FILTER - REGULATOR



- Filters the air to avoid damage caused by dust
- Regulates desired pressure between 1 and 8,5 bar

BP254	80x290x80	1-8,5	1,5	-5/+60	≤ 3.800	200	1/2	0,805
-------	-----------	-------	-----	--------	---------	-----	-----	-------

▶ AIR FILTER - REGULATOR - LUBRICATOR



- Filters the air to avoid damages caused by dust
- Regulates desired pressure between 1 and 8,5 bar
- Automatically lubricates the air to ensure correct operation and longer lifetime of the air tools

BP255	115x235x115	1-8,5	1,5	-5/+60	≤ 3.800	200	1/2	1,350
-------	-------------	-------	-----	--------	---------	-----	-----	-------

▶ STEEL AIR HOSE REEL



- Corrosion resistant
- Adjustable double guide arm
- Ball bearing swivel
- Strengthened frame
- 110° swivel base
- Positive latching system which automatically locks the hose at desired length for increased functionality and comfort

BPHRS1315	519x614x264	13/20	15	1/2-1/2	24
-----------	-------------	-------	----	---------	----

▶ AIR HOSE REELS



- 180° swivel bracket
- Detachable pin swivel
- Durable corrosion and rough environment resistant polypropylene housing
- Positive latching system which automatically locks the hose at desired length for increased functionality and comfort

BPHR1315	509x539x239	13/16	15	1/2-1/2	9,70
BPHR1020	509x539x239	10/14,5	20	3/8-3/8	9,70

▶ IN LINE MINI LUBRICATOR



- Lubricates the air to ensure correct operation and longer lifetime of the air tools

BPN251	33x60x33	1/4	0,008
--------	----------	-----	-------

THE PERFECT COMPANIONS TO BAHCO AIR TOOLS!

▶ IMPACT SOCKETS AND ACCESSORIES

Always use impact sockets with power tools. For the complete range of Bahco's robust impact sockets from 1/4" to 1 1/2", please see the Bahco catalogue, www.bahco.com

IMPACT SOCKETS AND ACCESSORIES 3/8"

3/8" Impact sockets metric



K7401M-7	7
K7401M-8	8
K7401M-9	9
K7401M-10	10
K7401M-11	11
K7401M-12	12
K7401M-13	13
K7401M-14	14
K7401M-15	15
K7401M-16	16
K7401M-17	17
K7401M-18	18
K7401M-19	19
K7401M-20	20
K7401M-21	21
K7401M-22	22
K7401M-24	24

3/8" Impact adaptor, universal holder



K172	1/4	3/8
------	-----	-----

3/8" Impact adaptors, bit holder



7407H	1/4	3/8
7408H	5/16	3/8



7409H	11 mm	3/8
-------	-------	-----

3/8" Clamping springs



K560F-2	3/8	7-12	E5-E14
K560F-3	3/8	13-19	

3/8" Impact sockets metric deep



K7406M-10	10
K7406M-13	13
K7406M-17	17

3/8" Impact extensions



K7760C-1	75	3/8	3/8
K7760C-2	150	3/8	3/8

3/8" Impact ball joint



K7767S	3/8	3/8
--------	-----	-----

3/8" Impact adaptors



K6964C	1/4	3/8
K8164C	1/2	3/8

1/2" Impact sockets metric



K7801VM-17	17
K7801VM-19	19
K7801VM-22	22
K7801VM-24	24

1/2" Impact socket set metric



K7801VM/S4	17-24
------------	-------

1/2" Impact sockets metric deep



K7806M-10	10
K7806M-11	11
K7806M-12	12
K7806M-13	13
K7806M-14	14
K7806M-16	16
K7806M-17	17
K7806M-18	18
K7806M-19	19
K7806M-21	21
K7806M-22	22
K7806M-23	23
K7806M-24	24
K7806M-27	27
K7806M-30	30

1/2" Impact socket set metric deep



K7806M/S4	17-24
-----------	-------

1/2" Impact sockets imperial



K7801Z-3/8	3/8
K7801Z-7/16	7/16
K7801Z-1/2	1/2
K7801Z-9/16	9/16
K7801Z-5/8	5/8
K7801Z-11/16	11/16
K7801Z-3/4	3/4
K7801Z-13/16	13/16
K7801Z-7/8	7/8
K7801Z-15/16	15/16
K7801Z-1	1
K7801Z-1.1/16	1.1/16
K7801Z-1.1/8	1.1/8
K7801Z-1.1/4	1.1/4

1/2" Impact sockets imperial deep



K7806Z-3/8	3/8
K7806Z-7/16	7/16
K7806Z-1/2	1/2
K7801Z-9/16	9/16
K7801Z-5/8	5/8
K7801Z-11/16	11/16
K7801Z-3/4	3/4
K7801Z-13/16	13/16
K7801Z-7/8	7/8
K7801Z-15/16	15/16
K7801Z-1	1
K7801Z-1.1/16	1.1/16
K7801Z-1.1/8	1.1/8
K7801Z-1.1/4	1.1/4
K7801Z-1.5/16	1.5/16
K7801Z-1.3/8	1.3/8
K7801Z-1.7/16	1.7/16
K7801Z-1.1/2	1.1/2

1/2" Impact sockets TORX®



K7801TORX-E10	E10
K7801TORX-E12	E12
K7801TORX-E14	E14
K7801TORX-E16	E16
K7801TORX-E18	E18
K7801TORX-E20	E20
K7801TORX-E24	E24

1/2" Impact socket sets imperial, 10 pcs



K7801Z/10	7/16-1
-----------	--------

1/2" Impact socket sets imperial, 10 pcs



K7806Z/10	7/16-1
-----------	--------

1/2" Impact socket sets metric



D/S10	280x160x70	10-19
D/S14	280x160x70	10-27

1/2" Impact socket sets metric deep



DD/S10	280x160x70	10-19
DD/S14	375x215x100	10-27

1/2" Impact socket set + metric deep



D-DD/S20	375x215x100	10-19
----------	-------------	-------

D-DD/S20

1/2" Impact extensions



K8160D-1	75	1/2	1/2
K8160D-2	125	1/2	1/2
K8160D-3	250	1/2	1/2

1/2" Impact ball joint



K8167S	1/2	1/2
--------	-----	-----

1/2" Impact adaptors



K7764D	3/8	1/2
K8964D	3/4	1/2

1/2" Impact adaptors, bit holder



7807H	1/4	1/2
7808H	5/16	1/2
7809H	11.2 mm	1/2

1/2" Clamping springs



K560F-4	1/2	10-14	E10-E20
K560F-5	1/2	15-32	E-24

IMPACT SOCKETS AND ACCESSORIES 3/4"

3/4" Impact sockets metric



K8901M-17	17
K8901M-18	18
K8901M-19	19
K8901M-21	21
K8901M-22	22
K8901M-23	23
K8901M-24	24
K8901M-27	27
K8901M-28	28
K8901M-29	29
K8901M-30	30
K8901M-32	32
K8901M-33	33
K8901M-34	34
K8901M-36	36
K8901M-38	38
K8901M-41	41
K8901M-46	46
K8901M-50	50
K8901M-55	55
K8901M-60	60

3/4" Impact sockets imperial



K8901Z-11/16"	11/16
K8901Z-3/4"	3/4
K8901Z-13/16	13/16
K8901Z-7/8	7/8
K8901Z-15/16	15/16
K8901Z-1	1
K8901Z-1.1/16	1.1/16
K8901Z-1.1/8	1.1/8
K8901Z-1.3/16	1.3/16
K8901Z-1.1/4	1.1/4
K8901Z-1.5/16	1.5/16
K8901Z-1.3/8	1.3/8
K8901Z-1.7/16	1.7/16
K8901Z-1.1/2	1.1/2
K8901Z-1.9/16	1.9/16
K8901Z-1.5/8	1.5/8
K8901Z-1.11/16	1.11/16
K8901Z-1.3/4	1.3/4
K8901Z-1.13/16	1.13/16
K8901Z-1.7/8	1.7/8
K8901Z-1.15/16	1.15/16
K8901Z-2	2
K8901Z-2.1/16	2.1/16
K8901Z-2.3/16	2.3/16
K8901Z-2.1/4	2.1/4
K8901Z-2.3/8	2.3/8

3/4" Impact sockets imperial



K8901Z-3/4	3/4
K8901Z-13/16	13/16
K8901Z-7/8	7/8
K8901Z-15/16	15/16
K8901Z-1	1
K8901Z-1.1/16	1.1/16
K8901Z-1.1/8	1.1/8
K8901Z-1.1/4	1.1/4
K8901Z-1.5/16	1.5/16
K8901Z-1.3/8	1.3/8
K8901Z-1.7/16	1.7/16
K8901Z-1.1/2	1.1/2
K8901Z-1.5/8	1.5/8
K8901Z-1.3/4	1.3/4

3/4" Impact sockets metric deep



K8906M-17	17
K8906M-19	19
K8906M-21	21
K8906M-22	22
K8906M-24	24
K8906M-27	27
K8906M-30	30
K8906M-32	32
K8906M-33	33
K8906M-34	34
K8906M-36	36
K8906M-41	41

3/4" Impact sockets imperial deep



K8906Z-3/4	3/4
K8906Z-13/16	13/16
K8906Z-7/8	7/8
K8906Z-15/16	15/16
K8906Z-1	1
K8906Z-1.1/16	1.1/16
K8906Z-1.1/8	1.1/8
K8906Z-1.1/4	1.1/4
K8906Z-1.5/16	1.5/16
K8906Z-1.3/8	1.3/8
K8906Z-1.7/16	1.7/16
K8906Z-1.1/2	1.1/2
K8906Z-1.5/8	1.5/8
K8906Z-1.3/4	1.3/4
K8906Z-2	2

3/4" Impact extensions



K8960F-2	175	3/4"	3/4"
K8960F-3	250	3/4"	3/4"

3/4" Impact ball joint



K8967S	3/4	3/4
--------	-----	-----

3/4" Impact adaptors



K8164F	1/2	3/4
K9564F	1	3/4

3/4" Impact adaptor, bit holder



K8909H-5	22 mm	3/4
----------	-------	-----

3/4" Clamping springs



K560F-6	3/4	17-46
---------	-----	-------

IMPACT SOCKETS AND ACCESSORIES 1"

1" Impact sockets metric



Part Number	Size
K9501M-22	22
K9501M-24	24
K9501M-27	27
K9501M-30	30
K9501M-32	32
K9501M-33	33
K9501M-34	34
K9501M-36	36
K9501M-38	38
K9501M-41	41
K9501M-42	42
K9501M-46	46
K9501M-50	50
K9501M-55	55
K9501M-60	60
K9501M-65	65
K9501M-70	70
K9501M-75	75
K9501M-80	80

1" Impact sockets imperial



Part Number	Size
K9501Z-1	1
K9501Z-1.1/16	1.1/16
K9501Z-1.1/8	1.1/8
K9501Z-1.3/16	1.3/16
K9501Z-1.1/4	1.1/4
K9501Z-1.5/16	1.5/16
K9501Z-1.3/8	1.3/8
K9501Z-1.7/16	1.7/16
K9501Z-1.1/2	1.1/2
K9501Z-1.9/16	1.9/16
K9501Z-1.5/8	1.5/8
K9501Z-1.11/16	1.11/16
K9501Z-1.3/4	1.3/4
K9501Z-1.13/16	1.13/16
K9501Z-1.7/8	1.7/8
K9501Z-1.15/16	1.15/16
K9501Z-2	2
K9501Z-2.1/8	2.1/8
K9501Z-2.3/16	2.3/16
K9501Z-2.1/4	2.1/4
K9501Z-2.5/16	2.5/16
K9501Z-2.9/16	2.9/16
K9501Z-2.3/4	2.3/4

1" Impact sockets metric deep



Part Number	Size
K9506M-22	22
K9506M-24	24
K9506M-27	27
K9506M-30	30
K9506M-32	32
K9506M-33	33
K9506M-34	34
K9506M-36	36
K9506M-38	38
K9506M-41	41
K9506M-46	46
K9506M-50	50
K9506M-55	55
K9506M-60	60

1" Impact sockets imperial deep



Part Number	Size
K9506Z-1	1
K9506Z-1.1/16	1.1/16
K9506Z-1.3/16	1.3/16
K9506Z-1.1/4	1.1/4
K9506Z-1.7/16	1.7/16
K9506Z-1.1/2	1.1/2
K9506Z-1.5/8	1.5/8
K9506Z-1.13/16	1.13/16
K9506Z-1.7/8	1.7/8

1" Impact extensions



Part Number	Length (mm)	Quantity
K9560G-1	125	1
K9560G-2	175	1
K9560G-3	325	1

1" Impact ball joint



Part Number	Quantity
K9567S	1

1" Impact adaptor



Part Number	Size	Quantity
K8964G	3/4"	1

1" Impact adaptor, bit holder



Part Number	Size	Quantity
K9509H5	22 mm	1

1" Screwdriver bits for hexagon metric socket head screws



Part Number	Size
K8909ML-12	12
K8909ML-14	14
K8909ML-17	17
K9509ML-19	19
K9509ML-22	22
K9509ML-24	24

1" Clamping springs



Part Number	Size
K560F-7	1
K560F-8	1 & 1.1/2 75-80 & 46-90

Impact sockets Scania



Part Number	Description	Quantity
BHVIS0895	SCANIA F WHEEL-8F X 95MM-3/4	3/4
BHVIS08100	SCANIA R WHEEL-8F X 100MM-3/4	3/4

- Special impact sockets to use for Scania truck wheels
- Output:
- HVIS0895: 8 flutes x 95 mm for front wheels
- HVIS08100: 8 flutes x 100 mm for rear wheels

Impact socket Volvo



Part Number	Description	Quantity
BHVIS08115	VOLVO WHEEL-8F X 115MM-3/4	3/4

- Special impact sockets to use for Volvo truck wheels
- Output: 8 flutes x 115 mm

Impact sockets BPW



Part Number	Size	Quantity
BHVIS111BPW12	111	1
BHVIS120BPW16	120	1
BHVIS109BPW12	109	1

- Special impact sockets to use on the axles made by one of the most well-known axle makers, BPW
- Output: Special shape with different sizes per axle type

Axle nut remover BPW



Part Number	Size	Quantity
BHVIS80BPW12	80	3/4"


1" Torsion bars



Part Number	MAX Nm	Size	Weight (kg)
BWTB0132450	450	32	1.54
BWTB0132600	600	32	1.58
BWTB0133600	600	33	1.61

- Special torsion bars for controlling the torque applied to wheels and other parts

Wheel socket sets

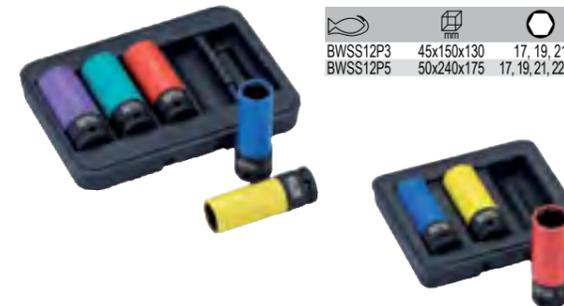

Part Number	Size	Quantity	Weight (kg)
BWSS12P3	45x150x130	17, 19, 21	0.8
BWSS12P5	50x240x175	17, 19, 21, 22, 24	1.47

- Plastic protection on socket walls to ensure protection of the rims
- Plastic protection inside the socket to ensure protection of wheel nuts

Torsion bar set, 10 pcs



Part Number	Size	Weight (kg)
BWTB12P10	1/2"	3,495

Color	MAX Nm
Red	75
Yellow	90
Green	110
Pink	120
Light blue	135
Navy blue	150
White	160
Black	190
Gray	205
Orange	240

- Torsion bars of special steel that limits the torque! When the maximum torque is reached the bar twists automatically
- (Always use a torque wrench after usage of torsion bars)

Safety wear

Always use appropriate safety equipment when operating power tools; safety glasses, ear protectors, gloves and protective clothing



Part Number	Description
3870-SAFETYGLASSES	Safety glasses



Part Number	Description
5428	Ear protectors



Part Number	Description	Size
GL008-8	PU Gloves	8
GL008-10	PU Gloves	10

- PU gloves with knuckle protector, reflective piping and soft cotton brow wipe on the thumb
- The orange material is a Spandex for comfort and fit. Elastic cuff with Velcro fastening for secure fitting



Part Number	Description	Size
GL010-8	Textured PU Gloves	8
GL010-10	Textured PU Gloves	10

- Textured PU gloves with additional padded cells to give protection whilst using power tools
- They also have the knuckle protector, reflective piping, cotton brow wipe, Spandex back and Elastic cuff



AUT-0816-INT

SNA Europe



www.bahco.com