


## Nature Line

■ Printing ■ Computer Stationery ■ Notebook Manufacturing

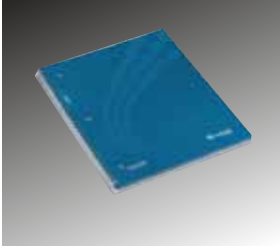

S.NO.	PARTICULARS		UOM	54/56 GSM	58/60 GSM	78/80 GSM
1	Substance		g/m <sup>2</sup>	± 2.5%	± 2.5%	± 2.5%
2	Bulk		cc/g	1.25 ± 0.03	1.25 ± 0.03	1.25 ± 0.03
3	Breaking Length (Min)	MD	meter	4200	4200	4200
		CD	meter	2100	2100	2100
4	Tear Factor (Min)	MD	-	40	40	40
		CD	-	42	42	42
5	Smoothness (Bendtsen)	I Side	ml/min	120 ± 20	120 ± 20	120 ± 20
		II Side	ml/min	240 ± 20	240 ± 20	240 ± 20
6	Cobb-60	TS	g/m <sup>2</sup>	25 ± 2	25 ± 2	25 ± 2
		WS	g/m <sup>2</sup>	26 ± 2	26 ± 2	26 ± 2
7	Brightness		% ISO	82 ± 1	82 ± 1	82 ± 1
8	Opacity (Print) (Min)		%	84 ± 1	85 ± 1	87 ± 1
9	Passed Wax Pick No.		no.	12A	12A	12A

## Cartridge Paper

■ Printing ■ Computer Stationery ■ Notebook Manufacturing



S.NO.	PARTICULARS		UOM	80 GSM	90 GSM	100 GSM	120 GSM
1	Substance		g/m <sup>2</sup>	± 2.5%	± 2.5%	± 2.5%	± 2.5%
2	Bulk		cc/g	1.45 ± 0.04	1.45 ± 0.04	1.45 ± 0.04	1.45 ± 0.04
3	Breaking Length (Min)	MD	meter	4200	4200	4200	4200
		CD	meter	2100	2100	2100	2100
4	Tear Factor (Min)	MD	-	40	40	40	40
		CD	-	42	42	42	42
5	Smoothness (Bendtsen)	I Side	ml/min	250 ± 50	250 ± 50	250 ± 50	250 ± 50
		II Side	ml/min	400 ± 50	400 ± 50	400 ± 50	400 ± 50
6	Cobb-60	TS	g/m <sup>2</sup>	25 ± 2	25 ± 2	25 ± 2	25 ± 2
		WS	g/m <sup>2</sup>	26 ± 2	26 ± 2	26 ± 2	26 ± 2
7	Brightness		% ISO	82 ± 1	82 ± 1	82 ± 1	82 ± 1
8	Opacity (Print) (Min)		%	88 ± 1	90 ± 1	92 ± 1	94 ± 1
9	Passed Wax Pick No.		no.	12A	12A	12A	12A

