

ABRR002 ROUND ROCKER SWITCH

SWITCHES

Specifications

ABRR002






Rating	6(2)A 250VAC T125/55 1E4 10A 125VAC		
Colour	Black body		
Switch action	SP On-off momentary		
Maximum contact resistance	30M Ω		
Minimum insulation resistance	500VDC 100M Ω		
Electrical life	10,000 cycles		
Operation force	300-600gf		
Operating temperature	-25°C~125°C		
Cut out	Z	Y	X
(diagram opposite)	0.75-1.25	20.8	20.2
	1.25-2.0	20.8	20.4
	2.0-3.0	20.8	20.6

Approval VDE, UL

Double pole versions available

Features

- ROHS compliant
- Housing material:
Nylon #66 UL 94V-2
- Rocker material:
Nylon #66 UL 94V-2
- Terminal material:
Copper alloy SN or AG plated
- Contact material:
AgNi (15) alloy plated

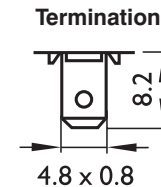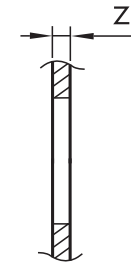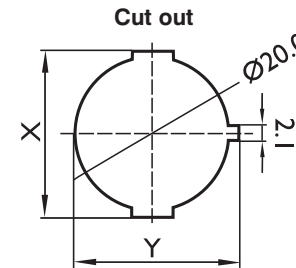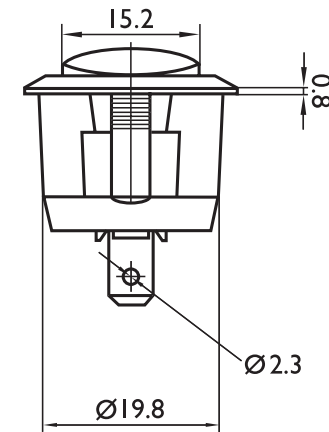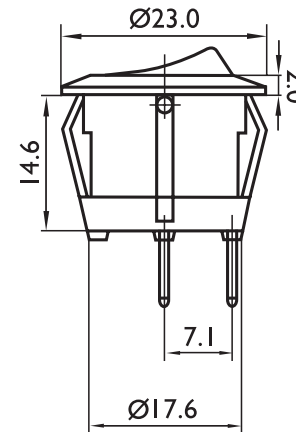

ALAN BUTCHER COMPONENTS LTD

Alan Butcher Components Ltd

Unit 1 Beechwood Clump Farm Industrial Estate Tin Pot Lane Blandford Dorset DT11 7TD

Telephone 01258 456360 Facsimile 01258 459194 Email sales@abcomponents.co.uk

www.abcomponents.co.uk



BS EN ISO 9001 Certification No 5239