



CHARACTERISTICS:

Material of shell: steel
Plating of shell: tin
Packaging: 100 pieces

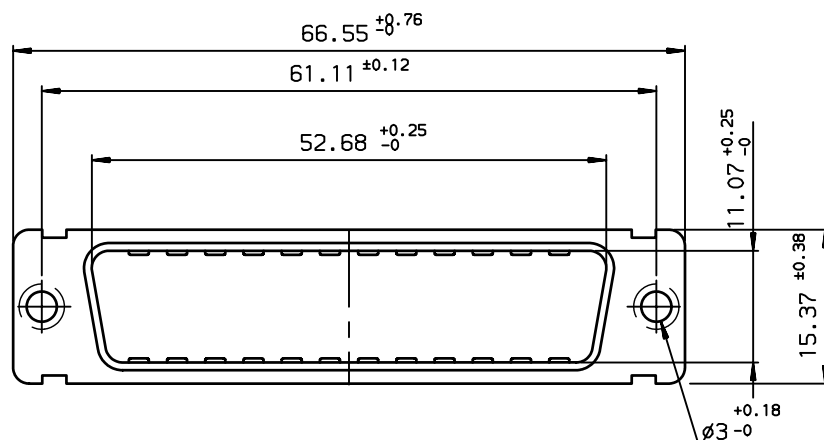

section A-A

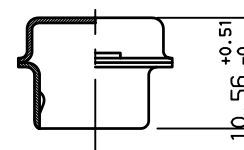

Part number 86553117TLF

European Views

www.fciconnect.com		surface ISO 1302	tolerance std ISO 406 ISO 1101	projection A3	mm
		TOLERANCES UNLESS OTHERWISE SPECIFIED		size	Scale
Dr	JARRY	2002/05/03	ANGULAR	0.X	±0.1
Eng	PESSON	2002/05/03	LINEAR	0.XX	±0.1
Chr	LEGARE	2002/05/03	0.XX' ±2'	0.XXX	±0.1
Appr	LEGARE	2002/05/03	Product family	D-SUB	Spec ref -
FCI		METAL CAPS		catLog no	Rev.
		SHELL 50 D SUB ACCESSORIES		C01-8655-1560	D
				CUSTOMER	sheet 1 of 1

NOTE: RoHS INFORMATIONS

- The "LF" products meet European union Directives and other country regulations as described in GS-22-008.
- Plating Sn (pure bright) over copper
- Packaging spec: see GS-14-920

rev	ecn no	dr	date
A	-	JAR	2002/05/03
B	LS05-0026	MPE	2005/07/08
C	LS06-0101	MPE	2006/06/19
D	LS09-0006	PCR	2009/01/08
-	-	-	-
-	-	-	-
-	-	-	-

REV F - 2006-04-17