


 R35 : D-SUB CRIMP TYPE

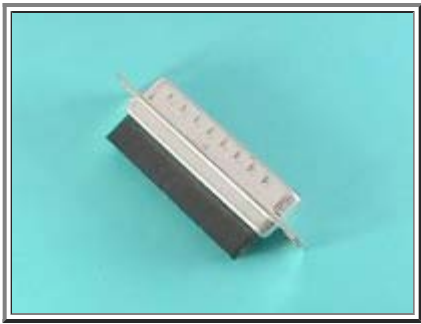

MATERIAL

Insulator: PBT + GF (UL94V-0)
Contact: Brass or Phosphor Bronze
RoHS compliant

SPECIFICATION

Contact Resistance: 30? Max. AT 1 AMP
Insulator Resistance: 1,000? Min. AT 500V DC
Current Rating: 1 AMP
Operating Temperature: -55?FJ TO +105?FJ
Dielectric Withstanding Vol.: 500 Vac Rms Min.