


- $\frac{1}{4}$  Wavelength **Whip** Antenna
- Rugged Flexible Plastic Finish.
- Available as BNC, SMA-Plug, M4 Screw Fixing
- Available as Straight or Right Angle
- Omni-Directional Design
- 50ohm Impedance
- Operating Temp  $-30$  to  $+60^{\circ}\text{C}$
- Insulation resistance  $500\text{M}\Omega$  @ $500\text{Vdc}$




## Applications

- General Low Power Radio
- M2M Applications
- Telemetry



## Mechanical Dimensions

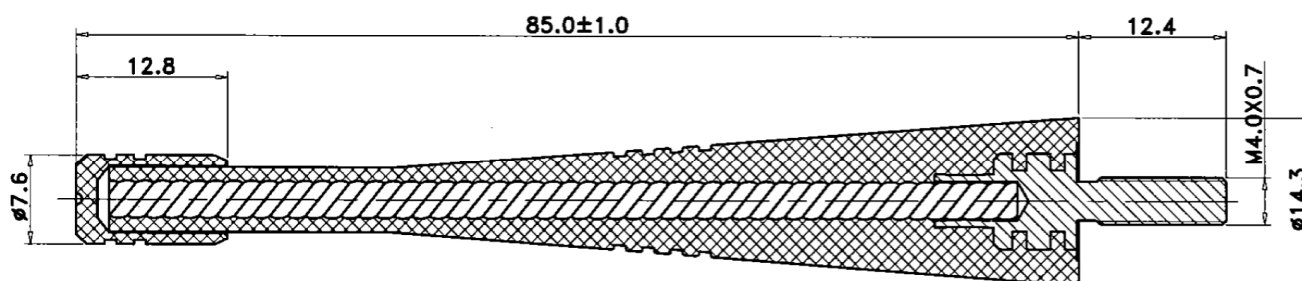

## Performance / VSWR Plot

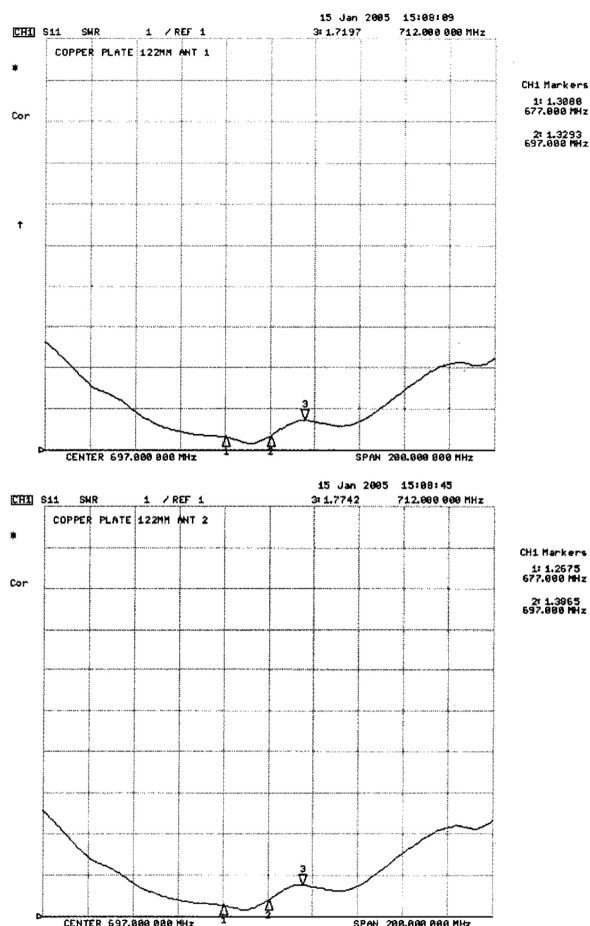

## Easy PCB Mount Terminal 'SCRTM4RA'

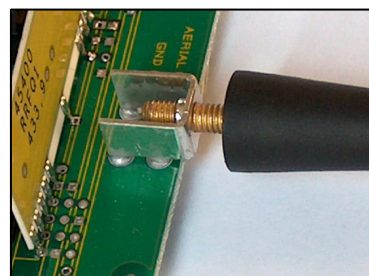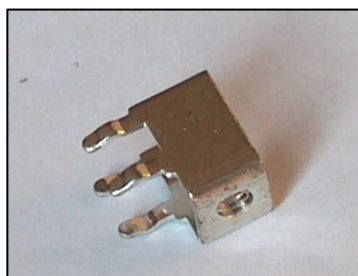

SCRTM4RA is a PCB Mounting terminal which accept any M4 screw thread antenna. For further data please see DS-SCRTM4RA

R F Solutions Ltd.,  
Unit 21, Cliffe Industrial Estate,  
Lewes, E. Sussex. BN8 6JL. England.

Email : [sales@rfsolutions.co.uk](mailto:sales@rfsolutions.co.uk) <http://www.rfsolutions.co.uk>

Tel: +44 (0)1273 898 000 Fax: +44 (0)1273 480 661