


PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [19211-0004](#)
Status: **Active**
Overview: [Wire Pins](#)
Description: Krimptite™ Wire Pin Terminal for 22-18 AWG Wire, Mylar Tape Carrier

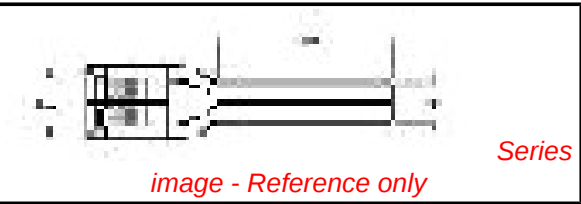

Documents:
[Drawing \(PDF\)](#) [Product Specification PS-19902-015 \(PDF\)](#)
[Product Specification PS-19902-011 \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

CSA	LR18689
UL	E32244

General

Product Family	Crimp Terminals
Series	19211
Application	Power
Comments	Pin Length 9.91mm
Crimp Quality Equipment	Yes
Overview	Wire Pins
Product Name	Wire Pin

Physical

Gender	Male
Material - Metal	Copper
Material - Plating Mating	Tin
Material - Plating Termination	Tin
Packaging Type	Adhesive Tape on Reel
Plating min - Mating	0.762µm
Plating min - Termination	0.762µm
Termination Interface: Style	Crimp or Compression
Wire Insulation Diameter	1.52mm max.
Wire Size AWG	18, 19, 20, 22
Wire Size mm²	22-18

Material Info

Old Part Number	WP-1218T
UPC	800753053212

Reference - Drawing Numbers

Product Specification	PS-19902-011, PS-19902-015
Sales Drawing	SD-19211-002

EU RoHS
ELV and RoHS
Compliant
REACH SVHC
Contains SVHC: No
Low-Halogen Status
Low-Halogen

China RoHS



Need more information on product environmental compliance?

Email productcompliance@molex.com
For a multiple part number RoHS Certificate of Compliance, [click here](#)

Please visit the [Contact Us](#) section for any non-product compliance questions.

Search Parts in this Series
[19211Series](#)

Application Tooling | FAQ
Tooling specifications and manuals are found by selecting the products below. Crimp Height Specifications are then contained in the Application Tooling Specification document.

Global	
Description	Product #
Mini-Mac™ Applicator	0638853800
ATP Tooling Kit for ATP-100 and ATP-300 Series Air Crimping Press for Mylar Tape Mounted Terminals	0190270034